


Subminiatur - Glühlampen - Wire Terminal

T^{3/4}

(2,5 x 6,5 mm)


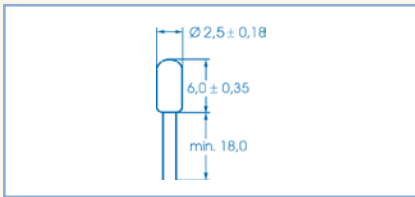


Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...	Preis je 100 in EURO
4 V	115 mA	0,5 W	21090415	368092	
5 V	60 mA	0,3 W	21090560	369808	
	80 mA	0,4 W	21090580	369815	
	115 mA	0,6 W	21090515	360003	
6 V	25 mA	0,15 W	21090625	368108	
12 V	25 mA	0,3 W	21091225	368115	
	50 mA	0,6 W	21091250	369822	
24 V	20 mA	0,48 W	21092420	369839	

Subminiatur - Glühlampen - Wire Terminal

T1

(3,2 x 6,5 mm)

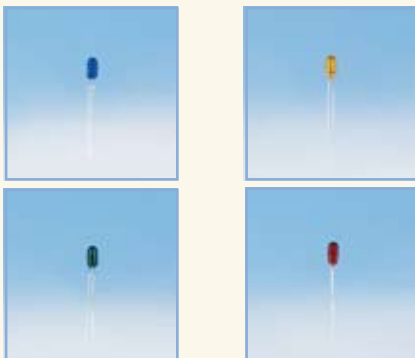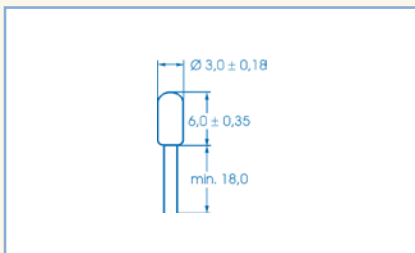

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...	Preis je 100 in EURO
1,5 V	75 mA	0,11 W	21109157	369846	
2,5 V	65 mA	0,16 W	21109255	368047	
3 V	12 mA	0,04 W	21109312	360034	
	40 mA	0,12 W	21109340	368306	
	115 mA	0,35 W	21109315	368122	
5 V	21 mA	0,11 W	21109521	369853	
	30 mA	0,15 W	21109530	369860	
	40 mA	0,2 W	21109540	368313	
	60 mA	0,3 W	21109560	369877	
	115 mA	0,6 W	21109515	369884	
	125 mA	0,63 W	21109525	369891	
6 V	25 mA	0,15 W	21109615	368139	
	40 mA	0,24 W	21109640	368320	
	50 mA	0,25 W	21109650	369907	
	60 mA	0,36 W	21109660	369914	
	70 mA	0,42 W	21109670	369921	
	115 mA	0,7 W	21109615	360041	
	80 mA	0,64 W	21109880	368337	
12 V	30 mA	0,36 W	21109123	369938	
	40 mA	0,48 W	21101240	369945	
	40 mA	0,48 W	2110124B	368009	
	40 mA	0,48 W	2110124G	368016	
	40 mA	0,48 W	2110124R	368023	
	40 mA	0,48 W	2110124Y	368030	
	40 mA	0,48 W	21109124	368344	
	40 mA	0,56 W	21109144	368351	
	50 mA	0,6 W	21109125	369952	
	60 mA	0,72 W	21109126	369969	
14 V	80 mA	1,12 W	21109148	369976	
18 V	21 mA	0,38 W	21109181	368146	
	26 mA	0,47 W	21109182	369983	
24 V	20 mA	0,48 W	21109242	369990	
28 V	24 mA	0,67 W	21109282	369099	
36 V	20 mA	0,72 W	21109362	368153	