

Subminiatur - Glühlampen - Pisello

WT 20 mm


(5 x 20 mm)



Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
3V	140mA	0,42W	00900314	368054
6V	100mA	0,60W	00900610	368061
12V	40mA	0,48W	00901242	368290
	80mA	0,96W	00901281	368078
24V	40mA	0,96W	00902442	368085

Subminiatur - Glühlampen - BI-PIN - Xenon T1 Superhell - reinweiß

(3,5 x 10,5 mm)

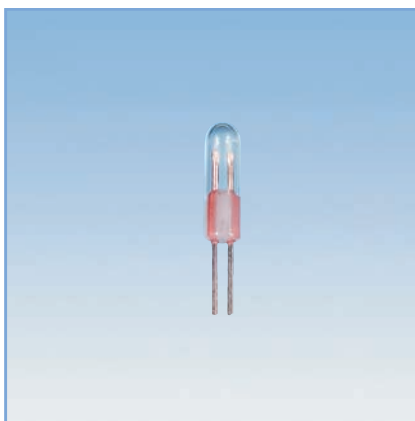


Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
1,35V	360mA	0,50W	20710136	360157
2,4V	420mA	1,0W	20710242	360164
2,6V	600mA	1,56W	20710260	360188
2,7V	310mA	0,84W	20710231	360195
3,0V	300mA	0,9W	20710330	360300
3,6V	340mA	1,22W	20710334	360171

(Stiftsockelabstand 1,27 mm)

Subminiatur

Subminiatur - Glühlampen - BI-PIN - Xenon T1^{1/4} Superhell - reinweiß

(4,15 x 8 mm)

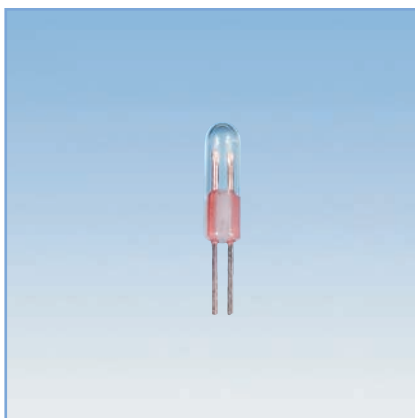


Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
1,35V	360mA	0,50W	20810136	360201
2,4V	420mA	1,0W	20810242	360218
2,6V	600mA	1,56W	20810260	360232
2,7V	310mA	0,84W	20810231	360249
3,6V	340mA	1,22W	20810334	360225

(Stiftsockelabstand 1,27 mm)

Subminiatur - Glühlampen - BI-PIN - Xenon T1^{1/2} Superhell - reinweiß

(5 x 13 mm)

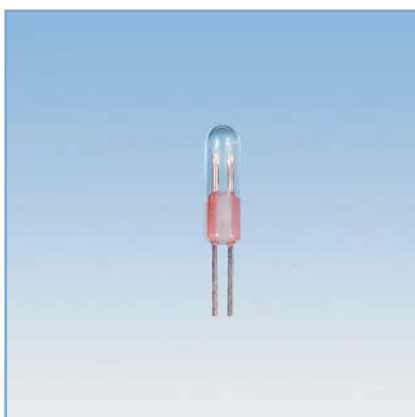

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
1,35V	360mA	0,5W	20920136	360256
2,4V	420mA	1,0W	20920242	360263
2,6V	600mA	1,56W	20920260	360287
2,7V	310mA	0,84W	20920231	360294
3,0V	300mA	0,90W	20920330	360355
3,6V	340mA	1,22W	20920334	360270

(Stiftsockelabstand 2,54 mm)