

## Subminiatur - Glühlampen - Pisello

WT 20 mm


(5 x 20 mm)



Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
3V	140mA	0,42W	<b>00900314</b>	368054
6V	100mA	0,60W	<b>00900610</b>	368061
12V	40mA	0,48W	<b>00901242</b>	368290
	80mA	0,96W	<b>00901281</b>	368078
24V	40mA	0,96W	<b>00902442</b>	368085

## Subminiatur - Glühlampen - BI-PIN - Xenon T1 Superhell - reinweiß

(3,5 x 10,5 mm)

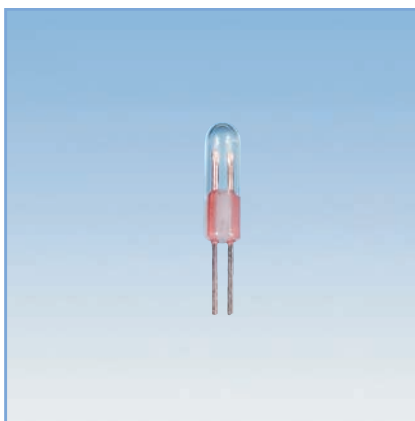


Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
1,35V	360mA	0,50W	<b>20710136</b>	360157
2,4V	420mA	1,0W	<b>20710242</b>	360164
2,6V	600mA	1,56W	<b>20710260</b>	360188
2,7V	310mA	0,84W	<b>20710231</b>	360195
3,0V	300mA	0,9W	<b>20710330</b>	360300
3,6V	340mA	1,22W	<b>20710334</b>	360171

(Stiftsockelabstand 1,27 mm)

Subminiatur

## Subminiatur - Glühlampen - BI-PIN - Xenon T1<sup>1/4</sup> Superhell - reinweiß

(4,15 x 8 mm)

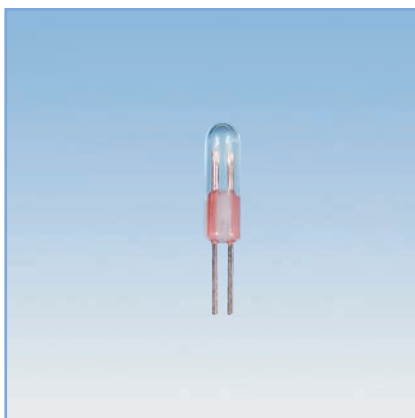


Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
1,35V	360mA	0,50W	<b>20810136</b>	360201
2,4V	420mA	1,0W	<b>20810242</b>	360218
2,6V	600mA	1,56W	<b>20810260</b>	360232
2,7V	310mA	0,84W	<b>20810231</b>	360249
3,6V	340mA	1,22W	<b>20810334</b>	360225

(Stiftsockelabstand 1,27 mm)

## Subminiatur - Glühlampen - BI-PIN - Xenon T1<sup>1/2</sup> Superhell - reinweiß

(5 x 13 mm)

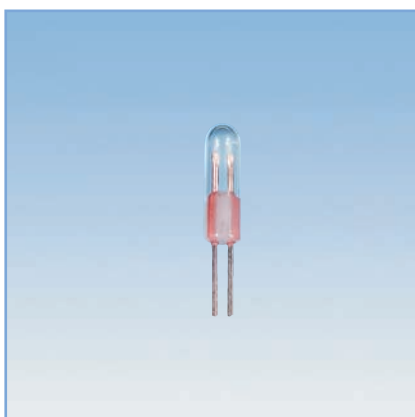

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
1,35V	360mA	0,5W	<b>20920136</b>	360256
2,4V	420mA	1,0W	<b>20920242</b>	360263
2,6V	600mA	1,56W	<b>20920260</b>	360287
2,7V	310mA	0,84W	<b>20920231</b>	360294
3,0V	300mA	0,90W	<b>20920330</b>	360355
3,6V	340mA	1,22W	<b>20920334</b>	360270

(Stiftsockelabstand 2,54 mm)