

## Liliput-Glimmlampen T2<sup>3/4</sup>

LG

Socket E10

(10 x 25 mm)



Bild 1

Spannung	Typ	Artikel-Nr.	EAN 4021553...
115V	LG 204	00012040	060002
230V	LG 234	00012340	060019
	LG 234/1 rot getaucht	00012341	060026
	LG 234/3 grün LST (Neon)	00012343	060033
400V	LG 274	00012740	060064
<b>Lampenzieher T2<sup>3/4</sup></b>		<b>01909006</b>	

## Liliput-Glimmlampen T2<sup>3/4</sup>

LG

Socket BA9s

(10 x 25 mm)



Bild 2

Spannung	Typ	Artikel-Nr.	EAN 4021553...
115V	LG 203	00012030	061009
230V	LG 233	00012330	061016
	LG 233/1 rot getaucht	00012331	061023
400V	LG 273	00012730	061054
<b>Lampenzieher T2<sup>3/4</sup></b>		<b>01909006</b>	

## Zwerg-Glimmlampen T3<sup>1/4</sup>

ZG

Socket E10

(10 x 28 mm)



Bild 3

Spannung	Typ	Artikel-Nr.	EAN 4021553...
115V	ZG 204	00022040	060101
230V	ZG 234	00022340	060118
	ZG 234/3 grün LST (Neon)	00022343	060132
	ZG 274	00022740	060163
<b>Lampenzieher T3<sup>1/4</sup></b>		<b>01909007</b>	

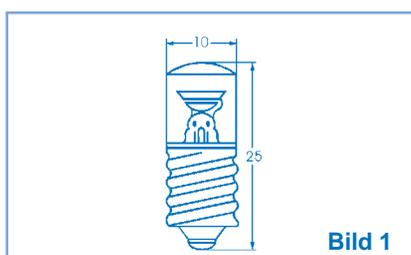


Bild 1

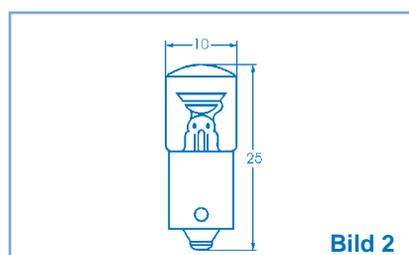


Bild 2

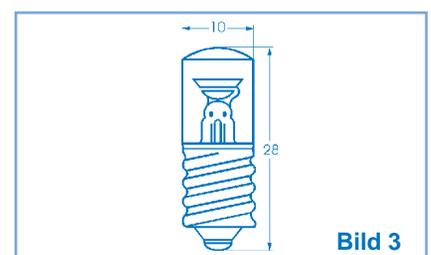


Bild 3

Abweichende Spannungen und Leistungen auf Anfrage lieferbar (VPE 100 Stück) !