

## Taschenlampenbirnen

NF-Breitlinse

Socket E10

(9 x 25 mm)



Bild 1

VPE 10 Stück

Spannung	Strom	Artikel-Nr.	EAN 4021553....
2,2V	0,25A	00612225	410005
	0,3A	00612230	410012
	0,4A	00612240	410029
2,4V	0,3A	00612430	410036
	0,4A	00612440	410395
	0,5A	00612450	410043
3,3V	0,3A	00613330	410050
3,7V	0,3A	00613730	410067
4,8V	0,3A	00614830	524712

## Taschenlampenbirnen

NF-Breitlinse

Socket P13,5s

(11,5 x 28 mm)



Bild 2

VPE 10 Stück

Spannung	Strom	Artikel-Nr.	EAN 4021553....
2,2V	0,25A	00622225	419008
	0,3A	00622230	419015
	0,4A	00622240	419022
2,5V	0,3A	00622530	419039
3,7V	0,3A	00623730	419046

## Taschenlampenbirnen

Spitzlinse

Socket E10

(9,5 x 22 mm)



Bild 3

VPE 10 Stück

Spannung	Strom	Artikel-Nr.	EAN 4021553....
1,2V	0,22A	00631222	410104
2,2V	0,18A	00632218	410111
	0,25A	00632225	410128
2,4V	0,60A	00632260	430041
	0,3A	00632430	016535
2,5V	0,2A	00632520	410135
	0,3A	00632530	410142
3,5V	0,2A	00633520	410173
3,7V	0,3A	00633730	410159

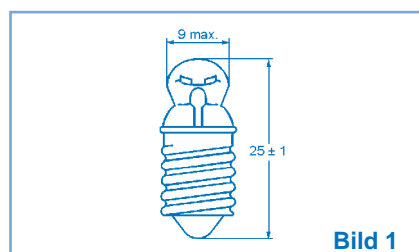


Bild 1

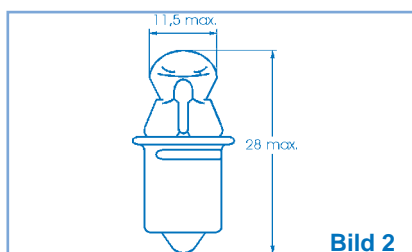


Bild 2

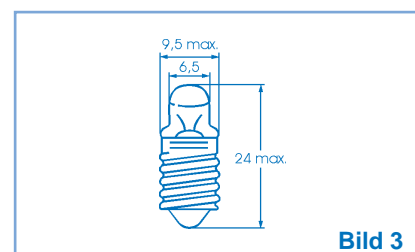


Bild 3