


Halogen-Glühlampen für Taschenlampen

Socket E10

(9,3 x 31 mm)

Spannung	Strom	Artikel-Nr.	EAN 4021553....
2,5V	0,5A	01702550	420066
2,8V	0,5A	01702850	420073
	0,85A	01702885	420202
3,75V	0,75A	01703775	420080
4,0V	0,5A	01704050	420097
	0,85A	01704085	420219
4,8V	0,5A	01704850	420158
	1,0A	01704810	420226
5,2V	0,5A	01705250	420233
	0,85A	01705285	420240
5,5V	1,0A	01705510	420257
6,0V	0,4A	01706040	420264
	0,7A	01706070	420165
	1A	01706010	420172
6,5V	0,7A	01706570	420271
7,2V	0,85A	01707285	420288

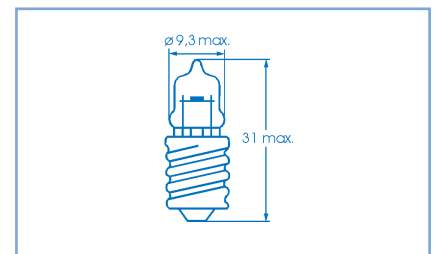

Halogen-Glühlampen für Taschenlampen

Socket P13,5s

(9,3 x 31 mm)

Spannung	Strom	Artikel-Nr.	EAN 4021553....
2,4V	0,83A	01692483	429144
2,5V	0,5A	01692550	429151
2,8V	0,5A	01692850	429168
	0,85A	01692885	429304
3,75V	0,75A	01693775	429175
4,0V	0,5A	01694050	429182
	0,85A	01694085	429311
	1A	01694010	429199
4,8V	0,5A	01694850	429328
	0,85A	01694885	429601
	1,0A	01694810	429335
5,2V	0,5A	01695250	429342
	0,85A	01695285	429359
5,5V	1,0A	01695510	429366
6,0V	0,4A	01696040	429373
	1A	01696010	429274
6,5V	0,7A	01696570	429380
7,2V	0,85A	01697285	429397

