

Subminiatur - Glühlampen - BI-PIN

T1

(3,17 x 9,5 mm)

| Spannung | Strom | Leistung | Artikel-Nr. | EAN 4021553... |
|----------|-------|----------|-----------------|-------------------|
| 2,5V | 200mA | 0,5W | 21012200 | 368399 |
| 5V | 60mA | 0,3W | 21010560 | 369501 |
| | 115mA | 0,58W | 21015115 | 368405 |
| 12V | 60mA | 0,72W | 21011260 | 369525 |
| 14V | 65mA | 0,9W | 21011465 | 368412 |
| 28V | 24mA | 0,67W | 21012824 | 369532 |
| | 40mA | 1,12W | 21012840 | 368429 |



Bild 1

(Stiftsockelabstand 1,27 mm)

Subminiatur - Glühlampen - BI-PIN

T1

(3,17 x 9,5 mm)

| Spannung | Strom | Leistung | Artikel-Nr. | EAN 4021553... |
|----------|-------|----------|-----------------|-------------------|
| 5V | 60mA | 0,3W | 21020560 | 369235 |
| | 115mA | 0,58W | 21025115 | 369204 |
| 6V | 115mA | 0,69W | 21026115 | 369792 |
| 12V | 60mA | 0,72W | 21021260 | 369211 |
| 18V | 26mA | 0,47W | 21021826 | 369259 |
| 24V | 20mA | 0,48W | 21022420 | 369242 |
| 28V | 24mA | 0,67W | 21022824 | 369228 |
| 36V | 20mA | 0,72W | 21023620 | 360065 |



Bild 2

(Stiftsockelabstand 2,54 mm)

Subminiatur

Subminiatur - Glühlampen - BI-PIN

T1¼

(4,12 x 14 mm)

| Spannung | Strom | Leistung | Artikel-Nr. | EAN 4021553... |
|----------|-------|----------|-----------------|-------------------|
| 6V | 60mA | 0,36W | 21420660 | 369341 |
| | 80mA | 0,48W | 21420680 | 360010 |
| 12V | 40mA | 0,48W | 21421240 | 369327 |
| | 50mA | 0,6W | 21421250 | 368436 |
| 14V | 80mA | 1,12W | 21421480 | 368443 |
| 24V | 35mA | 0,84W | 21422435 | 369303 |
| 28V | 24mA | 0,67W | 21422824 | 369334 |
| | 40mA | 1,12W | 21422840 | 369310 |
| 36V | 20mA | 0,72W | 21423620 | 368450 |



Bild 3

(Stiftsockelabstand 2,54 mm)

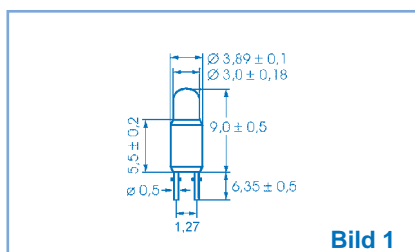


Bild 1

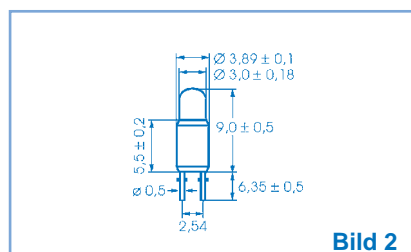


Bild 2

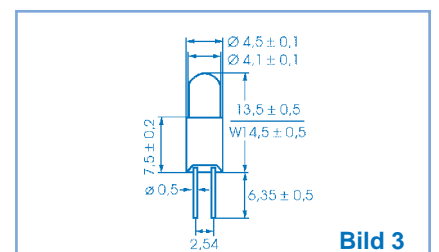


Bild 3

Abweichende Spannungen und Leistungen auf Anfrage lieferbar (VPE 100 Stück)!