


**Subminiatur - Glühlampen - BI-PIN**

T<sup>3/4</sup>

(5,7 x 15,87 mm)

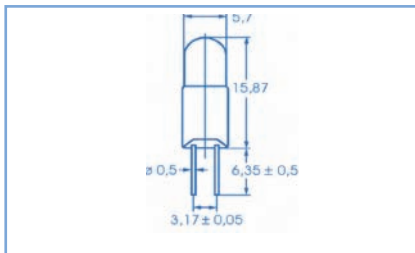

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
2,5V	350mA	0,88W	<b>21332535</b>	366814
3V	15mA	0,05W	<b>21330315</b>	366821
5V	60mA	0,3W	<b>21330560</b>	366838
6V	40mA	0,24W	<b>21330640</b>	369440
6,3V	200mA	1,26W	<b>21336320</b>	369419
12V	40mA	0,48W	<b>21331240</b>	369457
	60mA	0,72W	<b>21331260</b>	368467
14V	80mA	1,12W	<b>21331480</b>	369426
18V	40mA	0,72W	<b>21331840</b>	368474
28V	24mA	0,67W	<b>21332824</b>	369594
	40mA	1,12W	<b>21332840</b>	369402
48V	25mA	1,2W	<b>21334825</b>	369464
60V	20mA	1,2W	<b>21336020</b>	369433

(Stiftsockelabstand 3,17 mm)



Subminiatur

**Subminiatur - Glühlampen**

T<sup>3/4</sup> Sockel MM3s/6

(Micro Midget Flange)

(2,8 x 9,1 mm)

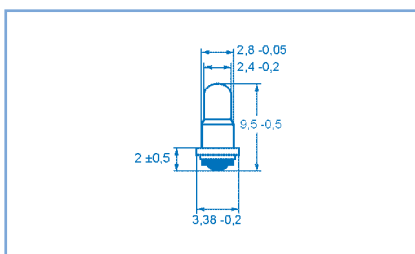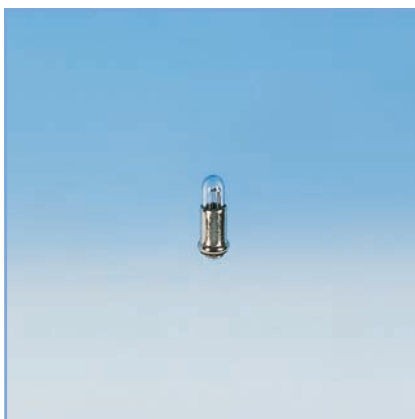

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
2V	50mA	0,1W	<b>21500250</b>	366449
5V	60mA	0,3W	<b>21500560</b>	366456
	115mA	0,58W	<b>21500511</b>	366463
6V	50mA	0,3W	<b>21500650</b>	366470
12V	50mA	0,6W	<b>21501250</b>	366487
14V	30mA	0,42W	<b>21501430</b>	366494
16V	30mA	0,48W	<b>21501631</b>	366531
24V	20mA	0,48W	<b>21502420</b>	366098
28V	20mA	0,56W	<b>21502820</b>	366548

Siehe auch Spielzeuglampen Seite 58, 59

**INFO**

**Subminiatur-Glühlampen auch in:**

- T<sup>1/2</sup> Wire Terminal ( ∅ 1,7+0,1 x 5+1 mm )
- T<sup>3/4</sup> BI-PIN ( ∅ 2,4+0,1 x 7+1 mm ) Stiftsockelabstand 1,27 mm

bis 24V lieferbar.

Abweichende Spannungen und Leistungen auf Anfrage lieferbar (VPE 100 Stück) !