


Subminiatur - Glühlampen - BI-PIN

T³/₄

(5,7 x 15,87 mm)

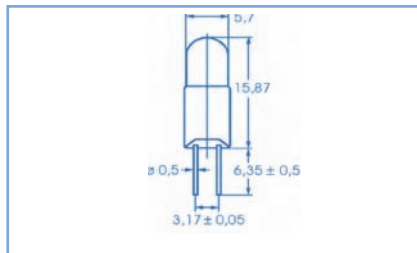

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
2,5V	350mA	0,88W	21332535	366814
3V	15mA	0,05W	21330315	366821
5V	60mA	0,3W	21330560	366838
6V	40mA	0,24W	21330640	369440
6,3V	200mA	1,26W	21336320	369419
12V	40mA	0,48W	21331240	369457
	60mA	0,72W	21331260	368467
14V	80mA	1,12W	21331480	369426
18V	40mA	0,72W	21331840	368474
28V	24mA	0,67W	21332824	369594
	40mA	1,12W	21332840	369402
48V	25mA	1,2W	21334825	369464
60V	20mA	1,2W	21336020	369433

(Stiftsockelabstand 3,17 mm)



Subminiatur

Subminiatur - Glühlampen

T³/₄ Sockel MM3s/6

(Micro Midget Flange)

(2,8 x 9,1 mm)

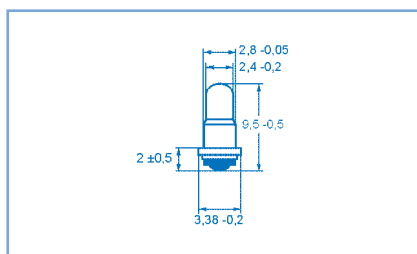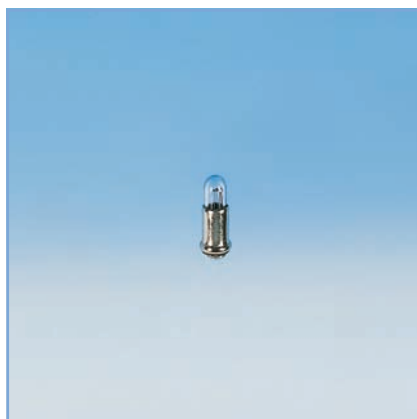

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...
2V	50mA	0,1W	21500250	366449
5V	60mA	0,3W	21500560	366456
	115mA	0,58W	21500511	366463
6V	50mA	0,3W	21500650	366470
12V	50mA	0,6W	21501250	366487
14V	30mA	0,42W	21501430	366494
16V	30mA	0,48W	21501631	366531
24V	20mA	0,48W	21502420	366098
28V	20mA	0,56W	21502820	366548

Siehe auch Spielzeuglampen Seite 58, 59

INFO

Subminiatur-Glühlampen auch in:

- T¹/₂ Wire Terminal (∅ 1,7+0,1 x 5+1 mm)
- T³/₄ BI-PIN (∅ 2,4+0,1 x 7+1 mm) Stiftsockelabstand 1,27 mm

bis 24V lieferbar.

Abweichende Spannungen und Leistungen auf Anfrage lieferbar (VPE 100 Stück) !