


Axiale Ø 2 mm-Stecker


SLS205-L SLS205-L/N

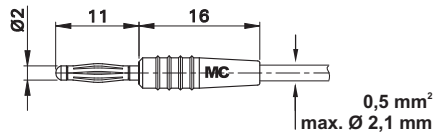

In-line Ø 2 mm Plugs



 Fiches Ø 2 mm droites



LS205-L
LS205-L/N



MA 136

Axialer Ø 2 mm-Stecker mit federnder Kontakt-lamelle für die Selbstmontage von Messleitungen. Vernickelte und vergoldete Version. **Lötanschluss.**

In-line Ø 2 mm plug with spring-loaded Multilam for self-assembly of test leads. Nickel-plated and gold-plated versions available. **Solder connection.**

Fiche à lamelles Ø 2 mm droite, destinée à la confection de cordons de mesure. Disponibles en versions dorée et nickelée. **Raccord à souder.**

Typ Type Type	Best.-Nr. Order No. N° de Cde	Bemessungsspannung / -strom Rated voltage / current Tension / intensité assignée	Einzelteile: Knüpfhülle / Stecker Component parts: Insulator / Plug Pièces détachées : Capuchon isolant / Fiche		*Farben *Colours *Couleurs									
SLS205-L	22.2618*	30 V _{AC} ~ 60 V _{DC} / max. 10 A	KT2-S, 22.2010-* / LS205-L, 22.1009	Au	<table border="1"> <tr> <td>21</td><td>22</td><td>23</td><td>24</td> </tr> <tr> <td>25</td><td>26</td><td>27</td><td>28</td><td>29</td> </tr> </table>	21	22	23	24	25	26	27	28	29
21	22	23	24											
25	26	27	28	29										
SLS205-L/N	22.2619*	30 V _{AC} ~ 60 V _{DC} / max. 10 A	KT2-S, 22.2010-* / LS205-L/N, 22.5029	Ni	<table border="1"> <tr> <td>21</td><td>22</td><td>23</td><td>24</td> </tr> <tr> <td>25</td><td>26</td><td>27</td><td>28</td><td>29</td> </tr> </table>	21	22	23	24	25	26	27	28	29
21	22	23	24											
25	26	27	28	29										