


**Axiale Ø 2 mm-Stecker**


**SLS205-L SLS205-L/N**

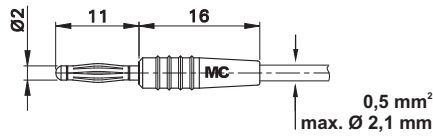

**In-line Ø 2 mm Plugs**



 **Fiches Ø 2 mm droites**



LS205-L  
LS205-L/N



MA 136

Axialer Ø 2 mm-Stecker mit federnder Kontakt-lamelle für die Selbstmontage von Messleitungen. Vernickelte und vergoldete Version. **Lötanschluss.**

In-line Ø 2 mm plug with spring-loaded Multilam for self-assembly of test leads. Nickel-plated and gold-plated versions available. **Solder connection.**

Fiche à lamelles Ø 2 mm droite, destinée à la confection de cordons de mesure. Disponibles en versions dorée et nickelée. **Raccord à souder.**

Typ Type Type	Best.-Nr. Order No. N° de Cde	Bemessungsspannung / -strom Rated voltage / current Tension / intensité assignée	Einzelteile: Knüpfhülle / Stecker Component parts: Insulator / Plug Pièces détachées : Capuchon isolant / Fiche		*Farben *Colours *Couleurs								
<b>SLS205-L</b>	<b>22.2618*</b>	30 V <sub>AC</sub> ~ 60 V <sub>DC</sub> / max. 10 A	KT2-S, 22.2010-* / LS205-L, 22.1009	<b>Au</b>	<table border="1"> <tr> <td>21</td> <td>22</td> <td>23</td> <td>24</td> </tr> <tr> <td>25</td> <td>26</td> <td>27</td> <td>28</td> </tr> </table>	21	22	23	24	25	26	27	28
21	22	23	24										
25	26	27	28										
<b>SLS205-L/N</b>	<b>22.2619*</b>	30 V <sub>AC</sub> ~ 60 V <sub>DC</sub> / max. 10 A	KT2-S, 22.2010-* / LS205-L/N, 22.5029	<b>Ni</b>	<table border="1"> <tr> <td>21</td> <td>22</td> <td>23</td> <td>24</td> </tr> <tr> <td>25</td> <td>26</td> <td>27</td> <td>28</td> </tr> </table>	21	22	23	24	25	26	27	28
21	22	23	24										
25	26	27	28										