

Steckzungen

Masse im Steckbereich
DIN 46342, Teil 1

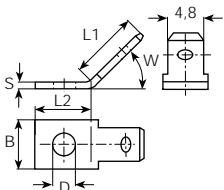
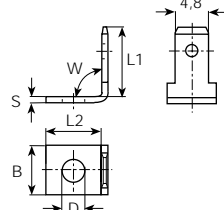
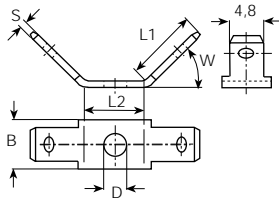
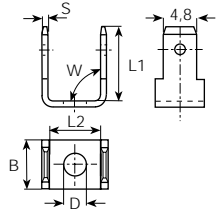
Languettes

Dimensions zone d'emboîtement selon
DIN 46342, partie 1

Tabs

Dimensions in the tab sector
DIN 46342, part 1

4,8 mm

45° + 90°	øD mm	B mm	L1 mm	L2 mm	W mm	S mm	Werkstoff Matière Material	Stand- Packg.	Artikel-Nr. Numéro d'article Part-No.
	2.8	6.5	10	7.5	45°	0.8	MS	1000	3811.6()
	3.2	6.5	10	7.5	45°	0.8	MS	1000	3815.6()
	3.7	6.5	10	7.5	45°	0.8	MS	1000	3819.6()
	4.3	6.5	10	7.5	45°	0.8	MS	1000	3823.6()
	2.8	6.5	10	7.5	90°	0.5	ST	1000	381205.9()
	2.8	6.5	10	7.5	90°	0.8	MS	1000	381208.6()
	3.2	6.5	10	7.5	90°	0.8	MS	1000	3816.6()
	3.7	6.5	10	7.5	90°	0.8	MS	1000	3820.6()
	4.3	6.5	10	7.5	90°	0.8	MS	1000	3824.6()
	3.2	6.5	9.5	8.5	45°	0.8	MS	1000	381745.6()
	3.7	6.5	9.5	8.5	45°	0.8	MS	1000	3821L4508.6()
	4.2	6.5	9.5	8.5	45°	0.5	MS	1000	3821R4505.6()
	4.2	6.5	9.5	8.5	45°	0.8	MS	1000	3821R4508.6()
	3.2	6.5	10	7.5	90°	0.8	MS	1000	381790.6()
	4.2	6.5	10	7.5	90°	0.8	MS	1000	3821R90.6()