

## Steckerstifte

## Fiches de goupille

## Seamless pins

Werkstoff:

MS = Messing

Matière:

MS = laiton

Material:

MS = brass

Oberflächenbehandlung:

bl = blank  
ag = versilbert  
au = vergoldet  
ni = vernickelt  
sn = verzinkt

Code

(0)  
(1)  
(2)  
(5)  
(8)

Traitements de surface:

bl = brut  
ag = argenté  
au = doré  
ni = nickelé  
sn = étamé

Code

(0)  
(1)  
(2)  
(5)  
(8)

Surface-plating:

bl = clean  
ag = silver-plated  
au = gold-plated  
ni = nickel-plated  
sn = tin-plated

Code


(0)  
(1)  
(2)  
(5)  
(8)

Bestellbeispiel:


Exemple de commande:

Example of order:

1364A.68  
(1364 A MS sn)

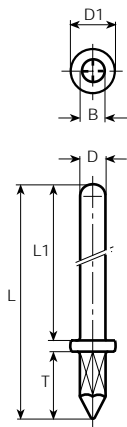

Print Trou Hole	D mm	L mm	T mm	L1 mm	D1 mm	B mm	Werkstoff Matière Material	Stand.- Packg. 2'000	Artikel-Nr. Numéro d'article Part-No.	Werkzeug Outils Tools		
∅ 1	∅ 1	9.5	2.4	6.6	∅ 1.8	1.05	MS	•	1364A.6( )	1035/85		
		10	3.5	6	∅ 1.8	1.05	MS	•	1364E.6( )	1035/85		
		14.1	3	10.6	∅ 1.8	1.05	MS	•	1364S.6( )	1035/86		
		10.8	4.5	5.8	∅ 1.8	1.05	MS	•	1364C.6( )	1035/85		
		11	4.5	6	∅ 1.8	1.05	MS	•	1364G.6( )	1035/85		
		11.5	3	8	∅ 1.8	1.05	MS	•	1364B.6( )	1035/86		
		12.5	5	7	∅ 1.8	1.05	MS	•	1364F.6( )	1035/85		
		15.5	3	12	∅ 1.8	1.05	MS	•	1364D.6( )	1035/86		
		20	3.5	16	∅ 1.8	1.05	MS	5000	1364T.6( )	1035/86		
		18	6	11.5	∅ 1.8	1.05	MS	•	1364R.6( )	1035/86		
		∅ 1.3	∅ 1.3	11	4.5	6	∅ 2.5	1.4	MS	1000	1365A.6( )	1035/84
				12.5	3.8	8.1	∅ 2.5	1.4	MS	1000	1365F.6( )	1035/83
				13.5	5	8	∅ 2.5	1.4	MS	1000	1365B.6( )	1035/83
13.5	5.5			7.5	∅ 2.5	1.4	MS	1000	1365C.6( )	1035/83		
14.7	2.5			11.7	∅ 2.5	1.4	MS	1000	1365D.6( )	1035/83		
15.9	5.7			9.7	∅ 2.5	1.4	MS	1000	1365E.6( )	1035/83		
16	3			12.5	∅ 2.5	1.4	MS	1000	1365M.6( )	1035/83		
∅ 1.33	∅ 1.33	9.5	3.5	5.5	∅ 2.5	1.43	MS	•	1365.6( )	1035/84		

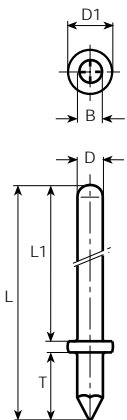

D mm	L mm	T mm	L1 mm	D1 mm	B mm	Werkstoff Matière Material	Stand.- Packg. 1'000	Artikel-Nr. Numéro d'article Part-No.	Werkzeug Outils Tools
∅ 1	10	3.5	6	∅ 1.8	∅ 1	MS	•	1364P.6( )	1035/85
	11	4.5	6	∅ 1.8	∅ 1	MS	•	1364K.6( )	1035/85
	15	8.5	6	∅ 1.8	∅ 1	MS	•	1364M.6( )	1035/85
	15.4	6	8.9	∅ 1.8	∅ 1	MS	•	1364H.6( )	1035/86
	15.4	9	5.9	∅ 1.8	∅ 1	MS	•	1364L.6( )	1035/85
∅ 1.3	16.2	5.9	9.8	∅ 2.5	∅ 1.3	MS	•	1365L.6( )	1035/83

Andere Abmessungen auf Anfrage  
Autres dimensions sur demande  
Further dimensions on request