


Artikel-Nr.: 741411

Bez.: Pfofen-Verbinder, 2x34-polig, Raster 1,27 mm, vergoldete Kontakte

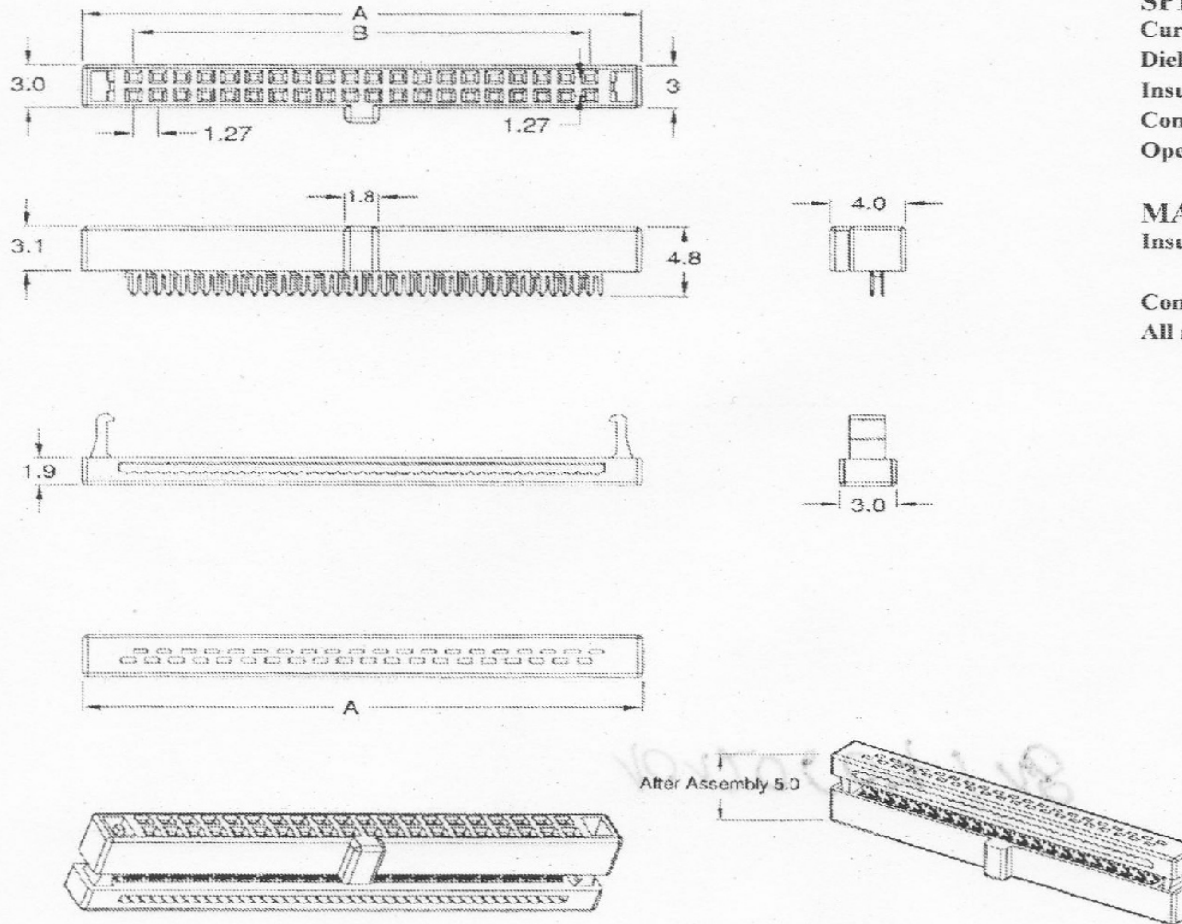

### SPECIFICATIONS

Current Rating: 0.5 Amp

Dielectric Withstand: 250V AC

Insulator Resistance: 1000 M $\Omega$  min.

Contact Resistance: 30m $\Omega$  Max.

Operating Temperature: -40 $^{\circ}$ c to + 105 $^{\circ}$ c

### MATERIALS

Insulator: Glass, UL94V-0

P.B.T

Contacts: Phosphor Bronze

All materials must be RoHS compliant.

No. of Contacts	Dimensions(mm)	
	A	B
06	8.01	2.54
08	9.28	3.81
10	10.55	5.08
12	11.82	6.35
14	13.09	7.62
16	14.36	8.89
20	16.90	11.43
22	18.17	12.70
26	20.71	15.24
30	23.25	17.78
34	25.79	20.32
40	29.60	24.13
44	32.14	26.67
50	35.95	30.48
60	42.30	36.83
68	47.38	41.91
80	55.00	49.53

# www.bkl-electronic.de

Technische Änderungen vorbehalten. Ausführungen können variieren. Sollten Sie ein Muster benötigen kontaktieren Sie uns bitte.

BKL-ELECTRONIC Kreimendahl GmbH • Märkenstück 14 • 58509 Lüdenscheid

Tel: +49 (0)2351-3621-0 • Fax: +49 (0)2351-3621-29 • info@bkl-electronic.de

