
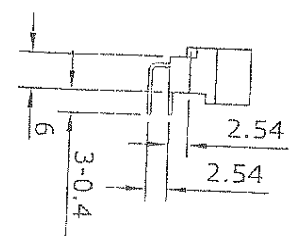


1 2 3 4 5 6

A

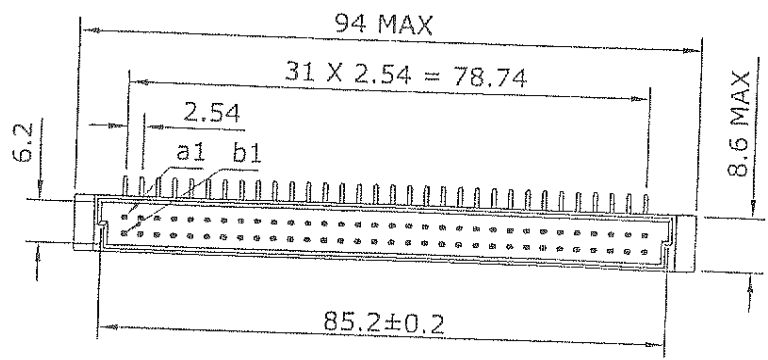


A

B

B

C

C


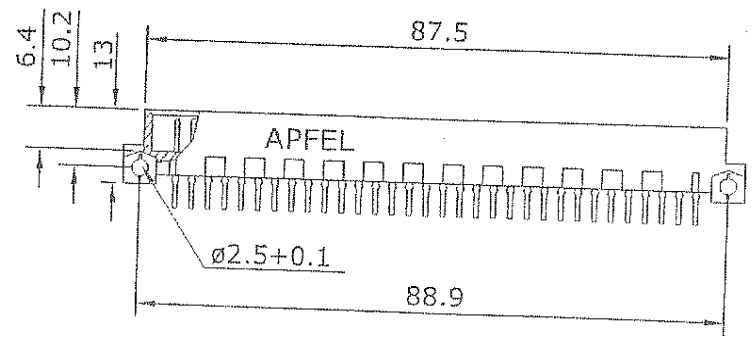


D

D

E

 E

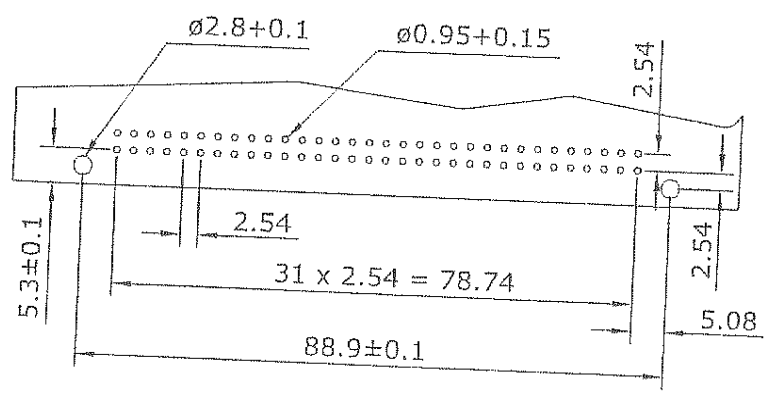

F

F

G

G

64poles = row a+b  
32poles = row a+b, all even

Current rating: 20°C, 2A  
70°C, 1A  
100°C, 0.5A

Operating voltage: 250V rms  
UL-File: E149341

Änderung	Datum	Name	Datum	Name	Benennung	
			Bearb. 06.03.02	Hellwig	DIN41612 Connector male, right angled, Type I  A-BM64abR A-BM32abR	
			Gep. 06.03.02	<i>(Signature)</i>		
			Norm.			
<b>ASSMANN</b> Electronic Components					Zeichnungsnummer	Blatt
					ASS 1262 CO	1/
					Ersatz für	Blatt

I

K

1 2 3 4 5 6 7