
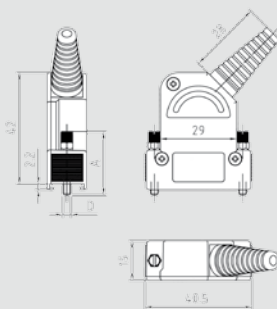
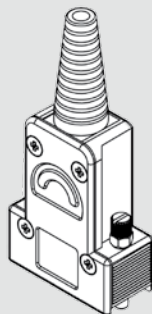
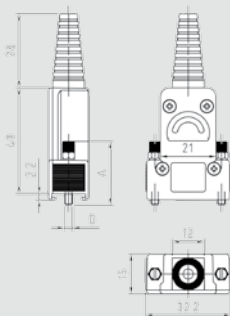


QuickMount Vollmetallhauben

QuickMount Die cast hoods

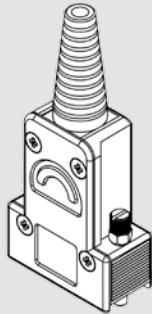

Abmessungen / Dimensions

Polzahl / Size			
9	40	25	32.2
15	42	28,5	46,5

Quickmount Vollmetallhauben-Serie 117: Kabelabgang 180°
QuickMount Die cast hoods series 117: cable exit 180°

	Kabelklemme intern Cable clamp internal	
9-polig	UNC 4-40	M3
Rändelschraube lang / long Knurled locking screw	117092DC50001	117093DC50001
Rändelschraube kurz / short knurled locking screw	117092DC24001	117093DC24001
Zylinder-Inbusschraube / allen screw	117092DC20001	117093DC20001
15-polig / 15 poles		
Rändelschraube lang / long Knurled locking screw	117152DC50001	117153DC50001
Rändelschraube kurz / short knurled locking screw	117152DC24001	117153DC24001
Zylinder-Inbusschraube / allen screw	117152DC20001	117153DC20001
	Crimpflansch und Kabelklemme extern Crimp flange and cable clamp external	
9-polig / 9 poles	UNC 4-40	M3
Rändelschraube lang / long Knurled locking screw	117090DC50001	117091DC50001
Rändelschraube kurz / short knurled locking screw	117090DC24001	117091DC24001
Zylinder-Inbusschraube / allen screw	117090DC20001	117091DC20001
15-polig / 15 poles		
Rändelschraube lang / long Knurled locking screw	117150DC50001	117151DC50001
Rändelschraube kurz / short knurled locking screw	117150DC24001	117151DC24001
Zylinder-Inbusschraube / allen screw	117150DC20001	117151DC20001

QuickMount Vollmetallhauben-Serie 147: Kabelabgang 45°
QuickMount Die cast hood series 147: cable exit 45°

	Kabelklemme intern cable clamp internal	
9-polig / 9 poles	UNC 4-40	M3
Rändelschraube kurz / short/long knurled locking screw	147092DC50001	147093DC50001
Rändelschraube kurz / short knurled locking screw	147092DC24001	147093DC24001
Zylinder-Inbusschraube / allen screw	147092DC20001	147093DC20001
15-polig / 15 poles		
Rändelschraube lang / long Knurled locking screw	147152DC50001	147153DC50001
Rändelschraube kurz / short knurled locking screw	147152DC24001	147153DC24001
Zylinder-Inbusschraube / allen screw	147152DC20001	147153DC20001
	Crimpflansch und Kabelklemme extern Crimp flange and cable clamp external	
9-polig / 9 poles	UNC 4-40	M3
Rändelschraube lang / long Knurled locking screw	147090DC50001	147091DC50001
Rändelschraube kurz / short knurled locking screw	147090DC24001	147091DC24001
Zylinder-Inbusschraube / allen screw	147090DC20001	147091DC20001
15-polig / 15 poles		
Rändelschraube lang / long Knurled locking screw	147150DC50001	147151DC50001
Rändelschraube kurz / short knurled locking screw	147150DC24001	147151DC24001
Zylinder-Inbusschraube / allen screw	147150DC20001	147151DC20001