


Maße für Muttern



Sechskantmuttern

DIN (ISO)	Maße	M 1	M 1,2	M 1,4	M 1,6	M 1,7*	M 2	M 2,3*	M 2,5
	m _{DIN/ISO}	0,8	1	1,2	1,3	1,4	1,6	1,8	2
	s _{DIN/ISO}	2,5	3	3	3,2	3,5	4	4,5	5
	Maße	M 2,6*	M 3	M 3,5	M 4	M 5	M 6	M 7	M 8
	m _{DIN/ISO}	2	2,4	2,8	3,2	4 / 4,7	5 / 5,2	5,5	6,5 / 6,8
	s _{DIN/ISO}	5	5,5	6	7	8	10	11	13
	Maße	M 10	M 12	M 14	M 16	M 18	M 20	M 22	M 24
	m _{DIN/ISO}	8 / 8,4	10 / 10,8	11 / 12,8	13 / 14,8	15 / 15,8	16 / 18	18 / 19,4	19 / 21,5
	s _{DIN/ISO}	17 / 16	19 / 18	22 / 21	24	27	30	32 / 34	36
	Maße	M 26*	M 27	M 30	M 33	M 36	M 39	M 42	M 45
	m _{DIN/ISO}	22	22 / 23,8	24 / 25,6	26 / 28,7	29 / 31	31 / 33,4	34	36
	s _{DIN/ISO}	41	41	46	50	55	60	65	70
	Maße	M 48	M 52	M 56	M 60	M 64	M 68	M 72	M 76
	m _{DIN/ISO}	38	42	45	48	51	54	58	61
	s _{DIN/ISO}	75	80	85	90	95	100	105	110
	Maße	M 80	M 85	M 90	M 95*	M 100	M 105*	M 110	M 120*
	m _{DIN/ISO}	64	68	72	75	80	82	88	95
	s _{DIN/ISO}	115	120	130	135	145	150	155	175


934
(4032)
(4033)
(8673)
(8674)

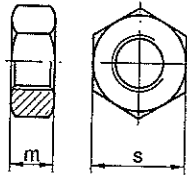

*gemäß DIN 934:1963

DIN (ISO)	Maße	M 8	M 10	M 12	M 14	M 16	M 18	M 20	M 22	M 24
	m _{DIN}	5	6	7	8	8	9	9	10	10
	m _{ISO}	4	5	6	7	8	9	10	11	12
	s _{DIN/ISO}	13	17 / 16	19 / 18	22 / 21	24	27	30	32 / 34	36
	Maße	M 26	M 27	M 28*	M 30	M 32*	M 33	M 35*	M 36	M 38*
	m _{DIN}	12	12	12	12	14	14	14	14	16
	m _{ISO}	13	13,5	14	15	16	16,5	17,5	18	19
	s _{DIN/ISO}	41	41	41	46	50	50	55	55	60
	Maße	M 39	M 40*	M 42	M 45	M 48	M 50*	M 52		
	m _{DIN}	16	16	16	18	18	20	20		
	m _{ISO}	19,5	20	21	22,5	24	25	26		
	s _{DIN/ISO}	60	60	65	70	75	75	80		

936
(4035)
(8675)

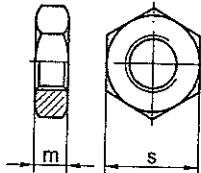

*gemäß DIN 936:1963

Maße	M 3	M 4	M 5	M 6	M 8	M 10	M 12	M 14
d _{k max}	5,8	6,5	7,5	9,5	12,5	15	17	20
m _{max}	2,4	3,2	4	5	6,5	8	10	11
r	2,9	3,25	3,75	4,75	6,25	7,5	8,5	10
s _{DIN/ISO}	5,5	7	8	10	13	17 / 16	19 / 18	22 / 21
t _{min}	4,5	5,26	7,21	7,71	10,65	12,65	15,65	17,65
w _{min}	2	2	2	2	2	2	3	4
Maße	M 16	M 18	M 20	M 22	M 24	M 27	M 30	
d _{k max}	23	26	28	33	34	39	44	
m _{max}	13	15	16	18	19	22	24	
r	11,5	13	14	16,5	17	19,5	22	
s _{DIN/ISO}	24	27	30	32 / 34	36	41	46	
t _{min}	20,58	24,58	25,58	28,58	30,5	35	39	
w _{min}	4	5	5	5	6	7	7	

937

