


Artikel 88136

Gewindeösen
Typ 48

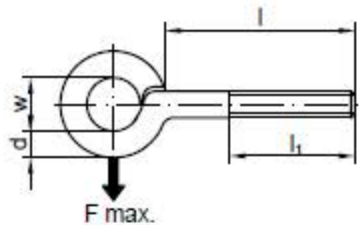

Maße	M 3	M 4	M 5	M 6
w	5	6	8	10
d	2,6	3,5	4,4	5,2
l	11/16	11/16/21/26/32/42	16/21/26/32/ 42/52/62	11/16/21/26/32/42/ 52/62/72/82
l ₁	10/15	10/15/20/25/30/40	15/20/25/30/ 40/50/60	10/15/20/25/30/40/ 50/60/70/80
F _{max.}	7,50 kg	12,50 kg	20 kg	35 kg

Maße	M 8	M 10	M 12	
w	12	14	18	
d	7	8,9	10,6	
l	21/26/32/42/ 52/62/82/102	32/42/52/62/ 72/82/102	102	
l ₁	20/25/30/40/ 50/60/80/100	30/40/50/60/ 80/70/100	100	
F _{max.}	50 kg	100 kg	175 kg	