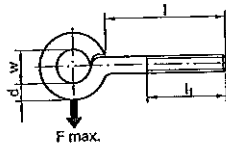


88136

Gewindeösen
Typ 48

Artikel

Maße

M3

M4

M5

M6

w

5

6

8

10

d

2,6

3,5

4,4

5,2

l

11/16

11/16/21/26/32/42

16/21/26/32/42/52/62

11/16/21/26/32/42/52/62/72/82

l₁

10/15

10/15/20/25/30/40

15/20/25/30/40/50/60

10/15/20/25/30/40/50/60/70/80

F_{max}

7,50 kg

12,50 kg

20 kg

35 kg

Maße

M8

M10

M12

w

12

14

18

d

7

8,9

10,6

l

21/26/32/42/52/62/82/102

32/42/52/62/72/82/102

102

l₁

20/25/30/40/50/60/80/100

30/40/50/60/80/70/100

100

F_{max}

50 kg

100 kg

175 kg