




Norm: ISO 8820-3

**Verpackungsmöglichkeiten:**

- 200 Stück
- 500 Stück
- 5.000 Stück

**Packing opinions:**

- 200 pcs.
- 500 pcs.
- 5.000 pcs.

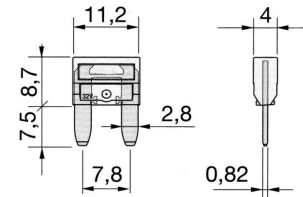

## Bemessungswerte / Ratings

Art.-No.	Strom Current	Spannung Voltage	Ausschaltvermögen Breaking capacity	Spannungsfall Voltage drop max [mV]	Farbe colour
341.120	2 A	32 V	1000 A	225	Grau / grey
341.122	3 A	32 V	1000 A	200	Violett / violet
341.123	4 A	32 V	1000 A	200	Rosa / pink
341.124	5 A	32 V	1000 A	175	Beige / beige
341.126	7,5 A	32 V	1000 A	150	Braun / brown
341.127	10 A	32 V	1000 A	140	Rot / red
341.129	15 A	32 V	1000 A	125	Blau / blue
341.131	20 A	32 V	1000 A	125	Gelb / yellow
341.132	25 A	32 V	1000 A	125	Weiß / white
341.133	30 A	32 V	1000 A	120	Grün / green




Norm: ISO 8820-3

**Verpackungsmöglichkeiten:**

- 100 Stück
- 1.000 Stück
- 2.000 Stück

**Packing opinions:**

- 100 pcs.
- 1.000 pcs.
- 2.000 pcs.

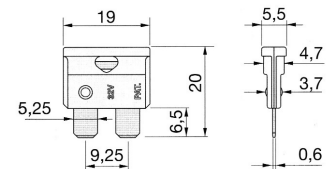

## Bemessungswerte / Ratings

Art.-No.	Strom Current	Spannung Voltage	Ausschaltvermögen Breaking capacity	Spannungsfall Voltage drop max [mV]	Farbe Colour
340.017	1 A	32 V	1000 A	250	Schwarz / black
340.020	2 A	32 V	1000 A	225	Grau / grey
340.022	3 A	32 V	1000 A	200	Violett / violet
340.023	4 A	32 V	1000 A	200	Rosa / pink
340.024	5 A	32 V	1000 A	175	Beige / beige
340.026	7,5 A	32 V	1000 A	150	Braun / brown
340.027	10 A	32 V	1000 A	140	Rot / red
340.029	15 A	32 V	1000 A	125	Blau / blue
340.031	20 A	32 V	1000 A	125	Gelb / yellow
340.032	25 A	32 V	1000 A	125	Weiß / white
340.033	30 A	32 V	1000 A	120	Grün / green
340.035	40 A	32 V	1000 A	120	Orange / orange