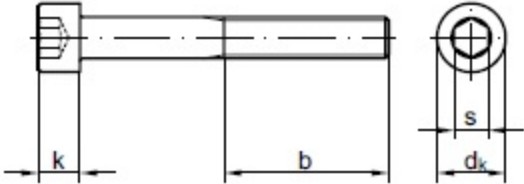
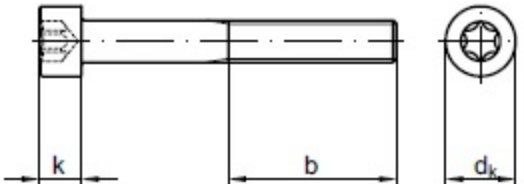


DIN (ISO)		Maße	M 1,4	M 1,6	M 2	M 2,5	M 3	M 4	M 5	M 6	M 8	M 10
	d_k	2,6	3	3,8	4,5	5,5	7	8,5	10	13	16	
	k	1,4	1,6	2	2,5	3	4	5	6	8	10	
	s	1,3	1,5	1,5	2	2,5	3	4	5	6	8	
	ISR	-	-	T6	T8	T10	T20	T25	T30	T45	T50	
	b ¹⁾	14	15	16	17	18	20	22	24	28	32	
	Maße	M 12	M 14	M 16	M 18	M 20	M 22	M 24	M 27	M 30	M 33	
	d_k	18	21	24	27	30	33	36	40	45	50	
	k	12	14	16	18	20	22	24	27	30	33	
	s	10	12	14	14	17	17	19	19	22	24	
	ISR	T55	T60	T70	T80	T90	-	-	-	-	-	
b ¹⁾	36	40	44	48	52	56	60	66	72	78		
	Maße	M 36	M 39	M 42	M 45	M 52	M 56	M 64	M 72			
	d_k	54	58	63	68	78	84	96	108			
	k	36	39	42	45	52	56	64	72			
	s	27	27	32	36	36	41	46	55			
	ISR	-	-	-	-	-	-	-	-			
b ¹⁾	84	90	96	102	116	124	140	156				

¹⁾ b nach ISO 4762