













 


 







 

 

 

 

 

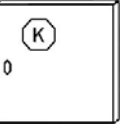




-  MONTAGEANLEITUNG
-  ASSEMBLY INSTRUCTION
-  DE INSTRUCTIE VAN DE ASSEMBLAGE
-  ISTRUZIONE DELL'ASSEMBLEA
-  INSTRUCCIÓN DE ASAMBLEA
-  INSTRUCTION DE MONTAGE
-  NÁVOD K MONTÁŽI
-  MONTERINGSANVISNING
-  MONTAJ TALIMATI
-  ASENNUSOHJE
-  BRUGSANVISNING
-  BRUKSANVISNING
-  UPUTE ZA MONTAŽU
-  NAVODILA ZA MONTAŽO
-  GYŰLÉS OKTATÁS
-  INSTRUCȚIUNI DE MONTAJ


















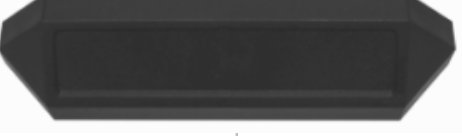



Art.-Nr. 12280

(12281, 12282, 12284, 12286, 12287)

2x			772 x 475 mm
2x			772 x 475 mm
1x			1057 x 473 mm
1x			1057 x 473 mm
1x			798 x 473 mm
1x			798 x 473 mm
1x			985 x 480 mm
1x			727 x 480 mm
1x			505 x 450 mm
1x			645 x 450 mm
1x			2400 x 600 mm


5x			450 x 445 mm
5x			470 x 130 mm
5x			450 x 120 mm
1x			955 x 445 mm
1x			975 x 130 mm
2x			468 x 403 mm
2x			400 x 25 mm
6x			450 x 20 mm

10x		5,5 x 19
14x		KU 4,2 x 13
34x		M5 x 10
34x		5,3
34x		M5
40x		M4 x 10
40x		M4
2x		M6 x 16
4x		6,4
2x		M6


2x		6 x 12
2x		
8x		
8x		M8
8x		
7x		
7x		
2x		
2x		




1. – 6./17.-21.

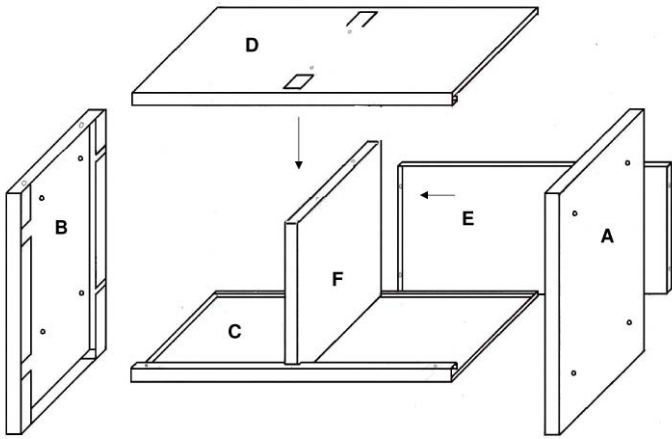


7./22.

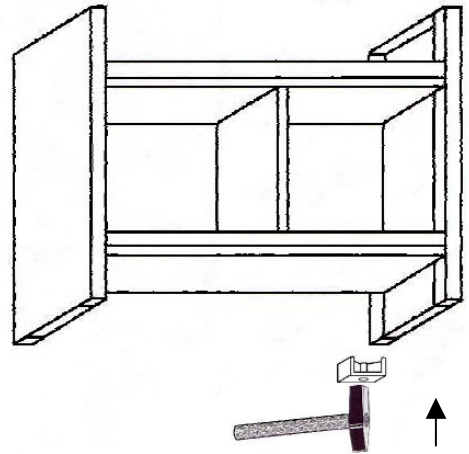


12./19./23.-25.

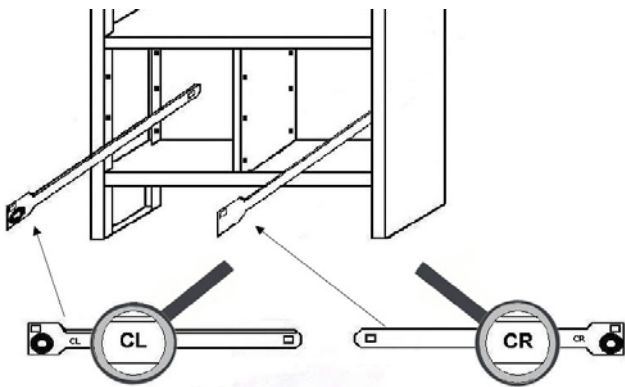

8.-10.

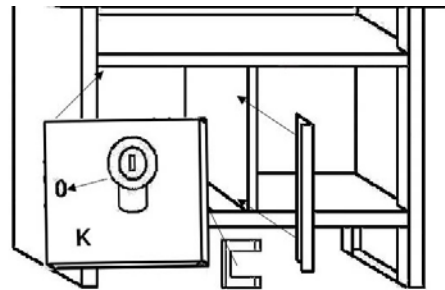


26. - 28.

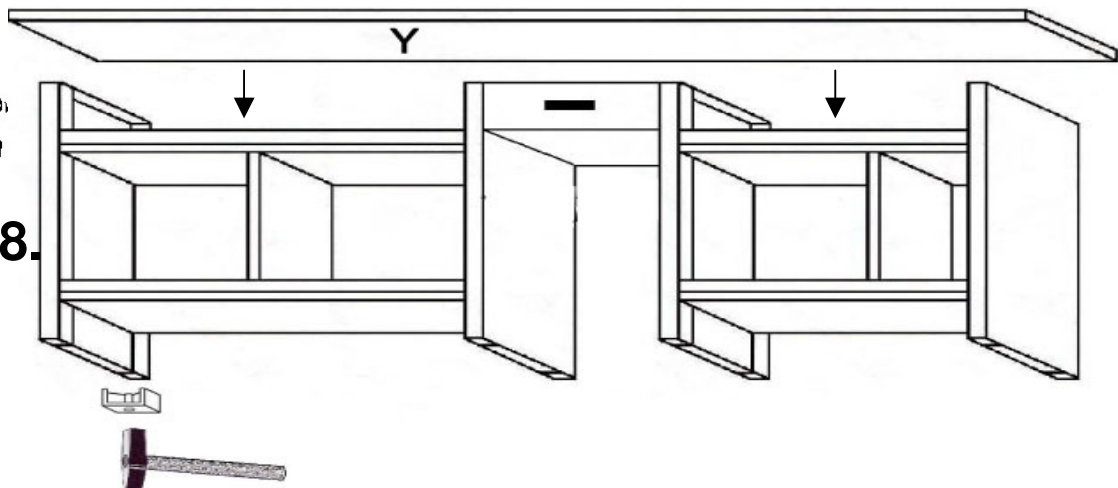




13. – 16.

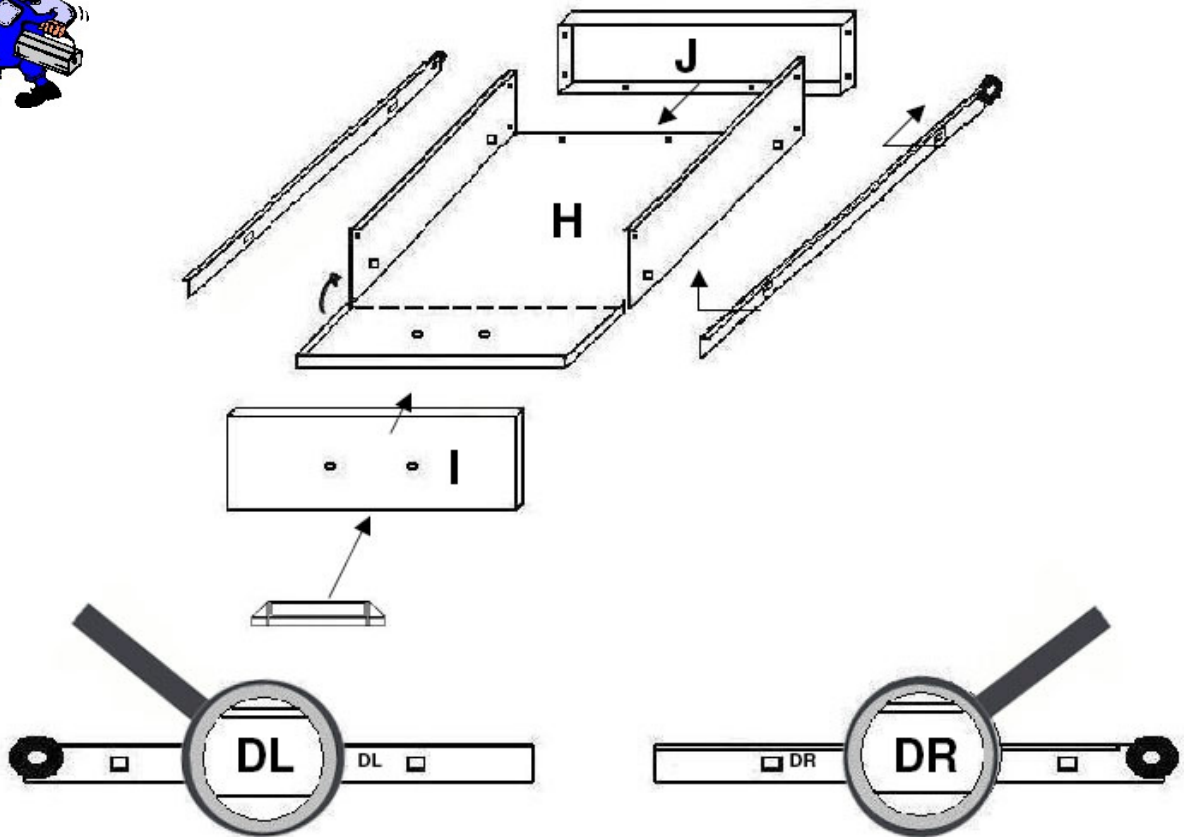


11. – 12.

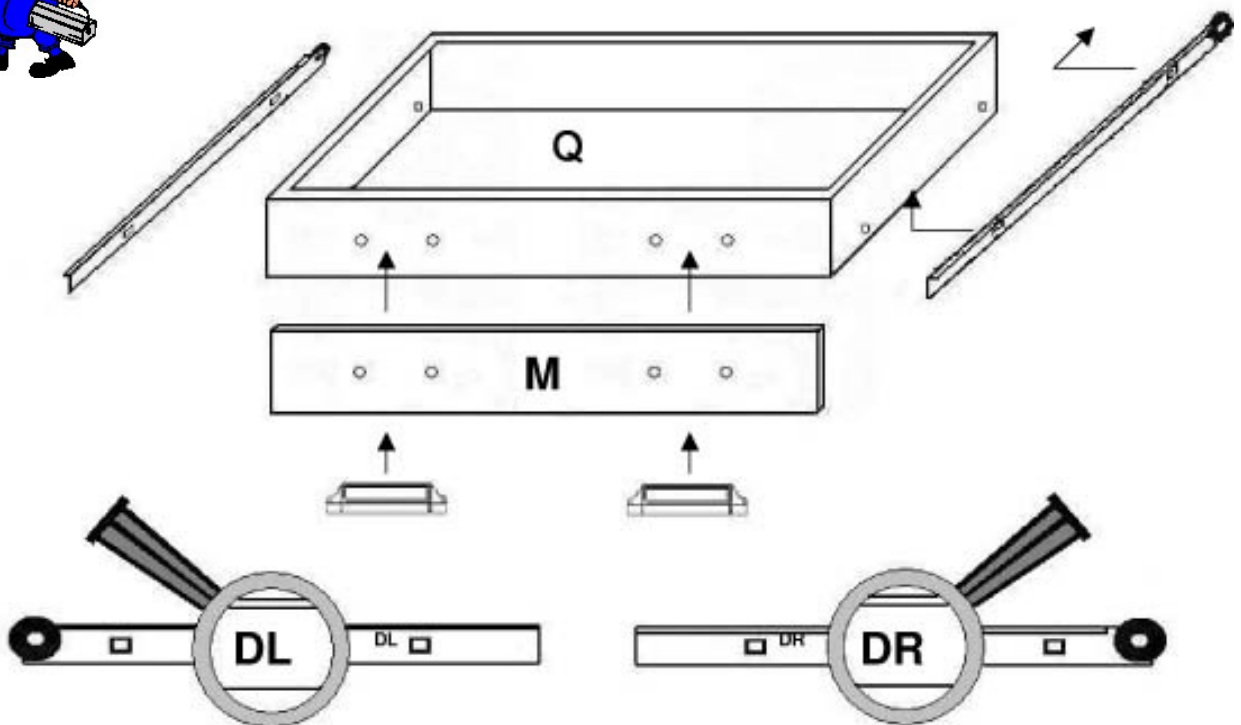




1.

Pack 1/3

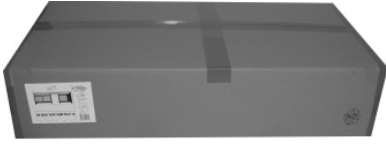





Pack 2/3

 

Pack 3/3





2.

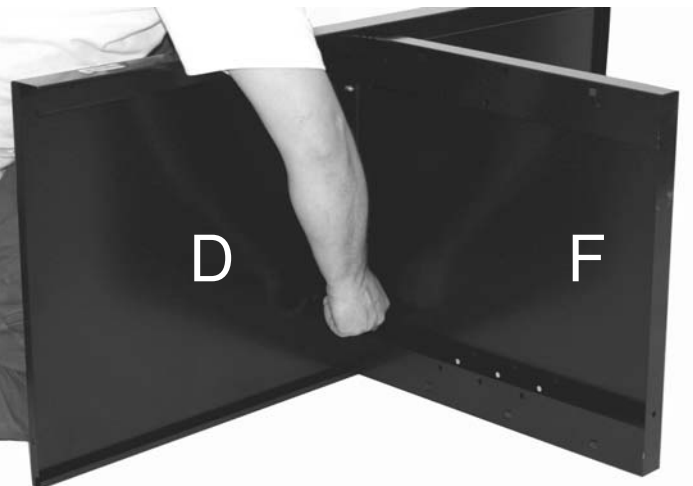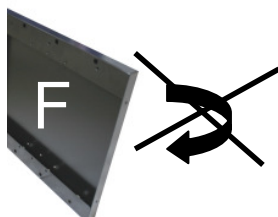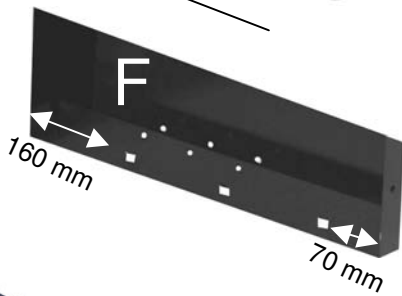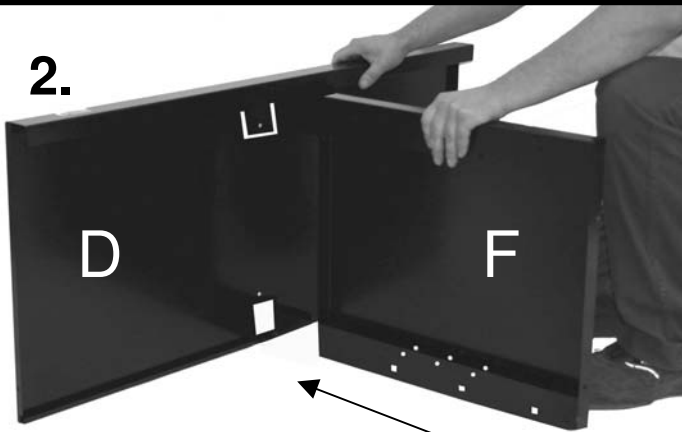



3.

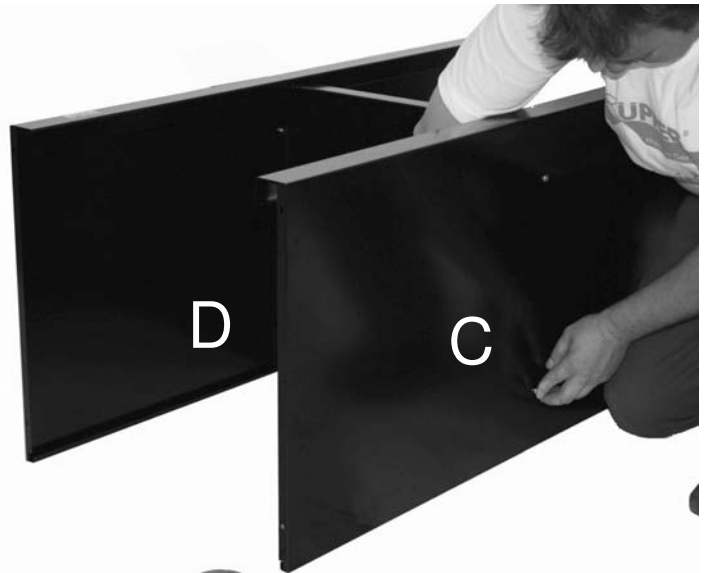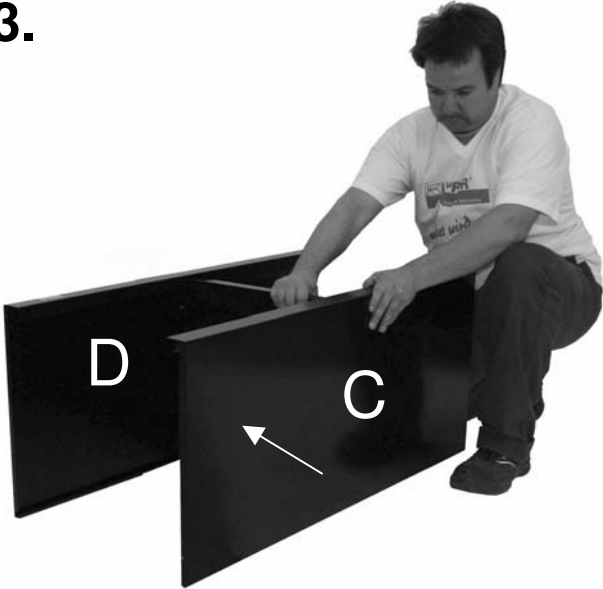

2x



M5 x 10

2x



5,3

2x



M5





PH 2 x 100





SW 8

4.

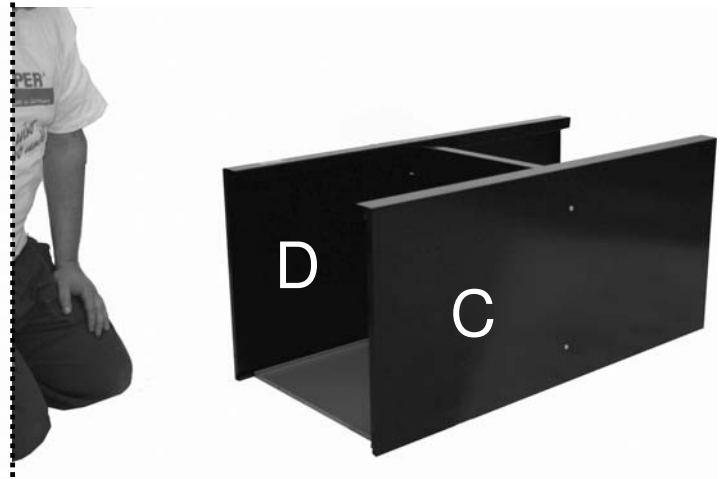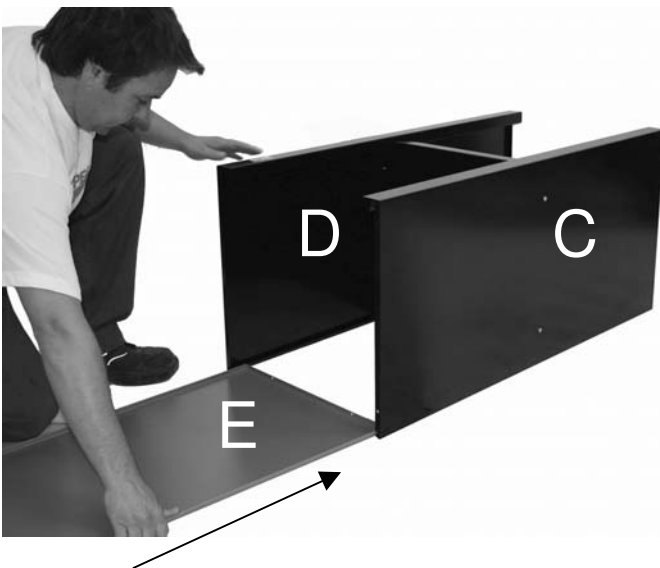



5.

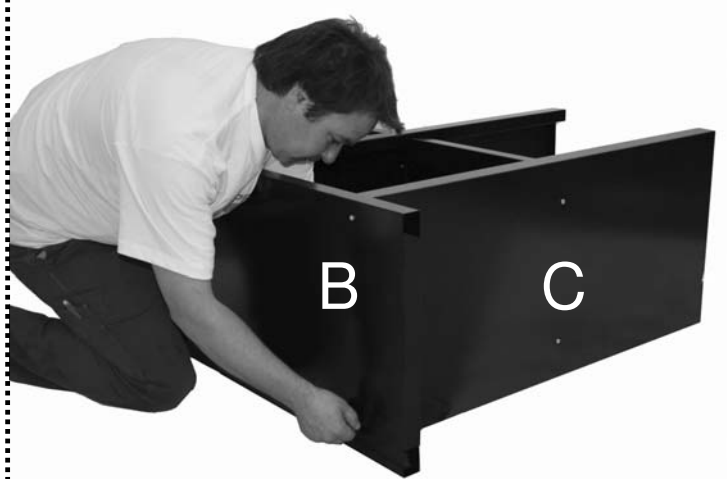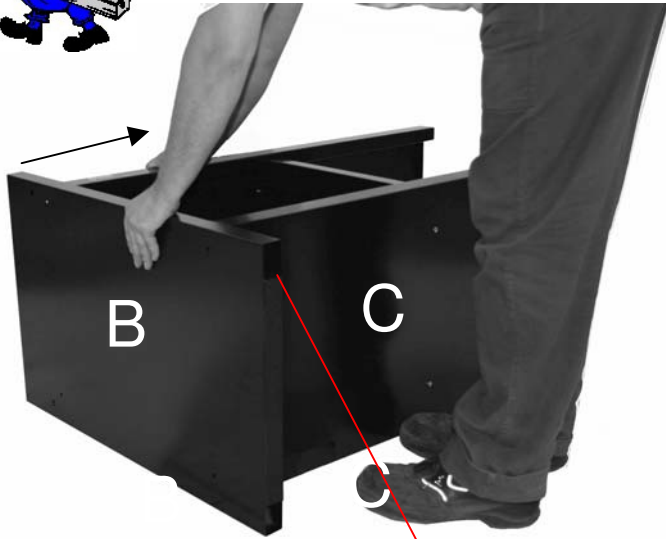

4x



4x





4x



PH 2 x 100

SW 8

6.

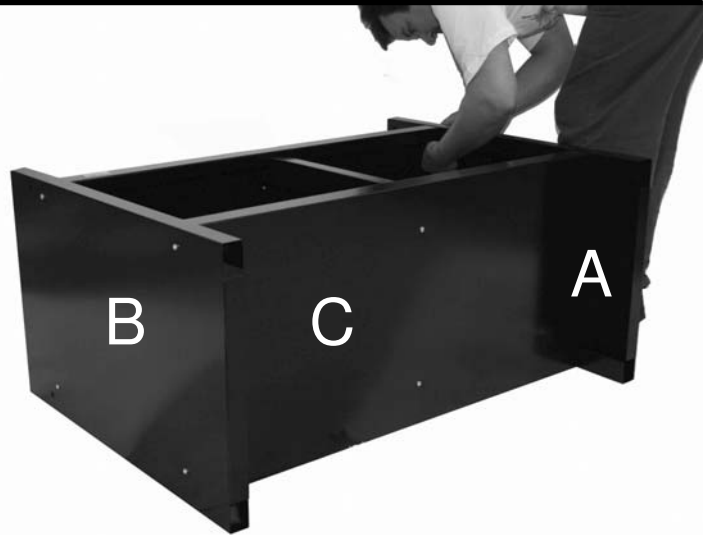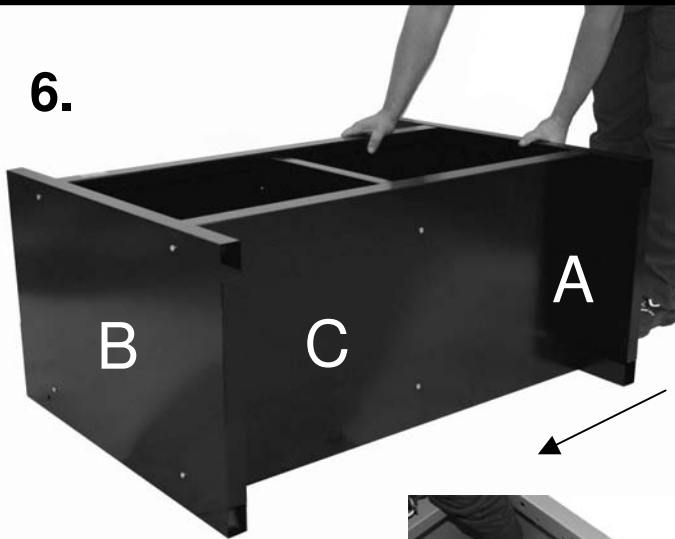

4x



4x



4x



PH 2 x 100



SW 8



4x



4x



4x






PH 2 x 100






SW 8



7.



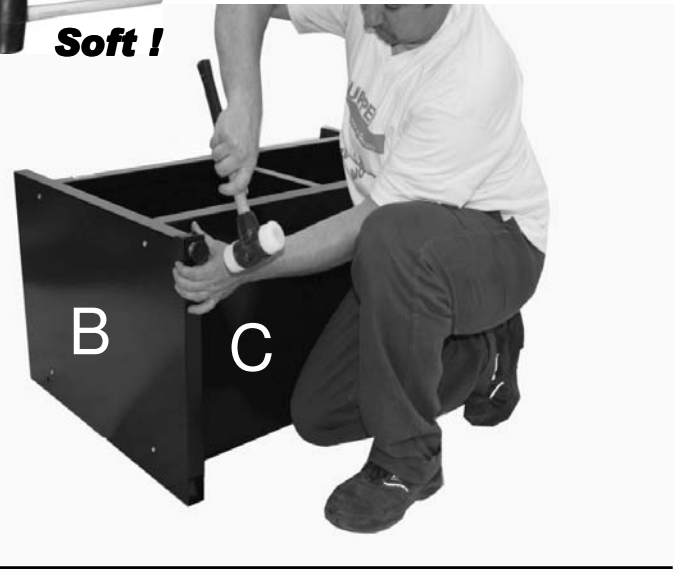
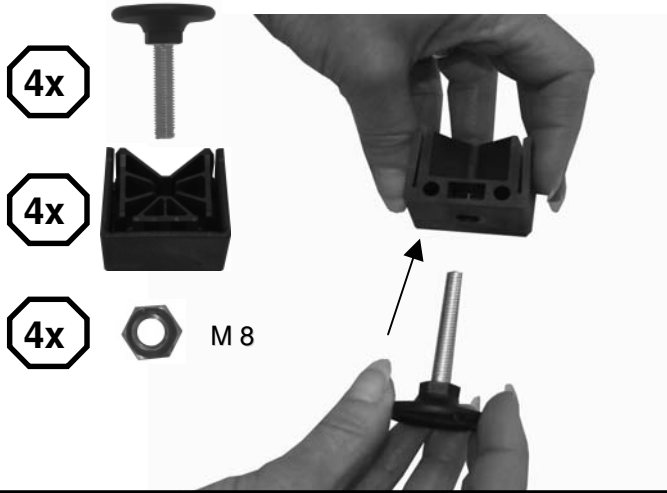
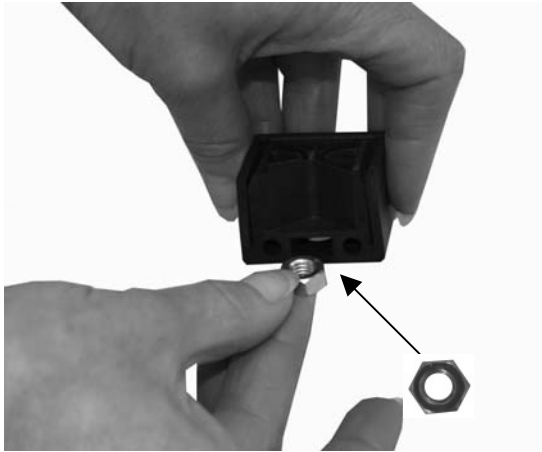


8.

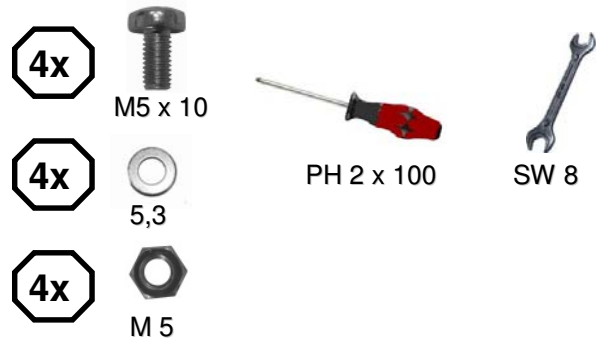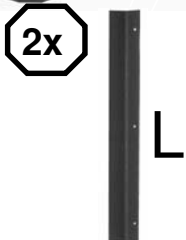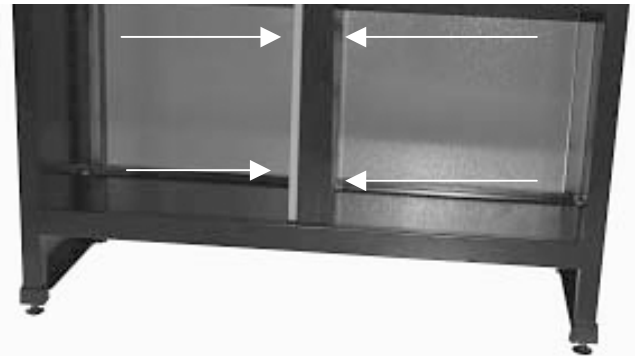




 9.

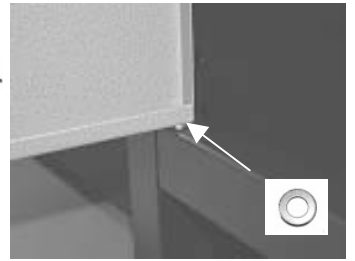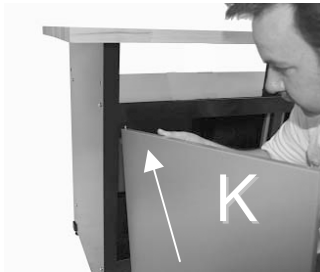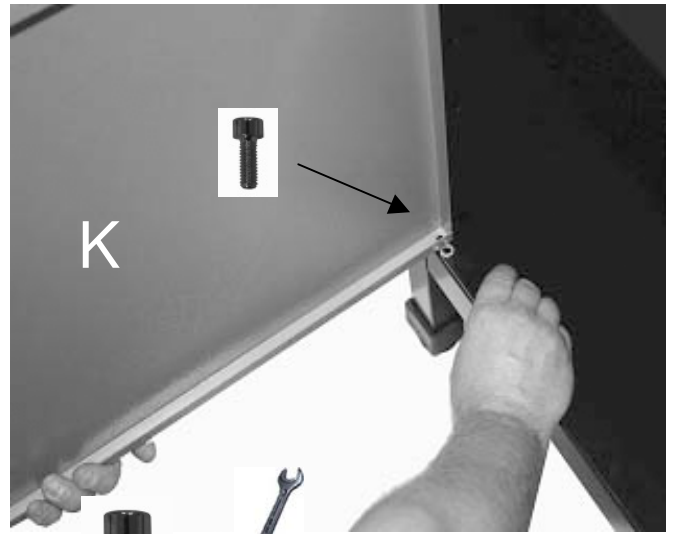
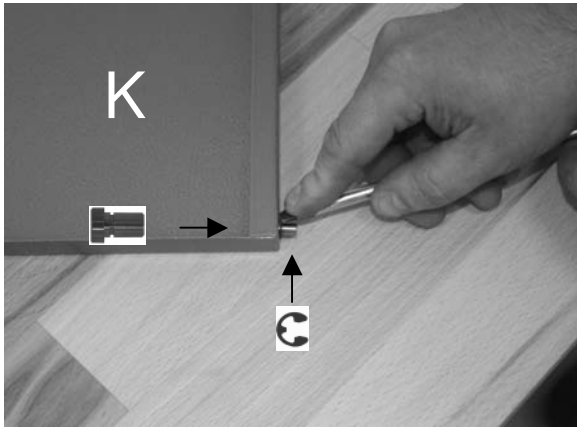


10.

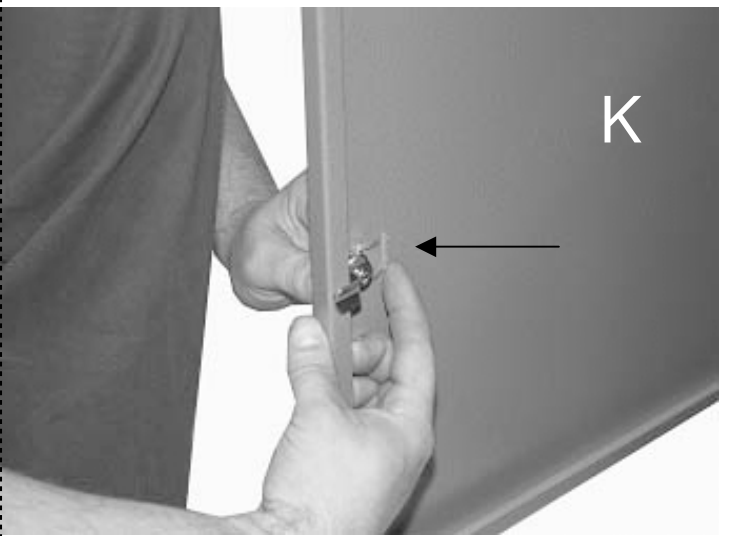



11.

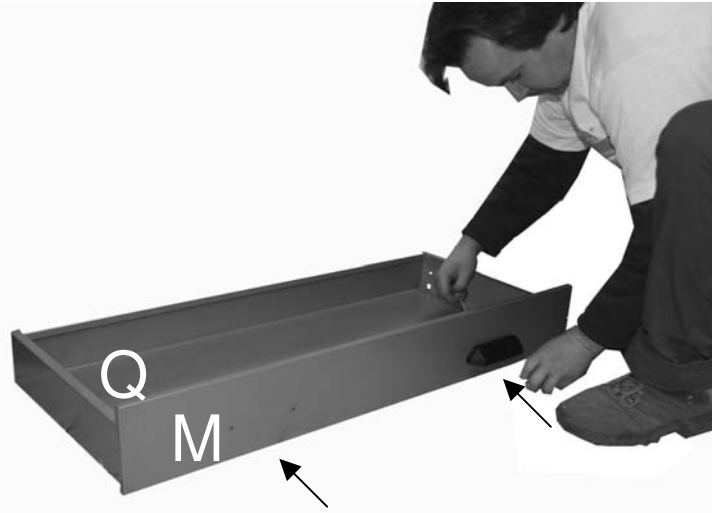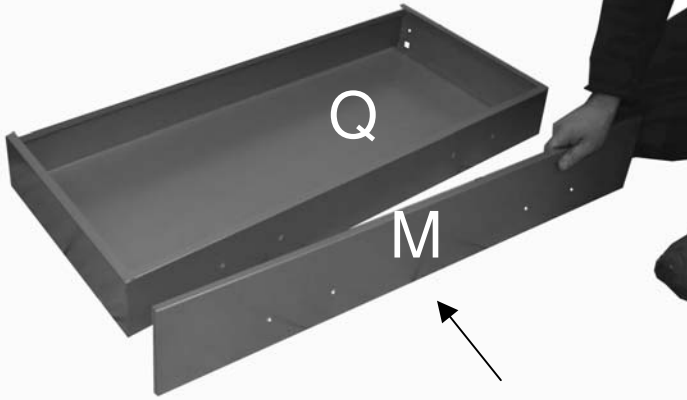

4x





KU 4,2 x 13

2x



PH 2 x 100

12.

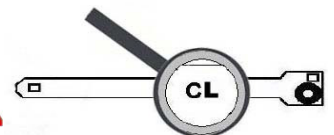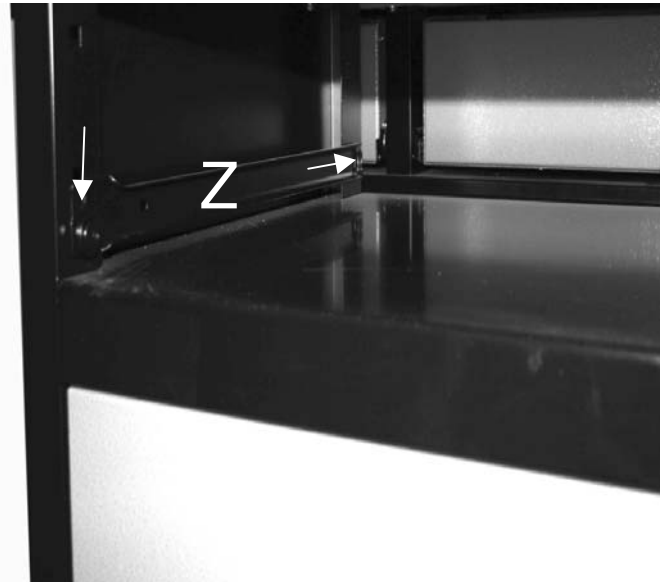




13.



14.

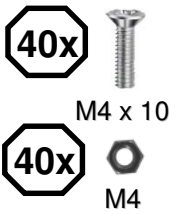

PH 1 x 100



SW 7





15.



16.



10x



KU 4


5x



PH 2 x 100





17.

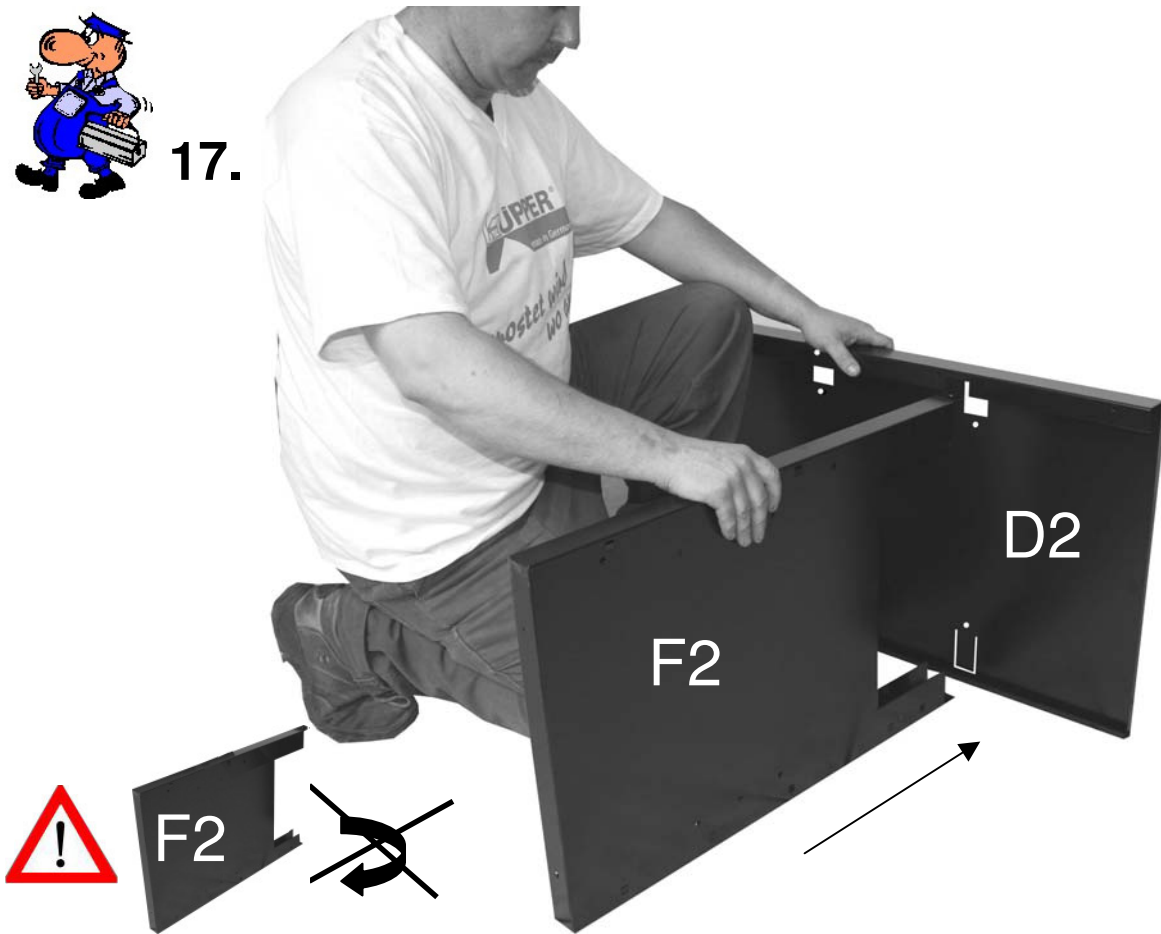

18.

- 4x M5 x 10
- 4x 5,3
- 4x M5

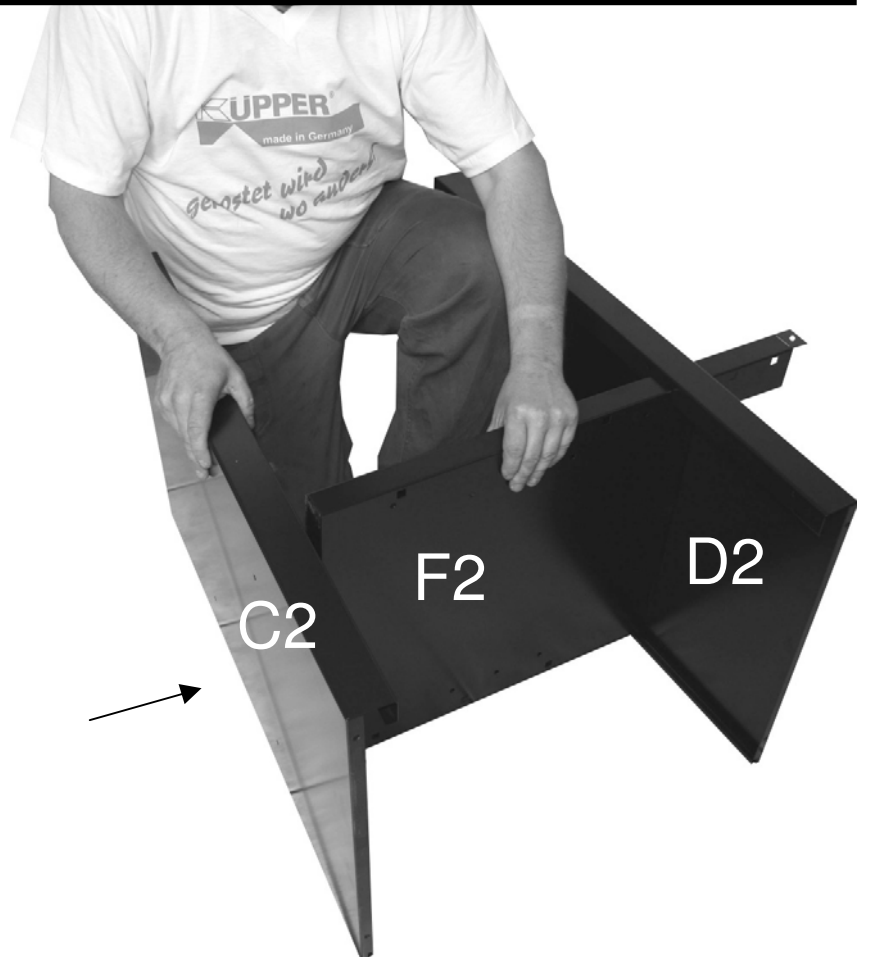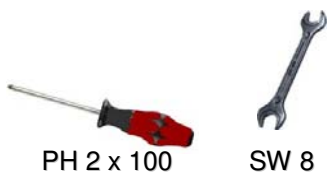



19.

4x



M5 x 10

4x



5,3

4x





M 5



PH 2 x 100



SW 8

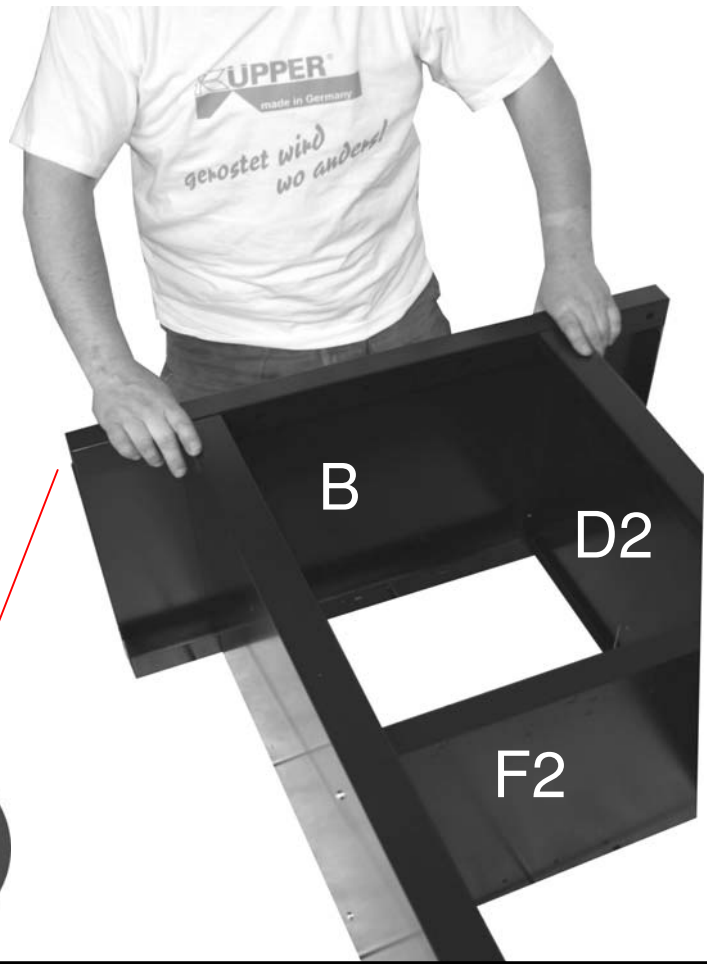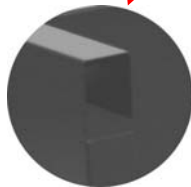

20.

2x



M5 x 10

2x



5,3

2x




M 5



PH 2 x 100




SW 8

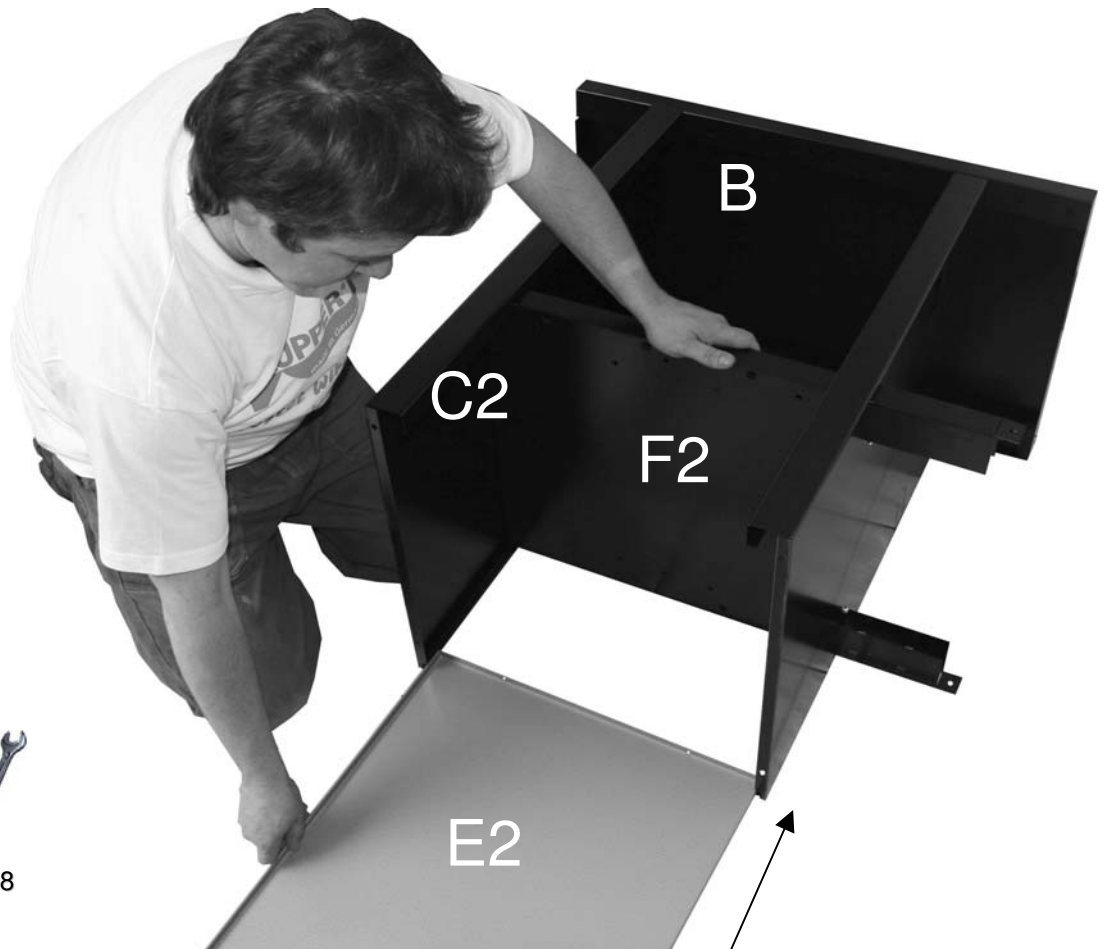



21.

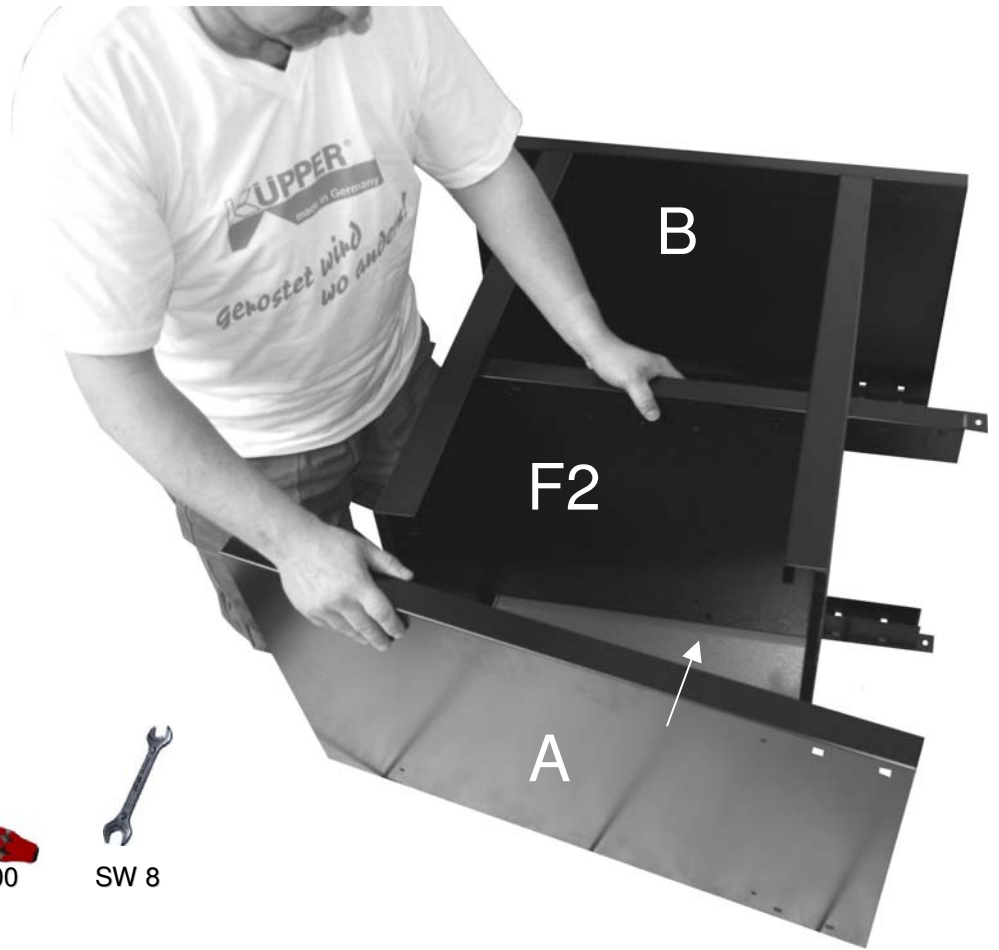

6x



M5 x 10

6x



5,3

6x



M 5





PH 2 x 100



SW 8

22.

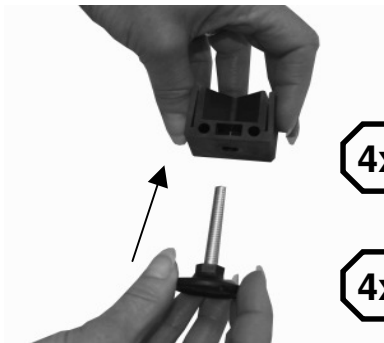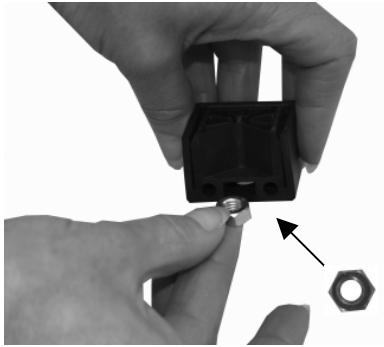

4x



4x



4x



M 8







23.




1x

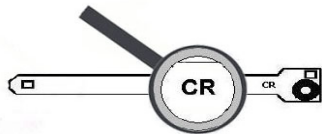

1x

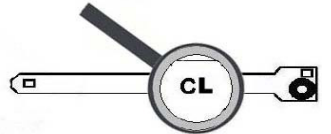


24.

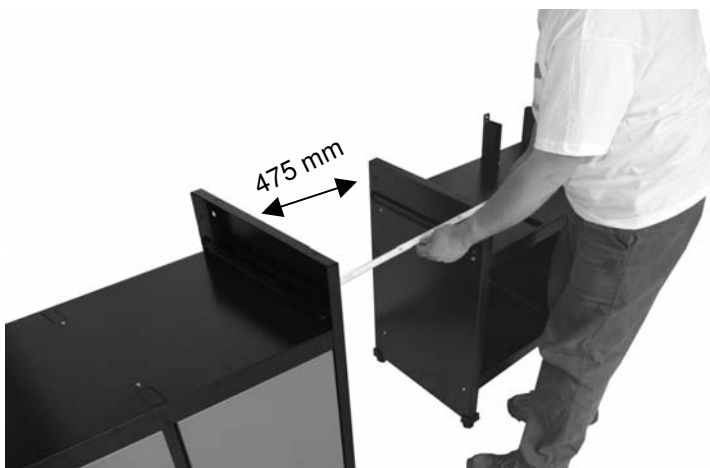


Test !



25.

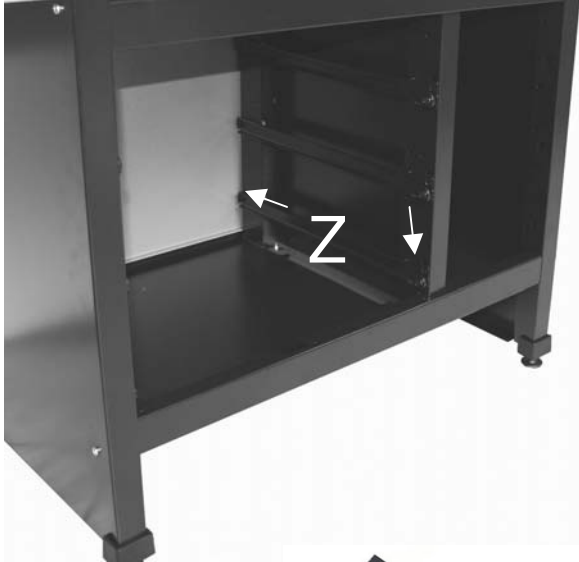

3x

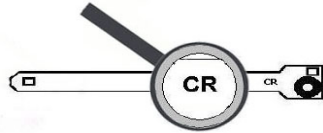

26.





27.



4 mm

↓ Max. 20 mm ↓

28.



10x




5,5 x 19



SW 8













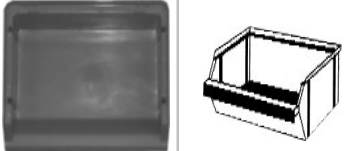

-  MONTAGEANLEITUNG
-  ASSEMBLY INSTRUCTION
-  DE INSTRUCTIE VAN DE ASSEMBLAGE
-  ISTRUZIONE DELL'ASSEMBLEA
-  INSTRUCCIÓN DE ASAMBLEA
-  INSTRUCTION DE MONTAGE
-  NÁVOD K MONTÁŽI
-  MONTERINGSANVISNING
-  MONTAJ TALIMATI
-  ASENNUSOHJE
-  BRUGSANVISNING
-  BRUKSANVISNING
-  UPUTE ZA MONTAŽU
-  NAVODILA ZA MONTAŽO
-  GYŰLÉS OKTATÁS
-  INSTRUCȚIUNI DE MONTAJ

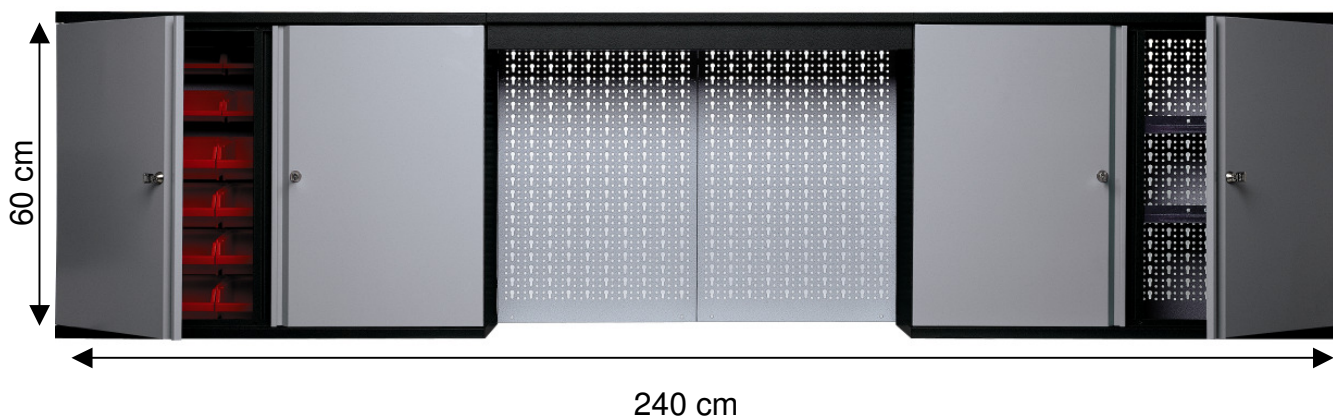





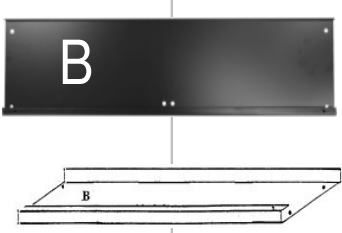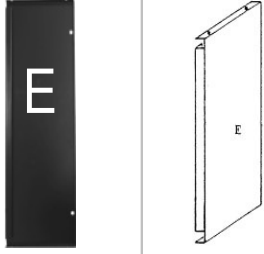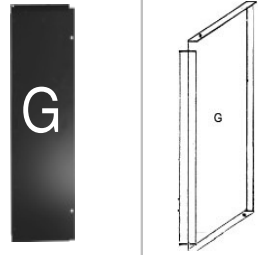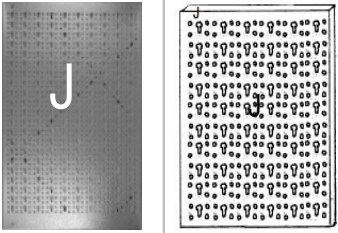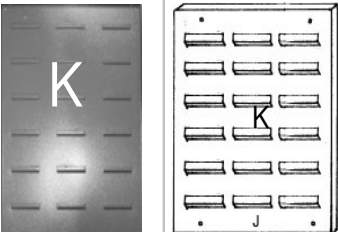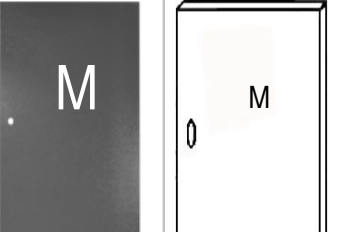

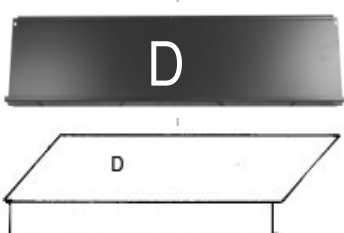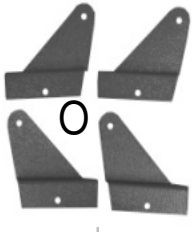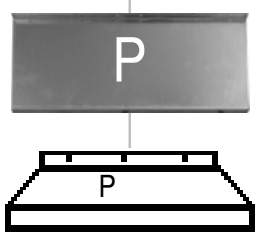



Art.-Nr. 70180

(70181, 70182, 70184, 70186, 70187)

4x		800 x 200 mm
4x		200 x 600 mm
2x		180 x 600 mm
4x		400 x 595 mm
2x		400 x 595 mm
4x		375 x 560 mm


1x		820 x 200 mm
1x		100 x 90 mm
4x		390 x 140 mm
12x		130 x 100 x 50 mm
24x		130 x 130 x 70 mm
1x		6 x 8 mm

54x		M5 x 10
54x		5,3
54x		M5
8x		6 x 12
8x		
8x		6,4


4x		
4x		
8x		4,5 x 45
8x		E 6 x 30




1. – 2. / 8. – 9.

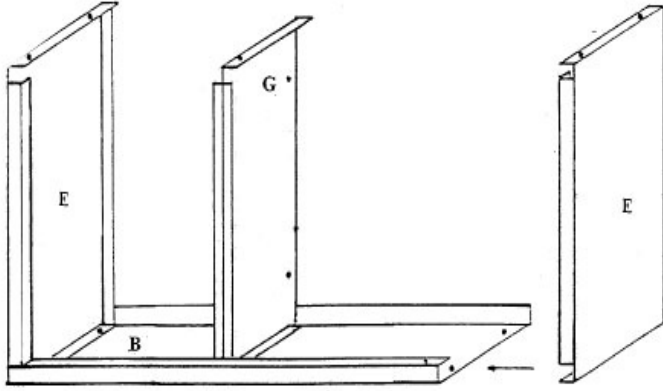


3. – 7. / 10. – 12.

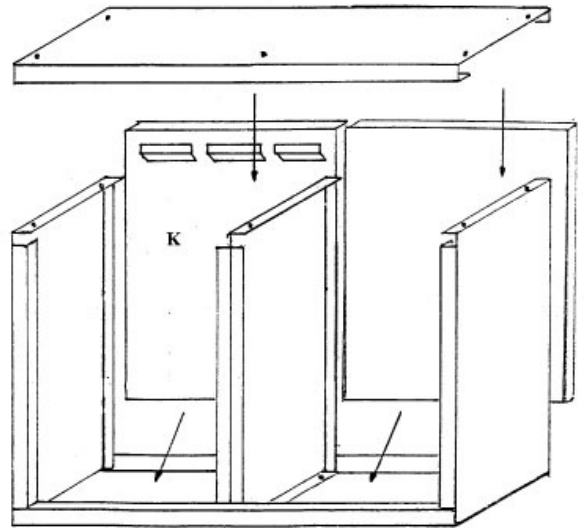

18. – 21.

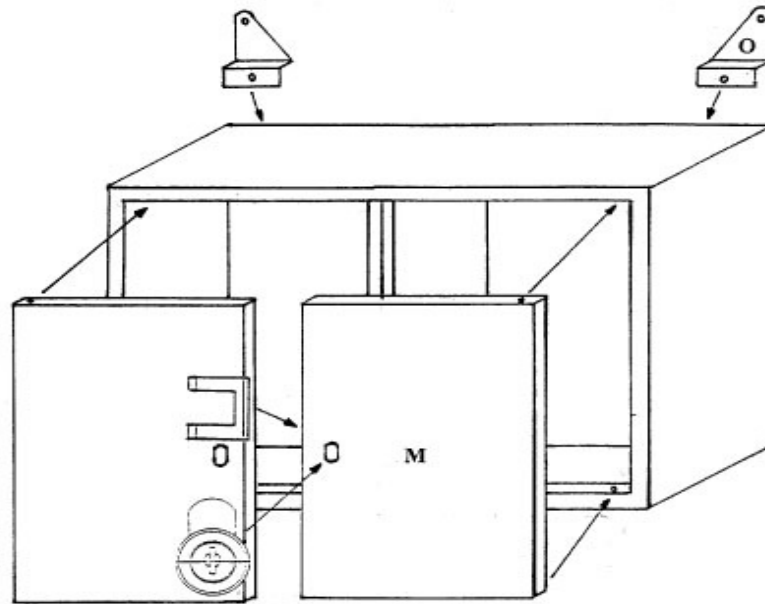


13. – 17. /
22. – 23.

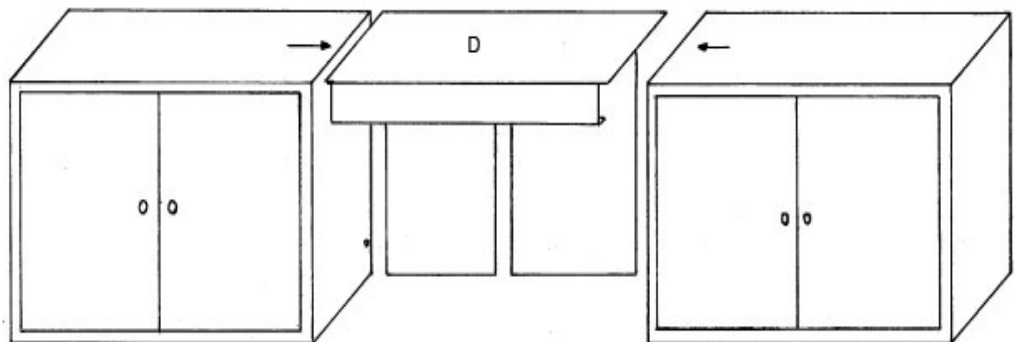




1.

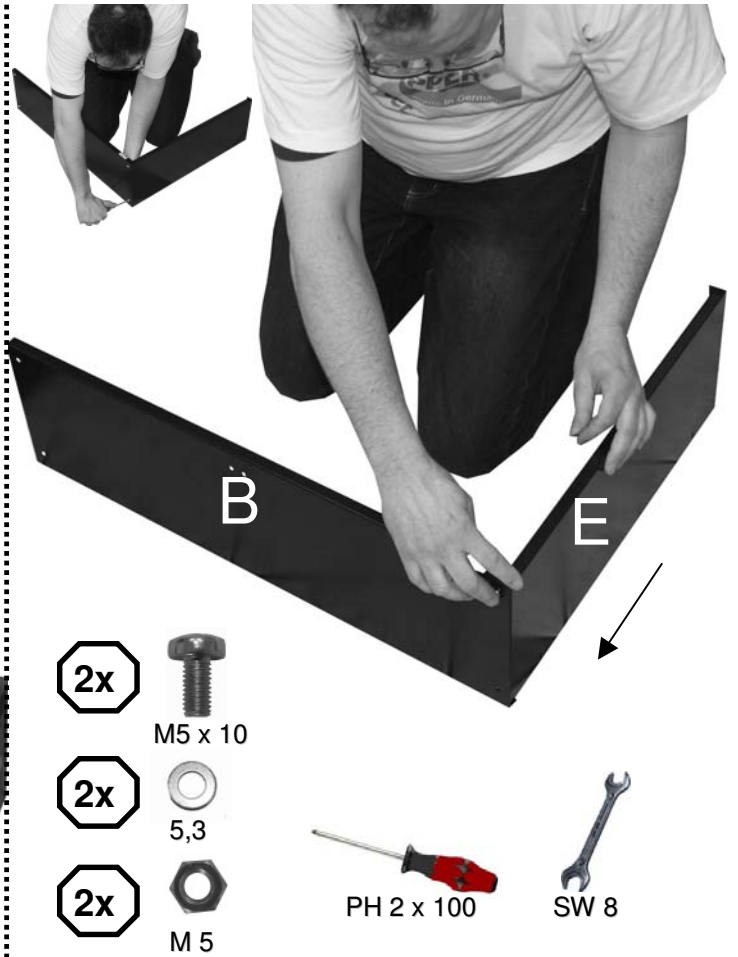


- 2x M5 x 10
- 2x 5,3
- 2x M5



2.

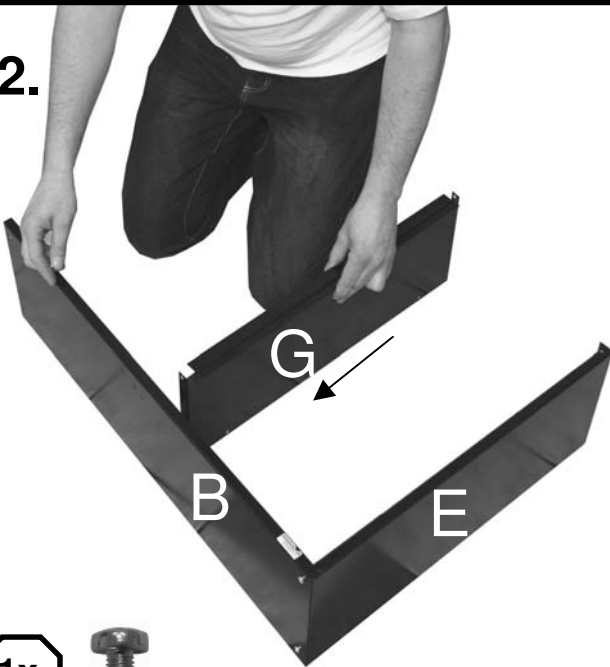

- 1x M5 x 10
- 1x 5,3
- 1x M5



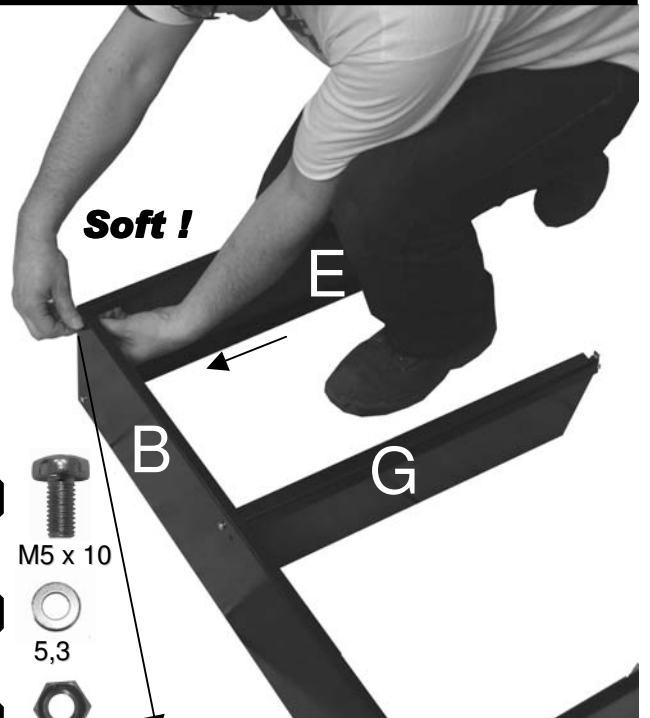


- 2x M5 x 10
- 2x 5,3
- 2x M5







3.

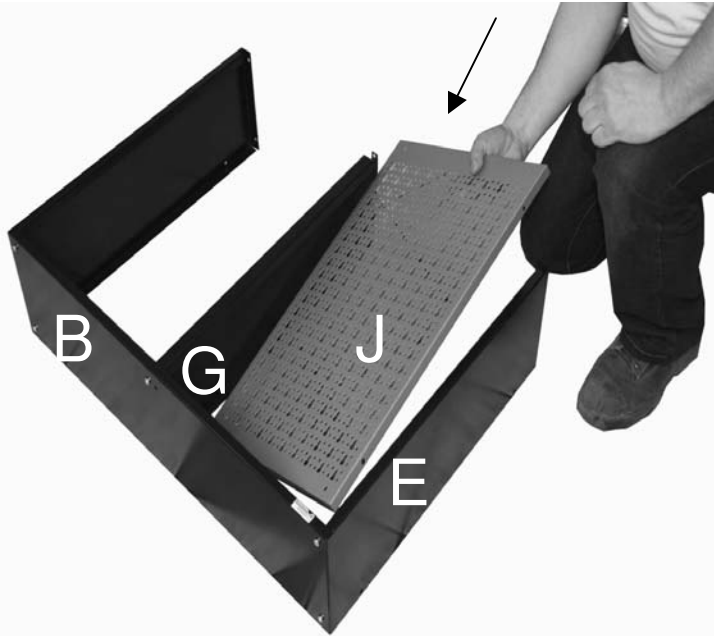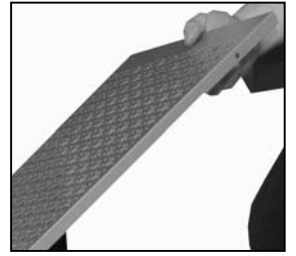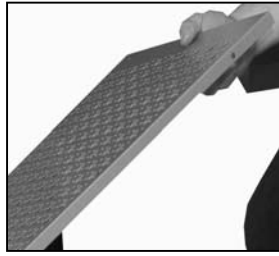



4.

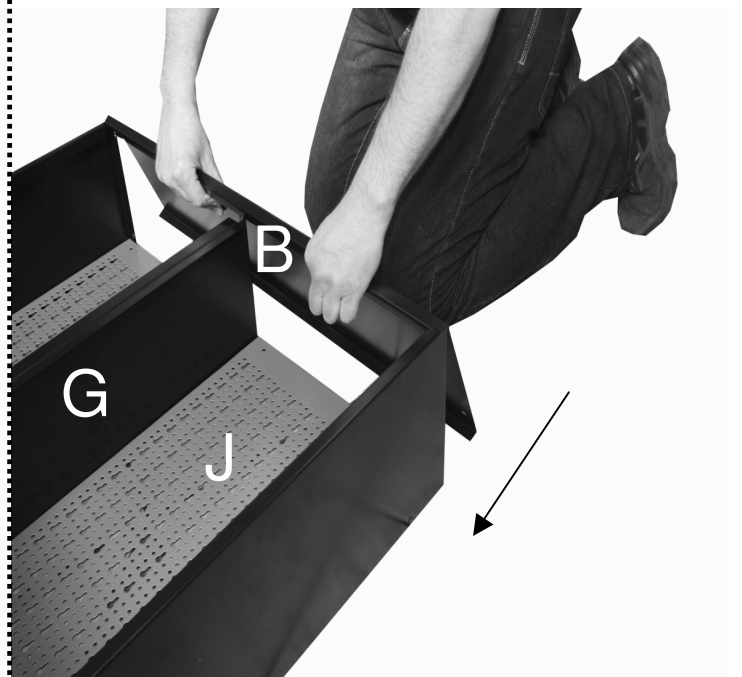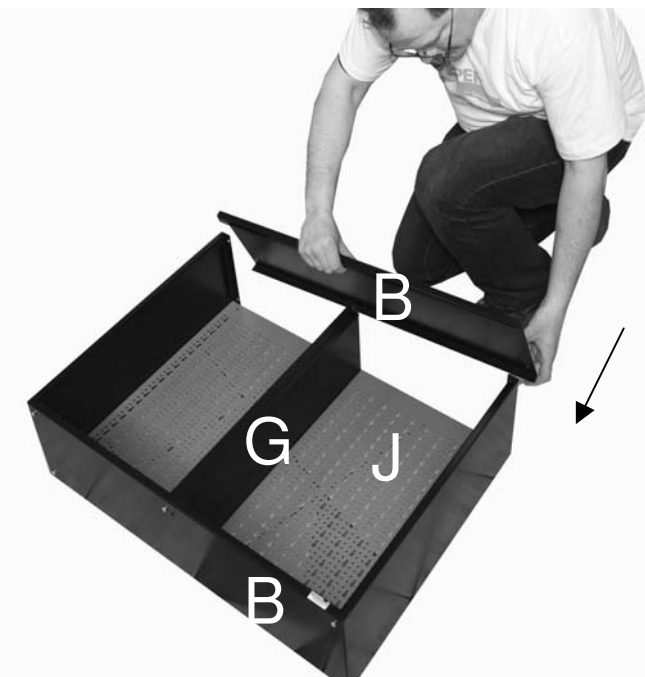




5.

- 5x M5 x 10
- 5x 5,3
- 5x M5

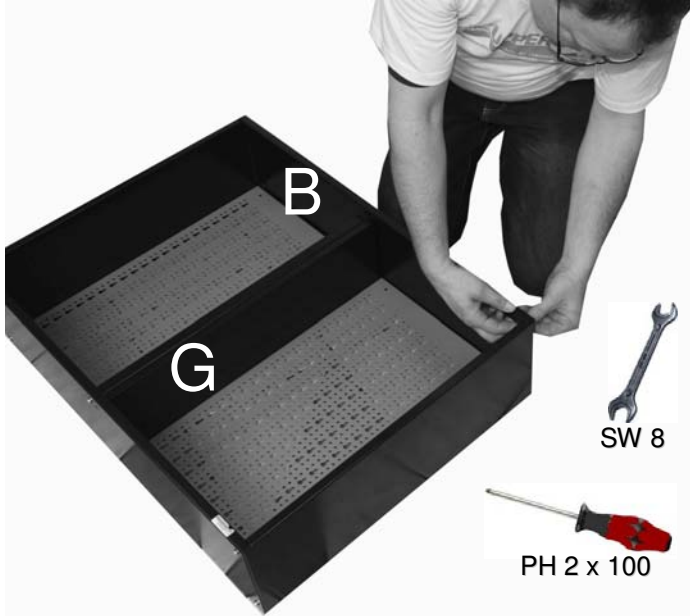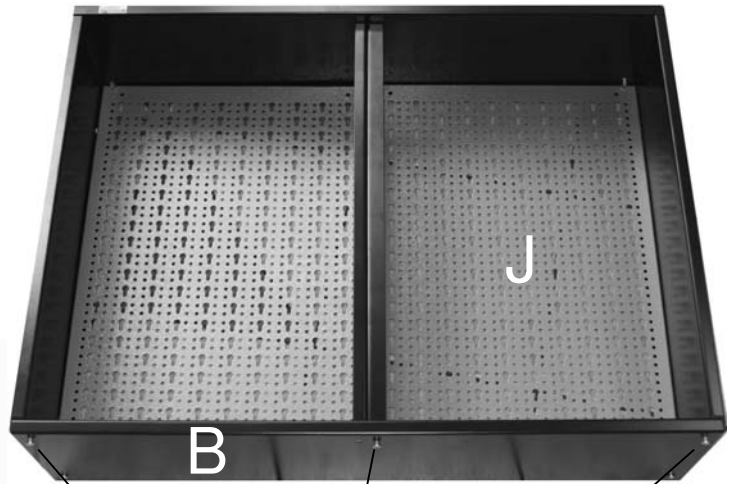

Soft !

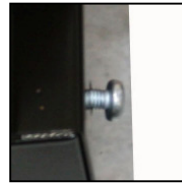

6.



- 2x M5 x 10
- 2x 5,3
- 2x M5



- 2x M5 x 10
- 2x 5,3
- 2x M5





7.

4x



16x



M5 x 10

16x



5,3

16x




M5




PH 2 x 100



SW 8

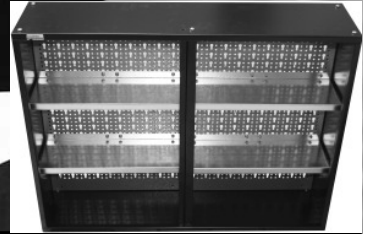

8.

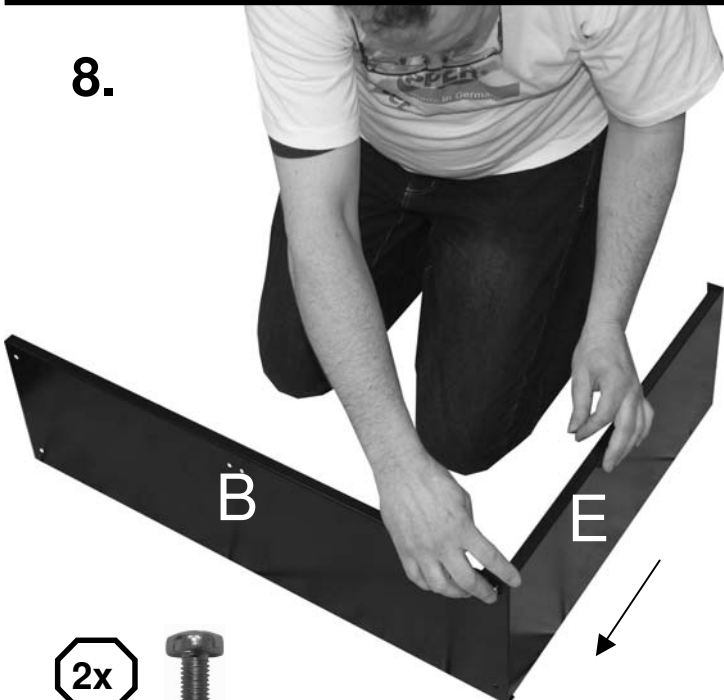

2x



M5 x 10

2x



5,3

2x



M5



Soft !





9.

PH 2 x 100



1x



M5 x 10

1x





5,3

1x



M 5

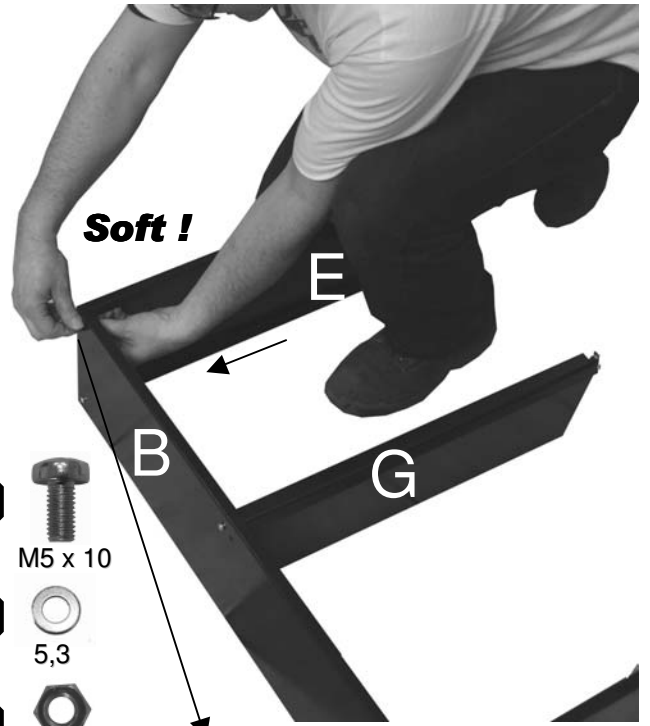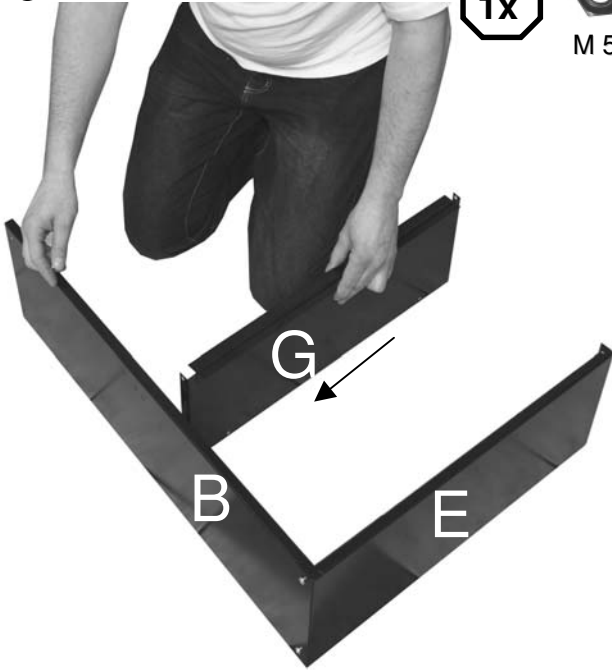

Soft !

2x



M5 x 10

2x



5,3

2x




M 5



Soft !



10.

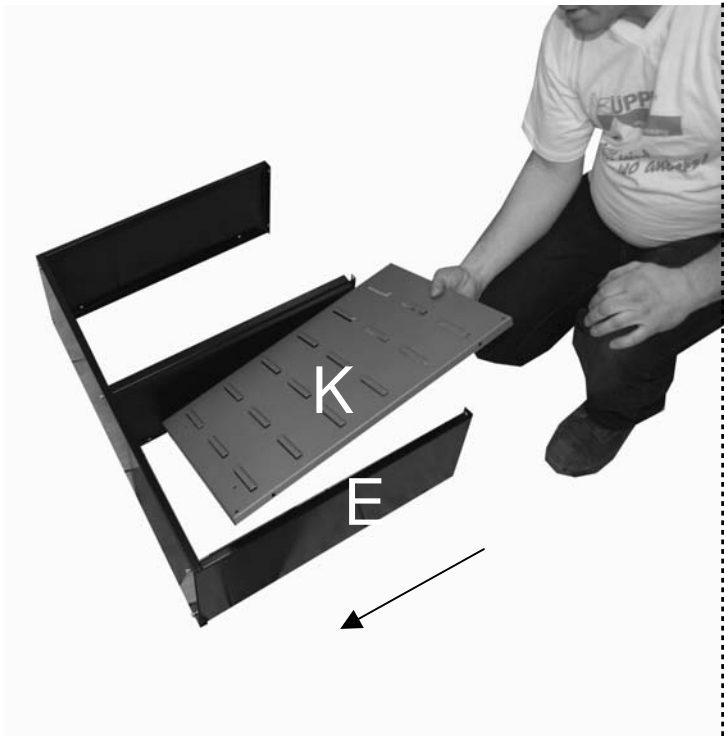



11.

5x



5x





5,3

5x



M 5

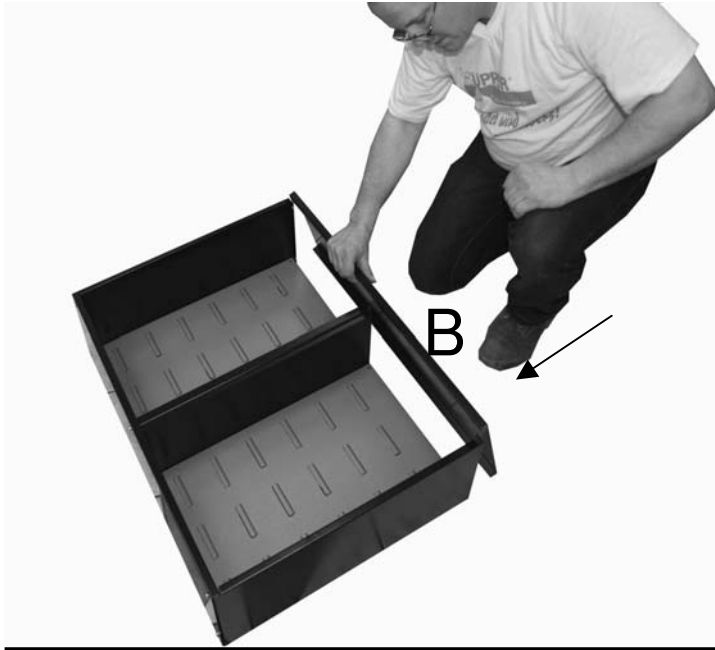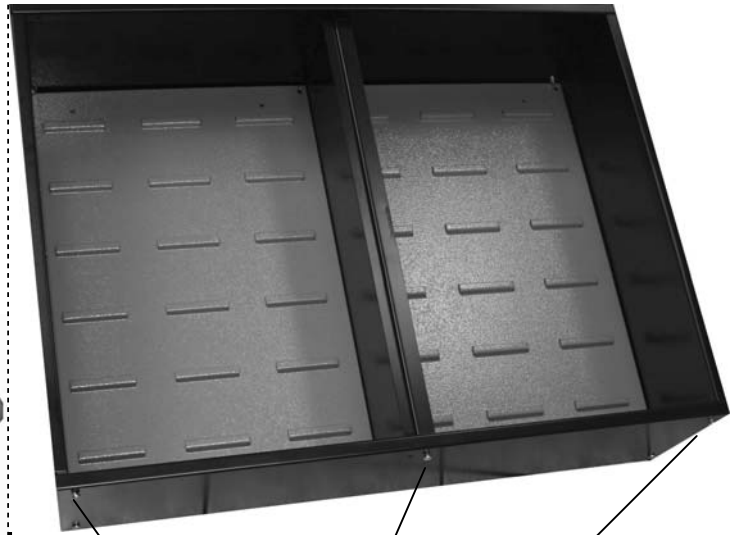

Soft !



12.



PH 2 x 100



SW 8

2x



M5 x 10

2x



5,3

2x



M 5



PH 2 x 100



SW 8

2x



M5 x 10

2x



5,3

2x



M 5





13.

2x



M5 x 10

2x



5,3

2x





M5



SW 8



PH 2 x 100

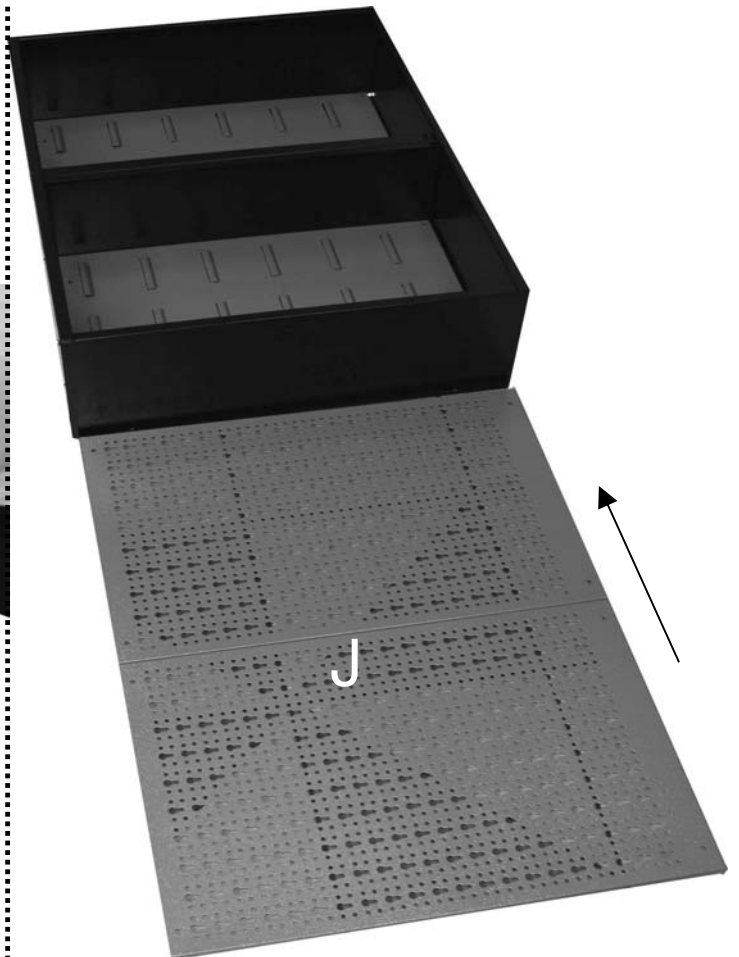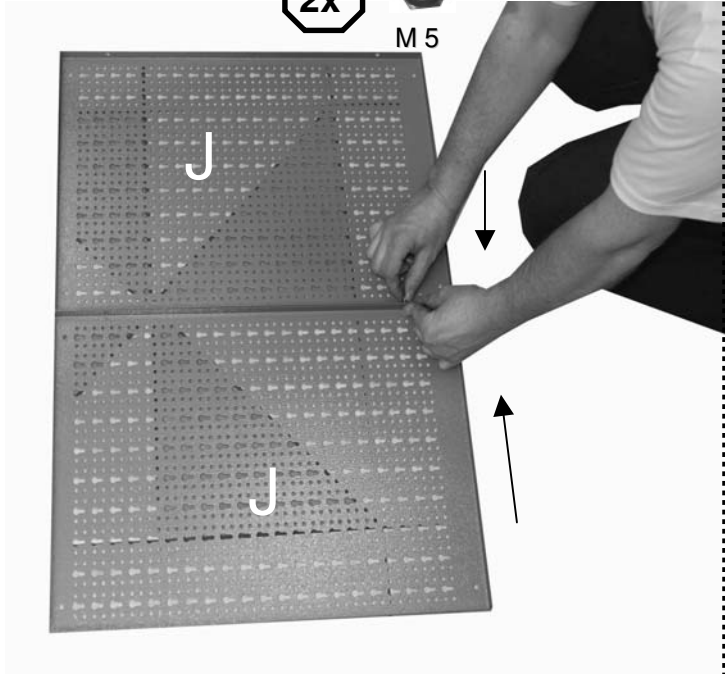

14.

2x



M5 x 10

2x



5,3

2x



M5




PH 2 x 100



SW 8





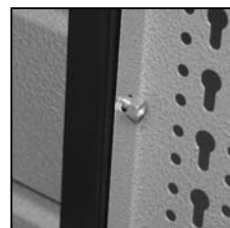


Soft !




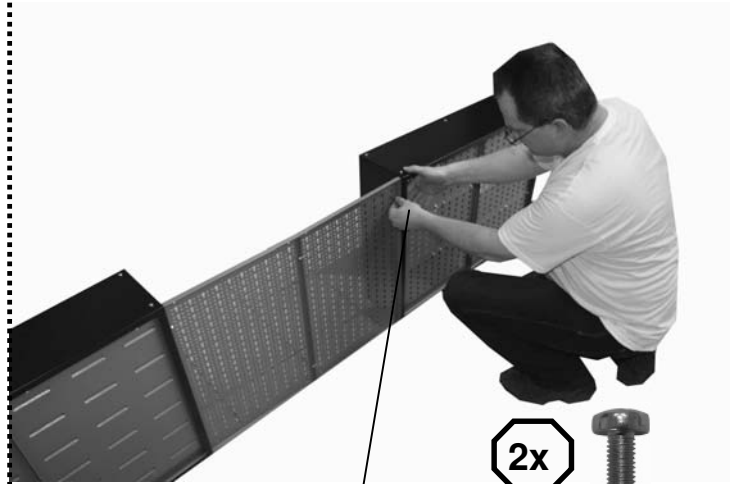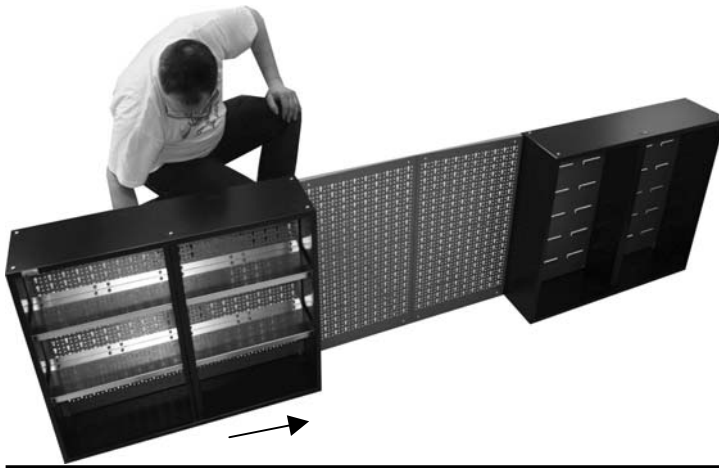



15.



- 2x  M5 x 10
- 2x  5,3
- 2x  M 5

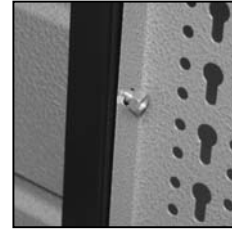

16.

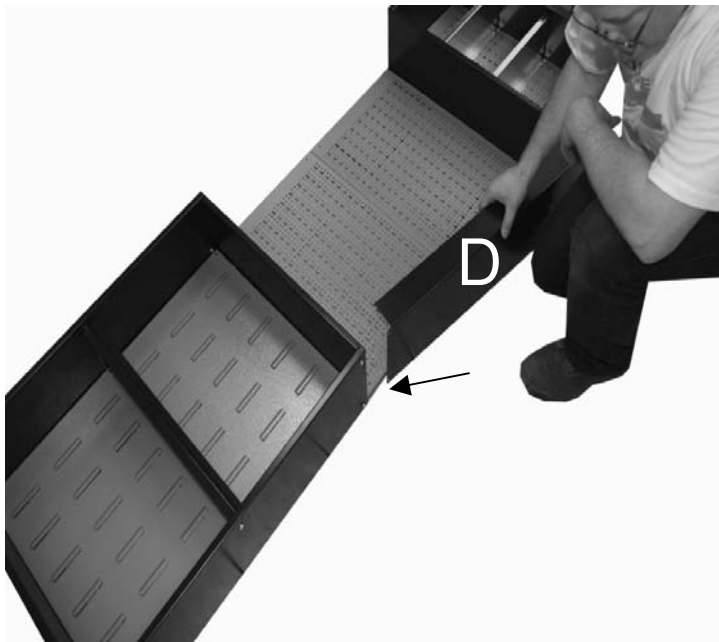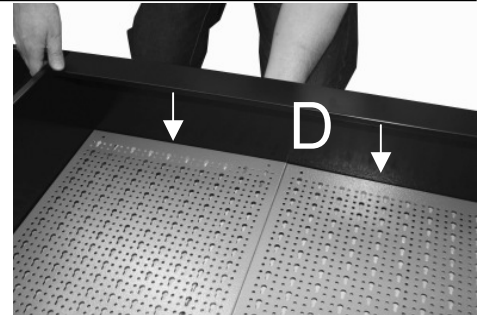



fix !



PH 2 x 100



SW 8

17.




fix !



PH 2 x 100






SW 8

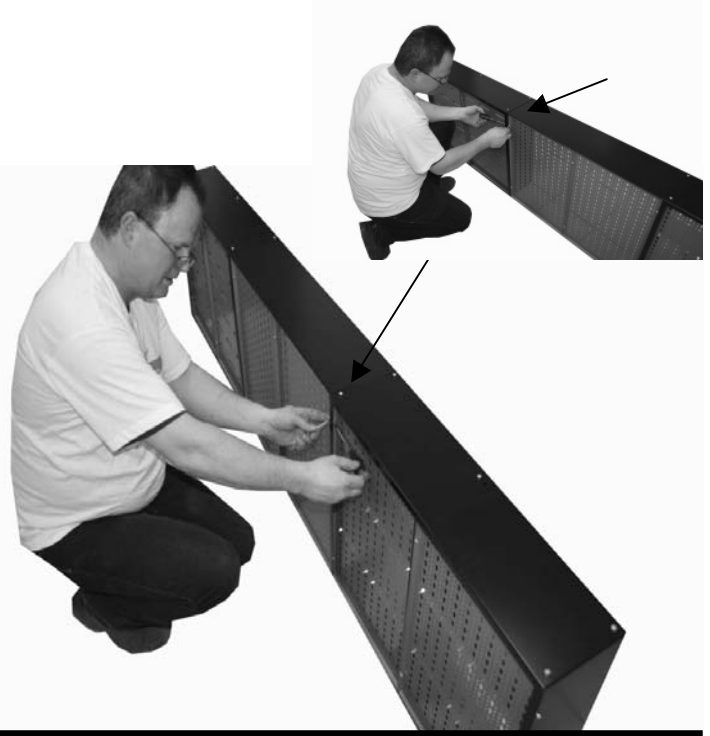




18.

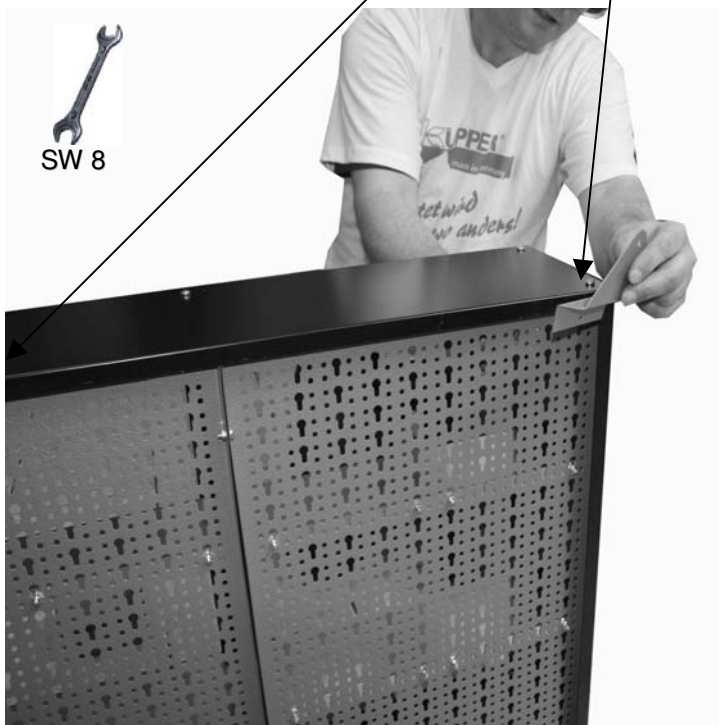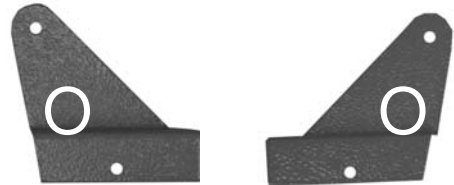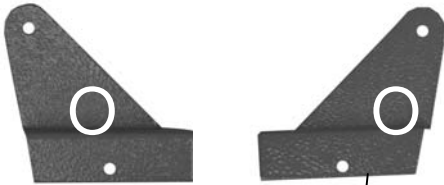


PH 2 x 100




SW 8

- 4x**  M5 x 10
- 4x**  5,3
- 4x**  M 5

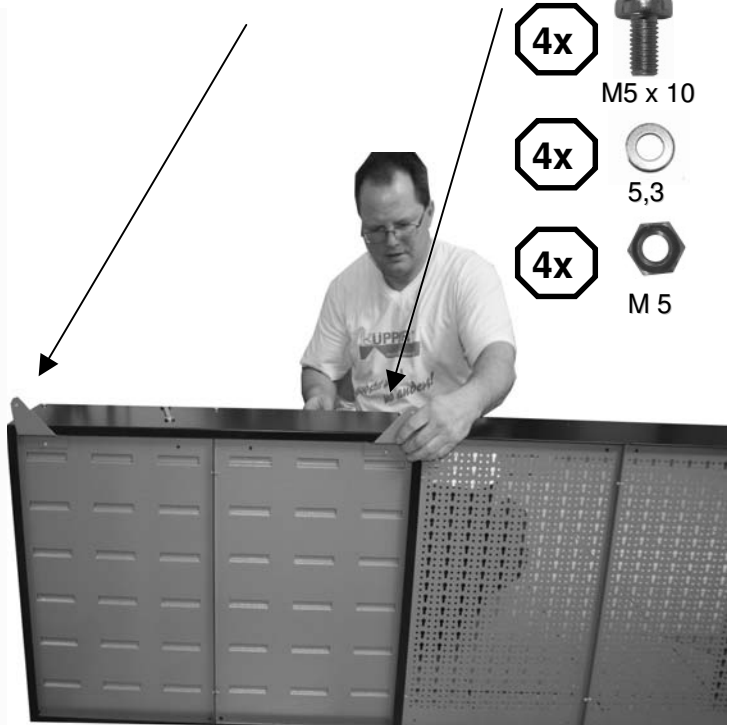




19.

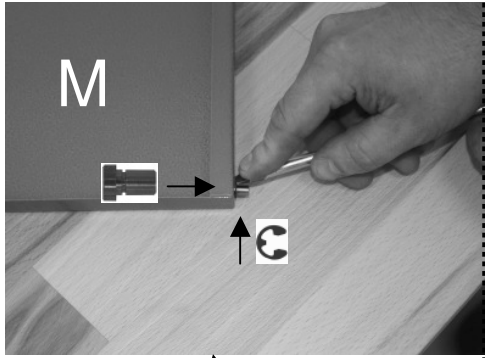

8x



8x

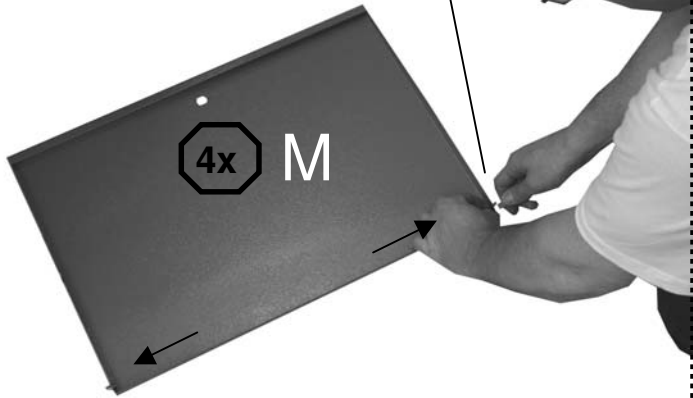


4x

M




8x

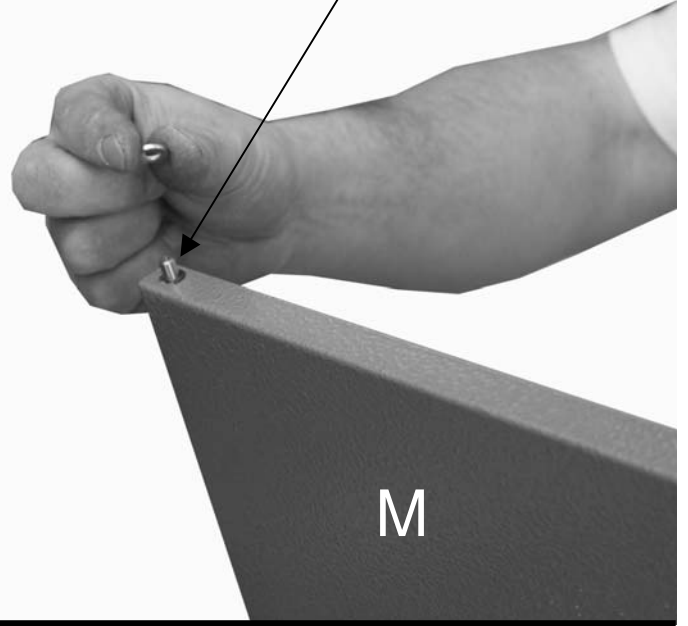

M

20.

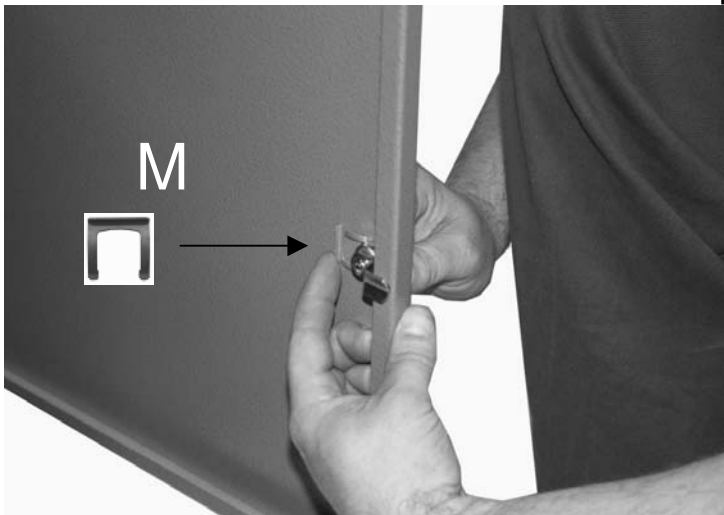

M



fix !



PH 2 x 100




SW 8

4x



4x

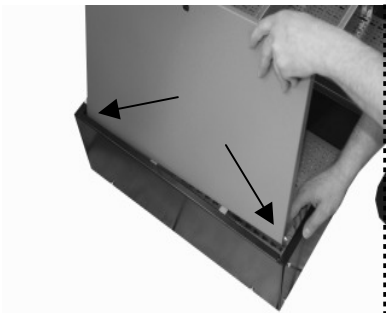



21.




fix !



PH 2 x 100




SW 8

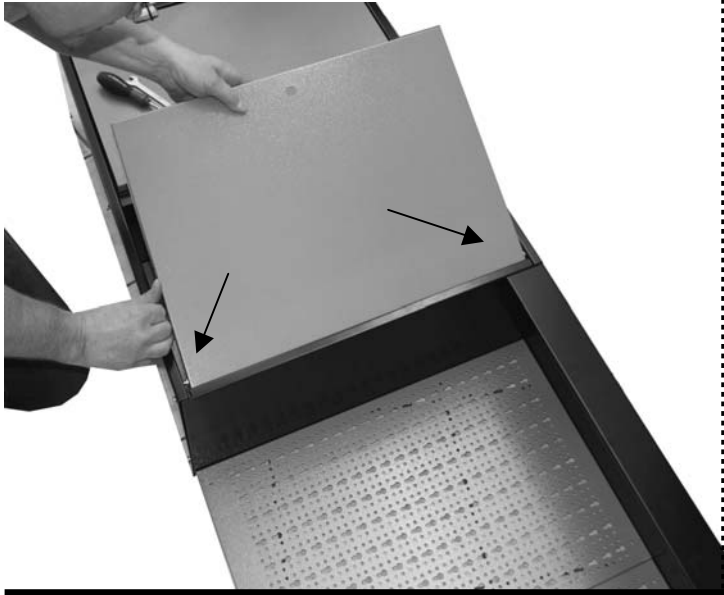


22.

 
12x



24x



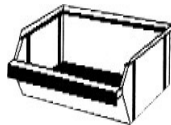


12x

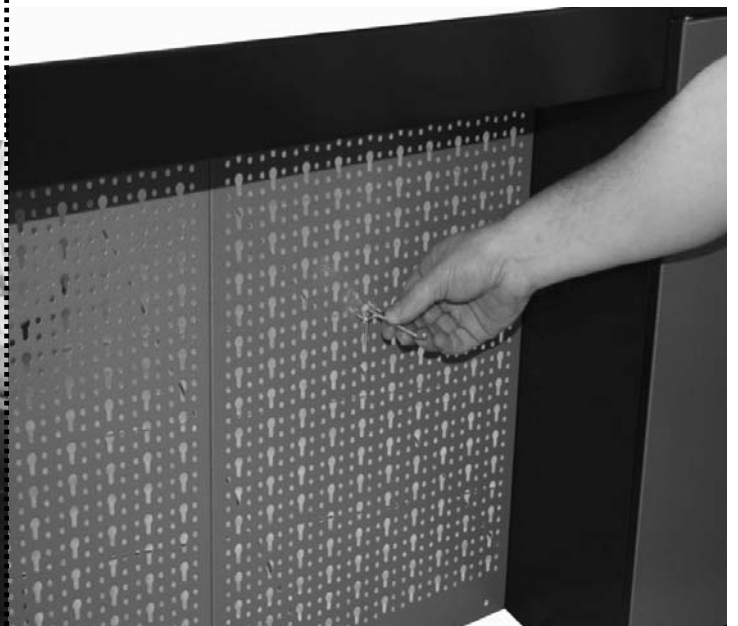




23.

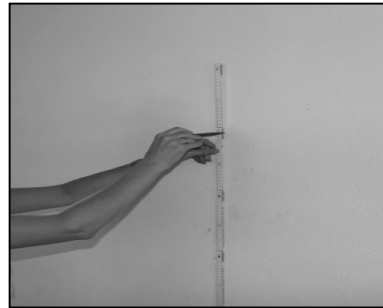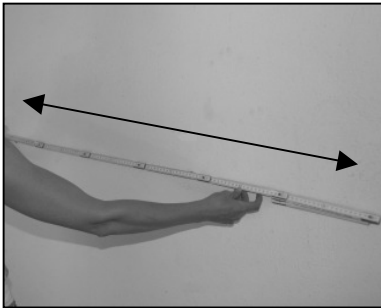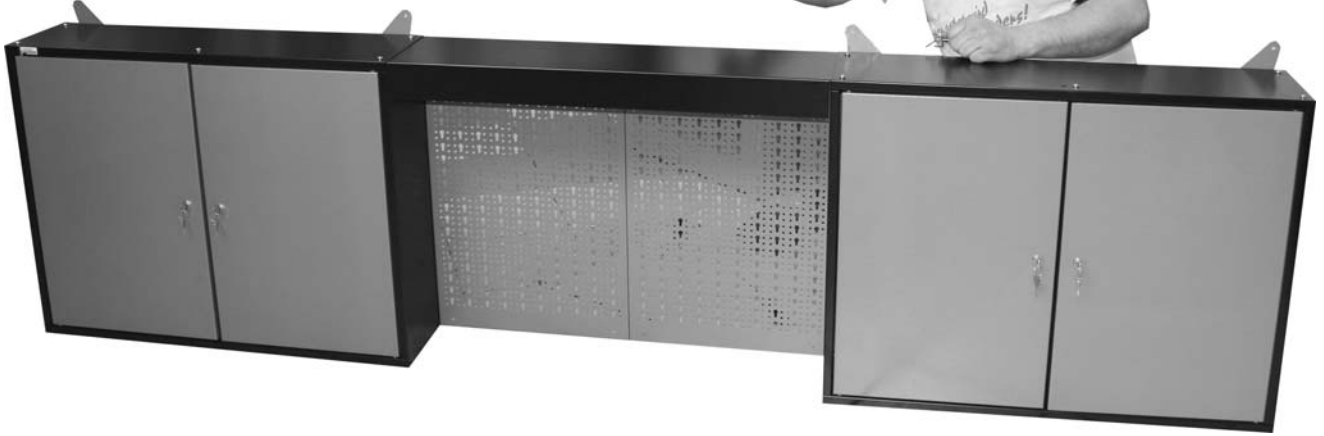

6 mm

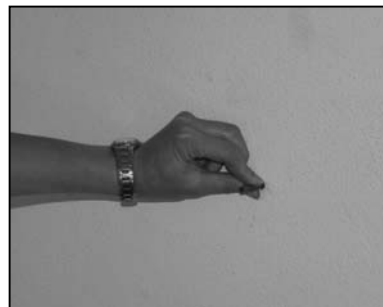

8 x
6 mm

