



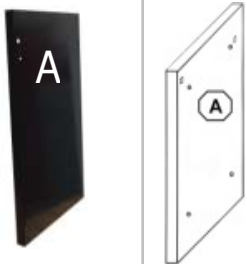
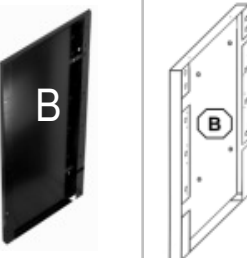
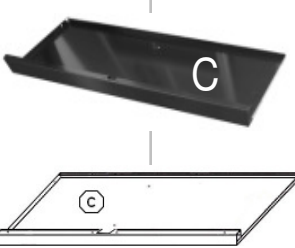








-  MONTAGEANLEITUNG
-  ASSEMBLY INSTRUCTION
-  DE INSTRUCTIE VAN DE ASSEMBLAGE
-  ISTRUZIONE DELL'ASSEMBLEA
-  INSTRUCCIÓN DE ASAMBLEA
-  INSTRUCTION DE MONTAGE
-  NÁVOD K MONTÁŽI
-  MONTERINGSANVISNING
-  MONTAJ TALIMATI
-  ASENUSOHJE
-  BRUGSANVISNING
-  BRUKSANVISNING
-  UPUTE ZA MONTAŽU
-  NAVODILA ZA MONTAŽO
-  GYŰLÉS OKTATÁS
-  INSTRUCȚIUNI DE MONTAJ

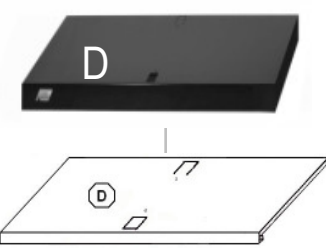

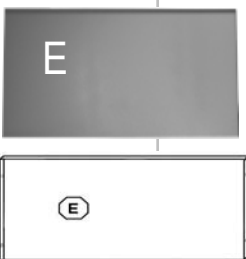

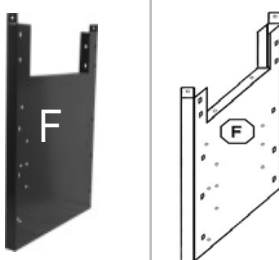

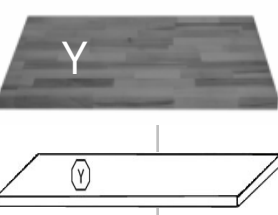

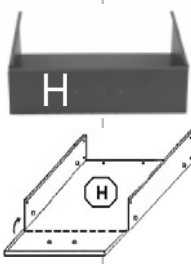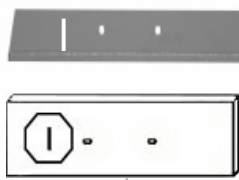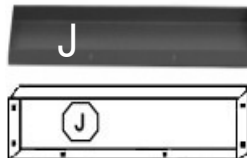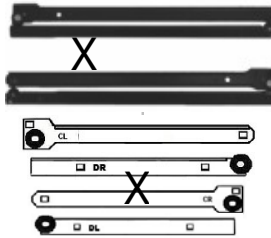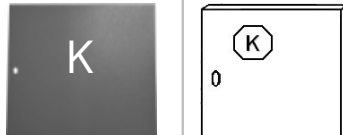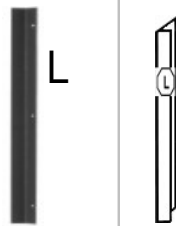








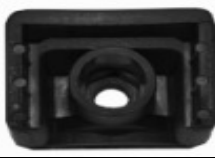




Art.-Nr. 12040

(12041, 12042, 12044, 12046, 12047)

1x		772 x 475 mm
1x		772 x 475 mm
1x		1057 x 473 mm
1x		1057 x 473 mm
1x		985 x 480 mm
1x		645 x 450 mm
1x		1200 x 600 mm


5x		450 x 445 mm
5x		470 x 130 mm
5x		450 x 120 mm
5x		450 x 20 mm
1x		468 x 403 mm
1x		400 x 25 mm

6x		5,5 x 19
10x		KU 4,2 x 13
18x		M5 x 10
18x		5,3
18x		M5
40x		M4 x 10
40x		M4
1x		M6 x 16
2x		6,4
1x		M6


1x		6 x 12
1x		
4x		
4x		8,3
8x		M8
4x		
5x		
5x		
1x		
1x		




1. – 6.

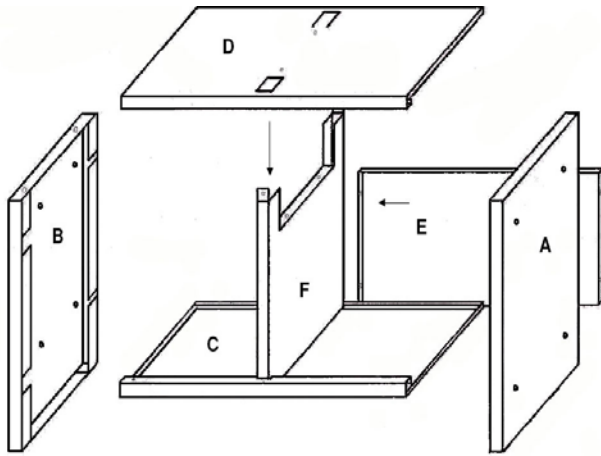


7./9./10.

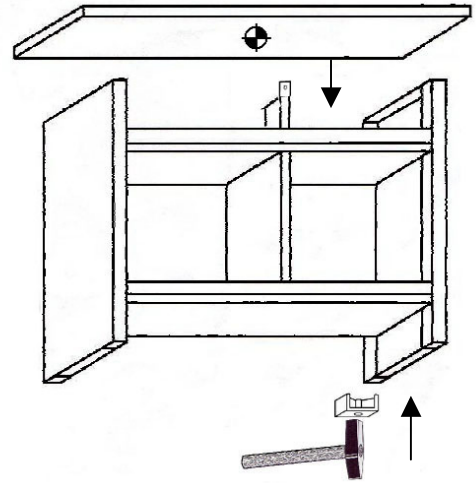


15.

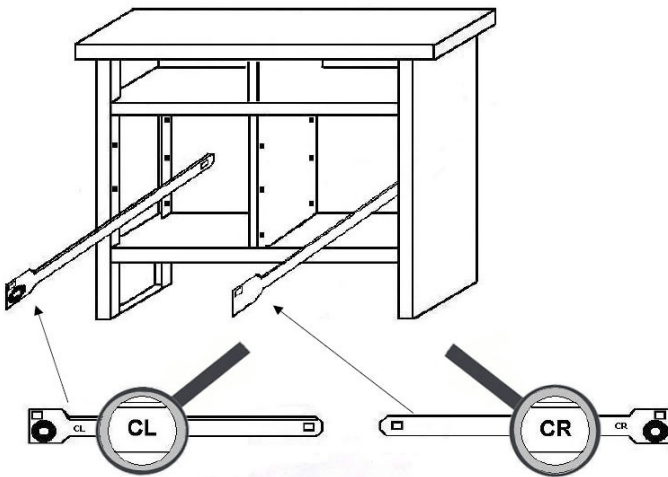

8./11./12./13.

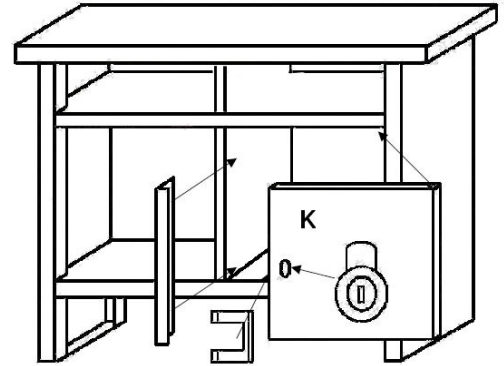

14. / 16.



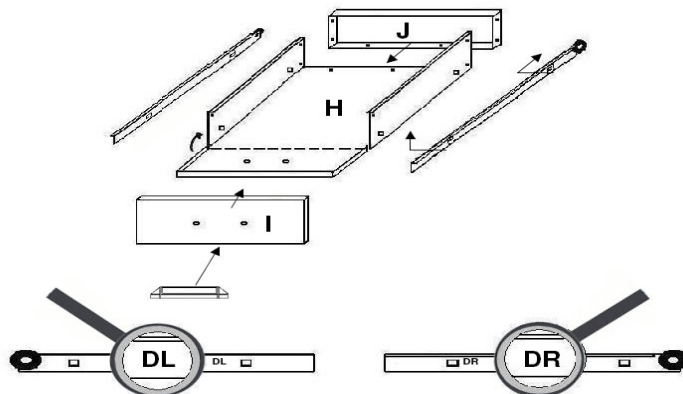




1.





2.

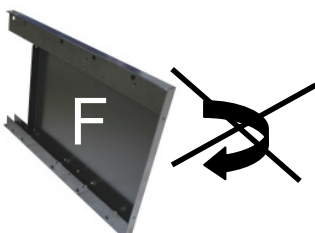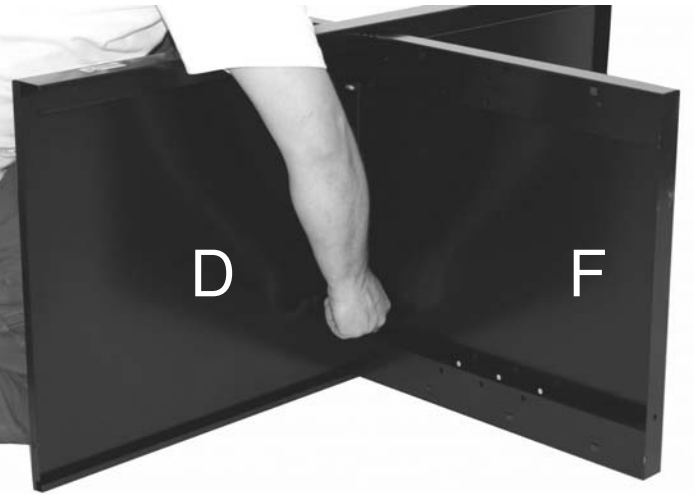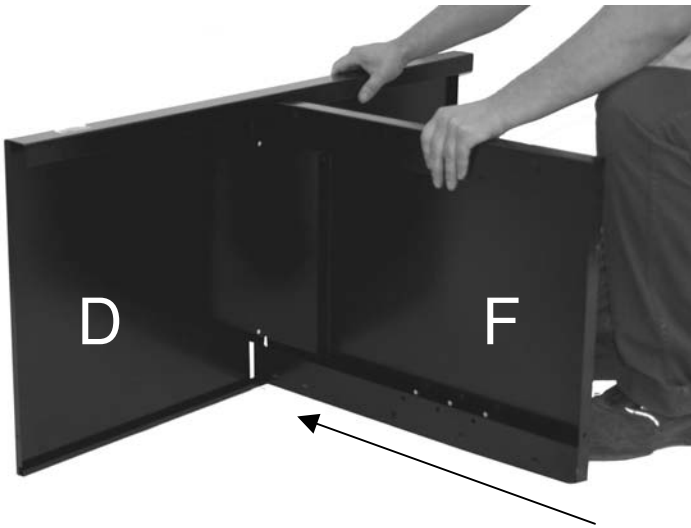



3.

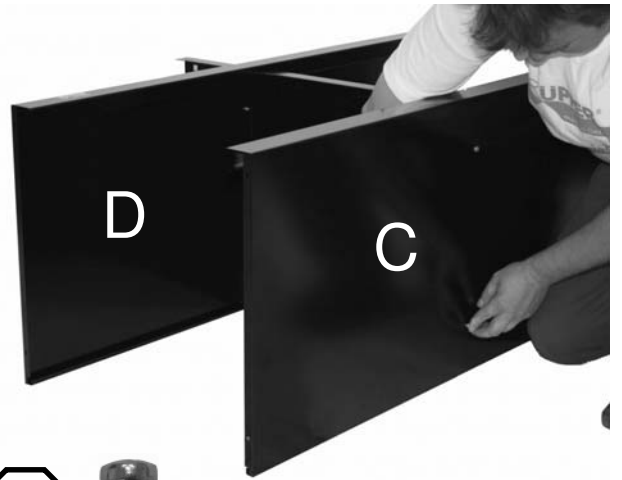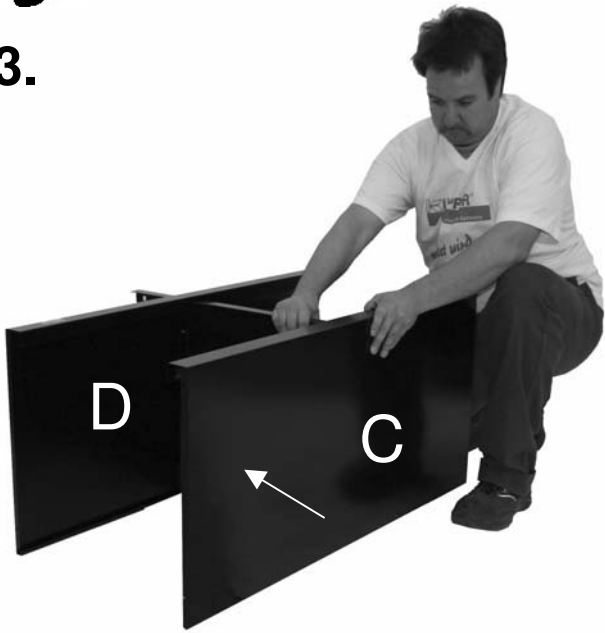

2x



M5 x 10

2x



5,3

2x



M5





PH 2 x 100





SW 8

4.

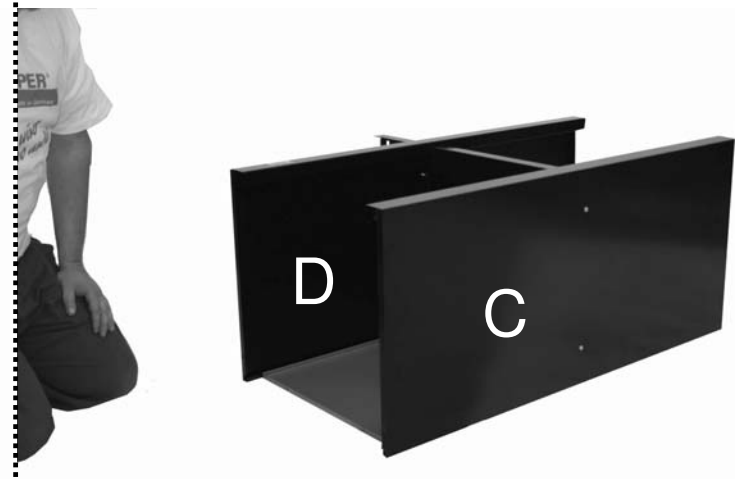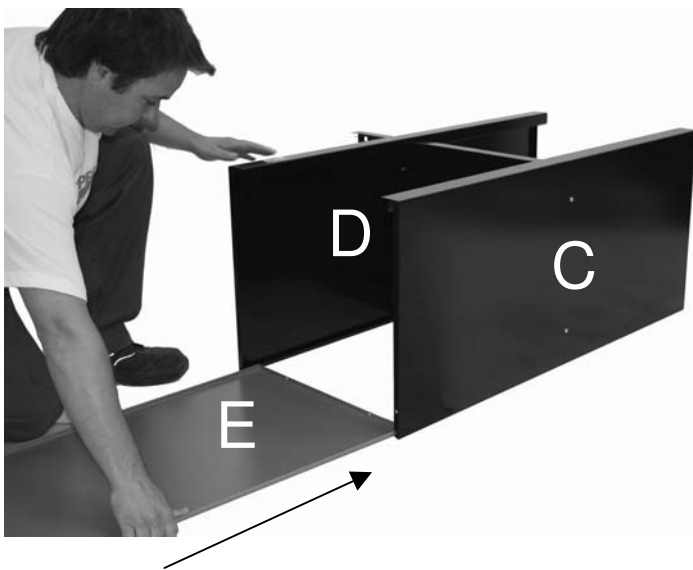



5.

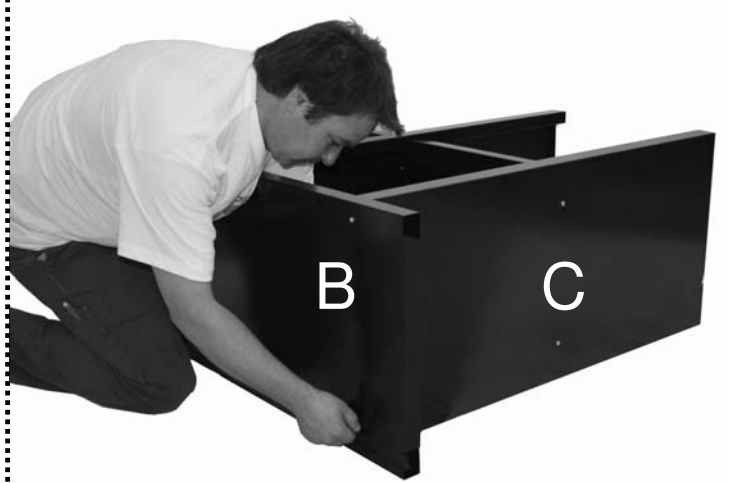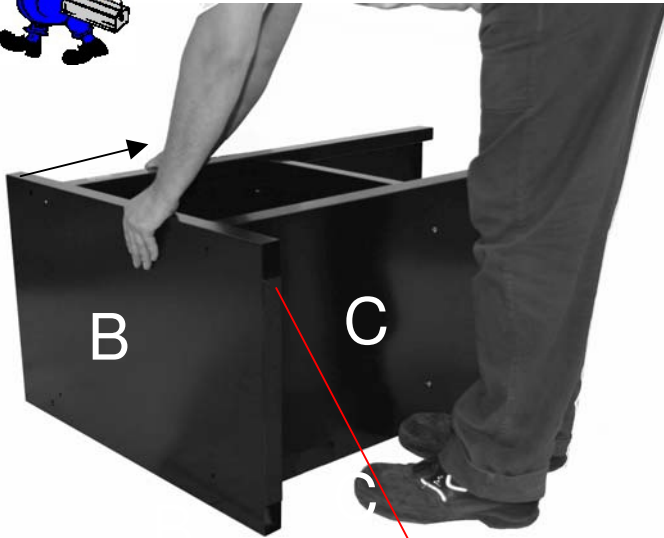

4x



4x





4x



PH 2 x 100

SW 8

6.

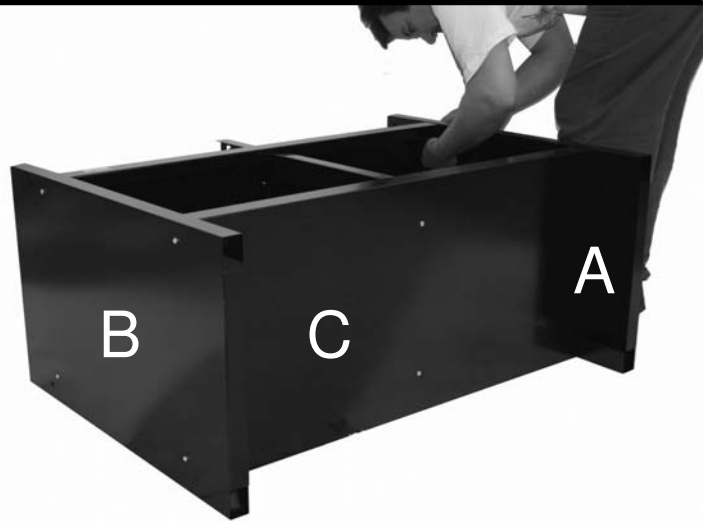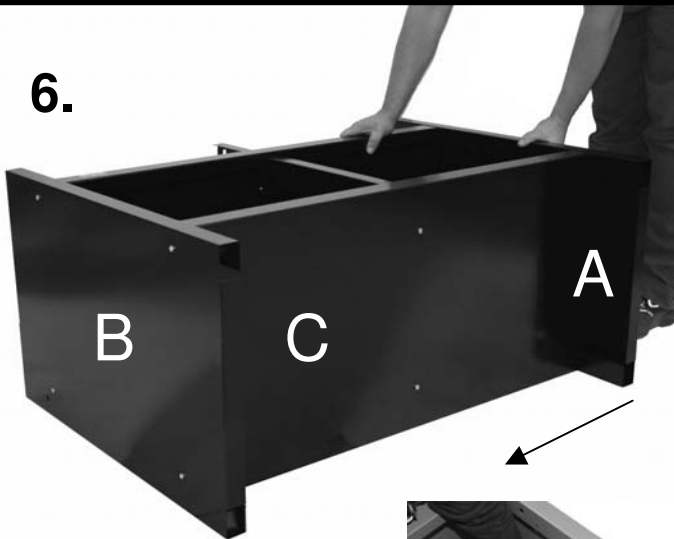

4x



4x



4x



PH 2 x 100



SW 8



4x



4x



4x








PH 2 x 100




SW 8



7.


- 4x 
- 4x  M 8
- 4x  8,3
- 4x 
- 4x  M 8

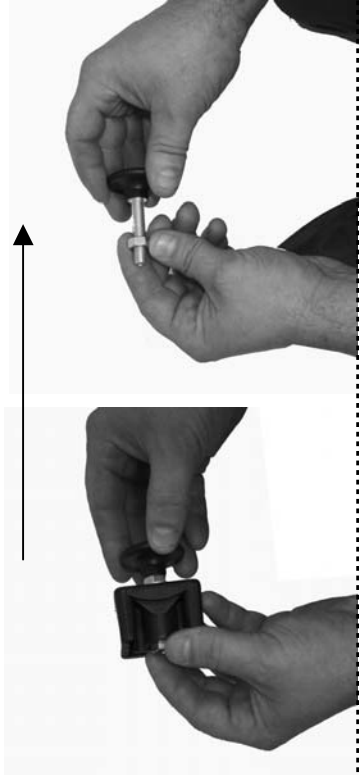





8.

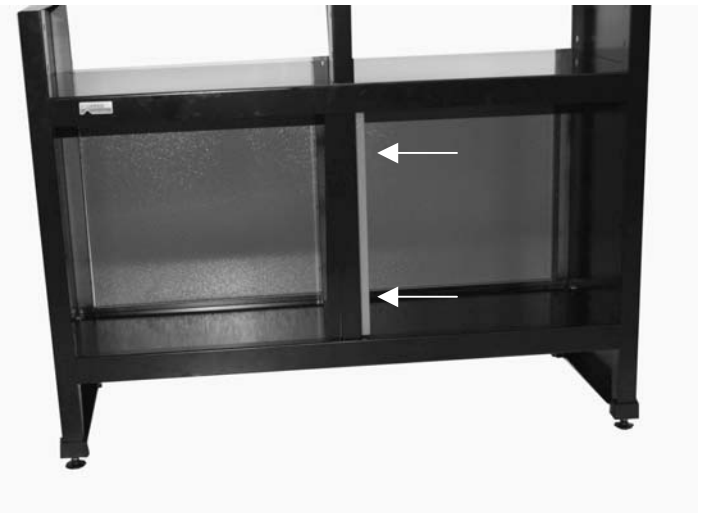

- 1x  L



- 2x  M5 x 10
- 2x  5,3
- 2x  M 5
-  PH 2 x 10
-  SW 8




9.

90°


F



Y

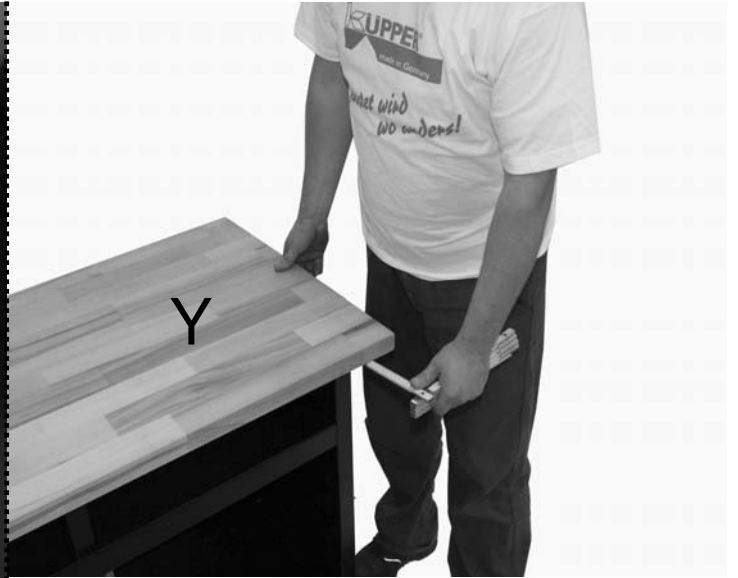

10.

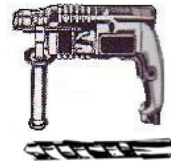

4 mm

↓ Max. 20 mm ↓

180°



6x




5,5 x 19





SW 8



11.

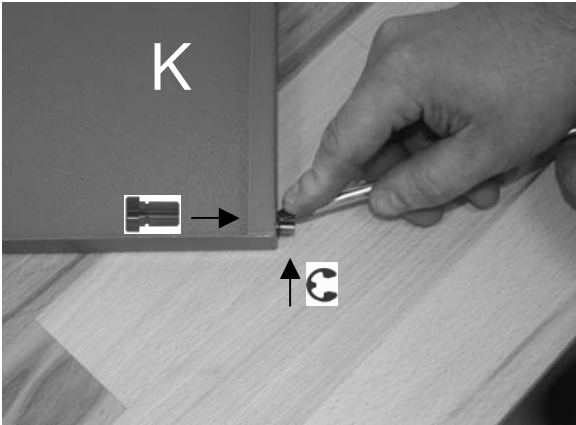


12.

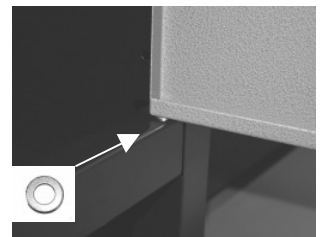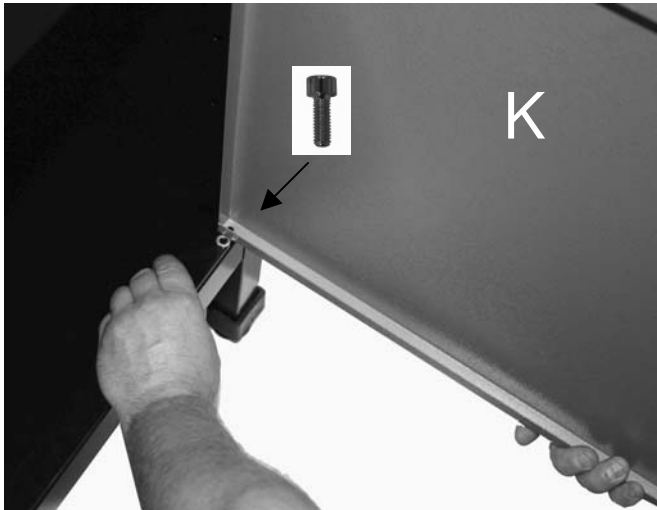



13.

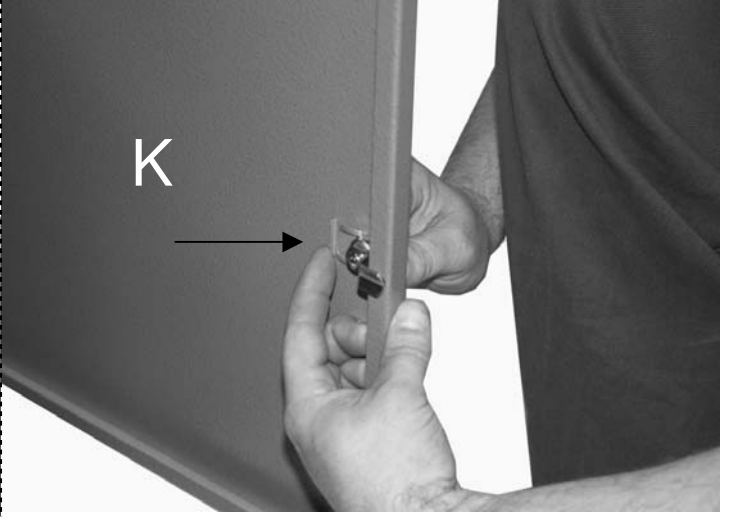

1x



1x



14.



40x



M4 x 10

40x



M4





PH 1 x 100




SW 7



15.

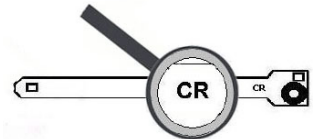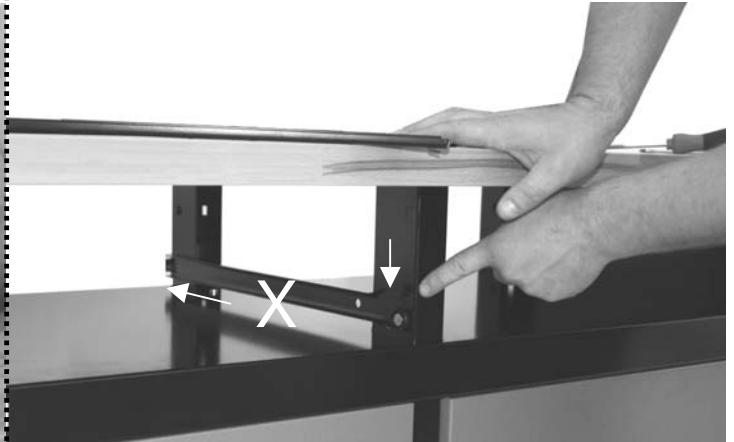

16.

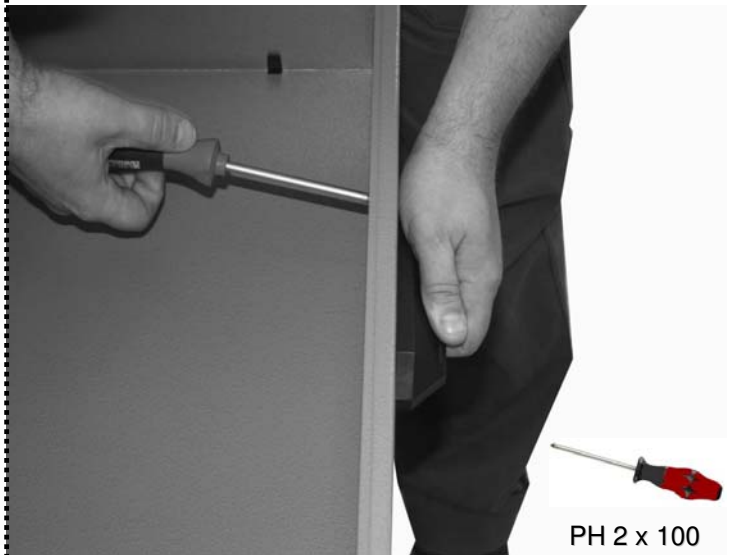


10x




KU 4



5x

 
 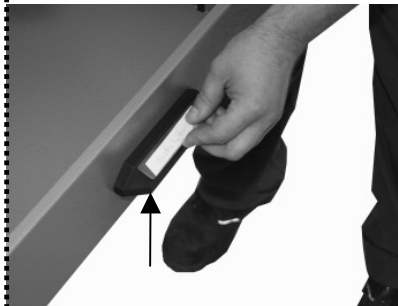

 




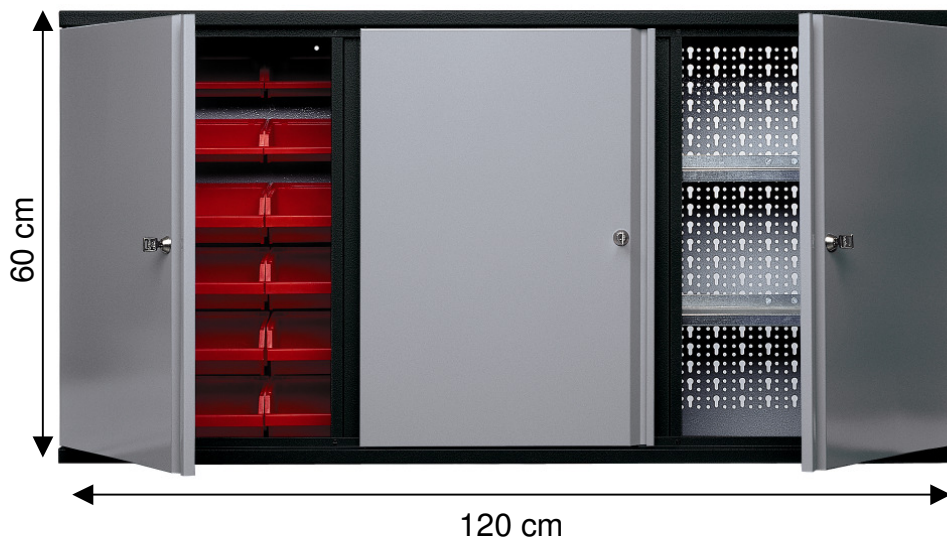


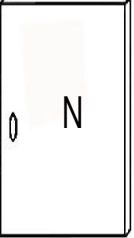





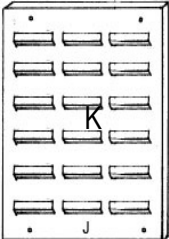

 
 

 
-  MONTAGEANLEITUNG
-  ASSEMBLY INSTRUCTION
-  DE INSTRUCTIE VAN DE ASSEMBLAGE
-  ISTRUZIONE DELL'ASSEMBLEA
-  INSTRUCCIÓN DE ASAMBLEA
-  INSTRUCTION DE MONTAGE
-  NÁVOD K MONTÁŽI
-  MONTERINGSANVISNING
-  MONTAJ TALIMATI
-  ASENNUSOHJE
-  BRUGSANVISNING
-  BRUKSANVISNING
-  UPUTE ZA MONTAŽU
-  NAVODILA ZA MONTAŽO
-  GYŰLÉS OKTATÁS
-  INSTRUCȚIUNI DE MONTAJ









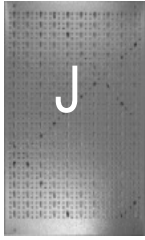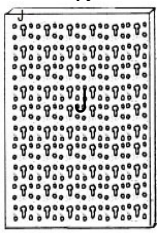



Art.-Nr. 70190

(70191, 70192, 70194, 70196, 70197)

2x	 	1200 x 200 mm
2x	 	200 x 600 mm
1x	 	180 x 600 mm
1x	 	180 x 600 mm
2x	 	375 x 560 mm
1x	 	400 x 560 mm


2x	 	400 x 595 mm
1x	 	400 x 595 mm
2x	 	390 x 140 mm
1x		100 x 90 mm
18x	 	130 x 100 x 50 mm

30x		M5 x 10
30x		5,3
30x		M5
6x		6 x 12
6x		
6x		6,4


3x		
3x		
4x		4,5 x 45
4x		E 6 x 30




1. – 3.

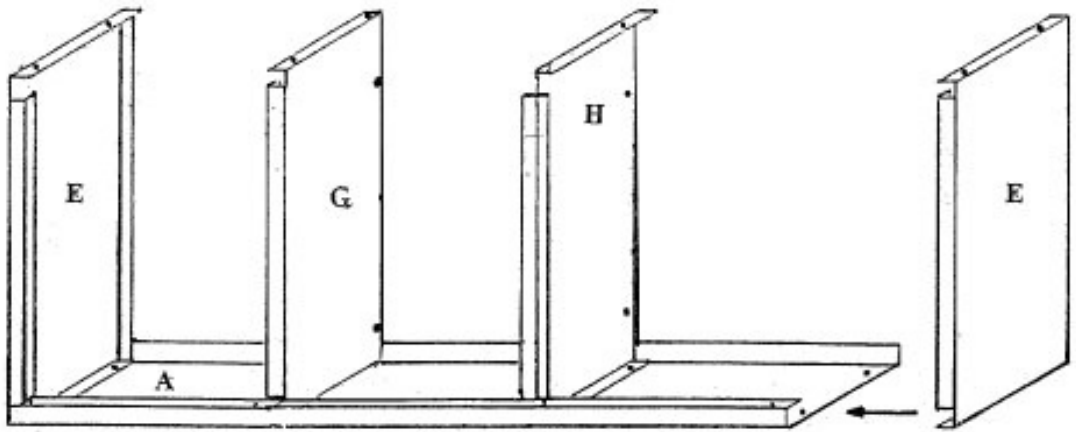

4. – 8.

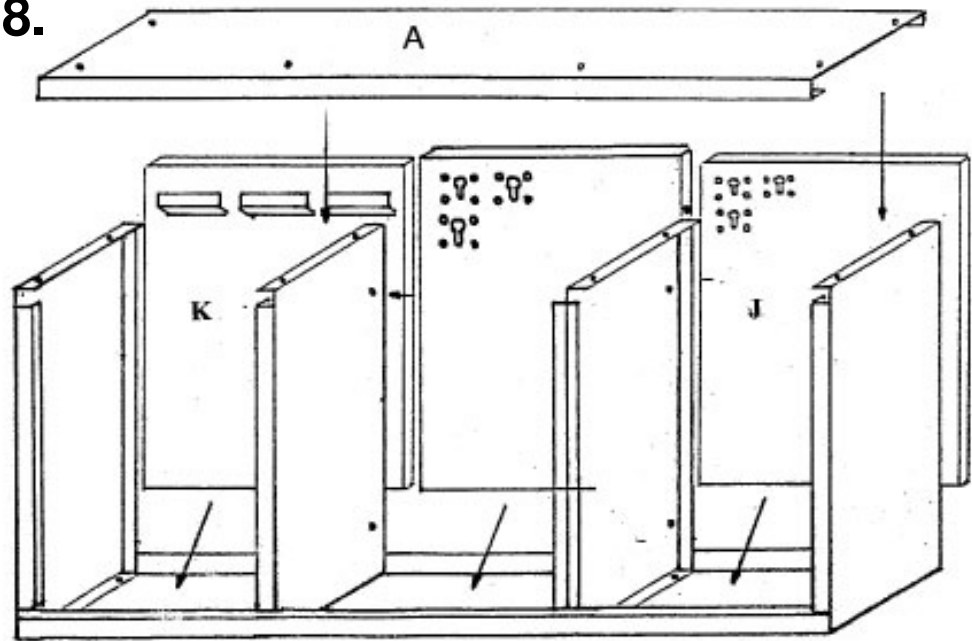


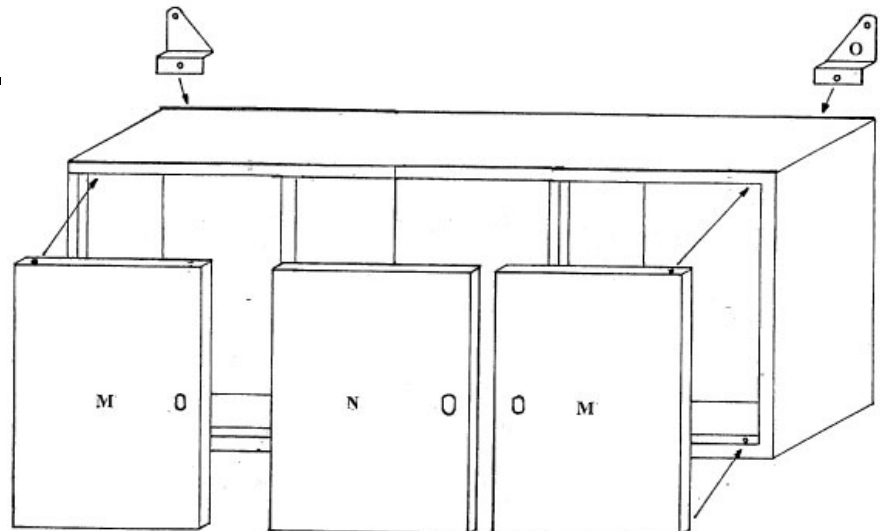


9. – 13.



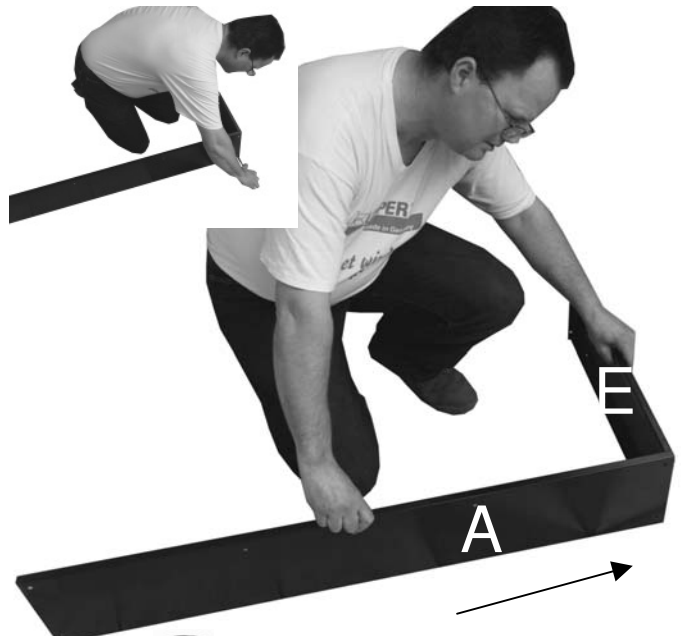



1.






- 2x  M5 x 10
- 2x  5,3
- 2x  M 5



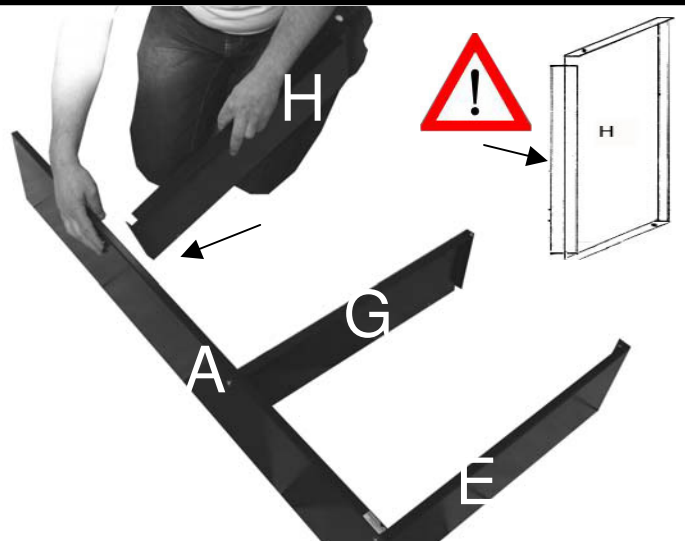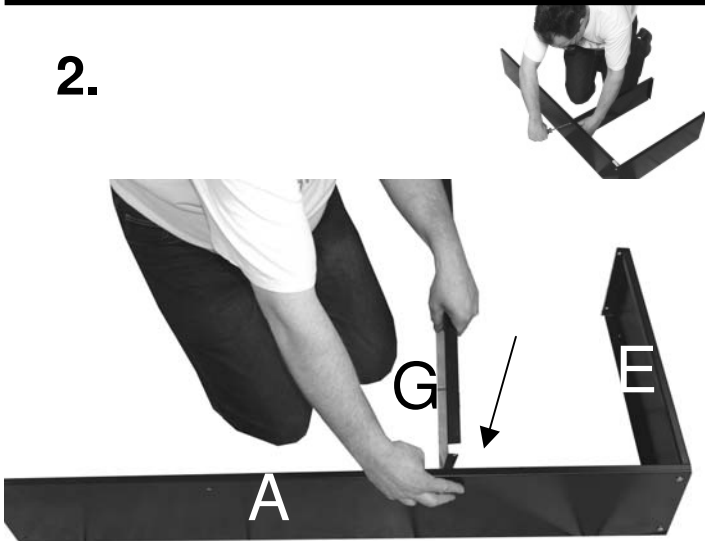


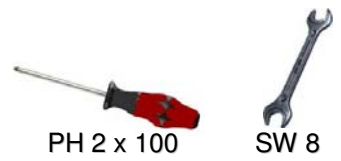
2.



- 1x  M5 x 10
- 1x  5,3
- 1x  M 5



- 1x  M5 x 10
- 1x  5,3
- 1x  M 5











3.




PH 2 x 100





SW 8

-   M5 x 10
-   5,3
-   M 5


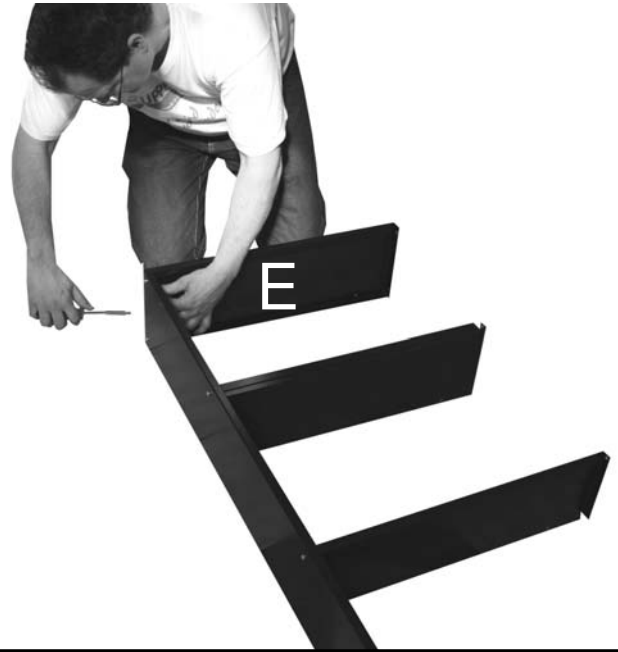


4.

 2x

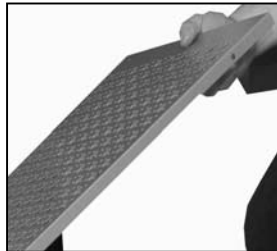

1x

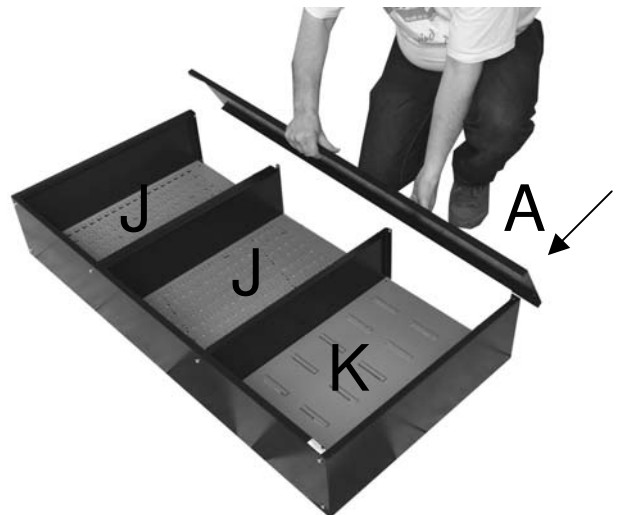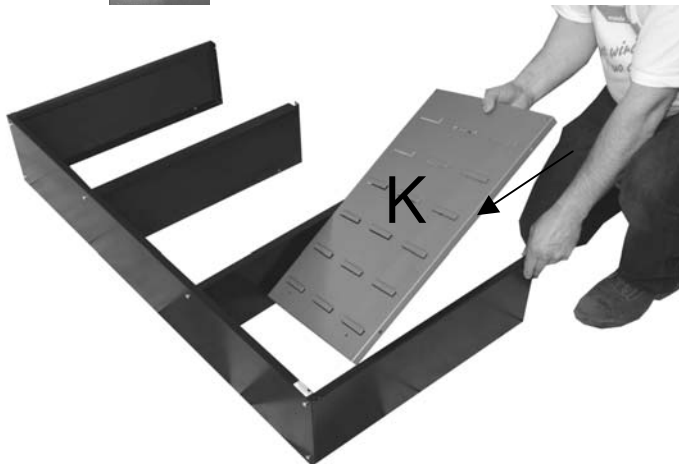



5.

6x



6x



6x



Soft !



4x



6.



fix !




PH 2 x 100



SW 8

2x

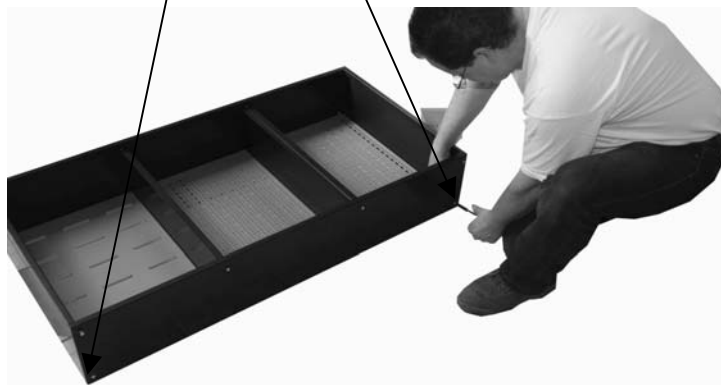

4x



4x




4x



PH 2 x 100




SW 8

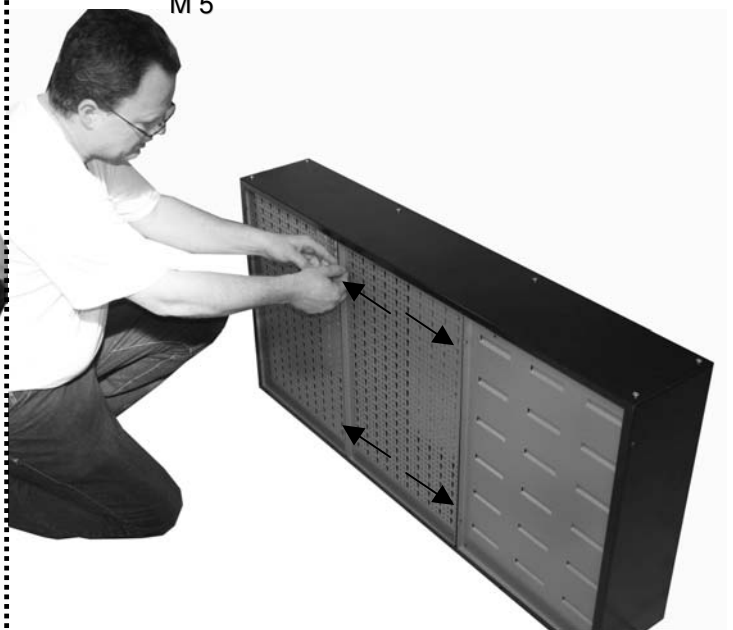



7.

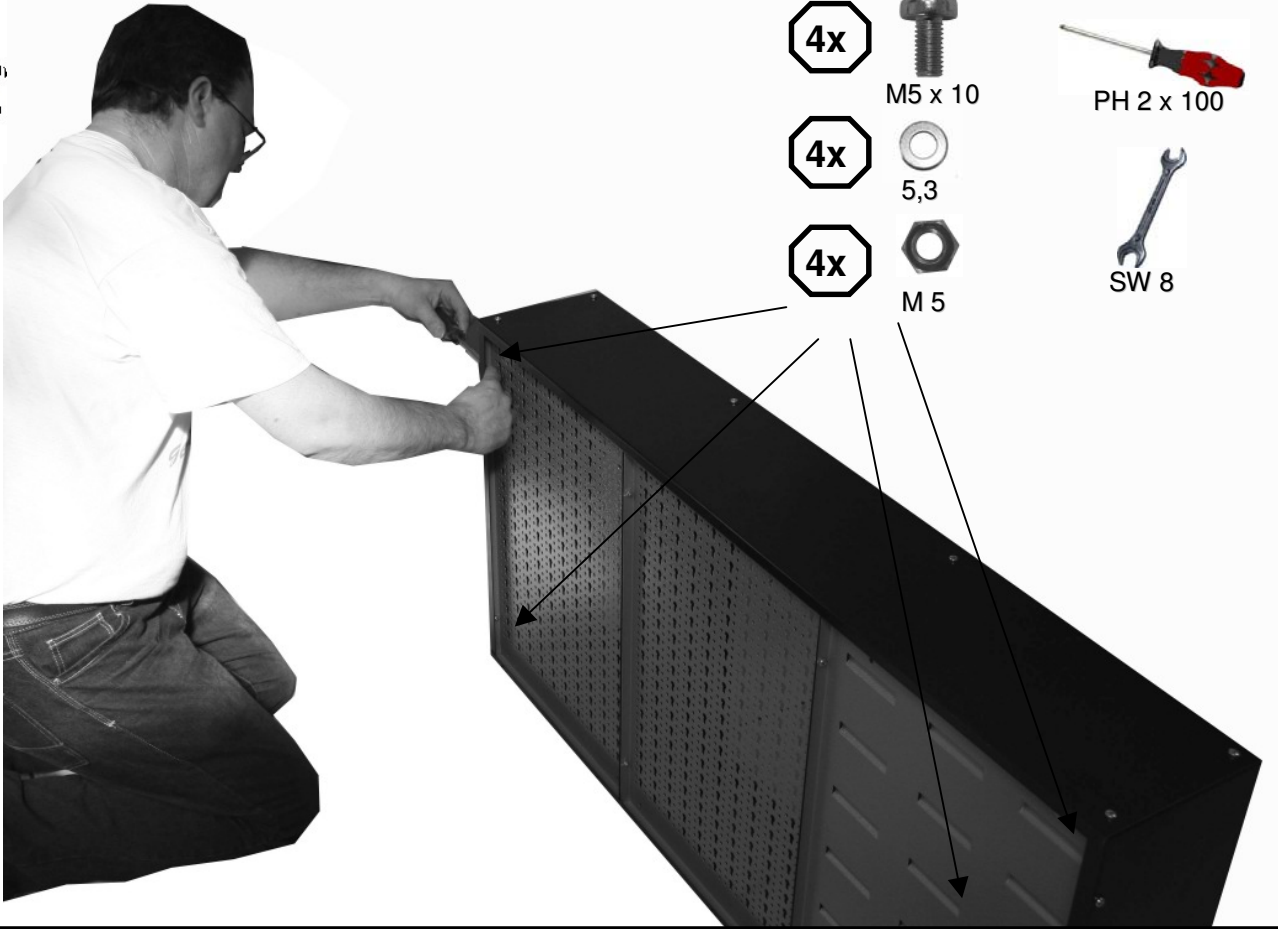

4x



4x



4x



PH 2 x 100



SW 8

8.

2x



8x



M5 x 10

8x



5,3

8x





M5



PH 2 x 100

SW 8

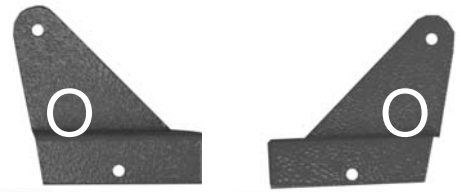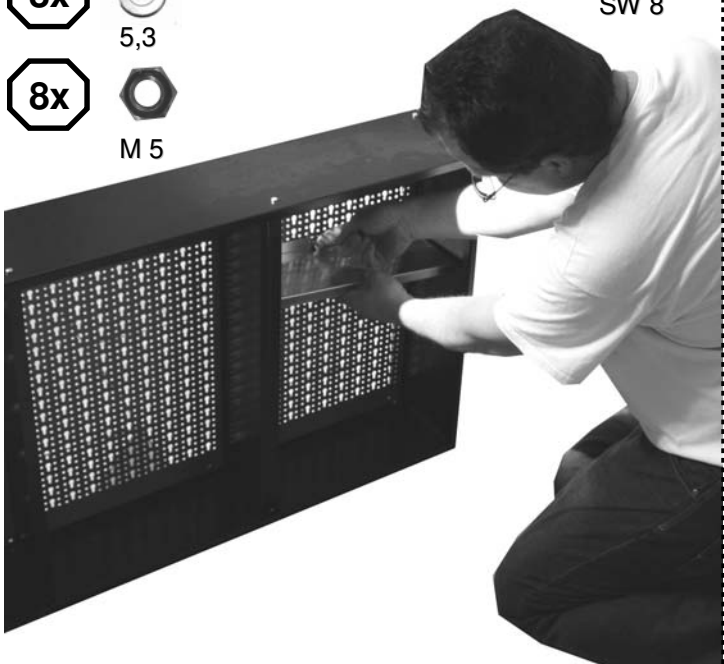

2x



M5 x 10

2x




5,3

2x






M5

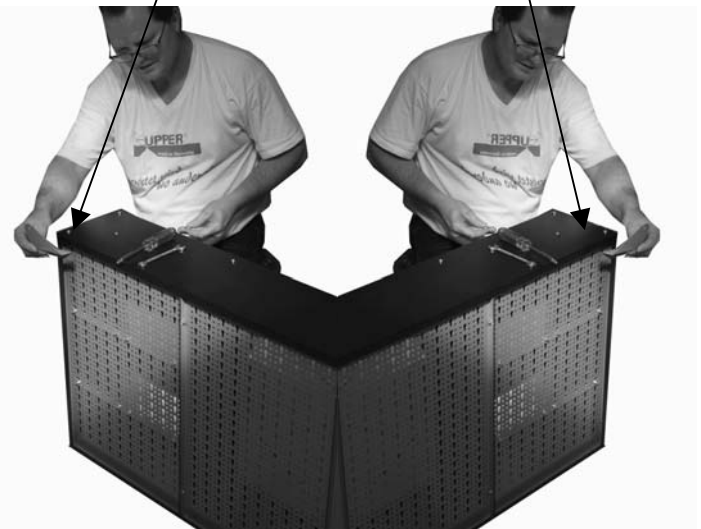



9.

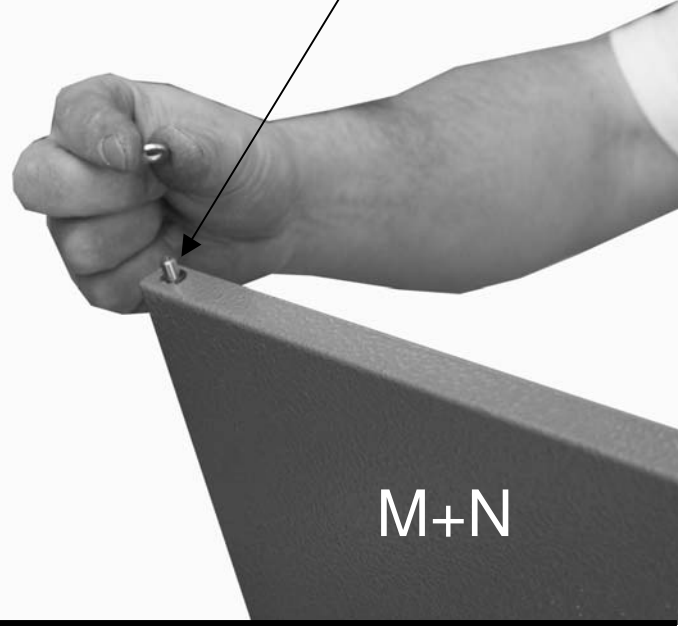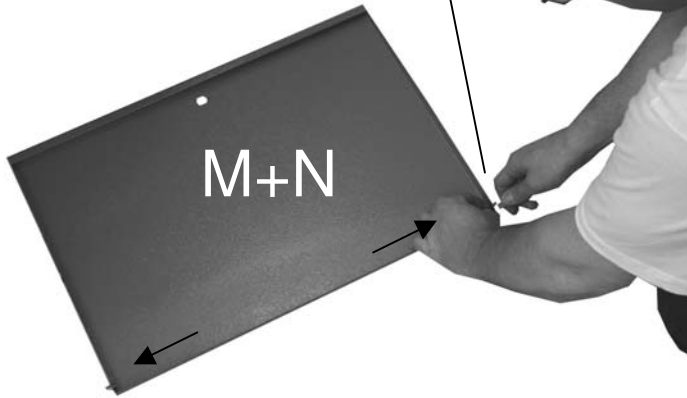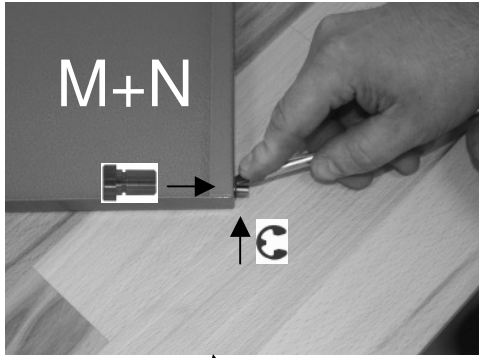

10.




fix !



PH 2 x 100



SW 8


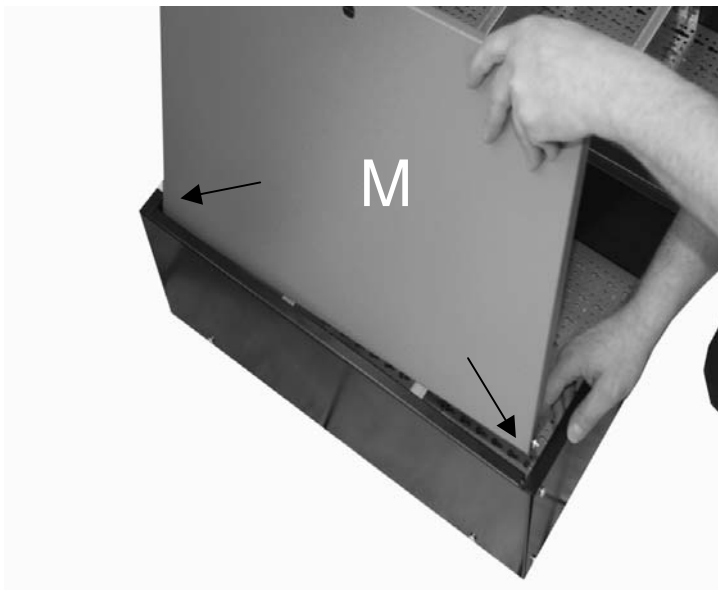




11.



400 mm

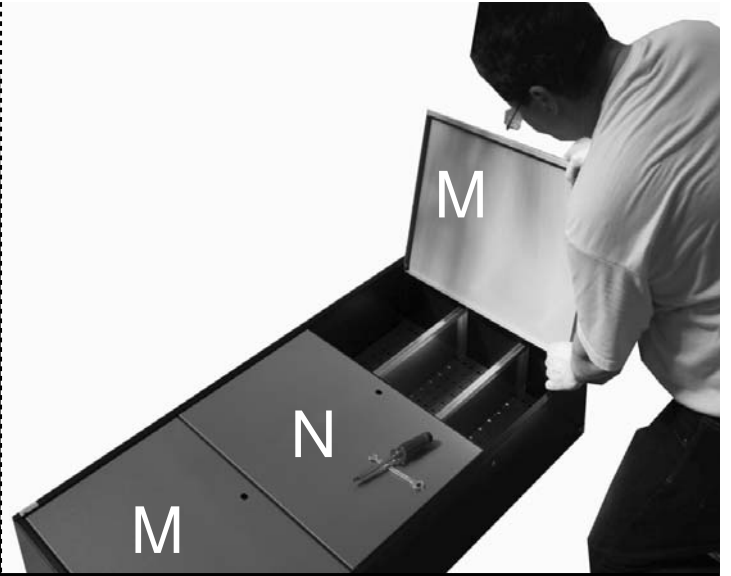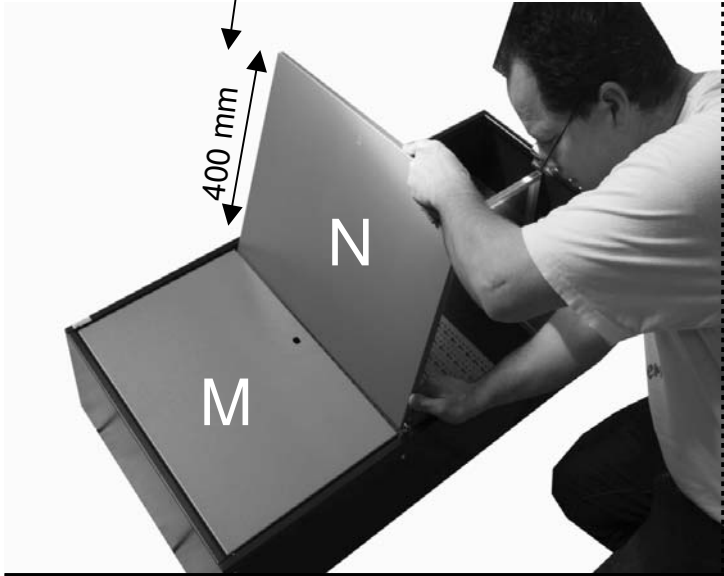

12.




fix !



PH 2 x 100



SW 8

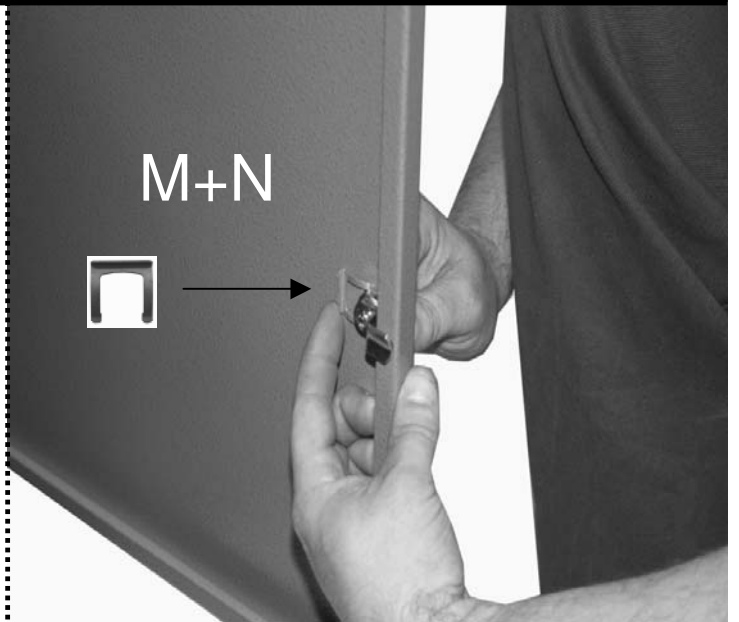

3x



3x





13.



