




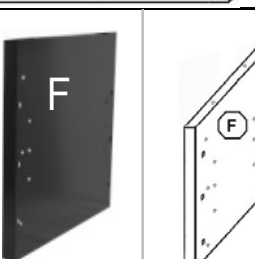
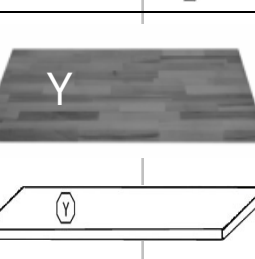








-  MONTAGEANLEITUNG
-  ASSEMBLY INSTRUCTION
-  DE INSTRUCTIE VAN DE ASSEMBLAGE
-  ISTRUZIONE DELL'ASSEMBLEA
-  INSTRUCCIÓN DE ASAMBLEA
-  INSTRUCTION DE MONTAGE
-  NÁVOD K MONTÁŽI
-  MONTERINGSANVISNING
-  MONTAJ TALIMATI
-  ASENNUSOHJE
-  BRUGSANVISNING
-  BRUKSANVISNING
-  UPUTE ZA MONTAŽU
-  NAVODILA ZA MONTAŽO
-  GYŰLÉS OKTATÁS
-  INSTRUȚIUNI DE MONTAJ

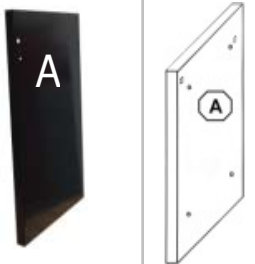

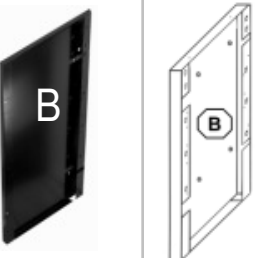

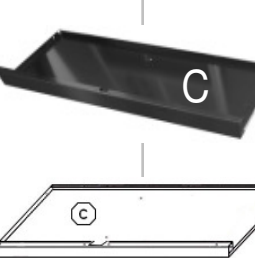

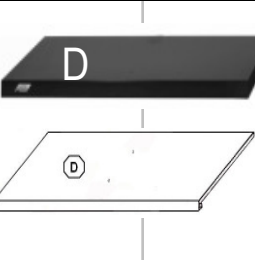

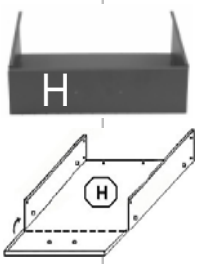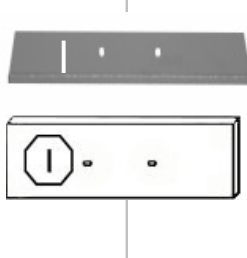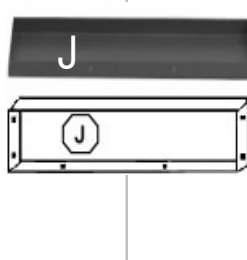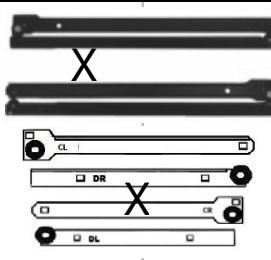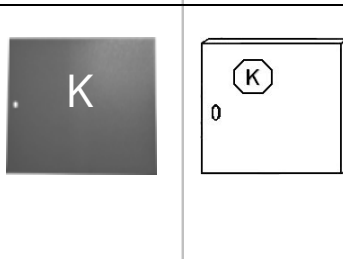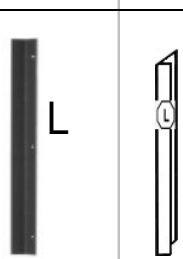













Art.-Nr. 12080

(12081, 12082, 12084, 12086, 12087)

1x		772 x 475 mm
1x		772 x 475 mm
1x		1057 x 473 mm
1x		1057 x 473 mm
1x		985 x 480 mm
1x		505 x 450 mm
1x		1200 x 600 mm


3x		450 x 445 mm
3x		470 x 130 mm
3x		450 x 120 mm
3x		450 x 20 mm
1x		468 x 403 mm
1x		400 x 25 mm

4x		5,5 x 19
6x		KU 4,2 x 13
18x		M5 x 10
18x		5,3
18x		M5
24x		M4 x 10
24x		M4
1x		M6 x 16
2x		6,4
1x		M6


1x		6 x 12
1x		
4x		
4x		8,3
8x		M8
4x		
3x		
3x		
1x		
1x		




1. – 6.

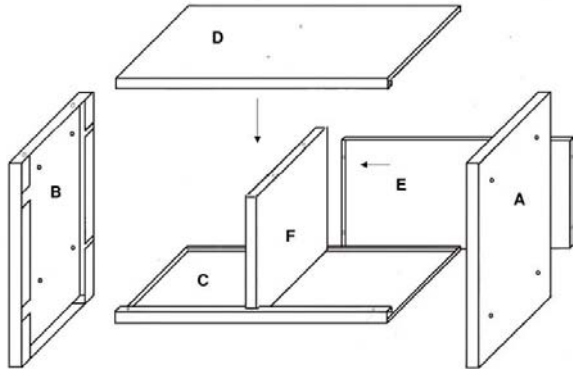


7./9./10.

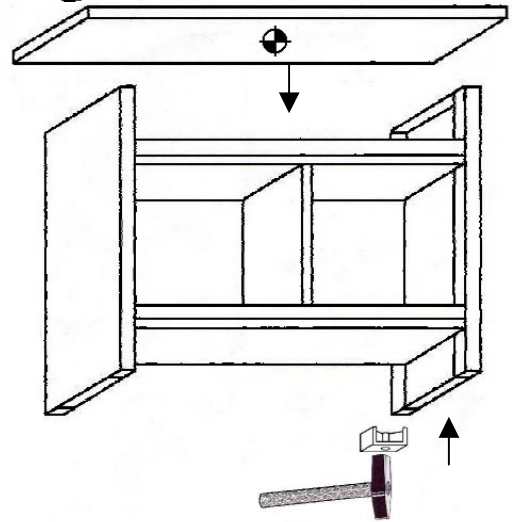


15.

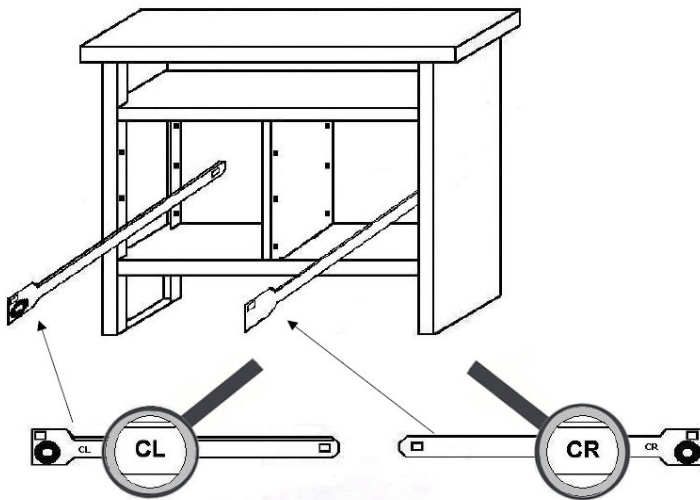

8./11./12./13.

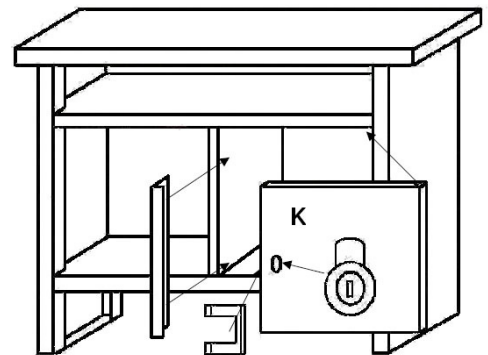

14. / 16.




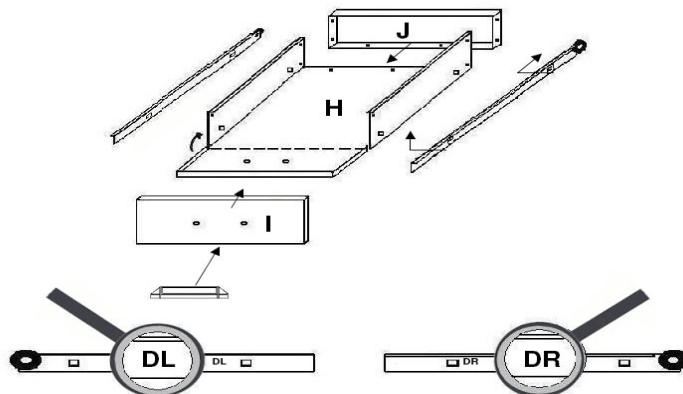




1.



2.

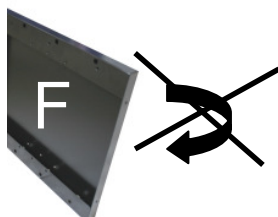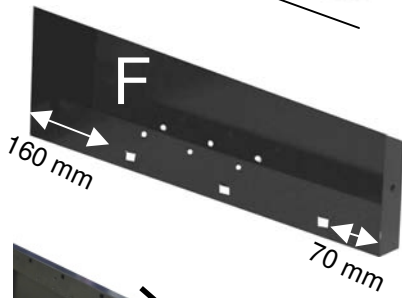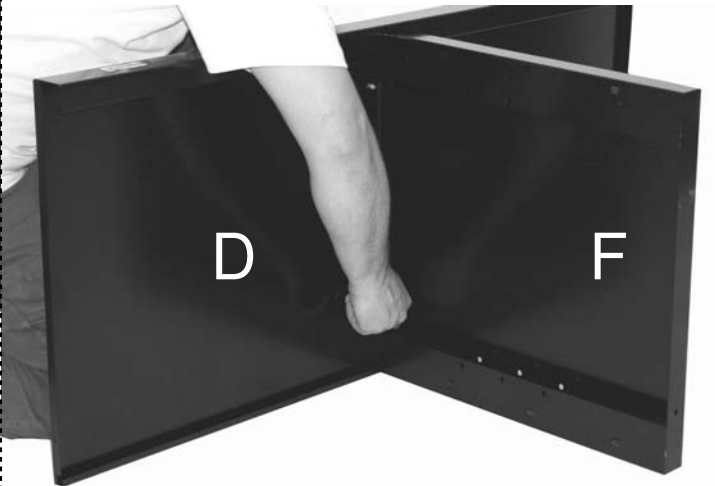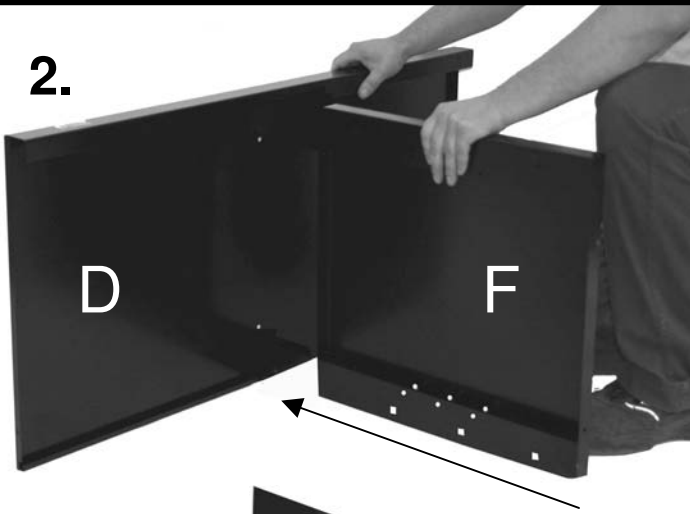

2x



M5 x 10

2x



5,3

2x



M5





PH 2 x 100



SW 8



3.

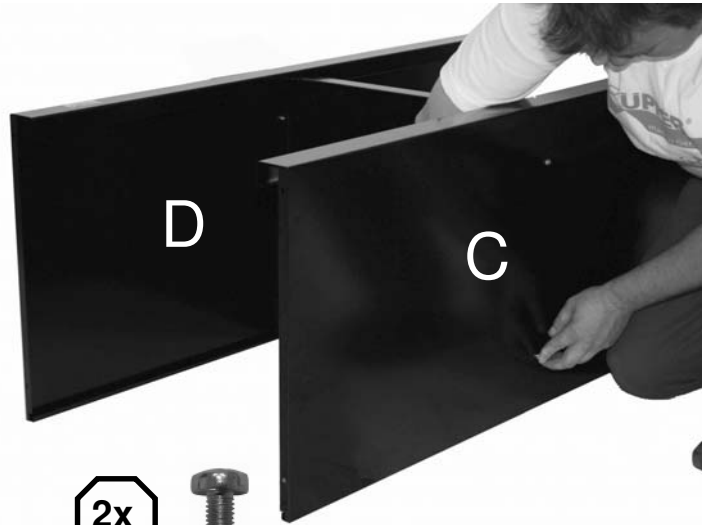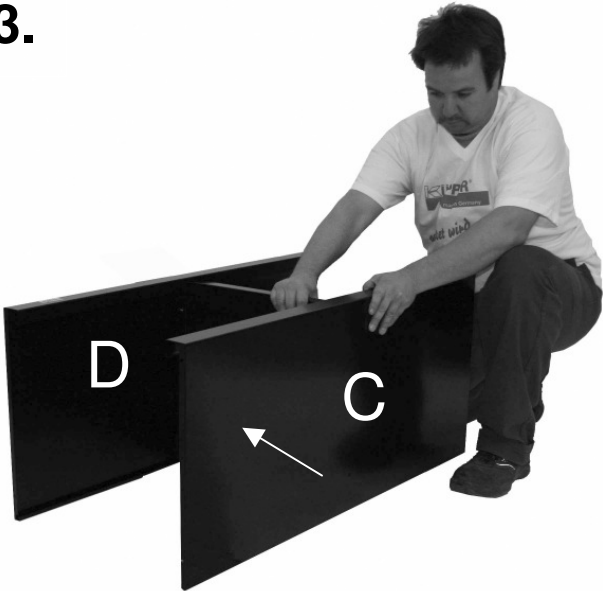

2x



M5 x 10

2x



5,3

2x



M5





PH 2 x 100





SW 8

4.

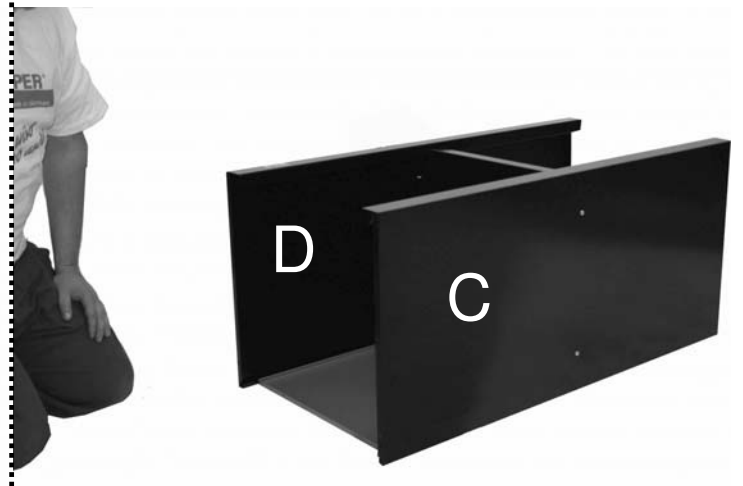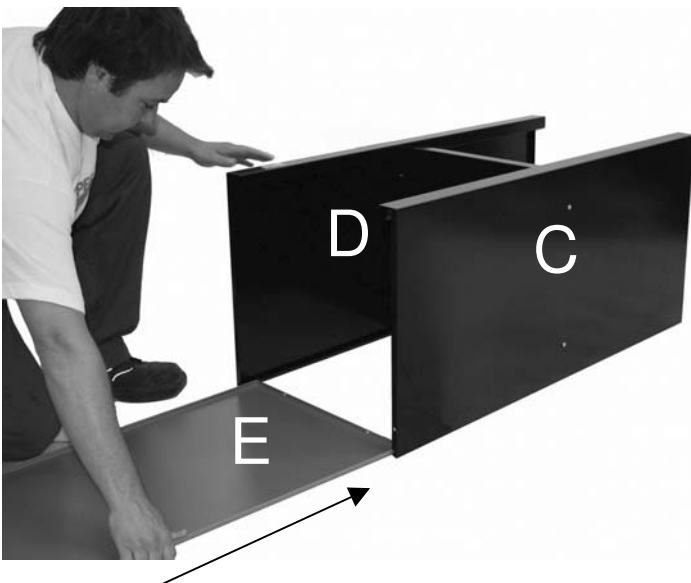



5.

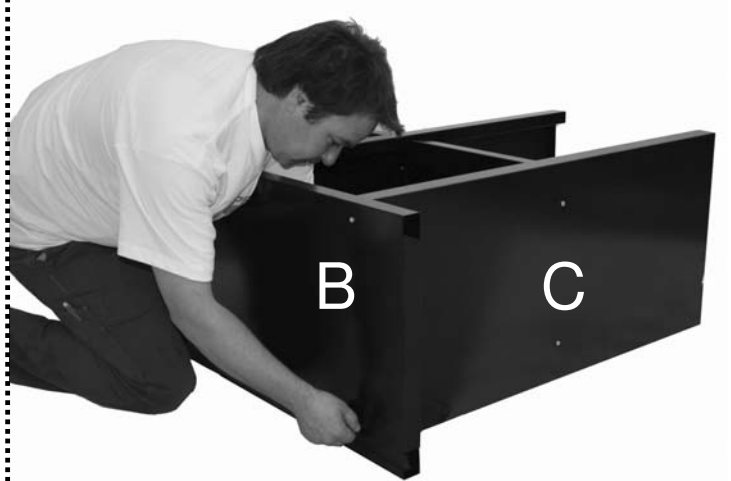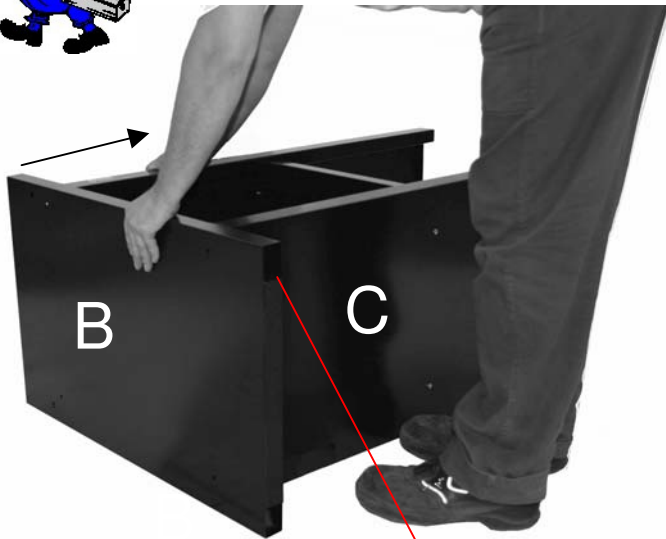

4x



4x



4x





PH 2 x 100

SW 8



6.

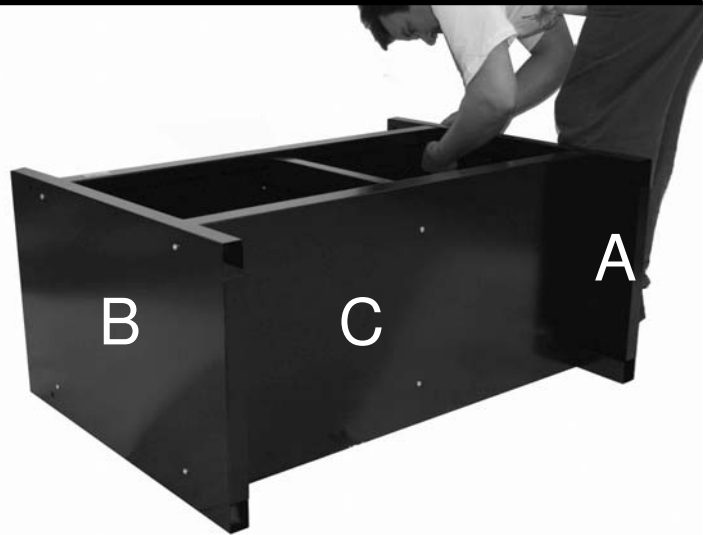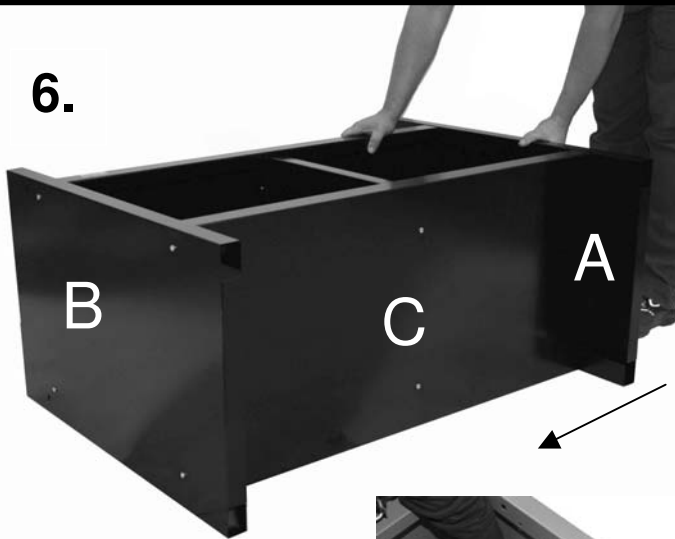

4x



4x



4x



PH 2 x 100

SW 8



4x



4x



4x








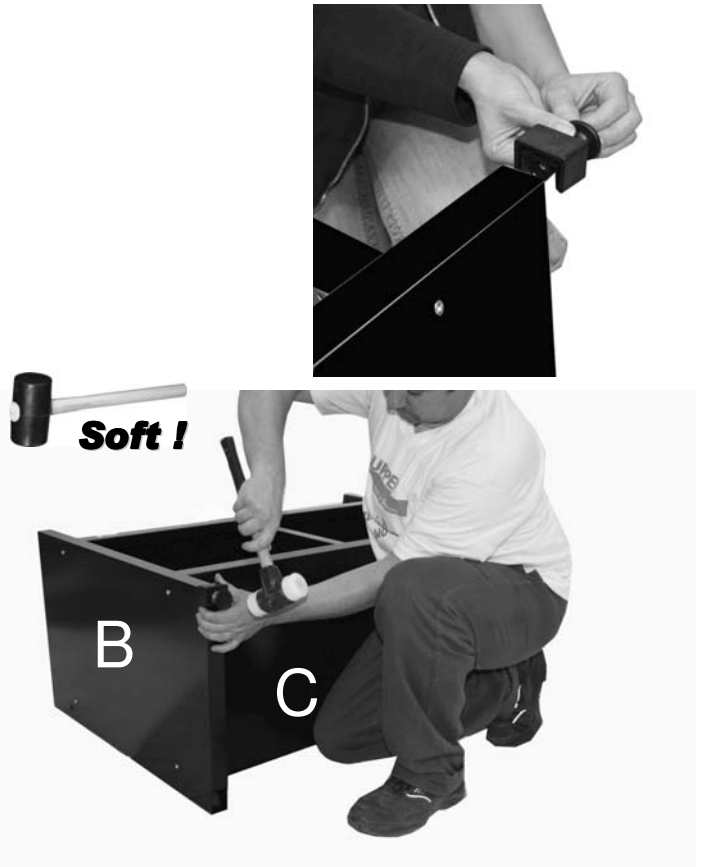
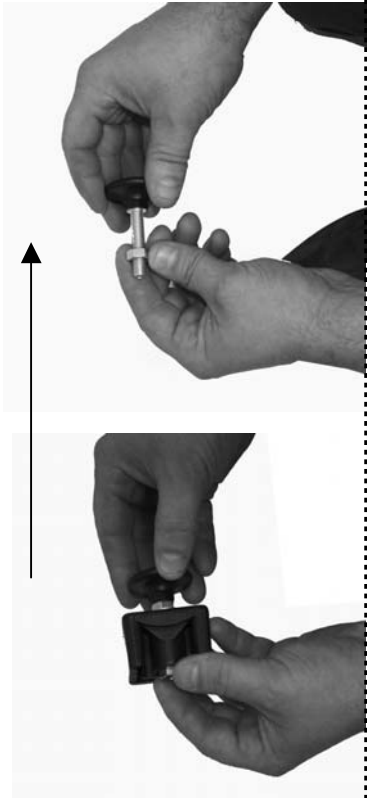
PH 2 x 100

SW 8




7.

- 4x 
- 4x  M 8
- 4x  8,3
- 4x 
- 4x  M 8







8.



- 1x 




- 2x  M5 x 10
- 2x  5,3
- 2x  M 5
-  PH 2 x 100
-  SW 8



9.




10.

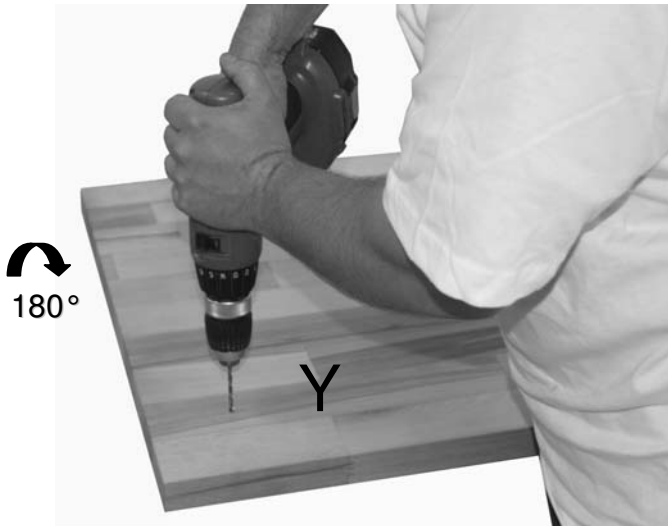

180°

Y

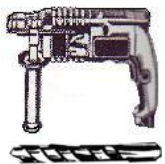

4 mm

↓ Max. 20 mm ↓

6x




5,5 x 19






SW 8



11.

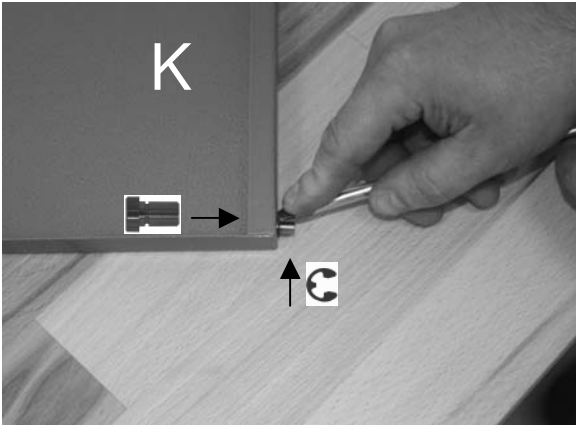


12.

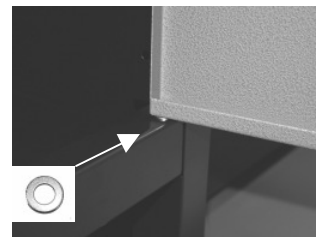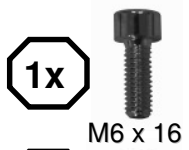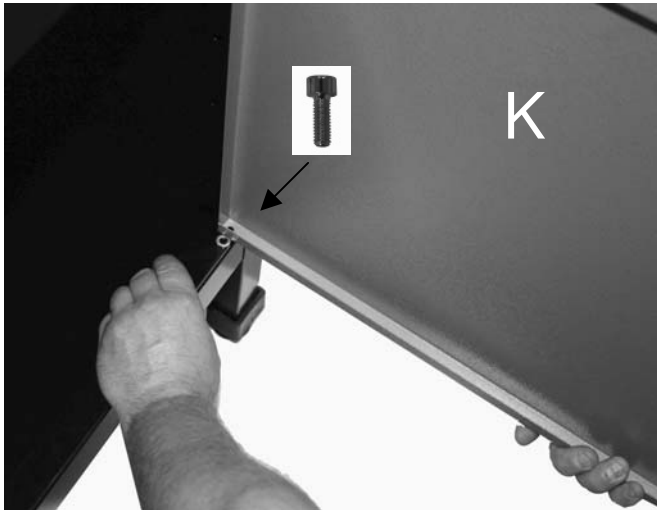



13.

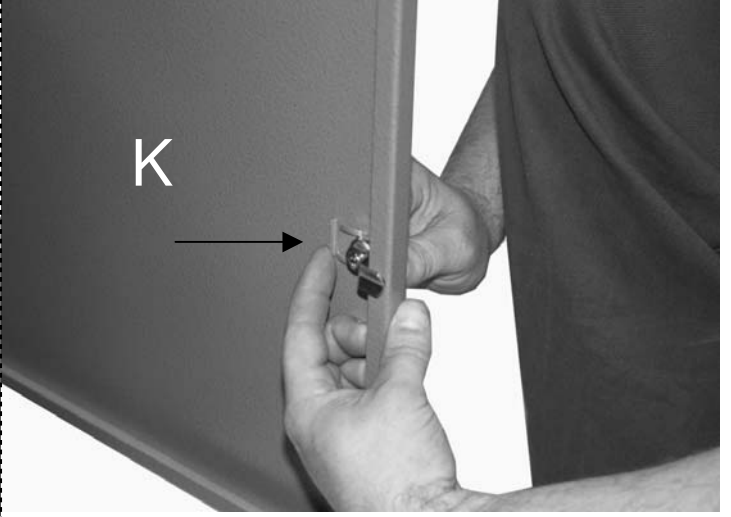

1x



1x



14.



24x



M4 x 10

24x



M4





PH 1 x 100



SW 7



15.

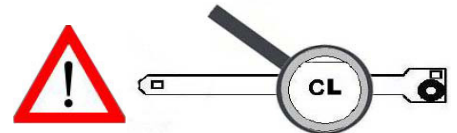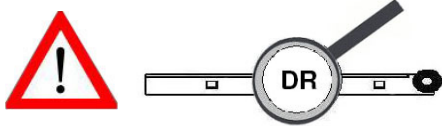

16.



6x



KU 4 2 x 12

3x

