




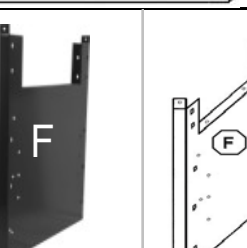
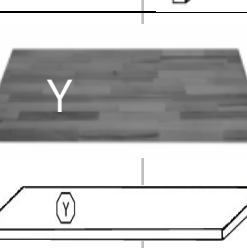








-  MONTAGEANLEITUNG
-  ASSEMBLY INSTRUCTION
-  DE INSTRUCTIE VAN DE ASSEMBLAGE
-  ISTRUZIONE DELL'ASSEMBLEA
-  INSTRUCCIÓN DE ASAMBLEA
-  INSTRUCTION DE MONTAGE
-  NÁVOD K MONTÁŽI
-  MONTERINGSANVISNING
-  MONTAJ TALIMATI
-  ASENNUSOHJE
-  BRUGSANVISNING
-  BRUKSANVISNING
-  UPUTE ZA MONTAŽU
-  NAVODILA ZA MONTAŽO
-  GYŰLÉS OKTATÁS
-  INSTRUCȚIUNI DE MONTAJ

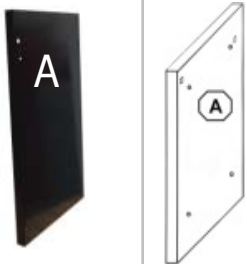

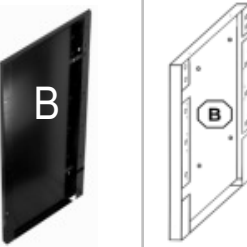

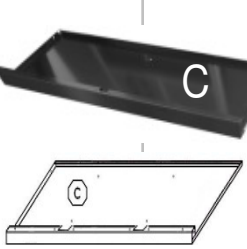

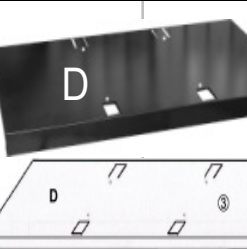

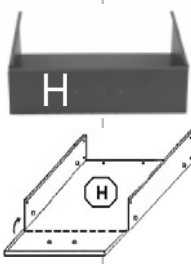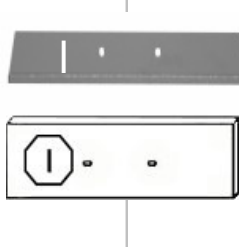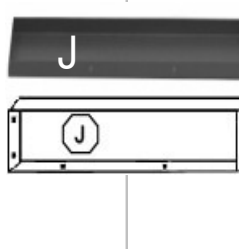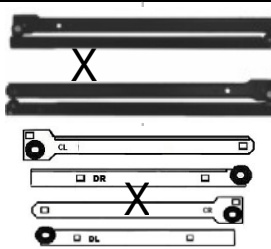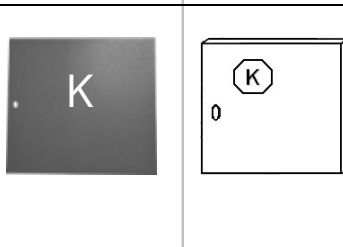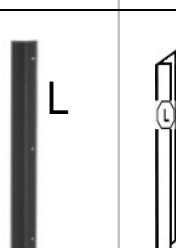








 



Art.-Nr. 12150

(12151, 12152, 12154, 12156, 12157)

1x		772 x 475 mm
1x		772 x 475 mm
1x		1570 x 473 mm
1x		1570 x 473 mm
1x		1500 x 480 mm
2x		645 x 450 mm
1x		1700 x 600 mm


3x		450 x 445 mm
3x		470 x 130 mm
3x		450 x 120 mm
3x		450 x 20 mm
3x		468 x 403 mm
3x		400 x 25 mm

8x		5,5 x 19
6x		KU 4,2 x 13
26x		M5 x 10
26x		5,3
26x		M5
24x		M4 x 10
24x		M4
3x		M6 x 16
6x		6,4
3x		M6


3x		6 x 12
3x		
4x		
4x		M8
4x		
3x		
3x		
3x		
3x		




1. - 5.

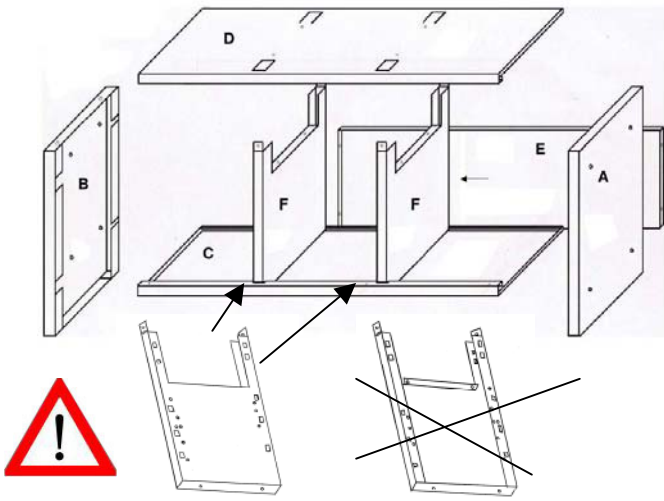


6./8./9.

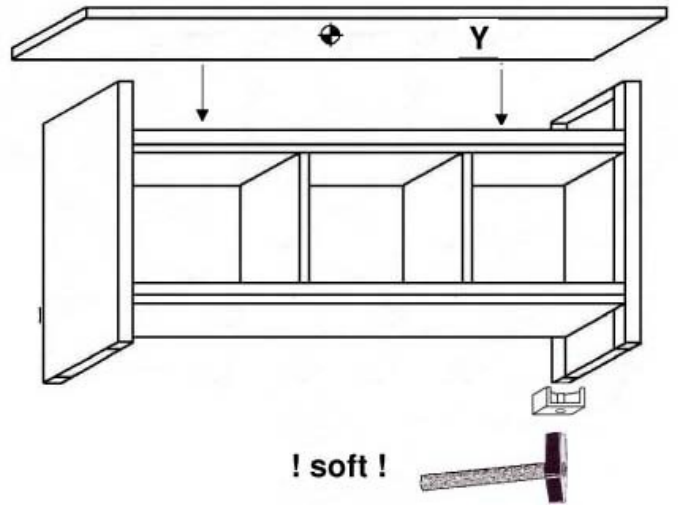


14.

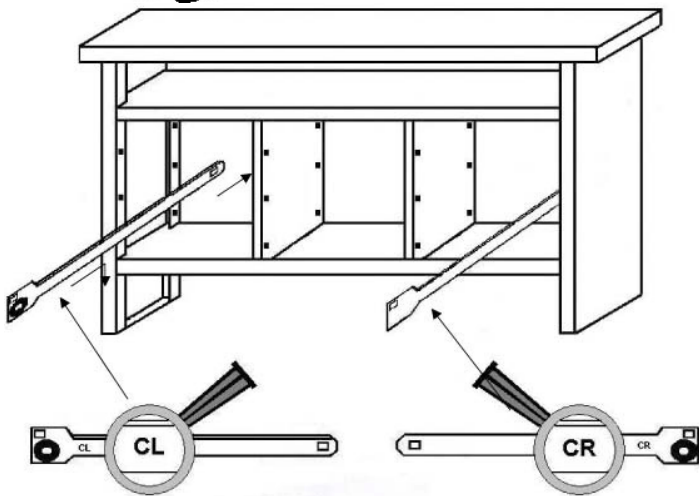

7./10./11./12.

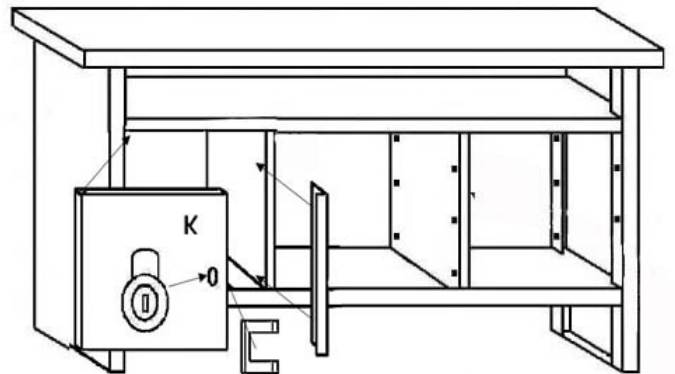

13.- 15.




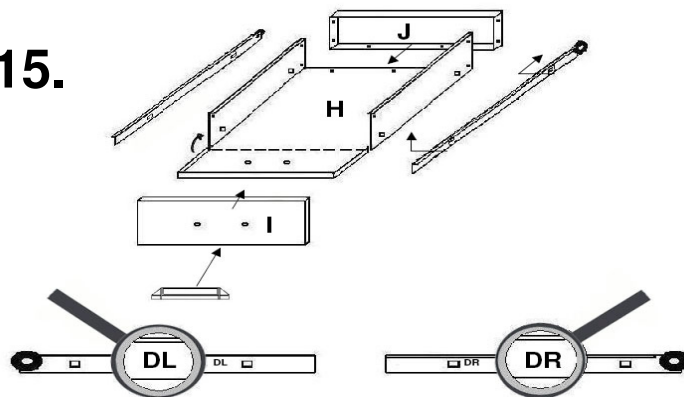




1.



2.

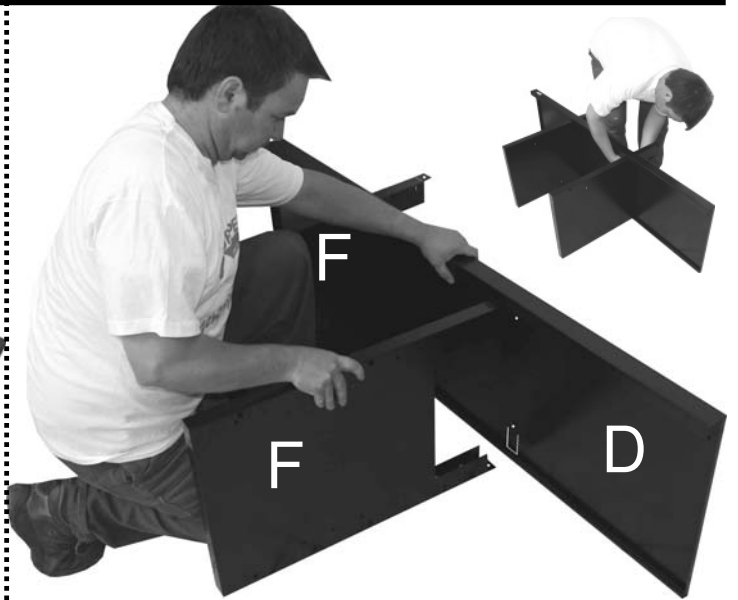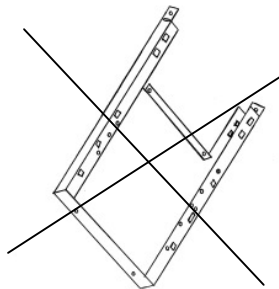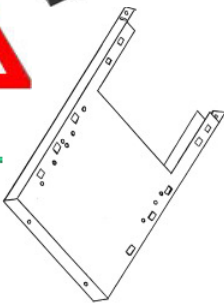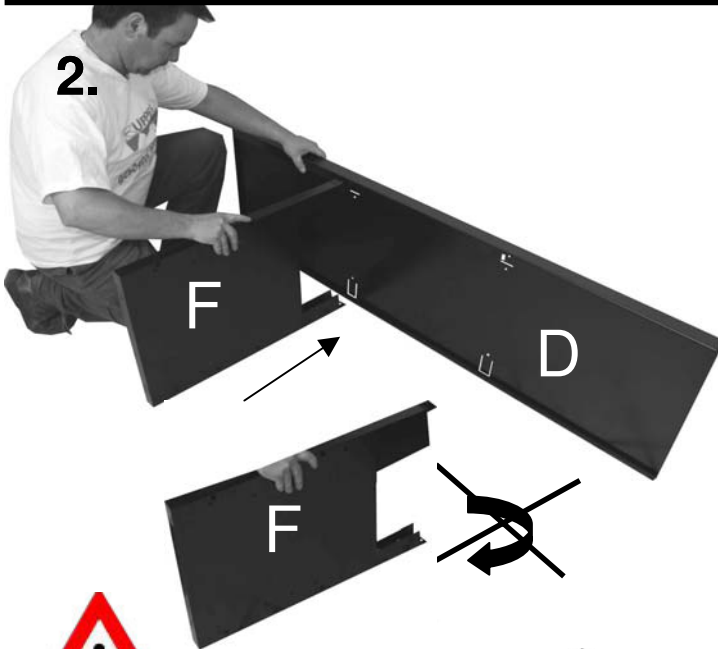

4x



M5 x 10

4x



5,3

4x



M5





PH 2 x 100



SW 8





3.

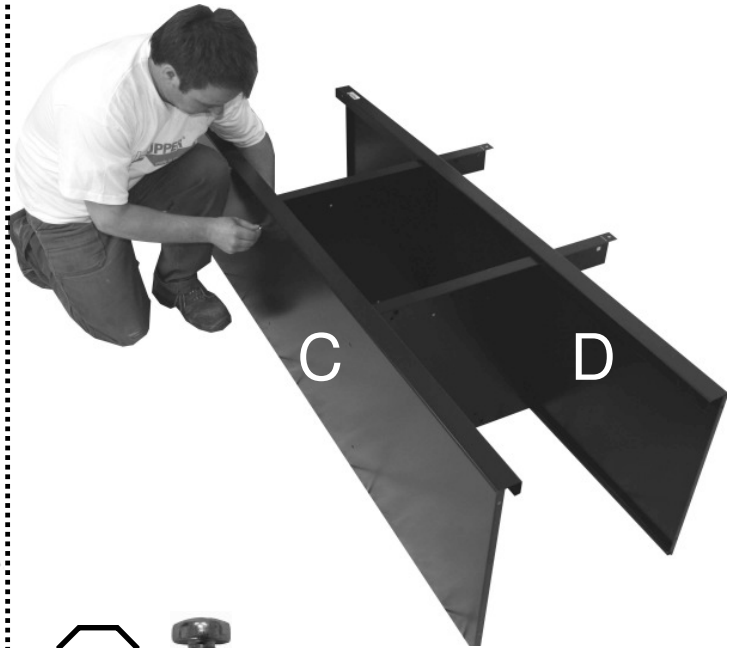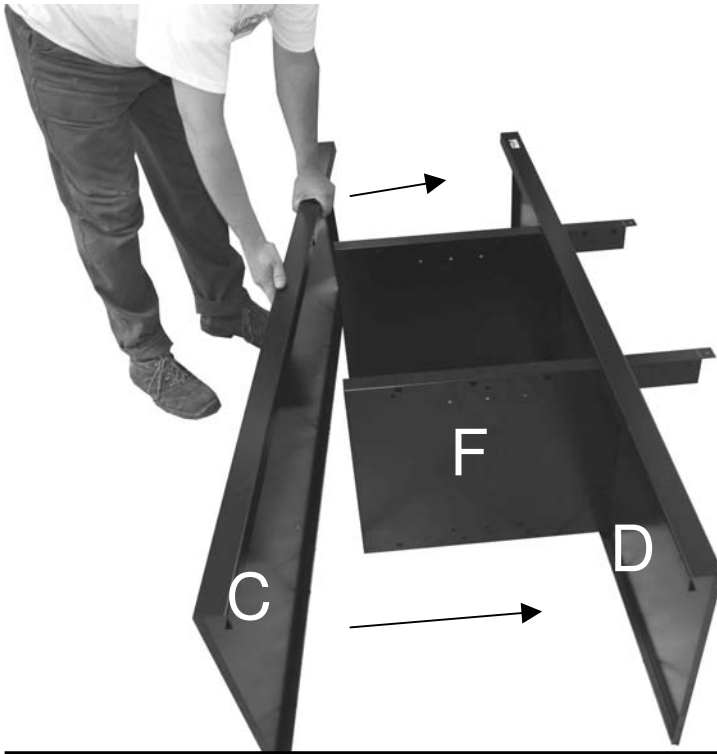


- 4x M5 x 10
- 4x 5,3
- 4x M5



4.

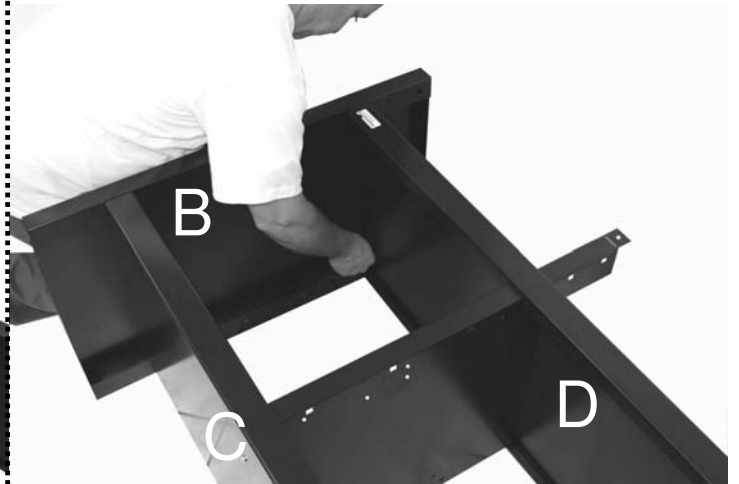
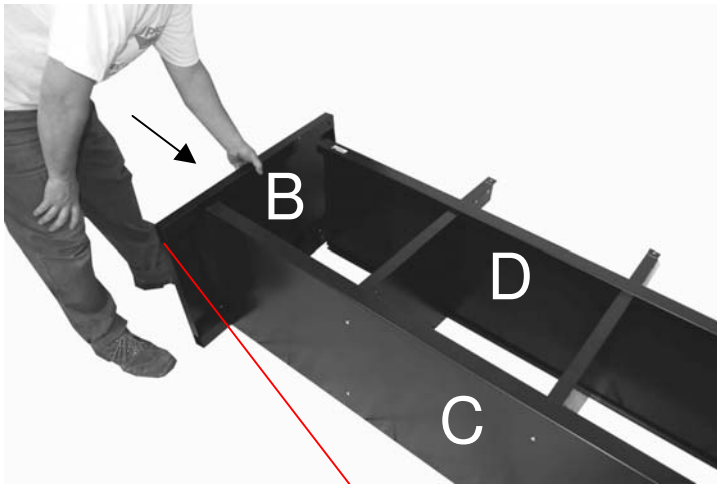


- 4x M5 x 10
- 4x 5,3
- 4x M5

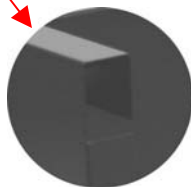



5.

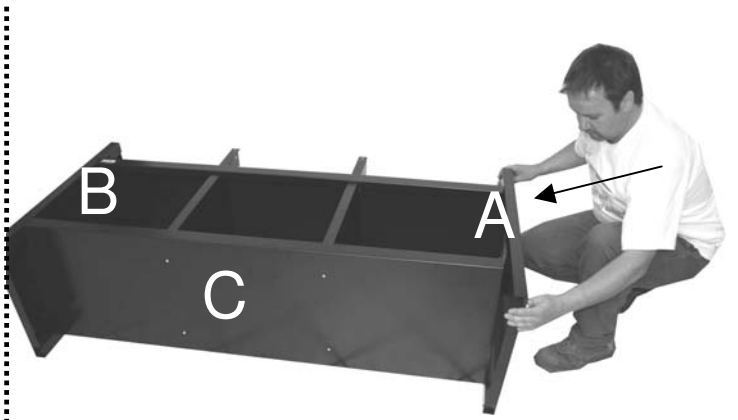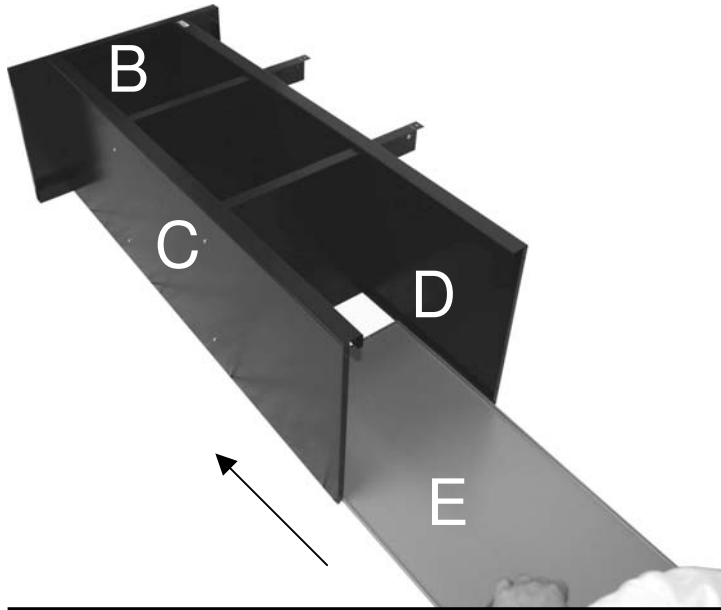

4x



M5 x 10

4x



5,3

4x



M 5



PH 2 x 100



SW 8



4x



M5 x 10

4x



5,3

4x



M 5




PH 2 x 100





SW 8



6.

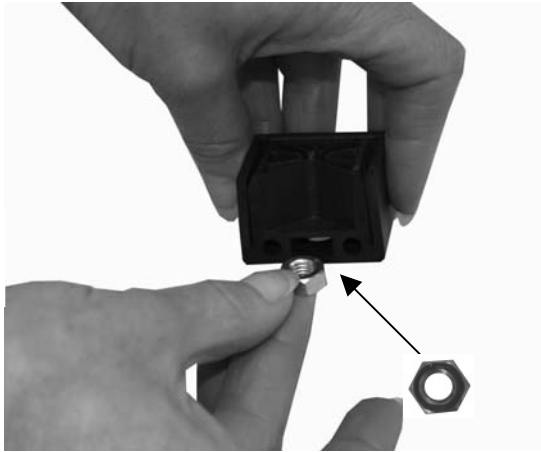

Soft!

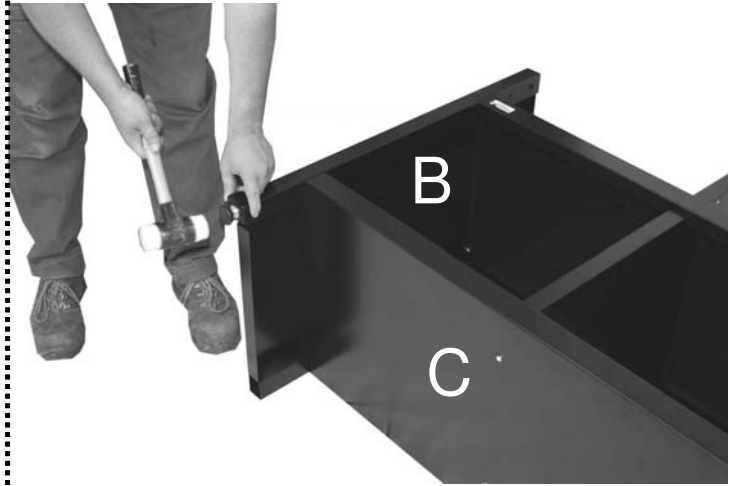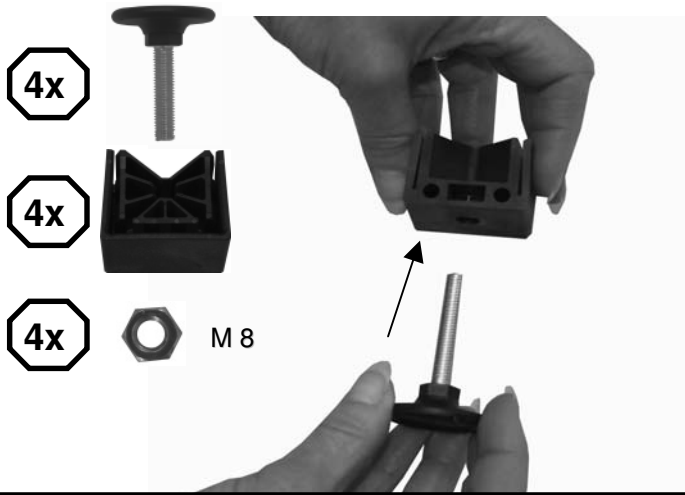

7.


- 6x M5 x 10
- 6x 5,3
- 6x M 5

PH 2 x 100

SW 8

3x

L

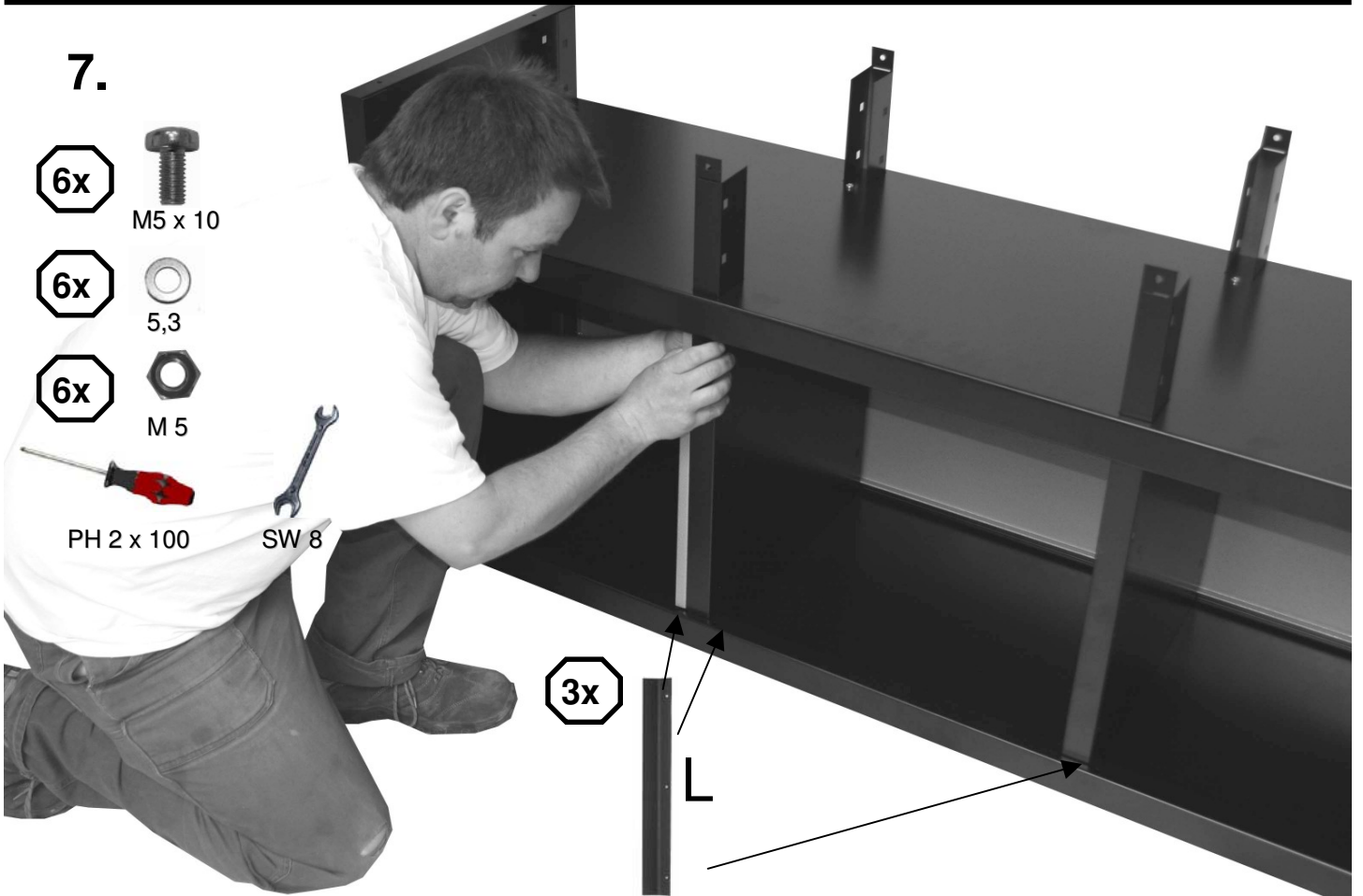



8.

90°

F



9.



4 mm

↓ Max. 20 mm ↓

180°



8x





5,5 x 19





SW 8



 10.

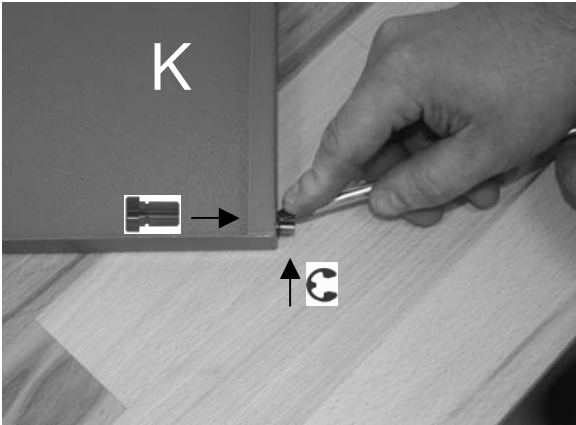


11.

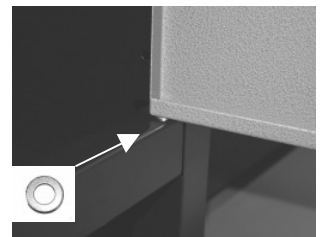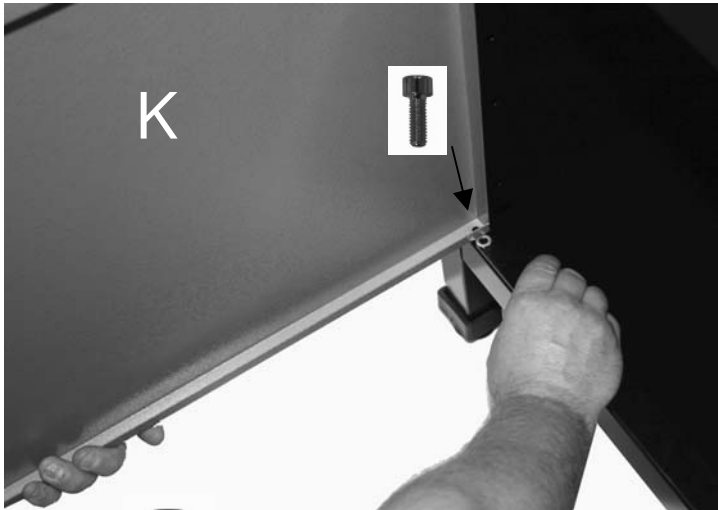



12.

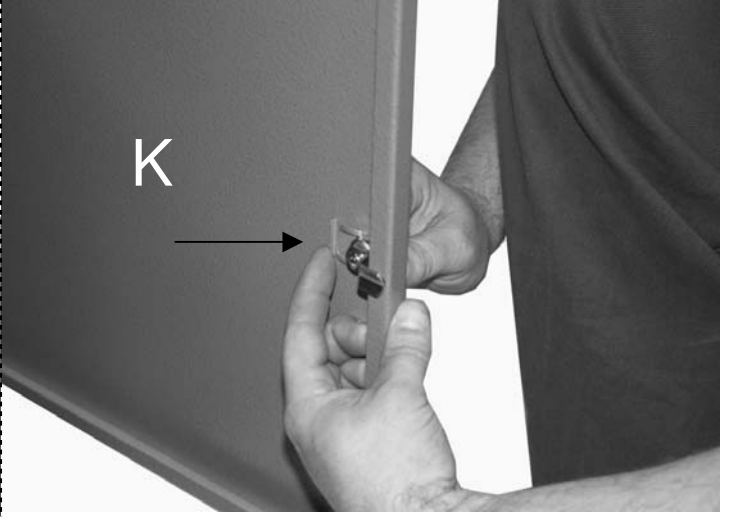

3x



3x



13.



24x



M4 x 10

24x



M4







PH 1 x 100



SW 7



14.

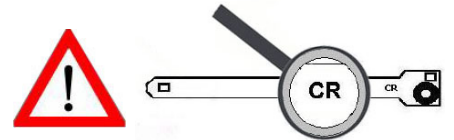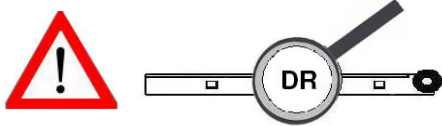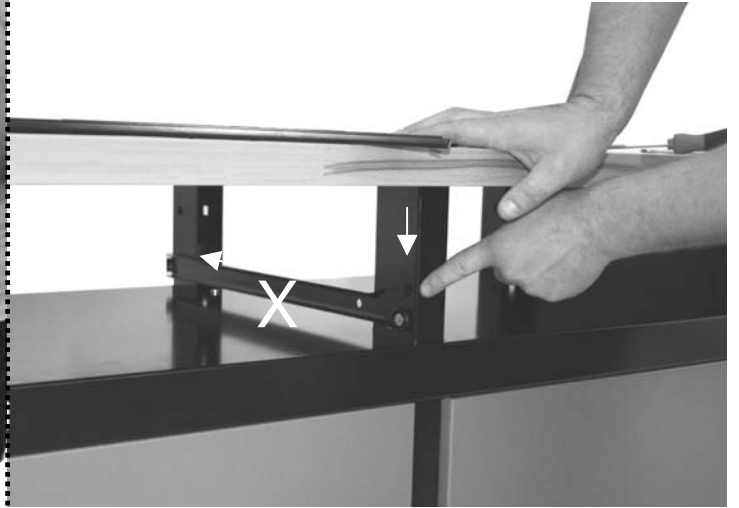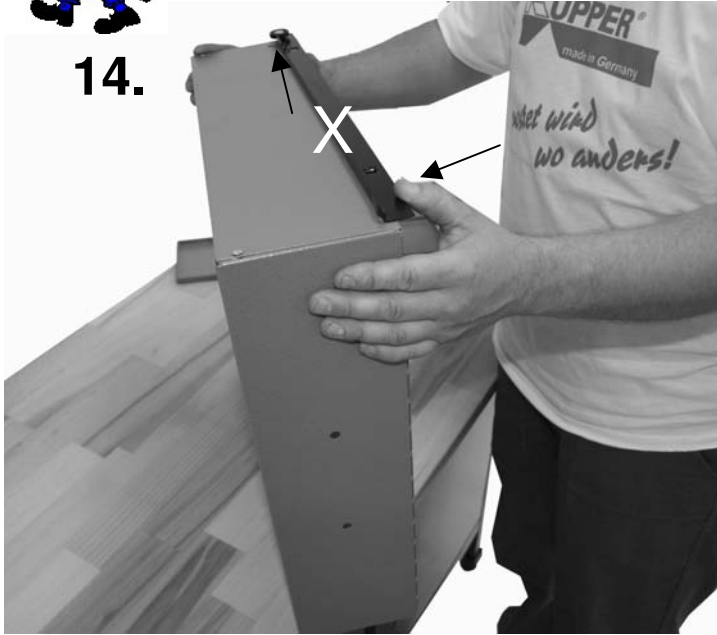

15.

