

















MONTAGEANLEITUNG

-  MONTAGEANLEITUNG
-  ASSEMBLY INSTRUCTION
-  DE INSTRUCTIE VAN DE ASSEMBLAGE
-  ISTRUZIONE DELL'ASSEMBLEA
-  INSTRUCCIÓN DE ASAMBLEA
-  INSTRUCTION DE MONTAGE
-  NÁVOD K MONTÁŽI
-  MONTERINGSANVISNING

-  MONTAJ TALIMATI
-  ASENNUSOHJE
-  BRUGSANVISNING
-  BRUKSANVISNING
-  UPUTE ZA MONTAŽU
-  NAVODILA ZA MONTAŽU
-  SZERELÉSI ÚTMUTATÓ
-  INSTRUCTIUNI DE MONTAJ



Modell-Nr.

12170

ART.-NR.	FRONT	KORPUS
12171	Grün	Silber
12172	Rot (ähnl. RAL 3002)	Silber
12174	Blau	Silber
12177	Ultramarinblau (RAL 5002)	Silber
12176	Silber	Schwarz

Friedrich Küpper GmbH
Friedrich-Küpper-Weg
54570 Berlingen
Deutschland

Telefon +49 (0) 65 91 - 95 42 0
Telefax +49 (0) 65 91 - 95 42 17
E-Mail info@friedrich-kuepper-gmbh.de
Internet www.friedrich-kuepper-gmbh.de

EINZELTEILE / PIECES

A



1x

772 mm x 475 mm

B



1x

772 mm x 475 mm

F



2x

645 mm x 450 mm

K



2x

403 mm x 468 mm

L



2x

400 mm x 25 mm

C



1x

1570 mm x 473 mm

 
D



1x

1570 mm x 473 mm

E



1x

1500 mm x 480 mm

Y



1x

1700 mm x 600 mm


H



6x

450 mm x 445 mm

I

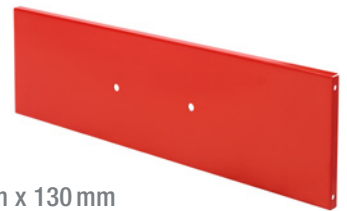

6x

470 mm x 130 mm

J



6x

450 mm x 120 mm


X







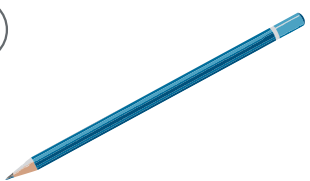
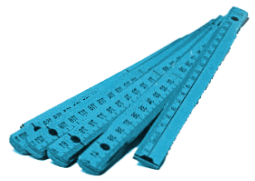
6x

450 mm x 20 mm

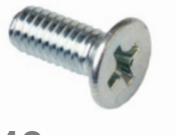BEUTELINHALT / BAG CONTENT

 8x 5,5x19 mm	 12x KU 4,2x13 mm	 24x M5x10 mm	 24x ø5,3 mm	 24x M5	 48x M4 x 10 mm
 48x M4	 2x M6x16 mm	 2x ø6,4 mm	 2x M6	 2x 6x12 mm	 2x
 2x	 2x	 4x	 4x	 4x M8	 6x

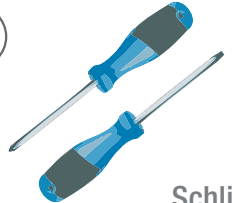BENÖTIGTES WERKZEUG / NEEDED TOOLS

<p>①</p>  <p>PH 1 x 100 PH 2 x 100 Schlitz 6,5 x 150</p>	<p>②</p>  <p>SW 7 SW 8 SW 10</p>	<p>③</p>  <p>4 mm</p>
<p>④</p> 	<p>⑤</p> 	<p>⑥</p>  <p>5 mm</p>
<p>⑦</p> 	<p>⑧</p> 	

1.




2. WICHTIG / IMPORTANT



3. WICHTIG / IMPORTANT



4.  4x M5  4x M5 x 10  4x 5,3MM

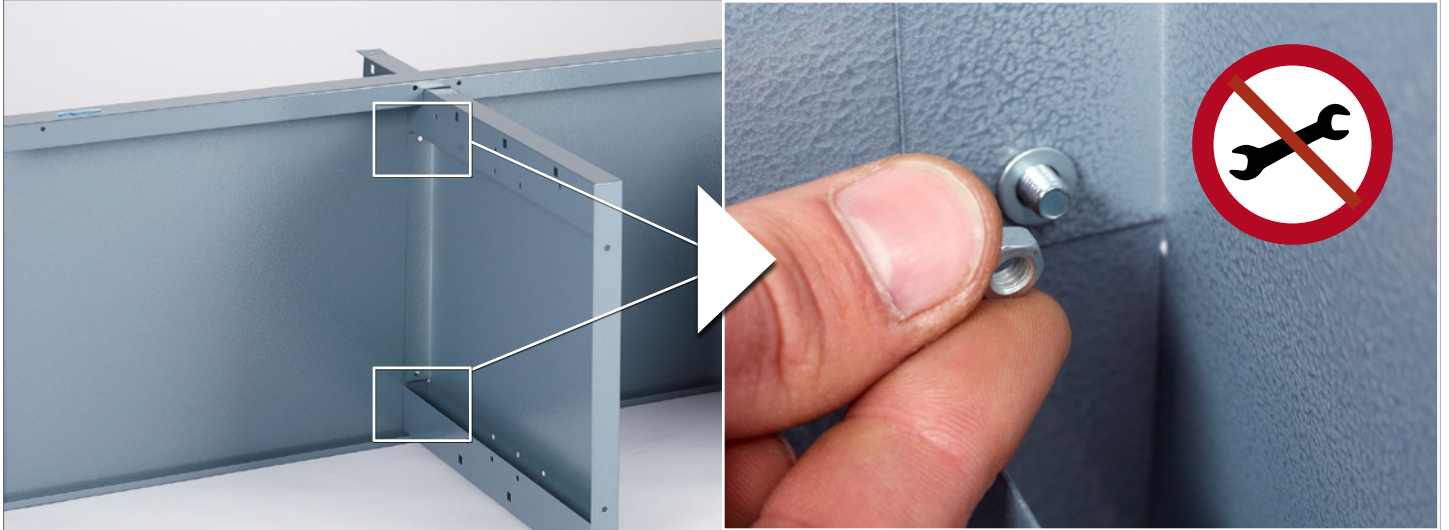

5.




6.  4x M5  4x M5 x 10  4x 5,3MM  ② SW 8  ① PH 2 X 100



7.




8.

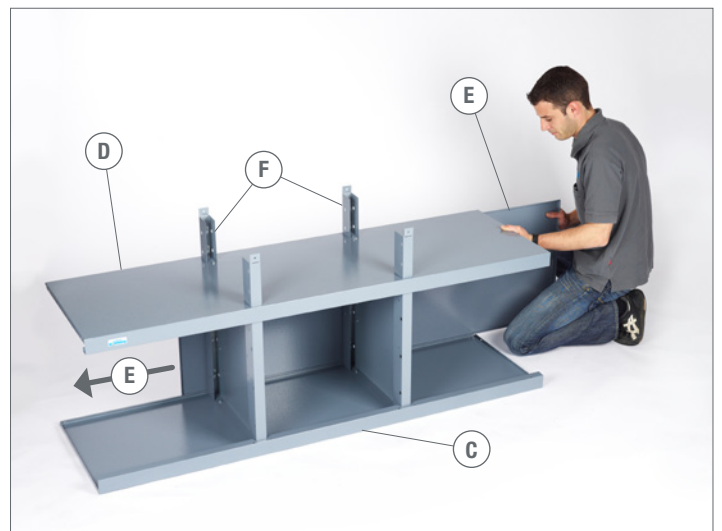

ZU SCHRITT 4. / IN ADDITION TO STEP 4.


②  SW 8 ①  PH 2x100

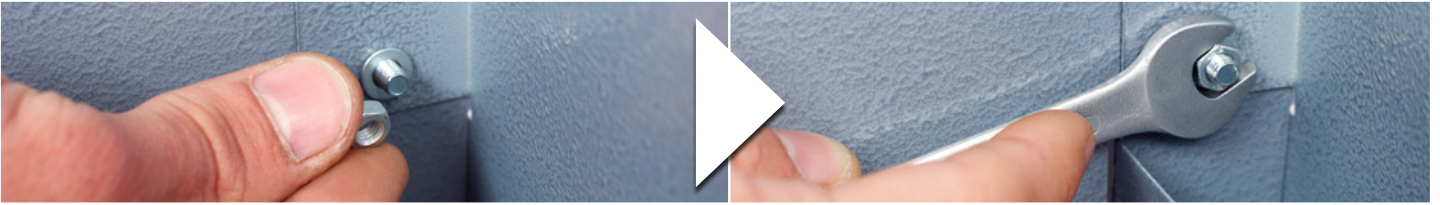

9. WICHTIG / IMPORTANT



10.  6x M5  6x M5x10  6x 5,3MM ②  SW 8 ①  PH 2x100

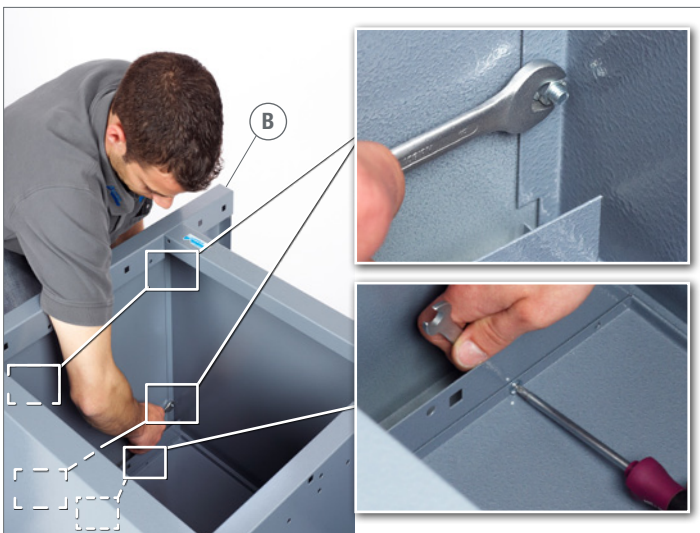

11.  6x M5  6x M5x10  6x 5,3MM ②  SW 8 ①  PH 2x100



12.




5



13.



2 SW 8
1 PH 2x100

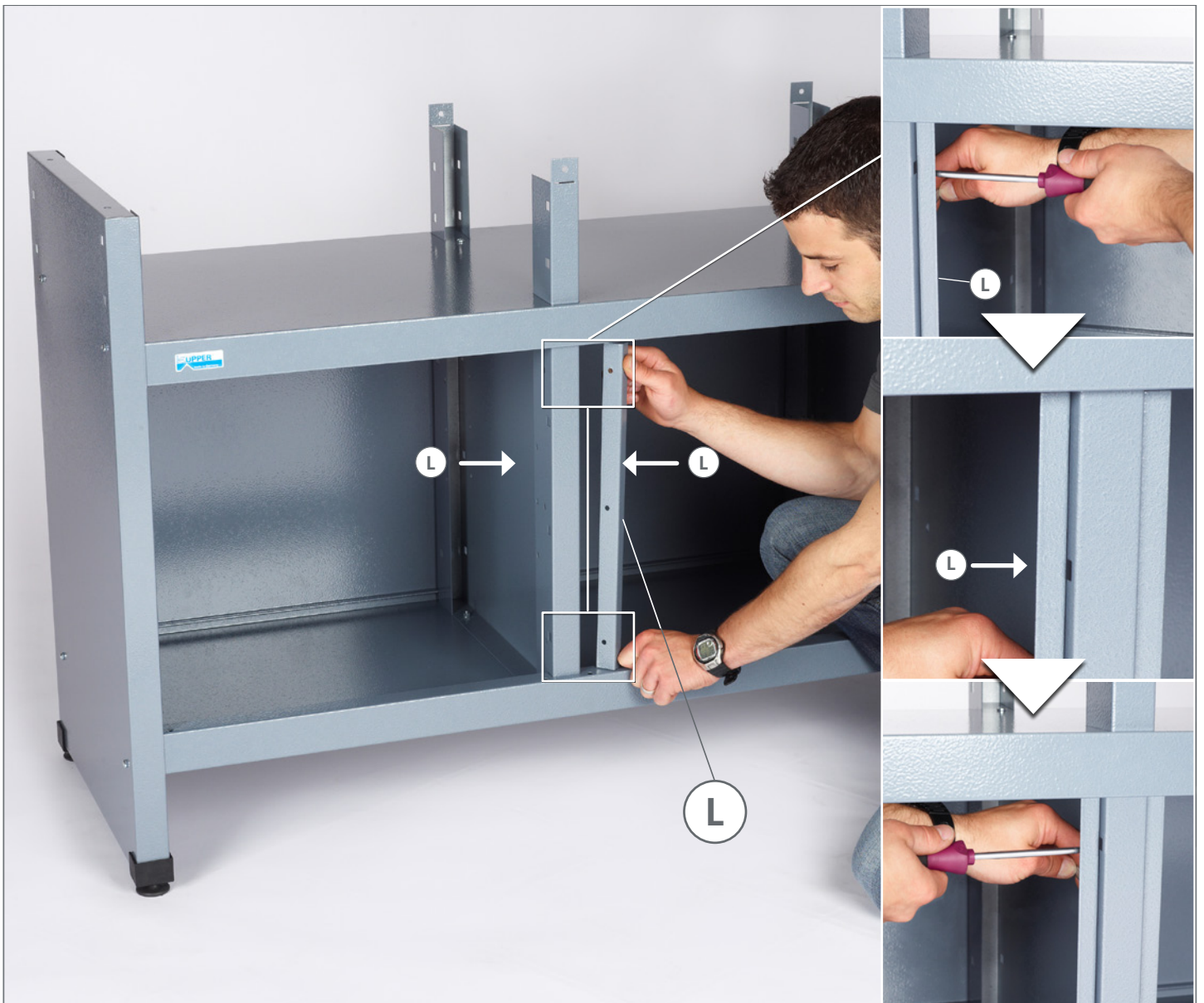


14.



15.

8 7

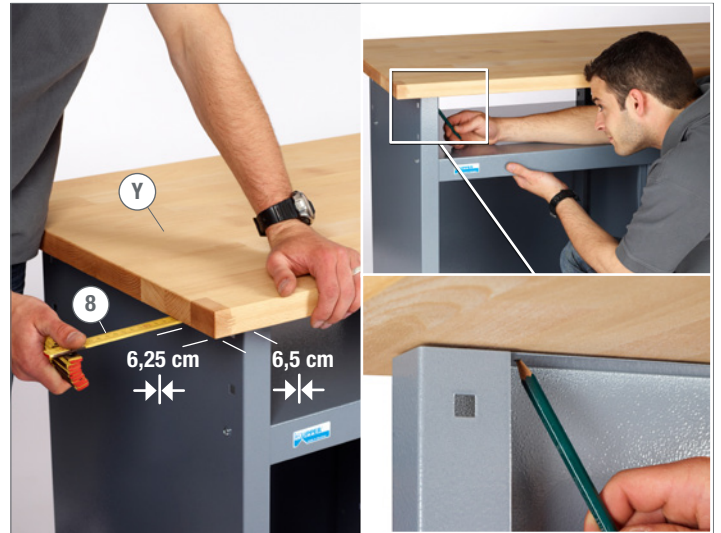

16.

4 3



17.

8x 5,5 x 19


2 SW 8



18.

2x 2x 6 x 12

1 Schlitz 6,5 x 150

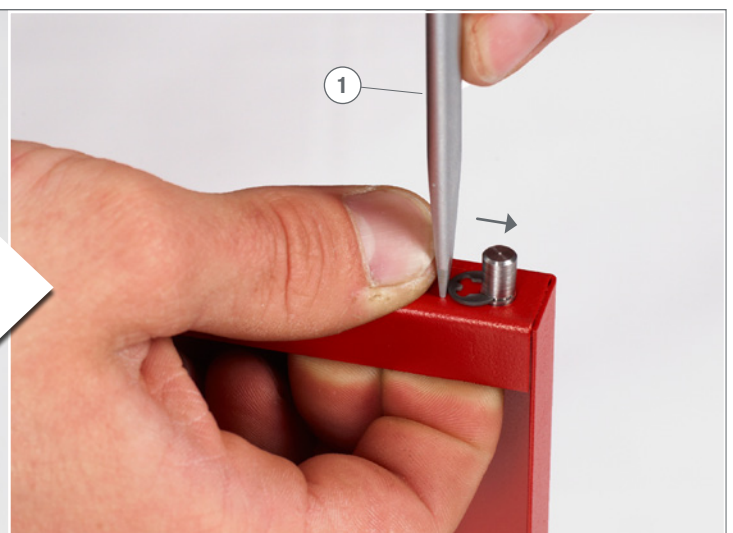


19.



20.

2x M6 2x M6 x 16 2x 6,4 mm ② SW 10 ⑥

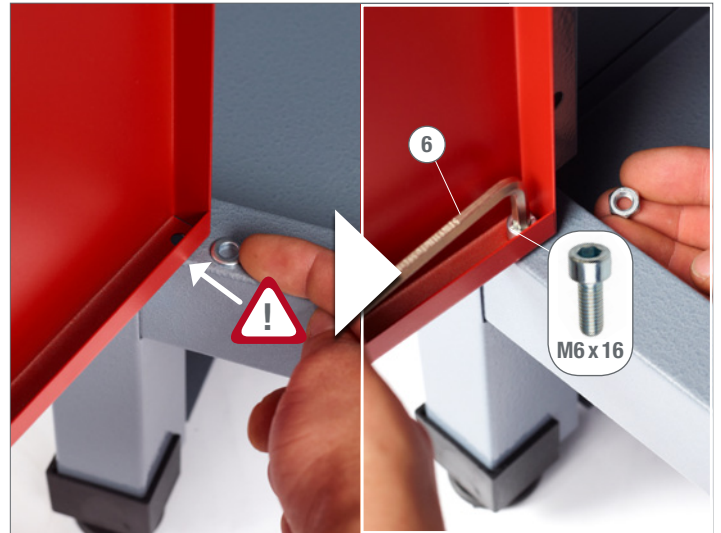

21.

2x 2x



22.

① 6x CR



23.

① 6x CL




24.

12x M4

12x M4x10

② SW7

① PH1x100

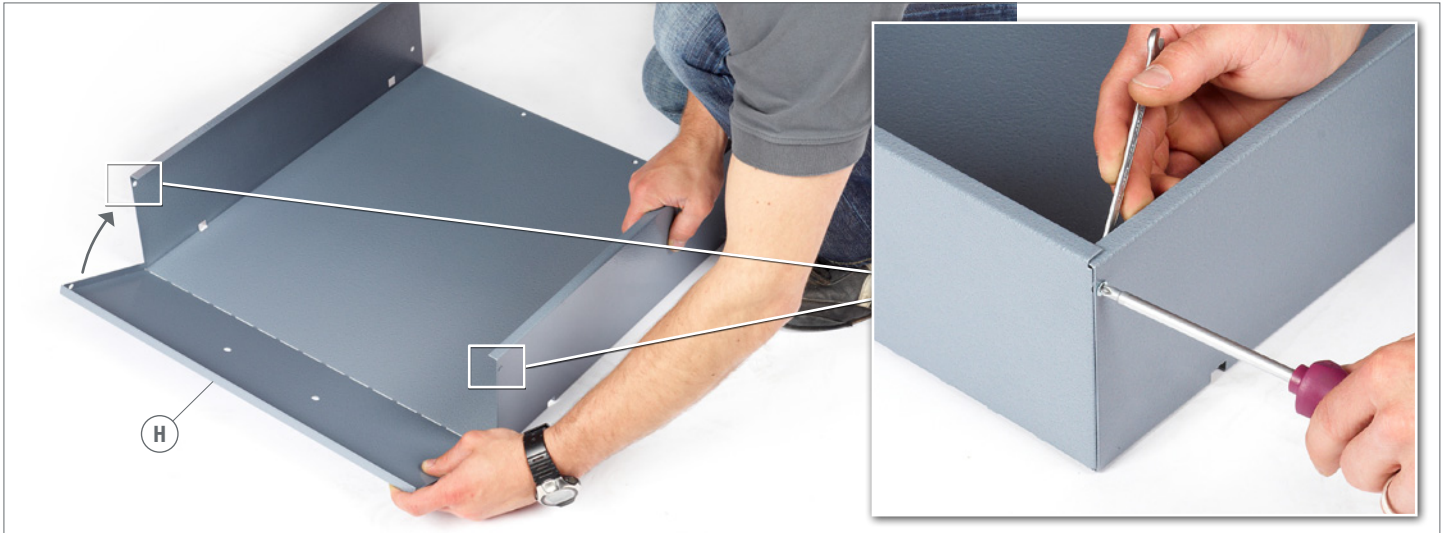


25.

36x M4


36x M4x10

② SW7


① PH1x100

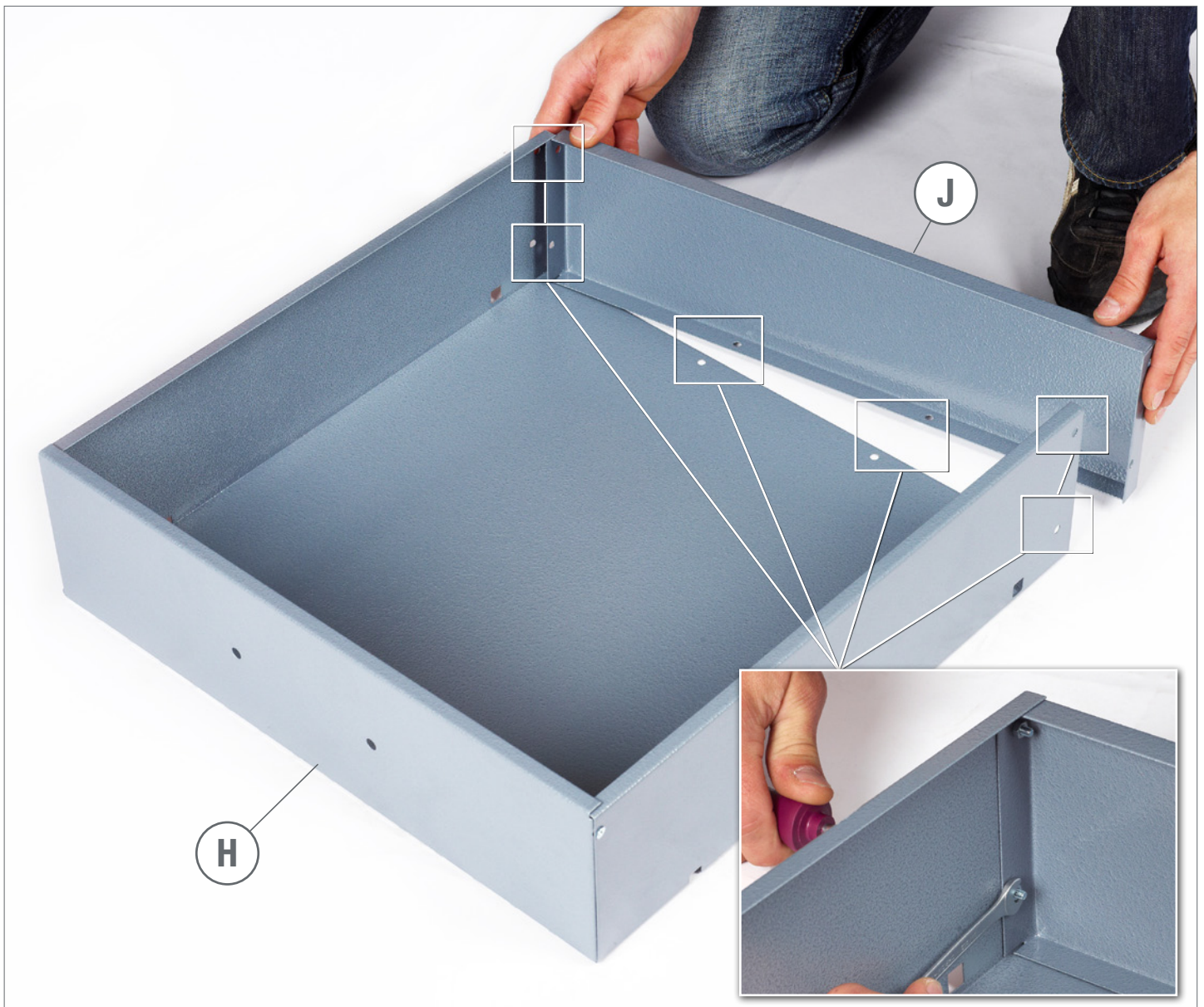

26.

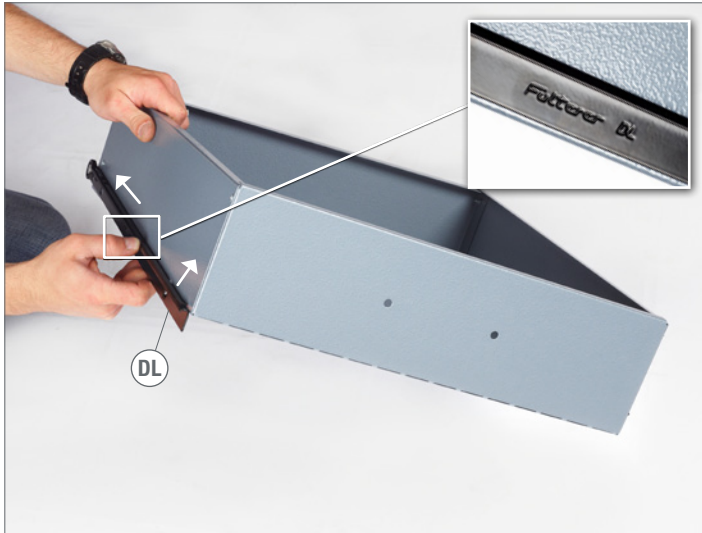

27.

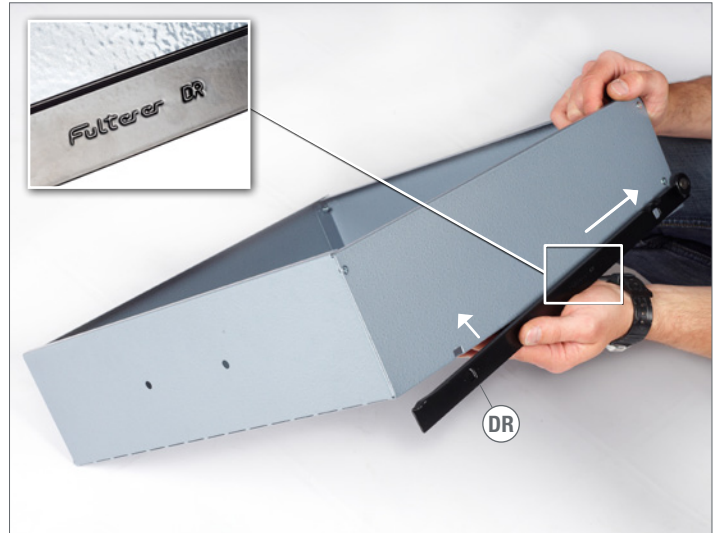

28.



29.


12x KU 4,2x13 6x  ①  PH2x100



30.



31.

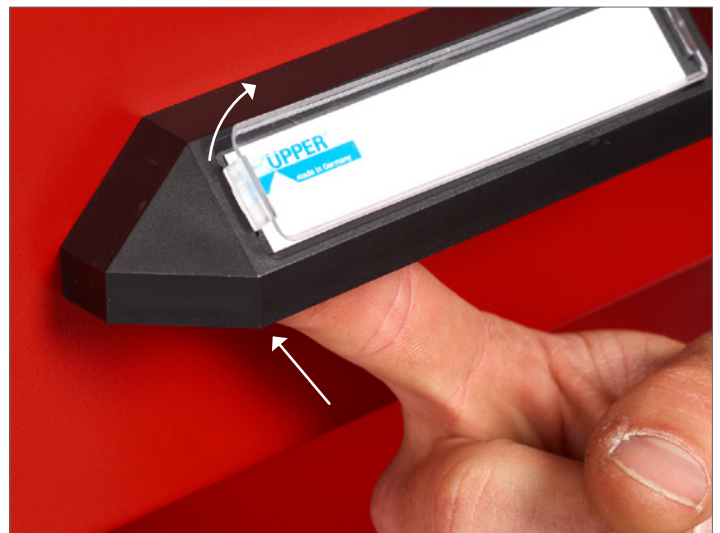



Modell-Nr.

12170