

















## MONTAGEANLEITUNG

-  MONTAGEANLEITUNG
-  ASSEMBLY INSTRUCTION
-  DE INSTRUCTIE VAN DE ASSEMBLAGE
-  ISTRUZIONE DELL'ASSEMBLEA
-  INSTRUCCIÓN DE ASAMBLEA
-  INSTRUCTION DE MONTAGE
-  NÁVOD K MONTÁŽI
-  MONTERINGSANVISNING

-  MONTAJ TALIMATI
-  ASENNUSOHJE
-  BRUGSANVISNING
-  BRUKSANVISNING
-  UPUTE ZA MONTAŽU
-  NAVODILA ZA MONTAŽO
-  SZERELÉSI ÚTMUTATÓ
-  INSTRUCTIUNI DE MONTAJ



Modell-Nr.

# 12190

ART.-NR. FRONT KORPUS

12191  Silber

12192  Silber

12194  Silber







12197  Silber

12196  

Friedrich Küpper GmbH  
Friedrich-Küpper-Weg  
54570 Berlingen  
Deutschland

Telefon +49 (0) 65 91 - 95 42 0  
Telefax +49 (0) 65 91 - 95 42 17  
E-Mail [info@friedrich-kuepper-gmbh.de](mailto:info@friedrich-kuepper-gmbh.de)  
Internet [www.friedrich-kuepper-gmbh.de](http://www.friedrich-kuepper-gmbh.de)




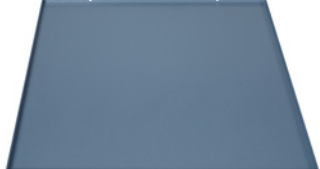



## EINZELTEILE / PIECES

<p><b>A</b></p> <p><b>1x</b></p> <p>750 mm x 475 mm</p> 	<p><b>B</b></p> <p><b>1x</b></p> <p>750 mm x 475 mm</p> 	<p><b>C</b></p> <p><b>1x</b></p> <p>548 mm x 473 mm</p> 
<p><b>D</b></p> <p><b>1x</b></p> <p>548 mm x 473 mm</p> 	<p><b>E</b></p> <p><b>1x</b></p> <p>474 mm x 480 mm</p> 	<p><b>K</b></p> <p><b>1x</b></p> <p>403 mm x 468 mm</p> 
<p><b>L</b></p> <p><b>1x</b></p> <p>400 mm x 25 mm</p> 	<p><b>Y</b></p> <p><b>1x</b></p> <p>600 mm x 600 mm</p> 	<p><b>X</b></p> <p><b>1x</b></p> <p>450 mm x 20 mm</p> 
<p><b>J</b></p> <p><b>1x</b></p> <p>450 mm x 120 mm</p> 	<p><b>H</b></p> <p><b>1x</b></p> <p>450 mm x 445 mm</p> 	<p><b>I</b></p> <p><b>1x</b></p> <p>470 mm x 130 mm</p> 

BEUTELINHALT / BAG CONTENT

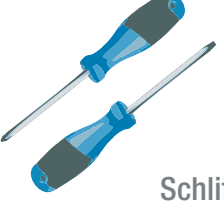 4x 5,5x19 mm	 2x KU 4x16 mm	 14x M5x10 mm	 14x ø5,3 mm	 14x M5	 24x M4 x 10 mm
 24x M4	 1x M6x16 mm	 1x ø6,4 mm	 1x M6	 1x 6x12 mm	 1x
 1x	 1x	 4x	 2x	 2x	 1x

BENÖTIGTES WERKZEUG / NEEDED TOOLS

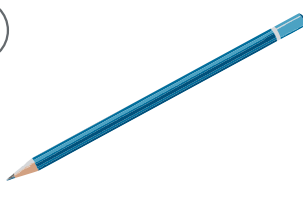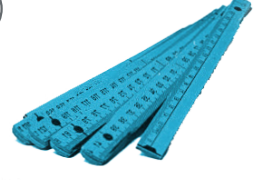 ① PH 1x100 PH 2x100 Schlitz 6,5x150	 ② SW 7 SW 8 SW 10	 ③ 4 mm
 ④	 ⑥ 5 mm	 ⑦
 ⑧		


1.



2.

2x M5 2x M5 x 10 2x 5,3 MM

② SW 8 ① PH 2 X 100

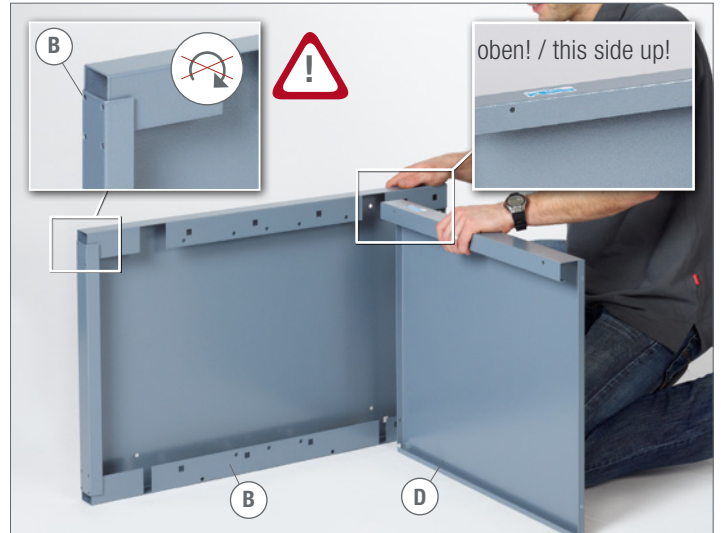

3.

2x M5 2x M5 x 10 2x 5,3 MM

② SW 8 ① PH 2 X 100




4.  2x M5  2x M5x10  2x 5,3MM

 2 SW8  1 PH2X100




5.  6x M5  6x M5x10  6x 5,3MM

 2 SW8  1 PH2X100

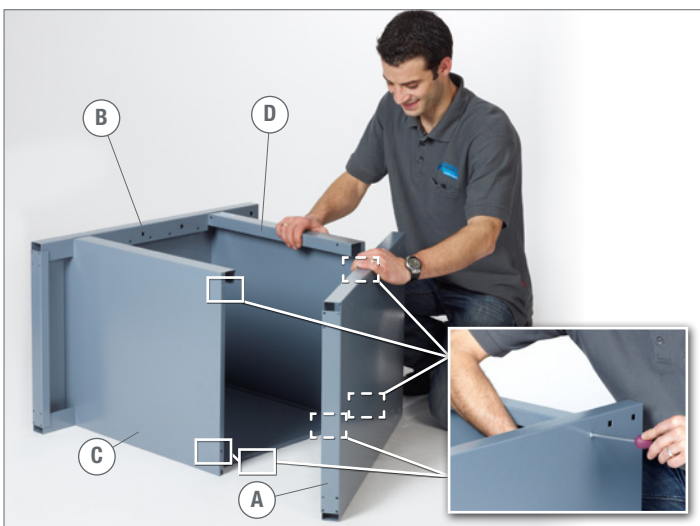

6.  16x M4  16x M4x10  4x

 1 PH2x100

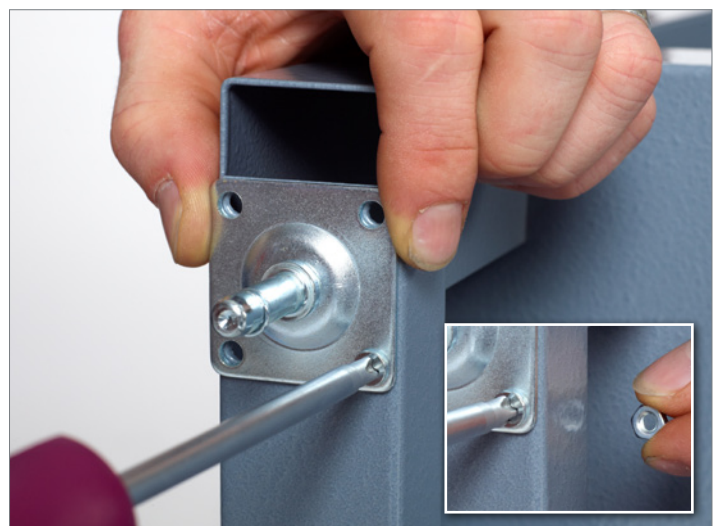

7.  2x



8.  2x




9.  2x M5  2x M5 x 10  2x 5,3 mm

 2 SW 8  1 PH 2 x 100



10.  1x  1x 6x12

 1 Schlitz 6,5 x 150

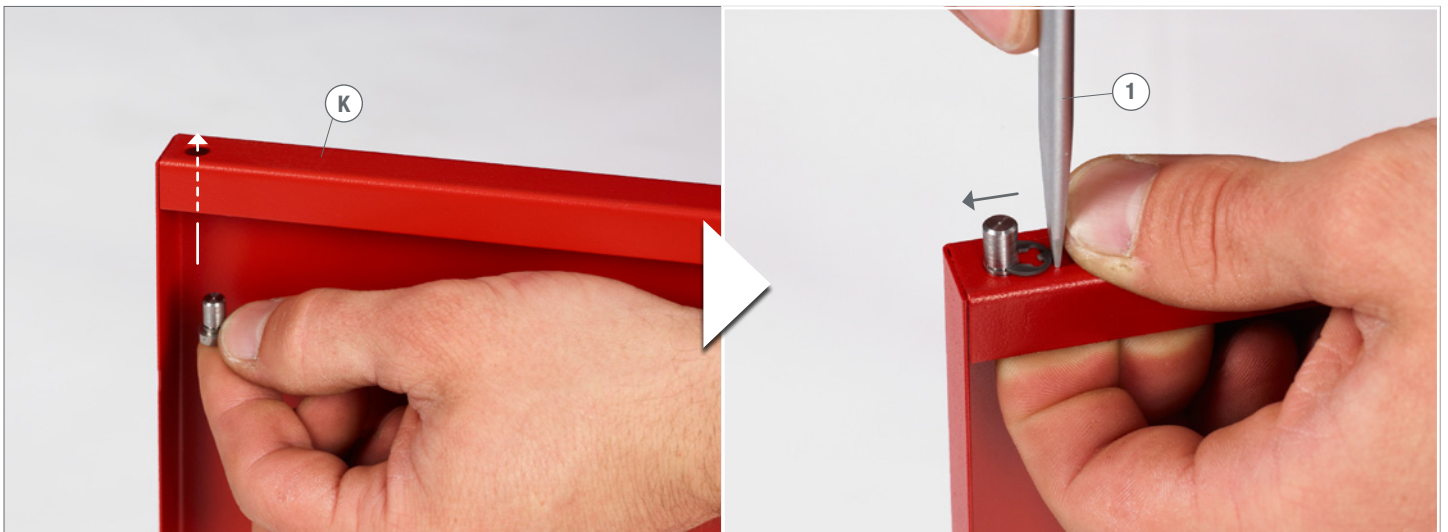

11.



12.

- 1x M6
- 1x M6x16
- 1x 6,4 mm
- ② SW 10
- ⑥



13.

- 1x
- 1x



14. <sup>(X)</sup>  
1x CR



15. <sup>(X)</sup>  
1x CL



16.

⑧  ⑦ 





17.



18.

4x 5,5x19



19.

2x M4 2x M4 x 10




20.

6x M4


6x M4 x 10

② SW7


① PH1x100

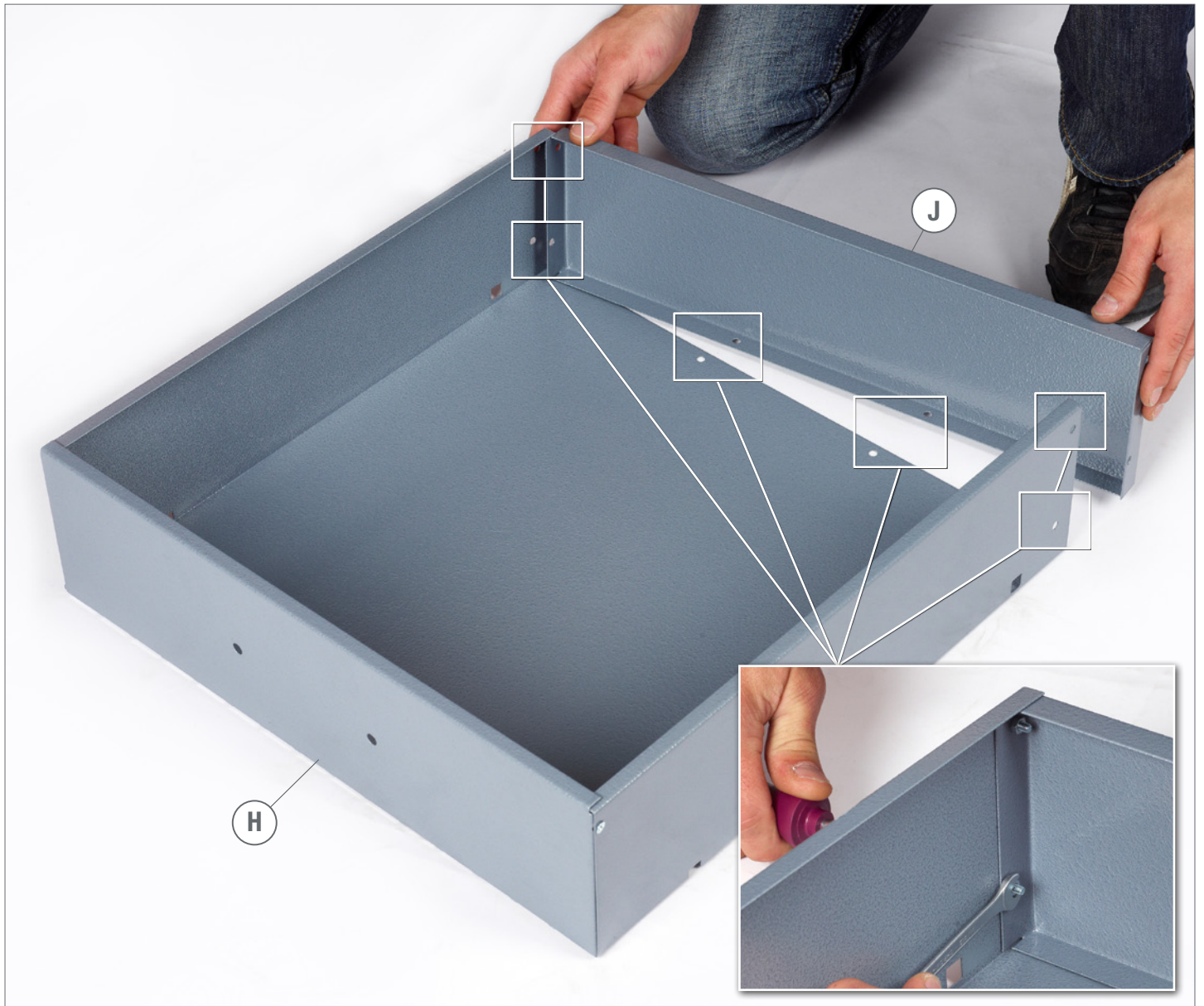

21.

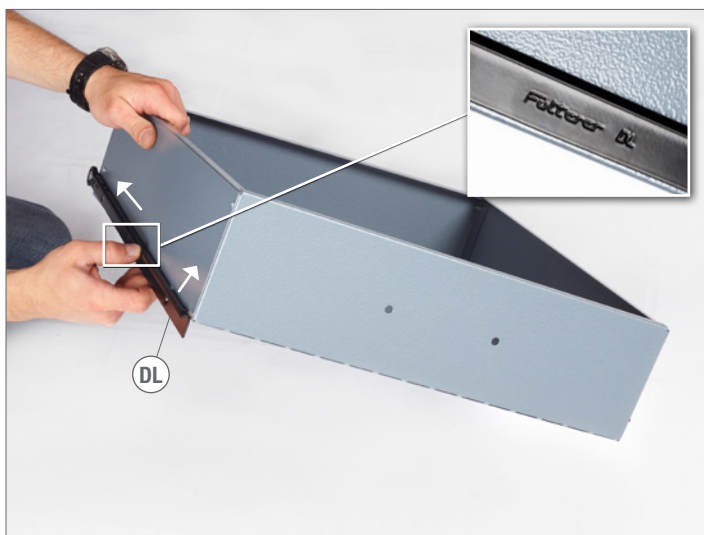

22.

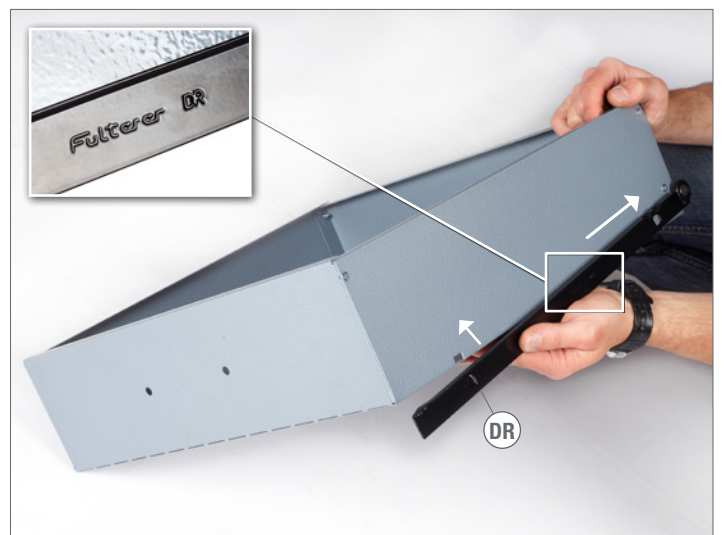

23.



24.

2x KU 4x16

1x



1 PH2x100



25.





Modell-Nr.

**12190**