

















## MONTAGEANLEITUNG

-  MONTAGEANLEITUNG
-  ASSEMBLY INSTRUCTION
-  DE INSTRUCTIE VAN DE ASSEMBLAGE
-  ISTRUZIONE DELL'ASSEMBLEA
-  INSTRUCCIÓN DE ASAMBLEA
-  INSTRUCTION DE MONTAGE
-  NÁVOD K MONTÁŽI
-  MONTERINGSANVISNING

-  MONTAJ TALIMATI
-  ASENNUSOHJE
-  BRUGSANVISNING
-  BRUKSANVISNING
-  UPUTE ZA MONTAŽU
-  NAVODILA ZA MONTAŽO
-  SZERELÉSI ÚTMUTATÓ
-  INSTRUCTIUNI DE MONTAJ



Modell-Nr.

# 71690

Friedrich Küpper GmbH  
Friedrich-Küpper-Weg  
54570 Berlingen  
Deutschland

Telefon +49 (0) 65 91 - 95 42 0  
Telefax +49 (0) 65 91 - 95 42 17  
E-Mail [info@friedrich-kuepper-gmbh.de](mailto:info@friedrich-kuepper-gmbh.de)  
Internet [www.friedrich-kuepper-gmbh.de](http://www.friedrich-kuepper-gmbh.de)

ART.-NR.	FRONT	KORPUS
71691	Grün	Silber
71692	Rot (ähnl. RAL 3002)	Silber
71694	Blau	Silber
71697	Ultramarinblau (RAL 5002)	Silber
71696	Silber	Schwarz

## EINZELTEILE / PIECES

**B**

**1x**

910 mm x 450 mm



**I**

**1x**

1075 mm x 70 mm



**D**

**1x**

905 mm x 405 mm



**K**

**1x**

910 mm x 100 mm



**E**

**1x**

1075 mm x 430 mm



**L**

**1x**

970 mm x 450 mm



**F**

**1x**

1075 mm x 430 mm



**M**

**1x**

970 mm x 458 mm



**G**

**2x**

1075 mm x 385 mm
























**N**

**3x**

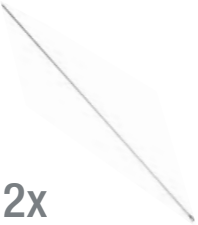




900 mm x 380 mm



BEUTELINHALT / BAG CONTENT

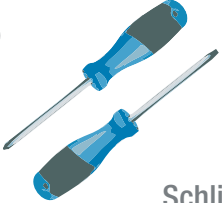
 4x M6x16 mm	 16x M6x12 mm	 4x M6x16 mm	 24x ø6,4 mm	 24x M6	 4x M4 x 10 mm
 4x M4	 4x ø4,3 mm	 4x 5x15	 4x 5x5	 4x	 4x
 4x	 4x	 2x	 1x	 1x	 1x
 1x	 1x	 1x			

BENÖTIGTES WERKZEUG / NEEDED TOOLS


 1 PH 1 x 100 PH 2 x 100 Schlitz 6,5 x 150	 2 SW 7 SW 10	 5
 6 5 mm	 9	

1.

①   
Schlitz 6,5 x 150

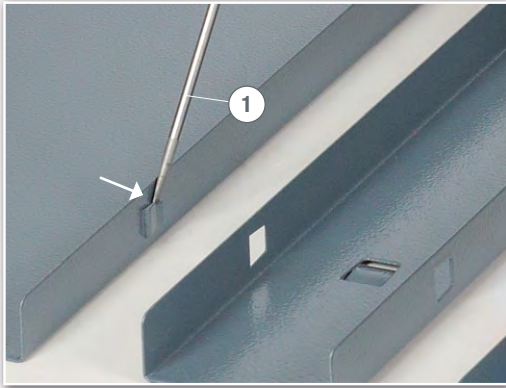

2.

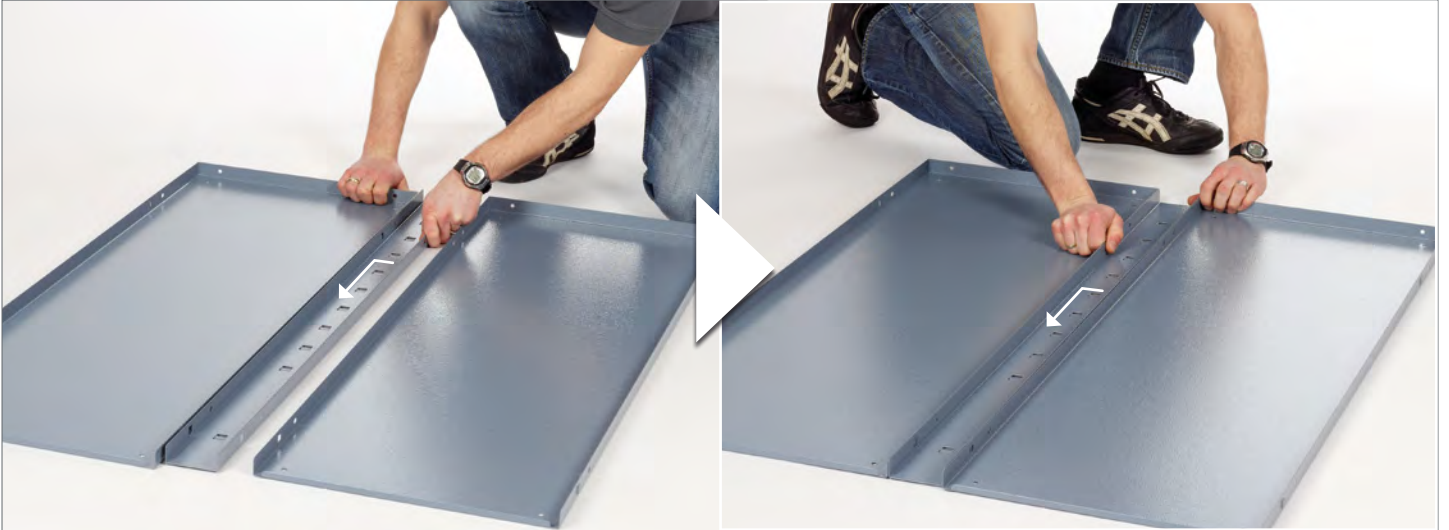

3.



4x M6



4x M6 x 12



4x 6,4 MM



2x SW 10

4.



5.



6.



7.




8.

4x M6

4x 6,4 MM

4x M6x12

②  SW10

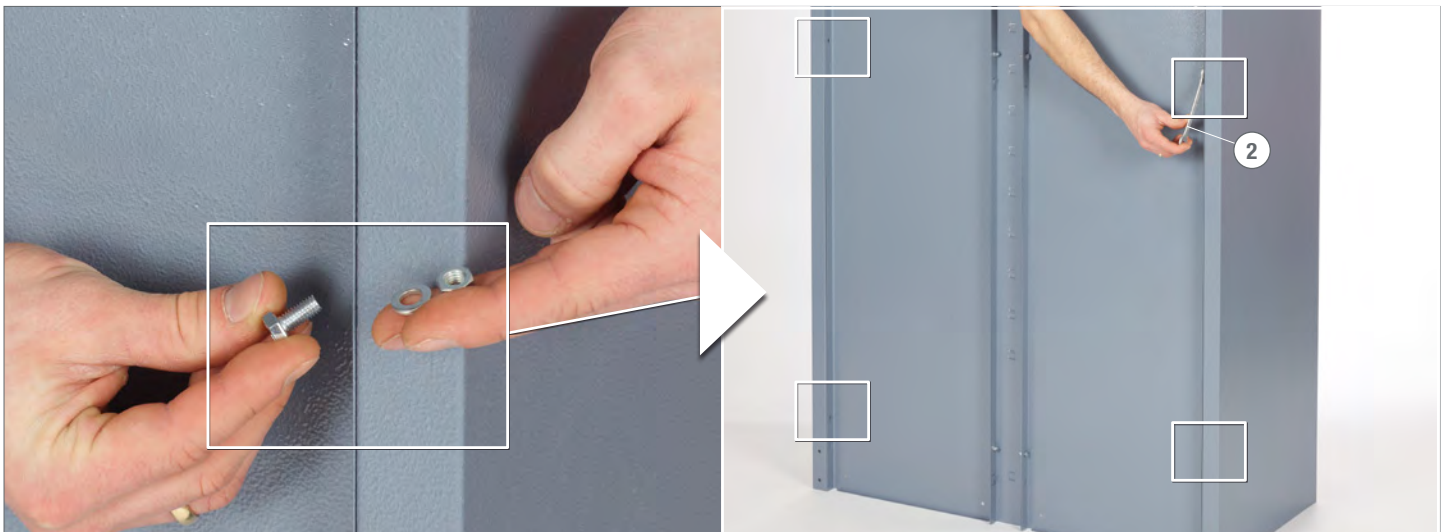


9.



10.

4x M6 4x M6 x 16 4x 6,4 mm 2x

⑥

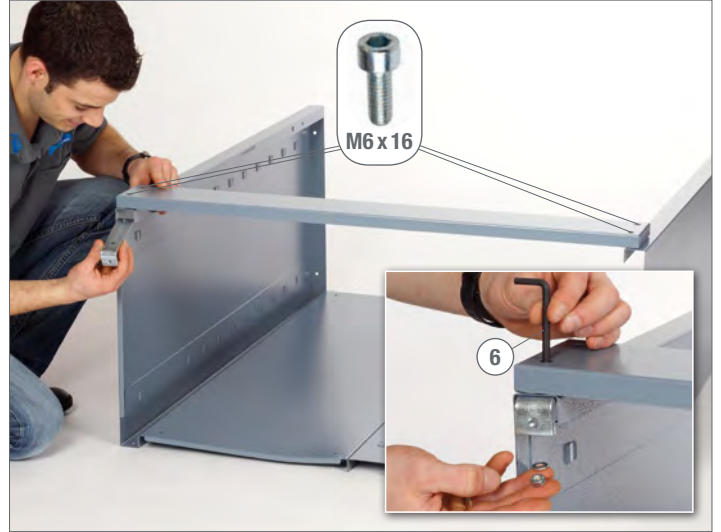

11.


4x



12.

2x

① PH 2 x 100

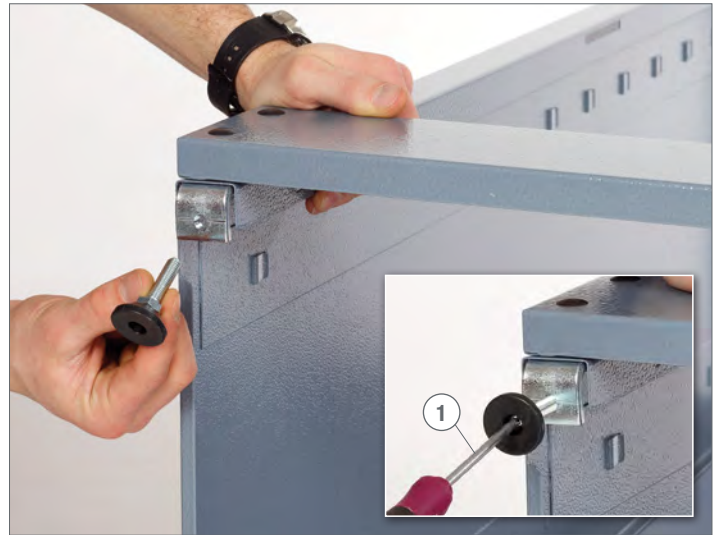


13.

2x




14.

4x M6 4x M6 x 16 4x 6,4 mm 2x ① PH 2 x 100 ② SW 10

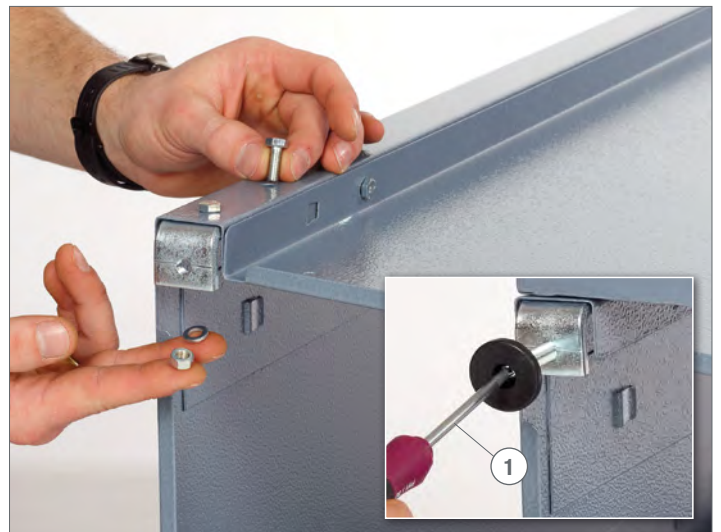

15.

vorne! / this side front!

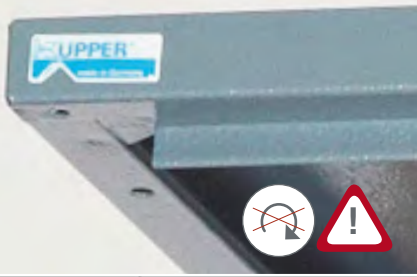

B



16.



8x M6



8x M6x12



8x 6,4 MM



SW10





17.

①   
Schlitz 6,5 x 150



18.



19.



20.




21.  2x 5x15

5 




22.  2x 5x5

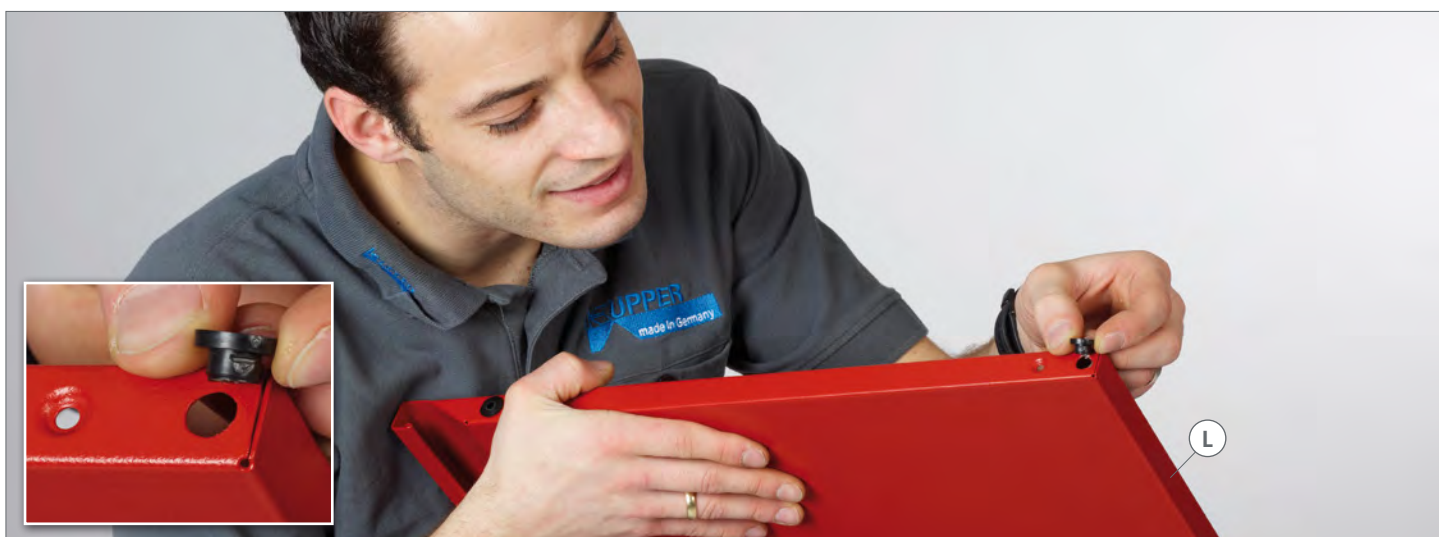


23.  2x 5x15

⑤ 

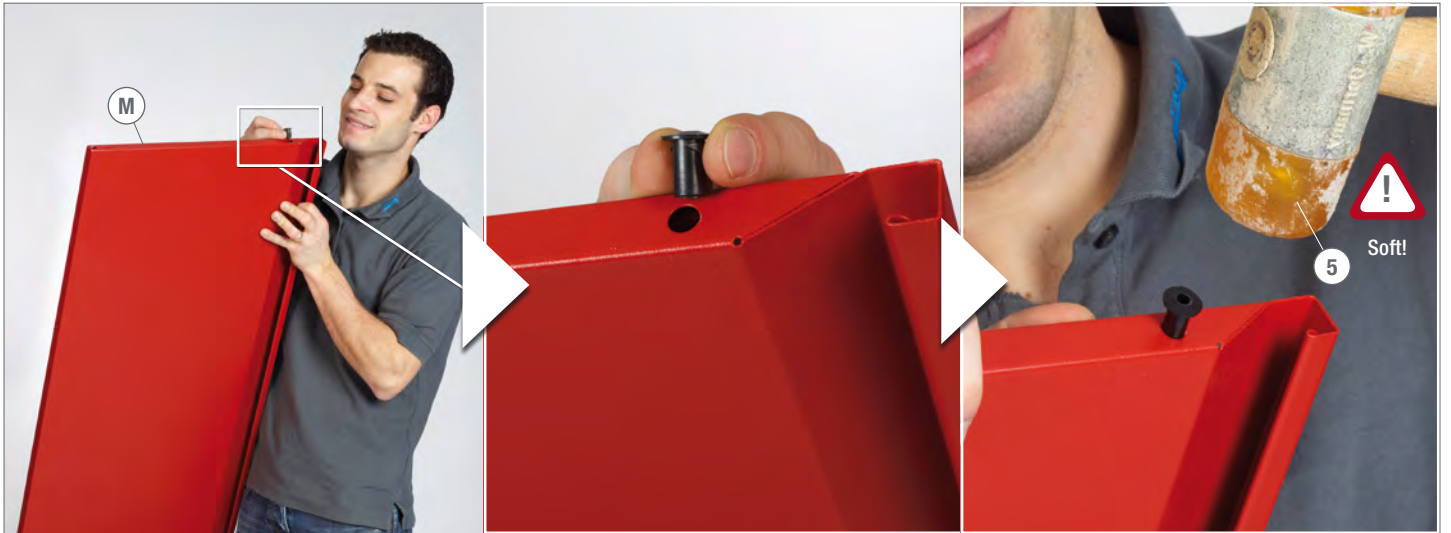

24.  2x 5x5

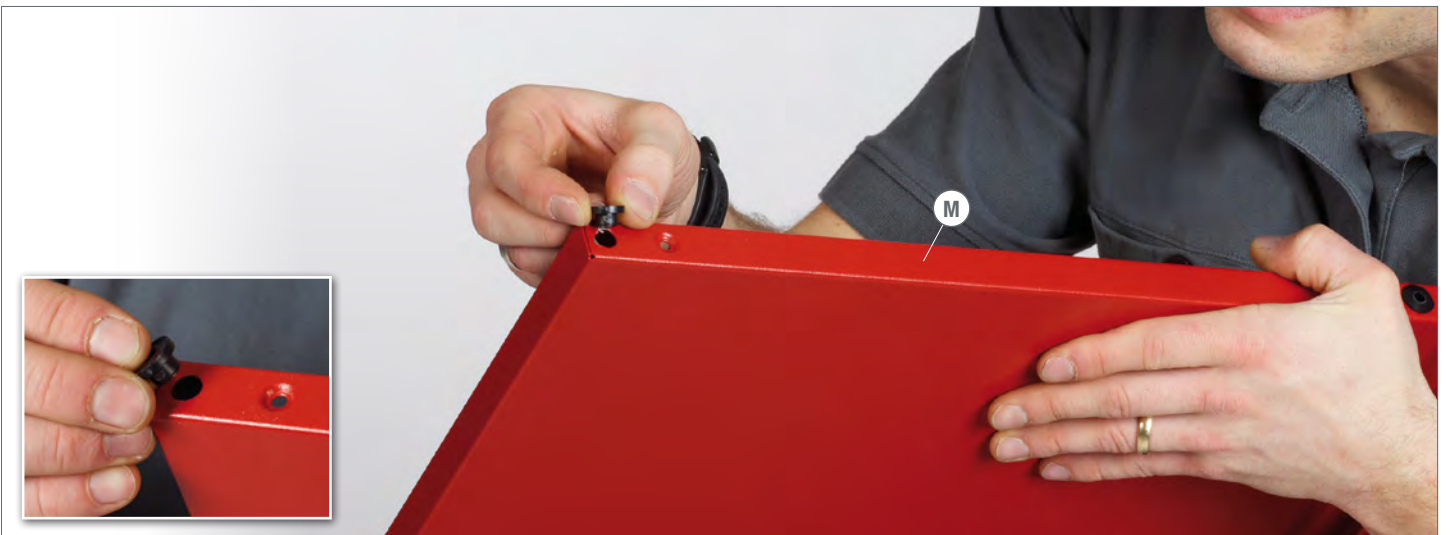

25.  1x



26.

1x M4

1x M4x10

1x 4,3mm

① PH 1 x 100

② SW 7



27.



28.

1x


1x M4

1x M4x10

1x 4,3mm

① PH 1 x 100

② SW 7

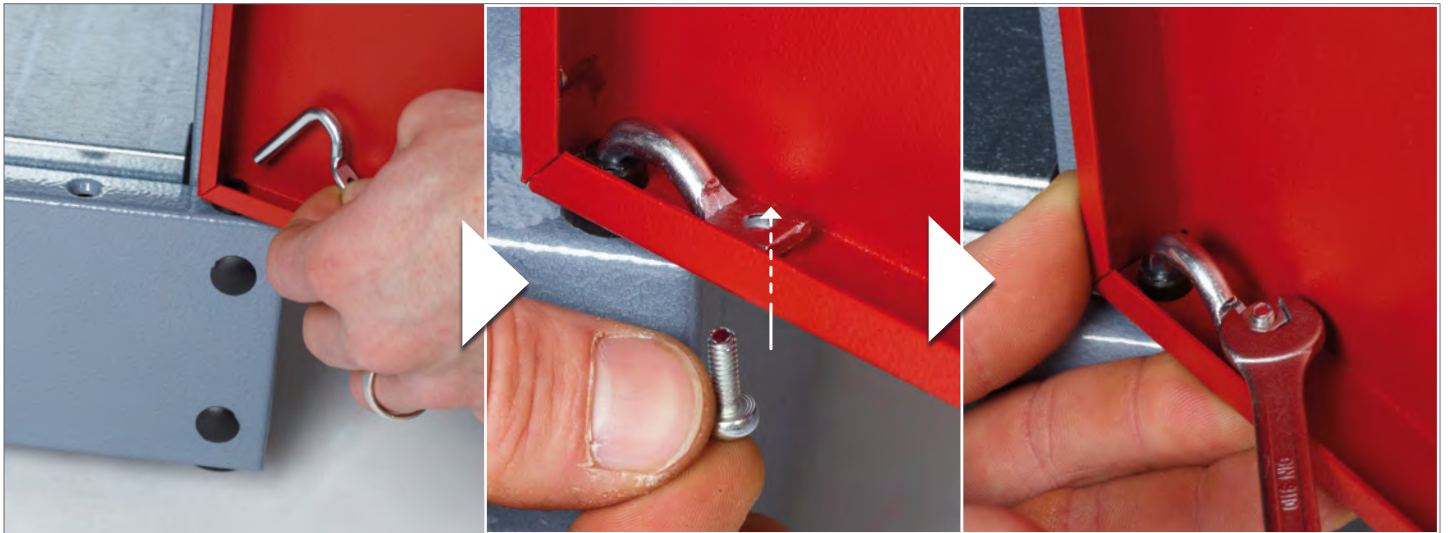

29.

1x



30. 1x M4 1x M4x10 1x 4,3mm ① PH 1 x 100 ② SW 7




31.



32. 1x 1x M4 1x M4x10 1x 4,3mm

① PH 1 x 100 ② SW 7

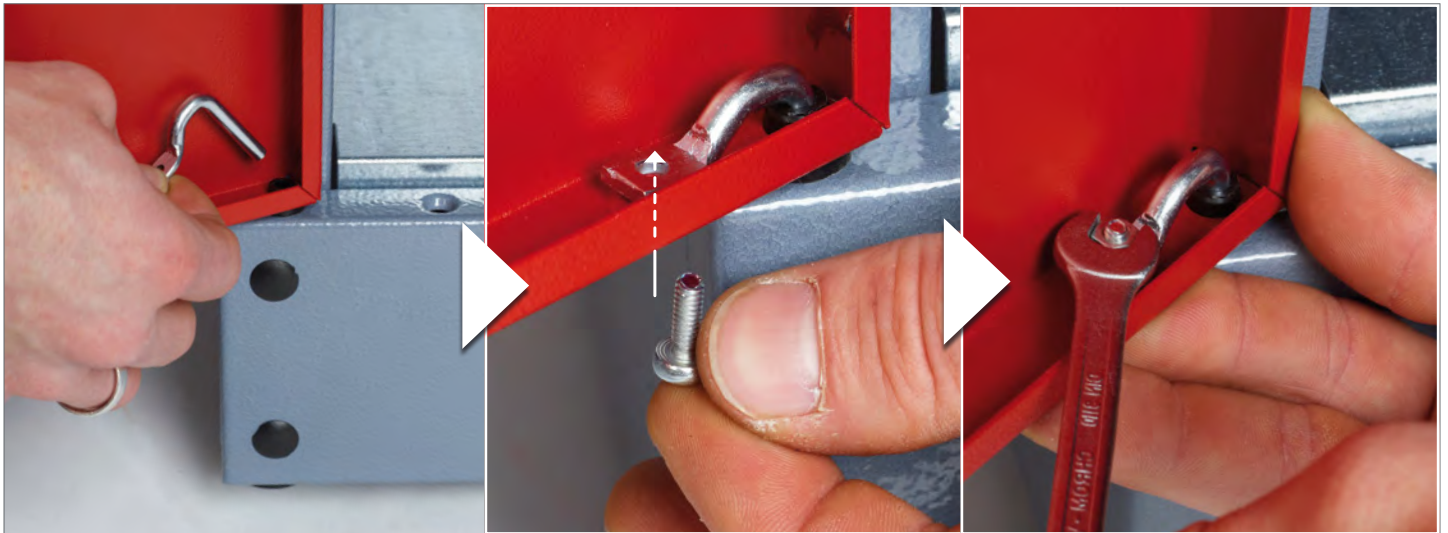

33. 1x 1x 1x

⑨



34. 1x \_\_\_\_\_




35. 1x \_\_\_\_\_



36. 1x \_\_\_\_\_




37.

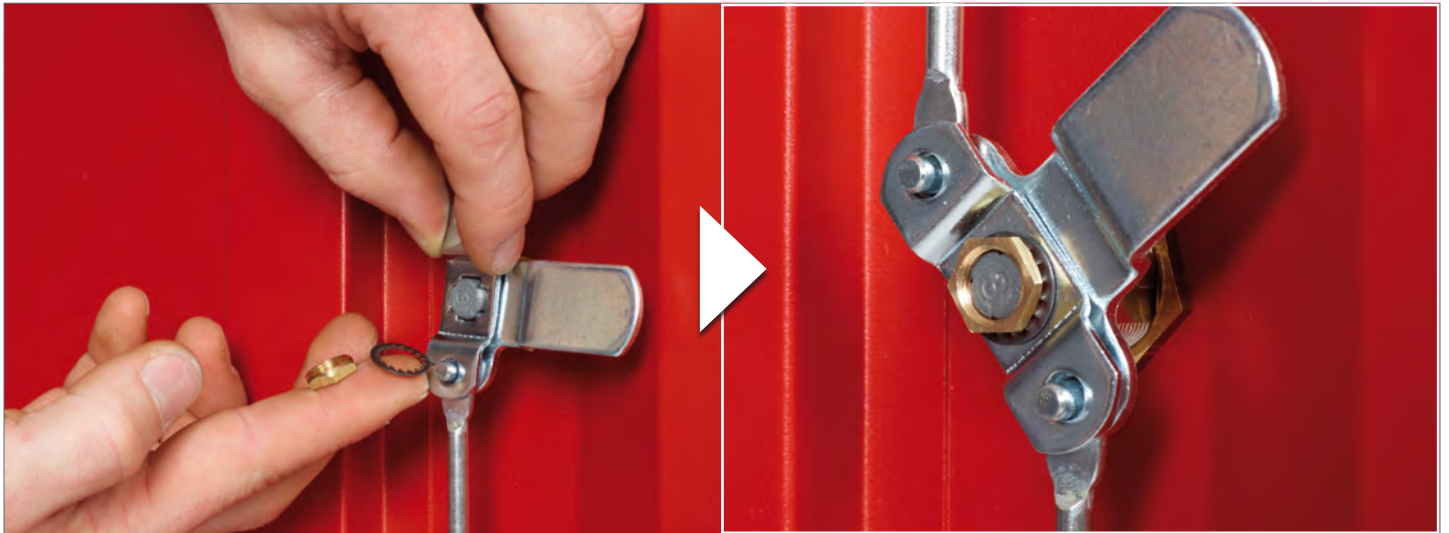

38.



A. 

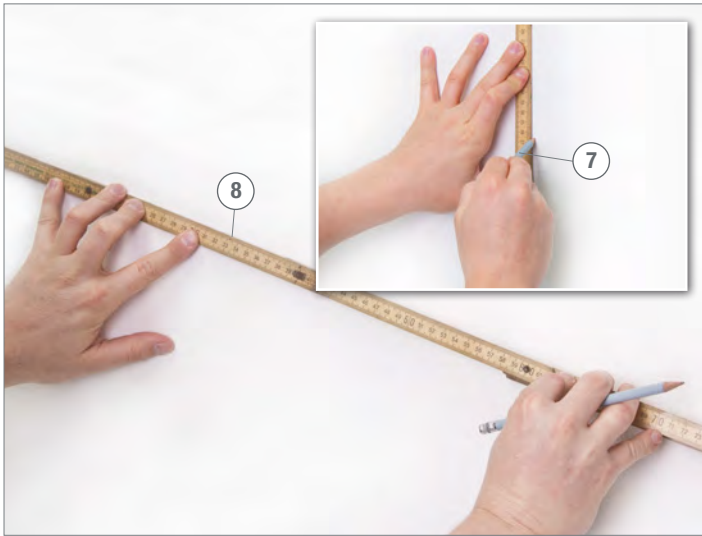

B. 



C. 



D. 



Modell-Nr.

**71690**