


# Vierkantmuttern

## DIN 557

### Vierkantmuttern

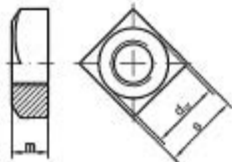

Maße	M 5	M 6	M 8	M 10	M 12	M16
$d_{w \min.}$	6,7	8,7	11,5	14,5/15,5	16,5/17,2	22
m	4	5	6,5	8	10	13
s	8	10	13	16/17	18/19	24