


Kleinstrohlampen T3^{1/4}

KRL 28

Socket E10

(10 x 28 mm)

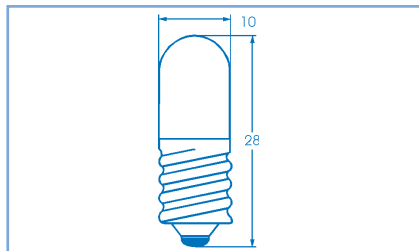

Die fettgedruckten Typen kommen in Leuchtmeldern und Leuchttastern aller namhaften Hersteller zum Einsatz

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553....	Preis/St. in €
6V	50mA	0,3W	00210650	100647	1,00
	75mA	0,45W	00210675	100654	1,00
	100mA	0,6W	00210610	100661	1,00
	180mA	1,1W	00210618	100012	1,00
	300mA	1,8W	00210630	100982	1,00
	333mA	2,0W	00210602	100029	1,00
	500mA	3,0W	00210603	100036	1,00
	830mA	5,0W	00210605	100043	1,00
	1000mA	6,0W	00210606	100050	1,00
6,3V	320mA	2W	00210632	100999	1,00
6-7V		2,0W	00210702	100364	1,00
7V	100mA	0,7W	00210710	100852	1,00
	300mA	2,1W	00210730	100678	1,00
8V	320mA	2,24W	00210722	100937	1,00
	100mA	0,8W	00210808	100456	1,70
9V	300mA	2,4W	00210830	100685	1,65
	450mA	4,0W	00210945	100500	1,10
10V	50mA	0,5W	00211050	100692	1,00
	100mA	1,0W	00211001	100708	1,00
	200mA	2,0W	00211020	100715	1,00
12V	50mA	0,6W	00211250	100470	1,00
	100mA	1,2W	00211210	100869	1,00
	120mA	1,44W	00211212	100067	1,00
	165mA	2,0W	00211202	100074	1,00
	200mA	2,4W	00211220	100876	1,00
	250mA	3,0W	00211203	100081	1,00
	417mA	5,0W	00211205	100098	1,00
12-15V		2,0W	00211502	100371	1,00
15V	50mA	0,75W	00211550	100722	1,00
	200mA	3,0W	00211520	100746	1,00
18V	100mA	1,8W	00211810	100753	1,00
	170mA	3W	00211817	090467	1,00
24V	20mA	0,5W	00212420	100487	1,00
	40mA	1,0W	00212440	100883	1,00
	50mA	1,2W	00212450	100104	1,00
	60mA	1,5W	00212460	100890	1,00
	80mA	2,0W	00212408	100111	1,00
	100mA	2,4W	00212410	100524	1,00
	125mA	3,0W	00212403	100128	1,00
	160mA	4,0W	00212404	100906	1,00
208mA	5,0W	00212405	100135	1,00	
24-30V		2,0W	00213002	100388	0,90
		4,0W	00213014	100395	1,00
Lampenzieher T3^{1/4}			01909007		3,45

Weitere Spannungen und Leistungen auf Anfrage lieferbar !