

## Zwerg-Glimmlampen T3<sup>1</sup>/<sub>4</sub>

ZG

Socket BA9s

(10 x 28 mm)



Spannung	Typ	Artikel-Nr.	EAN 4021553...	Preis/St. in €
115V	ZG 203	00022030	061108	4,10
230V	ZG 233	00022330	061115	2,65
	ZG 233/1 rot LST	00022331	061122	5,15
	ZG 233/3 grün LST (Neon)	00022333	061139	6,00
	ZG 233/9 rot getaucht	00022339	061153	3,10
400V	ZG 273	00022730	061177	3,25
Lampenzieher T3 <sup>1</sup> / <sub>4</sub>		01909007		3,45

## Verjüngte Miniatur-Signalglimmlampen T4<sup>1</sup>/<sub>2</sub>

VG

Socket E14

(14 x 30 mm)



Spannung	Typ	Artikel-Nr.	EAN 4021553...	Preis/St. in €
115V	VG 204	00032040	072005	4,30
230V	VG 234 m. Glas	00032341	072050	3,95
	MG 234/1 rot LST	00042341	072203	6,55
	MG 234/2 gelb LST	00042342	072210	5,95
	MG 234/3 grün LST	00042343	072227	7,75
	MG 234/9 rot getaucht	00042349	072234	6,55
400V	VG 274	00032740	072036	3,80
Lampenzieher T4		01909008		3,45

Kleinslampen

## Verjüngte Miniatur-Signalglimmlampen T4<sup>1</sup>/<sub>2</sub>




VG

Socket BA15d

(14 x 30 mm)



Spannung	Typ	Artikel-Nr.	EAN 4021553...	Preis/St. in €
115V	VG 203	00032030	073002	4,10
230V	VG 233	00032330	073019	4,90
400V	VG 273	00032730	073026	4,85
Lampenzieher T4		01909008		3,45

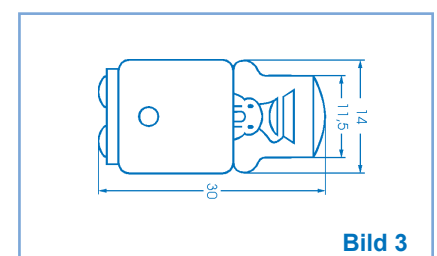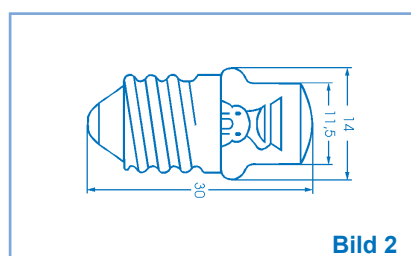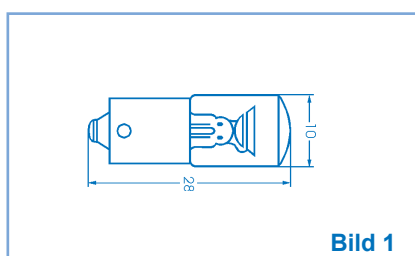

Weitere Typen auf Anfrage lieferbar !