

**Röhrenlampen**

RL

Sondersockel E12 (13 x 34 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EEK	EAN 4021553....	Preis/St. in €
12V	420mA	5W	00100209		172637	4,55
	850mA	10W	00100210		172859	6,10
18V	110mA	2W	00100201		172903	1,50
24V	80mA	2W	00100202		172910	1,50
	110mA	3W	00100203		172927	1,50
28V	70mA	2W	00100204		172934	1,50
30V	65mA	2W	00100205		172941	1,50
	100mA	3W	00100206		172958	1,50
130V	46mA	6W	00100207		172965	3,35
230V	23mA	5W	00100208	E	172972	3,35




**Röhrenlampen**

RL

Sondersockel E12 (20 x 52 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EEK	EAN 4021553....	Preis/St. in €
235V	60mA	15W	00112115	E	172712	3,45

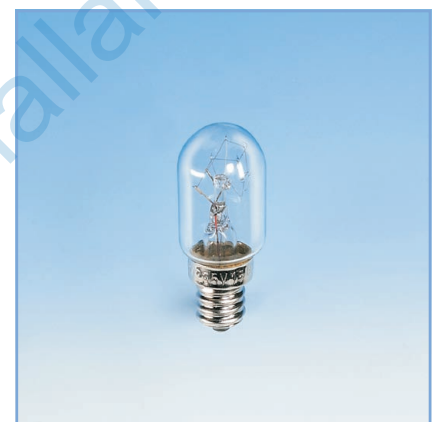


**Kugelbirnenlampen**

KB

Sondersockel E12 (19 x 48 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EEK	EAN 4021553....	Preis/St. in €
6V	1,0A	6W	00112659		172804	2,30
12V	420mA	6W	00112660		172781	2,30
	210mA	5W	00112661		172989	2,30
24V	250mA	6W	00112662		172866	2,30
	200mA	6W	00112663		172873	2,30
120V	50mA	6W	00112666		162072	2,30
250V	40mA	10W	00112658	F	172798	2,30

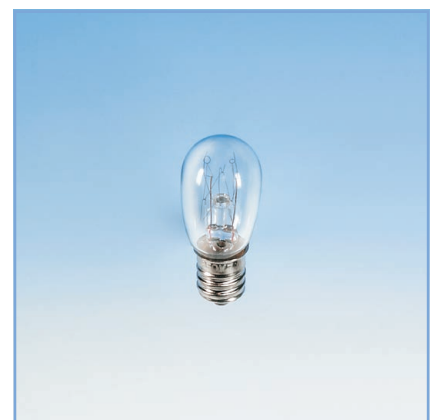

Röhrenlampen

Weitere Spannungen und Leistungen auf Anfrage lieferbar !