


**Röhrenlampen T5**

RL

Socket BA15d

(16 x 45 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EEK	EAN 4021553....	Preis/St. in €
6V	500mA	3W	00100001		243276	1,95
	666mA	4W	00100002		243283	1,95
	833mA	5W	00100003		243290	1,80
12V	333mA	4W	00100004		243306	1,80
	416mA	5W	00100005		243313	1,80
	833mA	10W	00100006		243320	2,00
	1,25A	15W	00100007		243337	1,95
24V	125mA	3W	00100008		243344	1,65
	166mA	4W	00100009		243351	1,65
	208mA	5W	00100010		243368	1,65
	416mA	10W	00100011		243375	1,65
	625mA	15W	00100012		243382	1,95
24-30V		6-10W	00100018		243221	1,80
30V	166mA	5W	00100014		243399	1,65
36V	140mA	5W	00100016		243412	1,85
42V	120mA	5W	00100017		243429	1,75
48V	104mA	5W	00100013		243436	1,85
	208mA	10W	00100019		243009	2,00
60V	66mA	4W	00100020		243443	1,85
	83mA	5W	00100021		243450	1,85
80V	75mA	6W	00100022		243467	2,10
110V	90mA	10W	00100023		243474	2,10
110-140V		5-7W	00100024		243481	2,00
		6-10W	00100025		243498	2,00
130V	38mA	5W	00100026		243504	2,00
220-260V		5-7W	00100032	E	243542	1,95
		6-10W	00100029	E	243238	1,95
240V		7,5W	00100028	D	243016	1,95
	63mA	15W	00100027	F	243511	2,20
380V	26mA	10W	00100031		243535	3,65
<b>Lampenzieher T5</b>			<b>01909009</b>			3,45

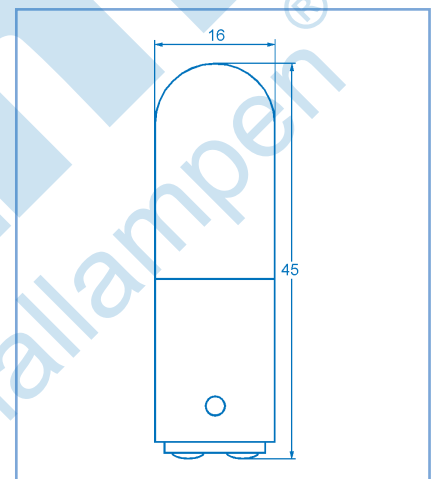

Weitere Spannungen und Leistungen auf Anfrage lieferbar !