


Röhrenlampen T5

RL

Sockel BA15d

(16 x 54 mm)

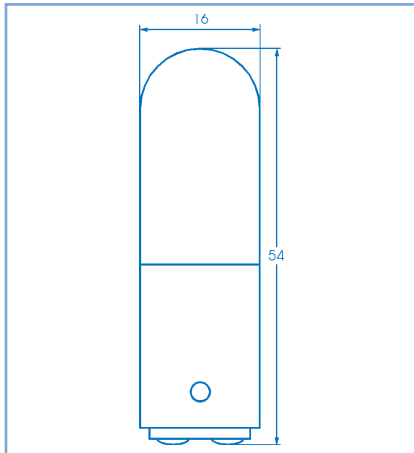

Spannung	Strom	Leistung	Artikel-Nr.	EEK	EAN 4021553....	Preis/St. in €
30V	100mA	3W	00123003		173306	1,75
	160mA	5W	00123005		173115	1,75
rot	160mA	5W	00123051		173122	2,20
	140mA	5W	00123605		173139	1,85
36V	270mA	10W	00123610		173276	1,85
	36-45V	6-10W	00124510		173511	1,95
42V	120mA	5W	00124205		173146	1,85
grün	120mA	5W	00124253		173153	2,20
42V	240mA	10W	00124210		173344	1,85
48V	80mA	4W	00124804		173283	1,85
	100mA	5W	00124805		173160	1,85
	200mA	10W	00124810		173375	2,05
48-60V		6-10W	00126010		173528	1,80
60V	66mA	4W	00126004		173177	1,85
	80mA	5W	00126005		173184	1,85
	160mA	10W	00126016		173290	2,00
65-95V		6-10W	00129510		173320	2,60
110-140V		3-5W	00121405		173535	2,00
		6-10W	00121410		173542	1,80
130V	40mA	5W	00121305		173399	1,85
220-260V		3-5W	00122605	B	173559	2,00
		5-7W	00122607	D	173566	1,55
		6-10W	00122610	E	173573	1,55
		10-15W	00122615	E	173580	1,95
230V	70mA	15W	00122215	E	173191	1,95
260V stossfest	27mA	7W	00122697	E	173627	2,40
380V		10W	00123800		173405	2,70
Lampenzieher T5			01909009			3,45

Röhrenlampen

Röhrenlampen

RL

Sondersockel E12

(16 x 54 mm)



Spannung	Strom	Leistung	Artikel-Nr.	EEK	EAN 4021553....	Preis/St. in €
24V	420mA	10W	00112401		172705	2,95
110-140V		6-10W	00111106		172569	2,95
235V	64mA	15W	00112315	E	172712	3,45
220-260V		6-10W	00112310	E	172743	2,95

Weitere Spannungen und Leistungen auf Anfrage lieferbar !