
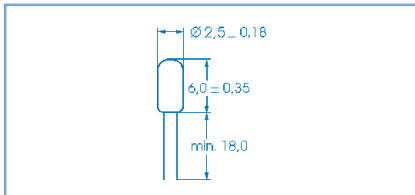


Subminiatur - Glühlampen - Wire Terminal

T^{3/4}

(2,5 x 6,5 mm)

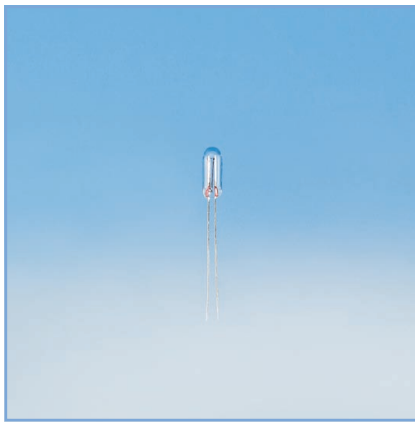



Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...	Preis/St. in €
4V	115mA	0,5W	21090415	368092	1,90
5V	60mA	0,3W	21090560	369808	1,80
	80mA	0,4W	21090580	369815	1,80
6V	115mA	0,6W	21090515	360003	2,00
	25mA	0,15W	21090625	368108	2,40
12V	25mA	0,3W	21091225	368115	2,40
	50mA	0,6W	21091250	369822	2,40
24V	20mA	0,48W	21092420	369839	1,20

Subminiatur - Glühlampen - Wire Terminal

T1

(3,2 x 6,5 mm)

Subminiatur

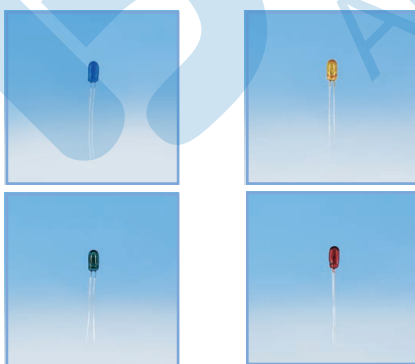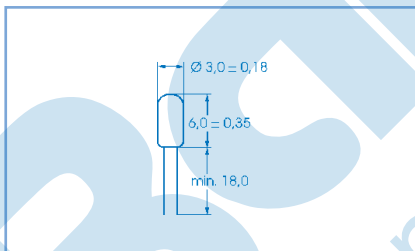

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...	Preis/St. in €
1,5V	75mA	0,11W	21109157	369846	1,15
2,5V	65mA	0,16W	21109255	368047	1,05
	12mA	0,04W	21109312	360034	2,20
3V	40mA	0,12W	21109340	368306	0,80
	115mA	0,35W	21109315	368122	1,90
5V	21mA	0,11W	21109521	369853	0,85
	30mA	0,15W	21109530	369860	0,85
	40mA	0,2W	21109540	368313	0,85
	60mA	0,3W	21109560	369877	0,85
6V	25mA	0,15W	21109615	368139	1,80
	50mA	0,25W	21109650	369907	0,85
	70mA	0,42W	21109670	369921	0,85
8V	115mA	0,7W	21109615	360041	1,80
	80mA	0,64W	21109880	368337	0,90
	12V	30mA	0,36W	21109123	369938
blau	40mA	0,48W	21101240	369945	0,90
	40mA	0,48W	2110124B	368009	0,95
	40mA	0,48W	2110124G	368016	0,95
	40mA	0,48W	2110124R	368023	0,95
	40mA	0,48W	2110124Y	368030	0,95
gelb	50mA	0,6W	21109125	369952	0,85
	60mA	0,72W	21109126	369969	0,85
14V	80mA	1,12W	21109148	369976	0,90
18V	21mA	0,38W	21109181	368146	1,70
	26mA	0,47W	21109182	369983	1,50
24V	20mA	0,48W	21109242	369990	1,50
28V	24mA	0,67W	21109282	369099	1,50
36V	20mA	0,72W	21109362	368153	1,80

Weitere Spannungen und Leistungen auf Anfrage lieferbar!