

Subminiatur - Glühlampen - Wire Terminal

T1^{1/4}

(4,1 x 11,5 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...	Preis/St. in €
6V	40mA	0,24W	00900640	369006	0,90
	60mA	0,36W	00900660	369068	0,95
6,3V	100mA	0,6W	00900680	368160	0,80
12V	20mA	0,24W	00901520	368177	0,90
	30mA	0,36W	00901530	369020	0,80
	40mA	0,48W	00901540	369037	0,90
14V	80mA	1,12W	00901680	369075	0,90
24V	24mA	0,58W	00902824	369051	0,90
	35mA	0,84W	00902535	369082	0,90
	40mA	0,96W	00902540	369044	0,85
	50mA	1,2W	00902550	369051	0,80
28V	40mA	1,22W	00902840	369785	0,90



Bild 1

Subminiatur - Glühlampen - Wire Terminal

T1^{1/2}

(5,1 x 13,2 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...	Preis/St. in €
6,3V	40mA	0,25W	00900740	369105	0,90
12V	40mA	0,48W	00901240	369112	0,90
	80mA	0,96W	00901280	369129	0,90
18V	40mA	0,72W	00901840	369143	0,90
24V	50mA	1,2W	00902450	369167	0,90



Bild 2

Subminiatur

Subminiatur - Glühlampen - Wire Terminal

T1^{3/4}

(5,7 x 13,2 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...	Preis/St. in €
6,3V	200mA	1,26W	00906320	369716	0,75
12V	40mA	0,48W	00901241	369723	0,75
14V	80mA	1,12W	00901481	369730	0,75
24V	40mA	0,96W	00902441	369747	0,80
	50mA	1,2W	00902451	369754	0,80
28V	24mA	0,67W	00902924	368276	0,80
	40mA	1,12W	00902841	368368	0,75
48V	20mA	0,96W	00904820	368375	1,20
60V	20mA	1,20W	00906020	368382	1,30



Bild 3

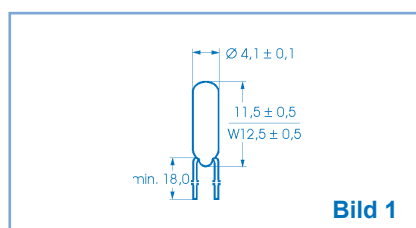


Bild 1

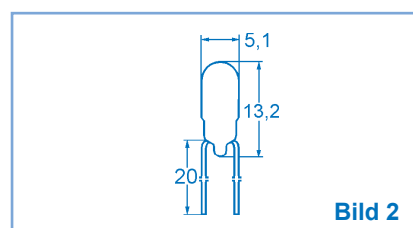


Bild 2

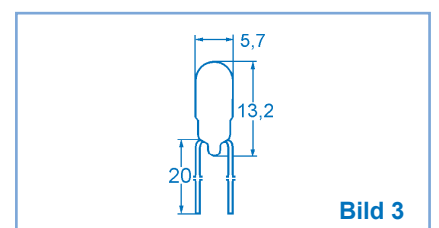


Bild 3

Weitere Spannungen und Leistungen auf Anfrage lieferbar!