

## Subminiatur - Glühlampen - Pisello

WT 20 mm

(5 x 20 mm)



| Spannung | Strom | Leistung | Artikel-Nr. | EAN<br>4021553... | Preis/St.<br>in € |
|----------|-------|----------|-------------|-------------------|-------------------|
| 3V       | 140mA | 0,42W    | 00900314    | 368054            | 0,65              |
| 6V       | 100mA | 0,60W    | 00900610    | 368061            | 0,65              |
| 12V      | 80mA  | 0,96W    | 00901281    | 368078            | 0,65              |
| 24V      | 40mA  | 0,96W    | 00902442    | 368085            | 0,65              |

## Subminiatur - Glühlampen - BI-PIN

T1

(3,17 x 9,5 mm)



Bild 1

| Spannung | Strom | Leistung | Artikel-Nr. | EAN<br>4021553... | Preis/St.<br>in € |
|----------|-------|----------|-------------|-------------------|-------------------|
| 2,5V     | 200mA | 0,5W     | 21012200    | 368399            | 2,00              |
| 5V       | 60mA  | 0,3W     | 21010560    | 369501            | 2,30              |
|          | 115mA | 0,58W    | 21015115    | 368405            | 2,20              |
| 12V      | 60mA  | 0,72W    | 21011260    | 369525            | 1,90              |
| 28V      | 24mA  | 0,67W    | 21012824    | 369532            | 2,50              |
|          | 40mA  | 1,12W    | 21012840    | 368429            | 1,90              |

(Stiftsockelabstand 1,27 mm)

Subminiatur

## Subminiatur - Glühlampen - BI-PIN

T1

(3,17 x 9,5 mm)



Bild 2

| Spannung | Strom | Leistung | Artikel-Nr. | EAN<br>4021553... | Preis/St.<br>in € |
|----------|-------|----------|-------------|-------------------|-------------------|
| 5V       | 60mA  | 0,3W     | 21020560    | 369235            | 2,30              |
|          | 115mA | 0,58W    | 21025115    | 369204            | 2,00              |
| 6V       | 115mA | 0,69W    | 21026115    | 369792            | 1,90              |
| 12V      | 60mA  | 0,72W    | 21021260    | 369211            | 2,00              |
| 18V      | 26mA  | 0,47W    | 21021826    | 369259            | 2,00              |
| 24V      | 20mA  | 0,48W    | 21022420    | 369242            | 3,00              |
| 28V      | 24mA  | 0,67W    | 21022824    | 369228            | 2,50              |
| 36V      | 20mA  | 0,72W    | 21023620    | 360065            | 2,50              |

(Stiftsockelabstand 2,54 mm)

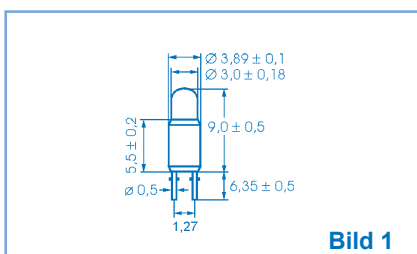


Bild 1

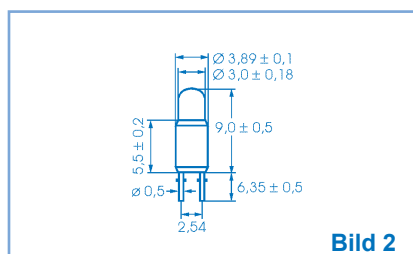


Bild 2

Weitere Spannungen und Leistungen auf Anfrage lieferbar!