
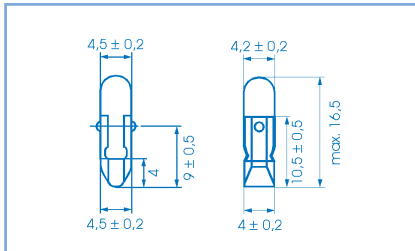


Telefonstecklampen

T4,5

(4,5 x 16,5 mm)

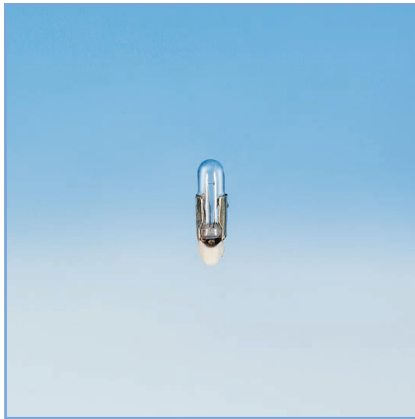



Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...	Preis/St. in €
6V	20mA	0,12W	00500620	325156	1,40
	40mA	0,24W	00500640	325002	1,40
	50mA	0,3W	00500650	325125	1,40
12V	20mA	0,24W	00501220	325019	1,40
	40mA	0,48W	00501240	325026	1,40
	50mA	0,54W	00501250	325033	1,40
	100mA	1,2W	00501210	325040	1,55
16V	60mA	1,0W	00501660	325132	1,55
24V	20mA	0,5W	00502420	325057	1,35
	40mA	1,0W	00502440	325163	1,45
	50mA	1,2W	00502450	325064	1,45
30V	20mA	0,6W	00503020	325071	1,45
	40mA	1,2W	00503040	325088	1,45
36V	20mA	0,72W	00503620	325095	1,60
48V	20mA	1,0W	00504820	325101	1,60
60V	20mA	1,2W	00506020	325118	1,60
Glimmlampe mit Widerstand					
230V	0,5mA		00502305	325149	7,30
Lampenzieher T1¼			01909002		3,45

Telefonstecklampen

T4,6

(4,6 x 22 mm)

Kleinslampen

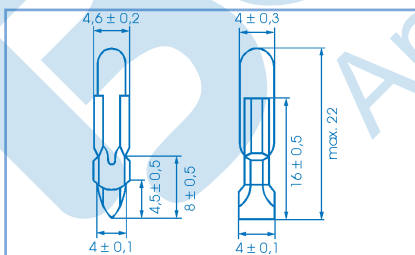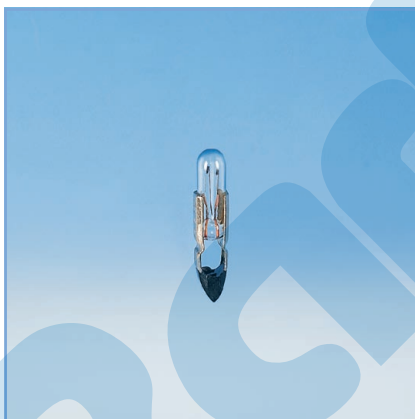

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...	Preis/St. in €
6V	20mA	0,12W	00510620	325200	1,40
	40mA	0,24W	00510640	325217	1,40
	50mA	0,3W	00510650	325224	1,40
12V	20mA	0,24W	00511220	325231	1,40
	40mA	0,48W	00511240	325248	1,40
	50mA	0,54W	00511250	325354	1,40
	100mA	1,2W	00511210	325361	1,40
16V	60mA	1,0W	00511660	325255	1,40
18V	25mA	0,45W	00511825	325392	3,65
24V	20mA	0,5W	00512420	325262	1,40
	40mA	1,0W	00512440	325378	1,40
	50mA	1,2W	00512450	325279	1,40
28V	20mA	0,56W	00512820	325330	1,40
30V	20mA	0,6W	00513020	325286	1,40
	40mA	1,2W	00513040	325293	1,40
36V	20mA	0,72W	00513620	325309	1,65
	35mA	1,2W	00513635	325385	1,65
48V	20mA	1,0W	00514820	325316	1,65
	30mA	1,44W	00514830	325408	1,65
60V	20mA	1,2W	00516020	325323	1,65
Glimmlampe mit Widerstand					
230V	0,5mA		00512305	325347	6,70
Lampenzieher T1¼			01909002		3,45