


## Telefonstecklampen

T5,5

(5,4 x 30 mm)

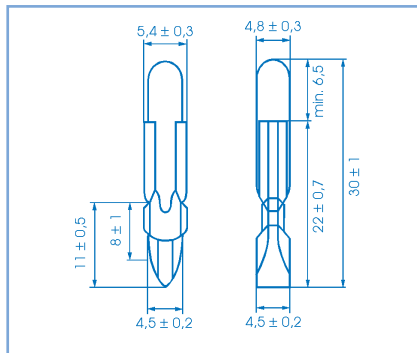

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...	Preis/St. in €
6V	20mA	0,12W	00530620	335209	1,40
	40mA	0,24W	00530640	335216	1,40
	50mA	0,3W	00530650	335575	1,40
	200mA	1,2W	00530602	335223	1,40
12V	20mA	0,24W	00531220	335230	1,40
	40mA	0,48W	00531240	335247	1,40
	50mA	0,54W	00531250	335254	1,40
	100mA	1,2W	00531210	335261	1,40
16V	50mA	0,8W	00531650	335278	1,40
18V	25mA	0,5W	00531825	524682	1,50
24V	20mA	0,5W	00532420	335285	1,40
	25mA	0,6W	00532425	335292	1,40
	30mA	0,7W	00532430	335308	1,40
	40mA	1,0W	00532440	335315	1,40
	50mA	1,2W	00532450	335322	1,40
	80mA	2,0W	00532480	335339	1,40
28V	20mA	0,56W	00532820	335346	1,40
	40mA	1,12W	00532840	335353	1,40
	50mA	1,4W	00532850	335360	1,40
30V	20mA	0,6W	00533020	335377	1,40
	40mA	1,2W	00533040	335384	1,40
	40mA	Grün	00533040-G	335612	3,40
	50mA	1,5W	00533050	335391	1,40
32V	33mA	1,0W	00533233	335407	1,40
36V	20mA	0,72W	00533620	335414	1,40
	35mA	1,2W	00533635	335582	1,40
	40mA	1,44W	00533640	335421	1,40
	50mA	1,8W	00533650	335438	1,40
48V	20mA	1,0W	00534820	335445	1,65
	25mA	1,2W	00534825	335452	1,65
	30mA	1,4W	00534830	335469	1,65
	40mA	2,0W	00534840	335476	1,65
60V	20mA	1,2W	00536020	335483	1,65
	40mA	2,4W	00536040	335599	1,75
70V	20mA	1,4W	00537020	335490	1,65
80V	20mA	1,6W	00538020	335506	2,10
<b>Glimmlampe mit Widerstand</b>					
115V			00531122	335537	6,60
230V			00532222	335513	5,50
<b>Glimmlampe mit Widerstand grün</b>					
115V			00531123	335544	9,30
230V			00532223	335520	9,30
<b>Lampenzieher T1½</b>			01909003		3,45

Weitere Spannungen und Leistungen auf Anfrage lieferbar!