


Telefonstecklampen

T6,8

(6,8 x 44 mm)

Spannung	Strom	Leistung	Artikel-Nr.	EAN 4021553...	Preis/St. in €
6V	20mA	0,12W	00540620	345000	1,40
	50mA	0,3W	00540650	345017	1,40
	80mA	0,48W	00540680	345024	1,40
	200mA	1,2W	00540618	345031	1,40
12V	20mA	0,24W	00541220	345048	1,55
	40mA	0,48W	00541240	345314	1,40
	50mA	0,54W	00541250	345055	1,40
	100mA	1,2W	00541210	345062	1,40
24V	20mA	0,5W	00542420	345079	1,40
	25mA	0,6W	00542425	345086	1,40
	40mA	1,0W	00542440	345093	1,40
	50mA	1,2W	00542450	345109	1,40
	80mA	2,0W	00542480	345116	1,40
28V	40mA	1,12W	00542840	345123	1,40
	45mA	1,26W	00542845	345130	1,40
	50mA	1,4W	00542850	345352	1,40
30V	20mA	0,6W	00543020	345284	1,40
	40mA	1,2W	00543040	345147	1,40
	50mA	1,5W	00543050	345154	1,40
	100mA	3,0W	00543010	345161	1,40
36V	20mA	0,72W	00543620	345178	1,55
	33mA	1,2W	00543633	345369	1,55
	40mA	1,44W	00543640	345321	1,55
Grün	40mA	1,44W	00543640-G	345376	3,20
	50mA	1,8W	00543650	345185	1,55
48V	20mA	1,0W	00544820	345192	1,55
	25mA	1,2W	00544825	345208	1,55
	40mA	1,4W	00544840	345215	1,65
	50mA	2,0W	00544850	345222	1,65
60V	20mA	1,2W	00546020	345239	1,65
	40mA	2,4W	00546040	345246	1,65
	60mA	3,6W	00546060	345338	1,65
70V	20mA	1,4W	00547020	345253	1,65
80V	20mA	1,6W	00548020	345345	2,25
Glimmlampe mit Widerstand					
230V			00542222	345260	6,10
Glimmlampe mit Widerstand grün					
230V			00542223	345277	9,30
Lampenzieher T2			01909005		3,45

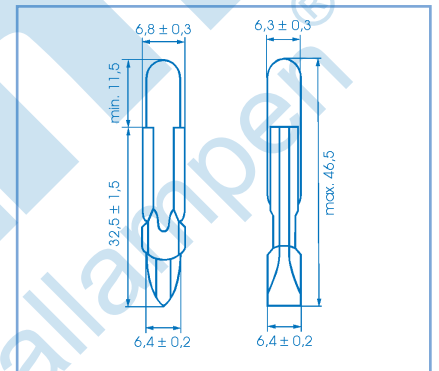

Sondertyp:

**T6,8K
(6,8 x 22 mm)**

auf Anfrage lieferbar !

Kleinslampen

Weitere Spannungen und Leistungen auf Anfrage lieferbar!