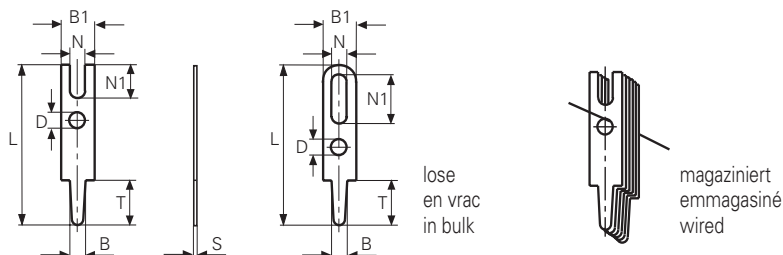


 
## Lötstifte Picots pour C.I. Soldering lugs for PCB

 
Werkstoff/Matière/Material  
.2 = Bronze/bronze  
.6 = Messing/laiton/brass

■ = Oberflächen/Surface/Surface-plating  
Seite/page/page 5.011



Federschlagwerkzeug / Appareil à percuter / Hand tool No. 1035

|                                               |  |  |  |  |  |  |
|-----------------------------------------------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|
| Artikelnummer<br>Numéro d'article<br>Part-No. | <b>1002d.6■</b>                                                                   | <b>01002d.6■</b>                                                                  | <b>1003.6■</b>                                                                    | <b>01003.6■</b>                                                                    | <b>1004k.6■</b>                                                                     | <b>1004.6■</b>                                                                      |
| Bohrung/Trou/Hole                             | Ø 1.2<br>T 3.7<br>L 10.2<br>B1 2.9<br>N 1.2<br>N1 2.1<br>øD 1.2<br>B 1.1<br>S 0.8 | Ø 1.2<br>T 3.7<br>L 10.2<br>B1 2.9<br>N 1.2<br>N1 2.1<br>øD 1.2<br>B 1.1<br>S 0.8 | Ø 1.2<br>T 4<br>L 13<br>B1 2.4<br>N 1.2<br>N1 1.9<br>øD<br>B 1.25<br>S 0.5        | Ø 1.2<br>T 4<br>L 13<br>B1 2.4<br>N 1.2<br>N1 1.9<br>øD<br>B 1.25<br>S 0.5         | Ø 1.2<br>T 4<br>L 13<br>B1 2.4<br>N<br>N1<br>øD 1.55<br>B 1.25<br>S 0.5             | Ø 1.2<br>T 4.5<br>L 15<br>B1 2<br>N 1<br>N1 2.5<br>øD<br>B 1.2<br>S 0.35            |
| Werkzeuge<br>Outils<br>Toolings               | <b>16</b>                                                                         | <b>1042g</b>                                                                      | <b>11</b>                                                                         | <b>1049</b>                                                                        | <b>19</b>                                                                           | <b>8</b>                                                                            |

|                                               |  |  |  |  |  |
|-----------------------------------------------|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|
| Artikelnummer<br>Numéro d'article<br>Part-No. | <b>1003d.6■</b>                                                                     | <b>01003d.6■</b>                                                                    | <b>1003e.6■</b>                                                                     | <b>01003e.6■</b>                                                                      | <b>1006.6■</b>                                                                        |
| Bohrung/Trou/Hole                             | Ø 1.2<br>T 5<br>L 11.3<br>B1 3<br>N 1.2<br>N1 2.2<br>øD<br>B 1.2<br>S 0.6           | Ø 1.2<br>T 5<br>L 11.3<br>B1 3<br>N 1.2<br>N1 2.2<br>øD<br>B 1.2<br>S 0.6           | Ø 1.2<br>T 5<br>L 11.3<br>B1 3<br>N 1.7<br>N1 2.4<br>øD<br>B 1.2<br>S 0.6           | Ø 1.2<br>T 5<br>L 11.3<br>B1 3<br>N 1.7<br>N1 2.4<br>øD<br>B 1.2<br>S 0.6             | Ø 1.2<br>T 5.5<br>L 18<br>B1 2<br>N 1<br>N1 2.5<br>øD<br>B 1.2<br>S 0.35              |
| Werkzeuge<br>Outils<br>Toolings               | <b>62</b>                                                                           | <b>1040de</b>                                                                       | <b>62</b>                                                                           | <b>1040de</b>                                                                         | <b>8</b>                                                                              |