 
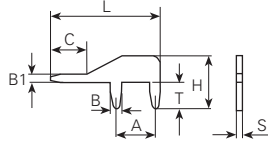
 
 
 

 
 







# Winkelstifte Chevilles angulaires p.CI Angle pins for P.C.B.

Werkstoff/Matière/Material  
 .2 = Bronze/bronze  
 .6 = Messing/laiton/brass  
 .7 = Neusilber/mailechort/german silver  
 .9 = Stahl/acier/steel

■ = Oberflächen/Surface/Surface-plating  
 Seite/page/page 5.011



Artikelnummer Numéro d'article Part-No.						
<b>1080z.2</b> ■	<b>1081a.6</b> ■	<b>1081m.6</b> ■	<b>1080u.6</b> ■	<b>10811.6</b> ■	<b>010811.6</b> ■	
Bohrung/Trou/Hole	Ø 0.8	Ø 0.8	Ø 0.8	Ø 0.8	Ø 0.8	Ø 0.8
T	0.9/1.7	1.8	2	2.1	2.4	2.4
H	2.45	3.2	4.4	3.5	5.8	5.8
L	12.7	11.2	11.2	9.5	11.85	11.85
C	7.3	6.2	6.2	2.8	6.95	6.95
A	3	2.5	2.5	2.5	2.5	2.5
B1	0.6	0.7	0.7	0.6	0.7	0.7
B	0.55	0.7	0.7	0.8	0.7	0.7
S	0.65	0.6	0.6	0.5	0.6	0.6
Werkzeuge Outils Toolings		<b>34</b>	<b>34</b>	<b>34</b>	<b>34</b>	<b>1051b</b>

Artikelnummer Numéro d'article Part-No.					
<b>1080q.6</b> ■	<b>1080h.6</b> ■	<b>1081p.6</b> ■	<b>1081b.6</b> ■	<b>01081b.6</b> ■	
Bohrung/Trou/Hole	Ø 0.8	Ø 0.8	Ø 0.9	Ø 1	Ø 1
T	3	3	3.2	2.2	2.2
H	4.4	4.4	5.35	3.71	3.71
L	8.5	11.2	17.6	7	7
C	3.5	6.2	12.7	2.3	2.3
A	2.5	2.5	2.5	2.5	2.5
B1	0.7	0.7	0.8	1	1
B	0.7	0.7	0.77	1	1
S	0.6	0.6	0.8	0.6	0.6
Werkzeuge Outils Toolings	<b>34</b>	<b>34</b>		<b>34</b>	<b>1051d</b>