
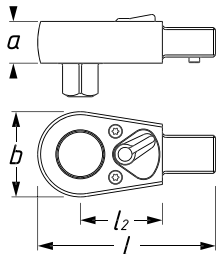
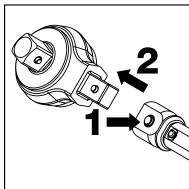


6401-1 Einsteck-Umschaltknarre

 **Made in Germany**

- 6401-1 20 Zähne · Betätigungswinkel 18° – maximal 40 Nm
- 6402-1 30 Zähne · Betätigungswinkel 12° – maximal 120 Nm
- 6403-1 32 Zähne · Betätigungswinkel 11,25° – maximal 120 Nm
- 6404-1 32 Zähne · Betätigungswinkel 11,25° – maximal 300 Nm
- Gesenkgeschmiedet
- Oberfläche: verchromt
- DIN 3120, ISO 1174-1



(E)

HAZET No.	Antrieb	Abtrieb	<i>l</i> mm	<i>l</i> ₂ mm	<i>a</i> mm	<i>b</i> mm	EAN-No. 4000896+	€
6401-1	■ 9x12	■ 6,3 = 1/4"	46,5	19,5	9,9	21,8	027439	
6402-1	■ 9x12	■ 10 = 3/8"	61	30	15	30	027460	
6403-1	■ 9x12	■ 12,5 = 1/2"	74,5	38,5	19,6	40	027521	
6404-1	■ 14x18	■ 12,5 = 1/2"	83,5	38,5	19,6	40	027552	