



Spannung	Ausf.	Leistung	Artikel-Nr.	EEK	EAN 4021553....
6V	klar	10W	00980610		252698
	klar	15W	00980615		252704
12V	klar	15W	00701215		252032
	klar	25W	00701225		252049
24V	klar	5W	00982405		252735
	klar	10W	00982410		252742
	klar	15W	00982415		252759
24V	klar	25W	00982425		252766
	klar	5W	00984205		252797
	klar	15W	00984215		252988
42V	klar	25W	00984225		252803
	klar	10W	00706510		252131
	klar	15W	00986515		252995
65V	klar	25W	00986525		252254
	klar	6-10W	00981410		252810
110-140V	klar	10-15W	00981415		252827
	klar	15W	00981315		252834
130V	klar	25W	00981325		252841
	klar	15W	00982215	F	252858
235V	TV-blau	15W	0098TV15	E	252919
	i-matt	15W	00982115	E	252117
	klar	25W	00982225	E	252926
	TV-blau	25W	0098TV25	E	252940
	klar	40W	00702240	E	252360
220-260V	klar	6-10W	00982610	E	252957
	klar	10-15W	00982615	E	252964
260V	klar, stossfest	15W	00706215	E	252209
	klar	25W	00982625	E	252971

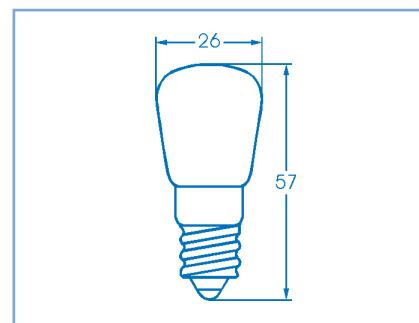

 **Industrielampe!**
Nicht für die Beleuchtung
im Privathaushalt geeignet!

AGL