



HP 90 W Smart Netzteil

Marke : HP
Artikel-Code: H6Y90AA
Produktname : 90 W Smart Netzteil

90 W Smart Netzteil
HP 90 W Smart Netzteil:

Reliable power for your mobile world
Mit einem HP Smart-Wechselstromnetzteil mit 90 W versorgen Sie Ihr HP Notebook optimal mit Energie und gleichen außerdem Stromschwankungen aus. Profitieren Sie jetzt auch von einem neuen rechtwinkligen Verbindungsstück, das Kabel vor dem Abknicken schützt, sowie einem optionalen 4,5-auf-7,4-mm-Adapter. Mit diesem Ersatz- oder Reserve-Adapter finden Sie immer den richtigen Anschluss. HP 90 W Smart Netzteil. Zweck: Laptop, Netzteiltyp: Drinnen, Ausgangsleistung: 90 W. Produktfarbe: Schwarz. Breite: 127 mm, Tiefe: 50 mm, Höhe: 29 mm. Verpackungsbreite: 156 mm, Verpackungstiefe: 210 mm, Verpackungshöhe: 77 mm. Produkte pro Palette: 800 Stück(e), Versandkarton pro Palettenlage: 10 Stück(e), Lagenanzahl pro Palette: 8 Stück(e)



Merkmale		Verpackungsdaten	
Zweck *	Laptop	Verpackungstiefe	210 mm
Netzteiltyp *	Drinnen	Verpackungshöhe	77 mm
Ausgangsleistung *	90 W	Paketgewicht	700 g
HP-Segment	Business	Markeneigenschaften	
Design		HP GTIN (EAN/UPC)	887758607756
Produktfarbe *	Schwarz	Technische Details	
Gewicht und Abmessungen		URL der allgemeinen Produktsicherheitsverordnung (GPSR) https://support.hp.com/us-en/document/ish_6126692-6126777-16?openCLC=true	
Breite	127 mm	Logistikdaten	
Tiefe	50 mm	Warentarifnummer (HS)	85044095
Höhe	29 mm	Produkte pro Palette	800 Stück(e)
Gewicht	370 g	Versandkarton pro Palettenlage	10 Stück(e)
Verpackungsdaten		Lagenanzahl pro Palette	8 Stück(e)
Verpackungsbreite	156 mm		



0887758607831



887758607831



0887758607824




887758607824




0887758607862




887758607862

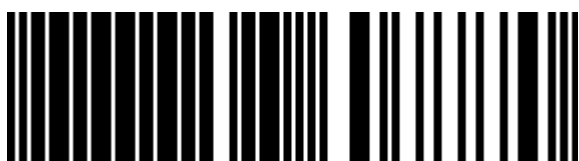

0887758607770

 


887758607770

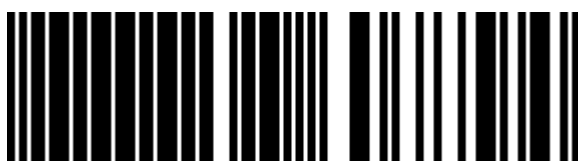

0887758607794



887758607794

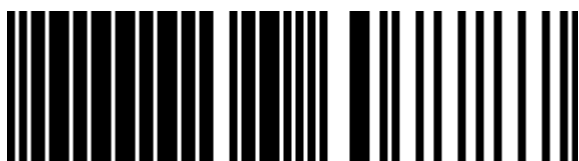

0887758607787



887758607787



0887758607886



887758607886



0887758607749



887758607749



0887758607732



887758607732



0887758607763



887758607763



0889899388280



889899388280



0887758700778



887758700778



0887758607879



887758607879



0887758607855




887758607855



0887758607848




887758607848

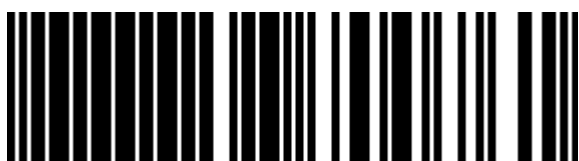

0887758700761




887758700761

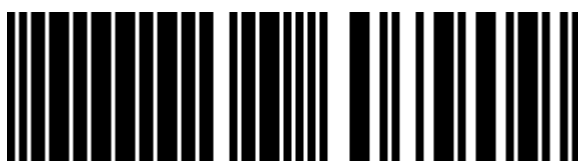

0887758607909



887758607909

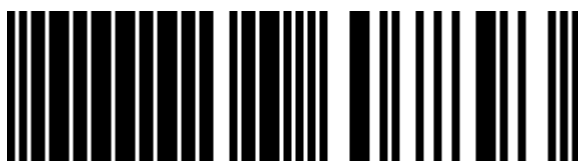

0887758607893



887758607893



0887758607800



887758607800



0195161323638



195161323638

Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.