




IP and IK classifications page 32
IP und IK Klassifikationen

Technical information page 33
Technische Eigenschaften

Material properties and performance pages 34-35
Material Vor-/Nachteile und Materialeigenschaften

Gaskets page 36
Gehäusedichtunge

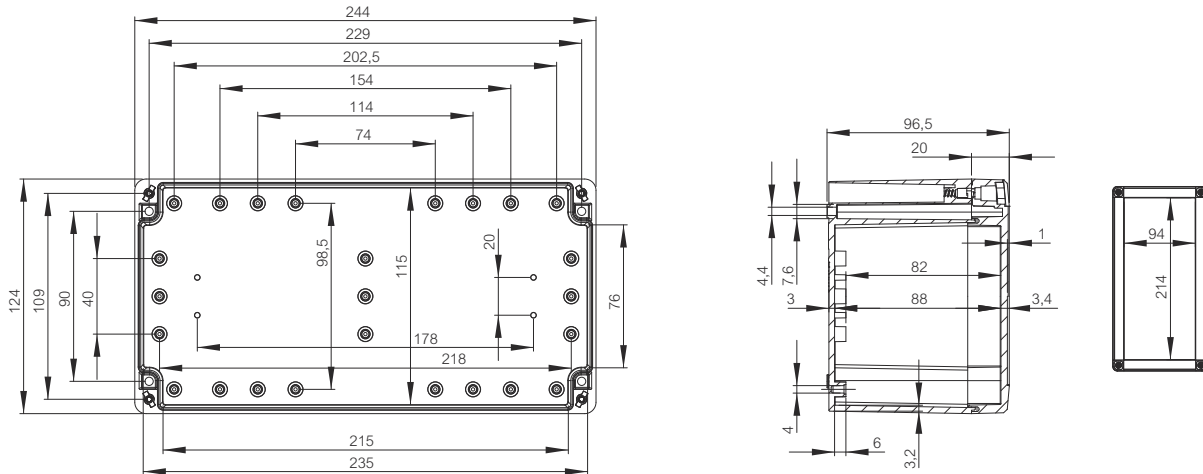

	Dimensions, mm Abmessungen, mm	Order symbol Bestellzeichen	Code & EAN Artikel-Nr. & EAN	Description Beschreibung
PC IP66/IP67 IK07/IK08	244x124x97	PCQ3 122410	7035781 6418074099075	Grey cover (quick-locking) grauer Deckel (QuickLock)
	244x124x97	PCTQ3 122410	7025780 6418074099082	Smoked transparent cover (quick-locking) rauchgrau transparenter Deckel (QuickLock)
ABS IP66/IP67 IK07	244x124x97	ABQ3 122410	7085781 6418074099068	Grey cover (quick-locking) grauer Deckel (QuickLock)
Accessories Zubehör	214x111	TM 1224	9512016 6418074034052	Mounting plate Montageplatte
	15x106	TRM 0812	9820009 6418074034151	DIN-15 Mounting rail Tragschiene TS 15
	15x225	MIN 20	6314578 6418074023308	DIN-15 Mounting rail Tragschiene TS 15
	35x110	TRH 1212	9822002 6418074034403	DIN-35 Mounting rail Tragschiene TS 35
	35x226	TRH 24	9822008 6418074034397	DIN-35 Mounting rail Tragschiene TS 35
		TF 28037	7028337 6418074033734	Wall fastening lug (4 pcs) incl. screws Befestigungsglasche 4 St. mit Schrauben
		TH A	9802001 6418074034120	Grey plastic hinges (2 pcs) incl. mounting screws Plastik-Scharniere, grau 2 Stück mit Schrauben
		EU 3 QuickLock set 60	7028244 6418074306340	QuickLock screws (60 pcs) QuickLock Deckelschrauben (60 St.)
		MR 28036EU Set 60	7028236 6418074306357	Mounting screws (60 pcs) Montageschrauben (60 St.)
		EU 3 Plug set 60/30	7038240 6418074305947	EU 3 Cover screw plug set 60/30 EU 3 Deko-Pfropfen set 60/30
		EU 3 Plug set 60/30 BL	7038242 6418074305831	EU 3 Cover screw plug set 60/30 black EU 3 Deko-Pfropfen set 60/30 schwarz

Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and quick-locking cover screws.
Besteht aus: Unterteil inkl. Montageschrauben, Deckel inkl. PUR Dichtung und Schnellverschluß-Deckelschrauben.