
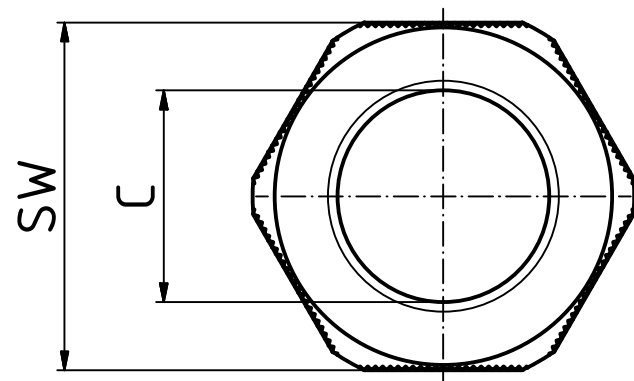
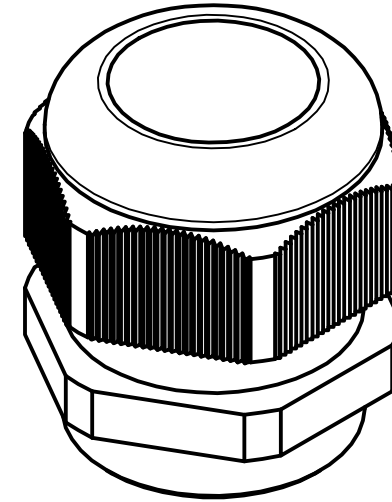


MBFO M 12 - M 32

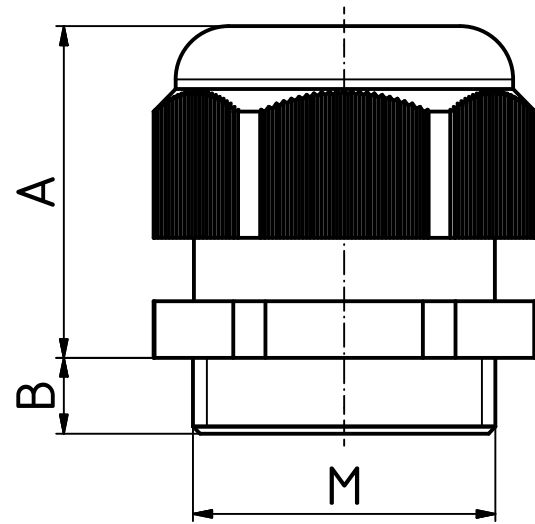

Modell	M	A	B	SW	C
MBFO 12	M 12 x 1,5	24	8	15	3 - 6,5 mm
MBFO 16 - 1	M 16 x 1,5	29	10	22	5 - 10 mm
MBFO 16 - 2	M 16 x 1,5	28	8	19	4 - 8 mm
MBFO 20	M 20 x 1,5	29	10	24	6 - 12 mm
MBFO 25	M 25 x 1,5	38	10	33	13 - 18 mm
MBFO 32	M 32 x 1,5	41	10	42	18 - 25 mm