


Übersicht

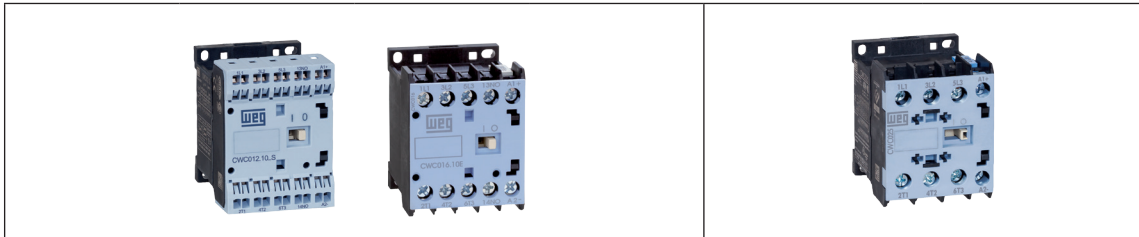

Typ	CWC07(S)	CWC09(S)	CWC012(S)	CWC016	CWC025
3-polig	+	+	+	+	+
4-polig	+	+	+	+	-
Federzug-klemmtechnik	+	+	+	-	-
Bemessungs-betriebsleistung					
400/415 V	3	4	5,5	7,5	11
440 V	3	4	5,5	7,5	11
500 V	3	4	5,5	7,5	11
690 V	3	5,5	7,5	7,5	11
Bemessungs-betriebsstrom I_e (AC-3) \leq 440 V	7	9	12	16	22
Konv. thermischer Strom $I_{th} = I_e, AC-1$	18	20	22	22	32
Bemessungs-betriebsstrom I_e (AC-4) \leq 440 V	2,8	3,5	4,5	5	9

Motorschutzrelais	A	RW17-1D		RW17-2D	
			0,28 ... 0,4 0,4 ... 0,63 0,56 ... 0,8 0,8 ... 1,2 1,2 ... 1,8 1,8 ... 2,8	2,8 ... 4,0 4,0 ... 6,3 5,6 ... 8,0 7,0 ... 10 8,0 ... 12,5 10,0 ... 15,0 11,0 ... 17,0	

Hilfsschalterblöcke	BFC0	BFC0...S	BFC025
	<ul style="list-style-type: none"> BFC0-20 (2S) BFC0-22 (2S/2Ö) BFC0-11 (1S/1Ö) BFC0-04 (4Ö) BFC0-02 (2Ö) BFC0-31 (3S/1Ö) BFC0-13 (1S/3Ö) 	<ul style="list-style-type: none"> BFC0-20S (2S) BFC0-22S (2S/2Ö) BFC0-11S (1S/1Ö) BFC0-04S (4Ö) BFC0-02S (2Ö) BFC0-31S (3S/1Ö) BFC0-13S (1S/3Ö) 	<ul style="list-style-type: none"> BFC025-11 (1S/1Ö) BFC025-20 (2S) BFC025-02 (2Ö) BFC025-22 (2S/2Ö)

Mechanische Verriegelung	BICO

Zeitrelaisblöcke	T
	<ul style="list-style-type: none"> TECO - anzugsverzögert TDCO - abfallverzögert TETCO - Stern-Dreieck

Löschglieder	RC-Löschglieder:	Varistor-Löschglieder:	Dioden-Löschglieder:
	<ul style="list-style-type: none"> RCCO-1 D49 12-24 V 50/60 Hz RCCO-2 D53 24-48 V 50/60 Hz RCCO-3 D55 48-127 V 50/60 Hz RCCO-4 D63 127-250 V 50/60 Hz RCCO-5 D84 250-380 V 50/60 Hz RCCO-6 D73 400-510 V 50/60 Hz RCACO D87 180-230 V 50/60 Hz 	<ul style="list-style-type: none"> VRCO-1 E49 12-48 V AC/12-60 V DC VRCO-2 E34 50-127 V AC/60-180 V DC VRCO-3 E50 130-275 V AC/180-300 V DC VRCO-4 E41 277-380 V AC/300-510 V DC VRCO-5 D73 400-510 V 50/60 Hz 	<ul style="list-style-type: none"> DICO-1 C33 12-600 V DC DIZCO C26 12-250 V DC