


Rev	Modify	Date	Firma	Approved

Rev	Modify	Date	Firma	Approved

Rev	Modify	Date	Signed	Approved

CUSTOMER APPROVAL	
SIGNATURE	DATE
PLEASE SIGN AND RETURN	

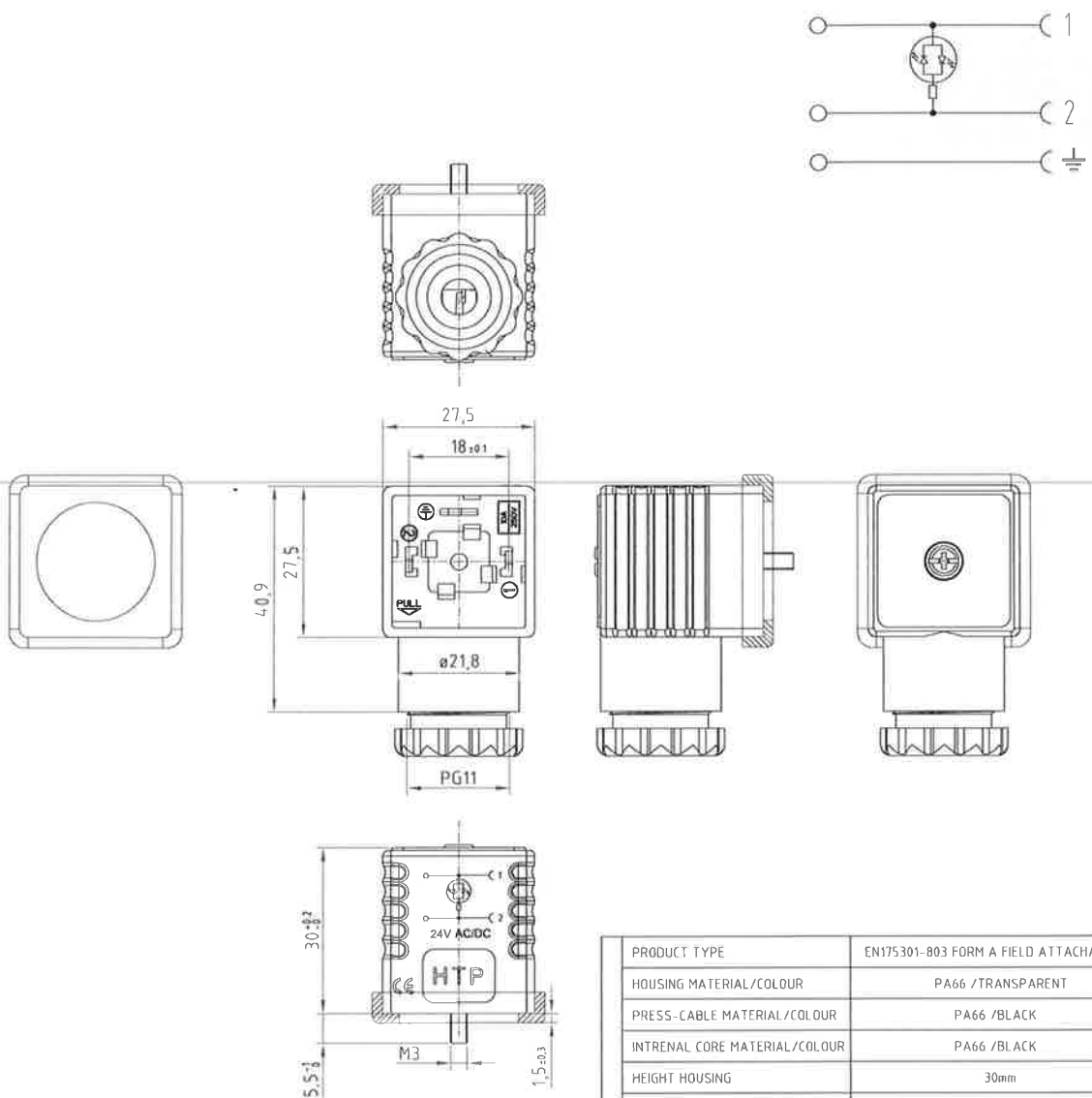

PRODUCT TYPE	EN175301-803 FORM A FIELD ATTACHABLE
HOUSING MATERIAL/COLOUR	PA66 /TRANSPARENT
PRESS-CABLE MATERIAL/COLOUR	PA66 /BLACK
INTRINAL CORE MATERIAL/COLOUR	PA66 /BLACK
HEIGHT HOUSING	30mm
CONTACTS SPACING	18mm
CONTACTS TYPE	SCREW CONTACTS(with protection plate)
NUMBER OF POLES	2POLES+EARTH
EARTH POSITIONING	H 12 (TURNABLE)
CABLE EXIT	PG9/11 UNIFIED
SUITABLE CABLE	FROM ø6mm TO ø10mm
MAX CONDUCTOR SIZE	1,5mm <sup>2</sup>
PROTECTION CLASS	IP67
CIRCUIT TYPE	BIPOLAR RED LED
RATED VOLTAGE	24V AC/DC
CONNECTOR TEMPERATURE RANGE	from -40°C to +90°C
GASKET TYPE	PROFILED NBR
FIXING SCREW	M3X0,5 L=32,5mm
CONNECTOR WITH H.T.P. LOGO	

Designer	SUGLIANI R	Date	2016-05-30	Tolerance	+0,2	Units	mm	Series	EN175301-803 (form A)	Drawing n	1/1
Approved	CIMMINO L	Date	2016-05-30	Scale	1:1	Size	A4	Customer code			

**DESCRIPTION**  
 SQUARE CONNECTOR EN175301-803 FORM A, FIELD ATTACHABLE, 2P +PE,  
 WITH BIPOLAR RED LED, 24V AC/DC, TRANSPARENT HOUSING,  
 PG9/11 unified, CONNECTOR WITH H.T.P. LOGO

H.T.P. PART NUMBER  
 G1TU2L01