

Data sheet

LED-Dimmer for external actuation Type 8122

Leading edge dimmer with
Soft-Start and Memory-function

230 V ~ (+/- 10 %), 50 Hz,

4-160 W/VA (LED 3-55 W),


external push-button with low voltage fail-safe



suitable for:

- **dimmable LED lamps**
- **high voltage halogen lamps**
- **incandescent lamps**

function:	on/off/dim by external push-button
Temperature protection:	thermal protection
Overload-/	
short-circuit protection:	Electronic
max. cord diameter:	8 mm
cut-off:	electronic & &
cycle of operation:	> 50.000
connection:	screw terminals 0,5 - 1,5 mm ² (flexible)
mode of operation:	S1
protection class:	2
safety class:	IP 20
contamination level:	1
push-button activation:	safety extra-low voltage

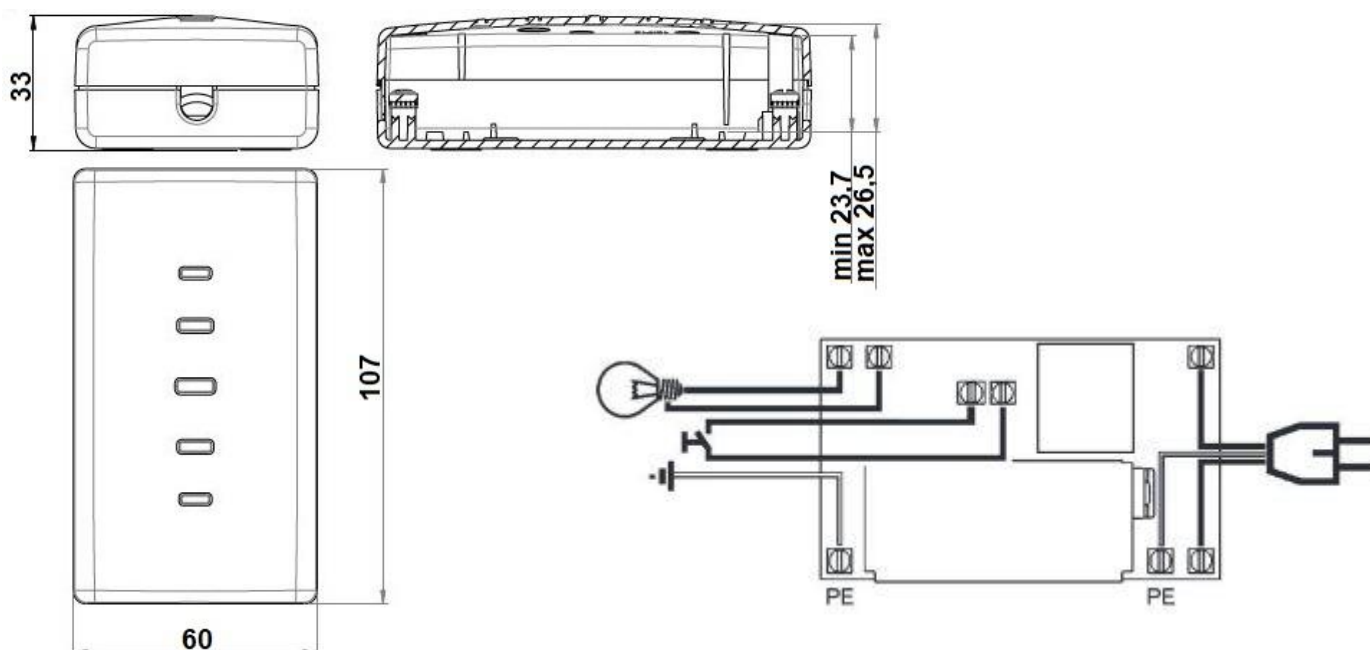

inter BÄR-No.	colour	version
8122-004...	black	without cable

Technical modifications reserved!!!

Works at 230V-mains must only be carried out by a specialist!!!